

MAXIMUM HORSEPOWER RATINGS FOR 3 PHASE MOTORS

VOLTAGE (V)	200V	230V	460V	575V
HORSEPOWER	250	300	600	800
MAXIMUM CURRENT	INDUCTIVE (AC3) --- 630A			
	RESISTIVE (AC1) --- 1000A			
AUXILIARY CONTACTS BUILT-IN	NO --- 1*			
	NC --- 0			

*THIS ONE NORMALLY OPEN HOLDING CIRCUIT CONTACT IS INCORPORATED IN THE DESIGN OF THE COIL.

COIL VOLTAGE CODE

VOLTS	50/60 HZ AC COIL CODE (1)	DC COIL CODE (1)
24	-	-
48	E7	ED
110	F7	FD
120	F7	-
125	-	GD
208	L7	-
220	M7	MD
240	U7	-
250	-	UD
380	Q7	-
415	N7	-
440	-	RD
480	N7	-
600	X7**	-

(1) = SELECT DESIRED SUFFIX FOR COMPLETE CATALOG NUMBER

**600 VOLT COIL NOT AVAILABLE FOR F780

Catalog Number: LC1 F630(1)

Ratings: SEE CHART

UL File/Guide: -

CSA File/Guide: -

Meets Standards: IEC 158-1, 947-4, NFC 63-110, VDE 0660, BS 5424, JEM 1038


Weight: -

Wire Size: LUG KIT (D22 FL6) - 3 X 600MCM

Terminal torque: -

Mounting Hwd.: -

Minimum to wall or barrier to insure adequate wire bending space to lug surface when the maximum wire size is used with standard lugs. REF NEC 430-10

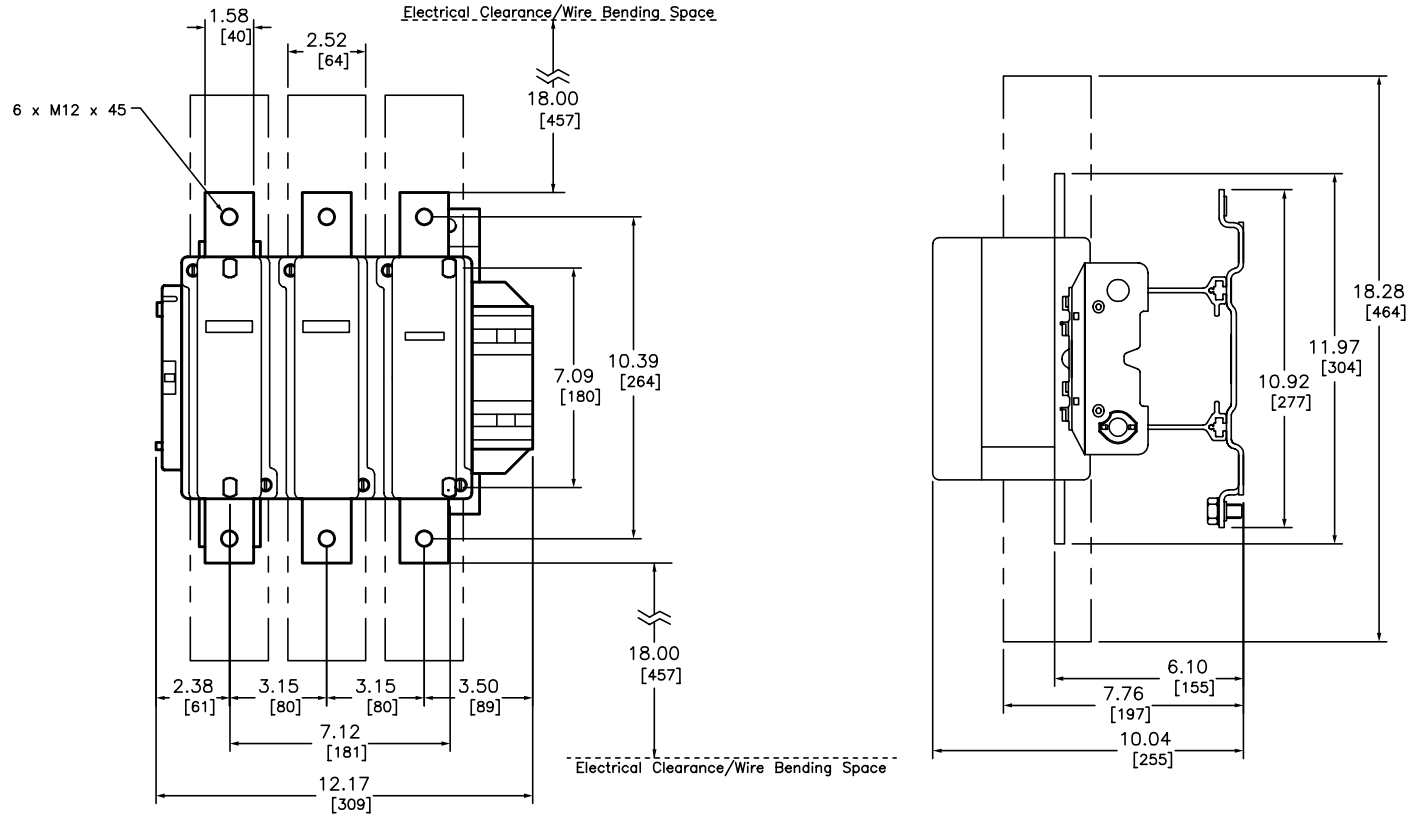

IEC 3-POLE NON-REVERSING CONTACTOR
AC OR DC (F-LINE)
LC1 F630 (1)



DWG# E0220701-01
NO.