
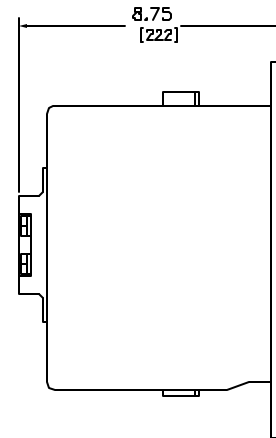


NEMA SIZE 4 CONTACTOR
3-POLE POLYPHASE - 600 VAC, 50-60 HZ

COIL VOLTAGE CODE (1)	VOLTAGE	
	60 HZ	50 HZ
V02	120	110
V08	208	-
V03	240	220
V06	480	440
V07	600	550
V99	SPECIFY	SPECIFY

ELECTRICAL CLEARANCE/WIRE BENDING SPACE

MINIMUM TO WALL OR BARRIER TO INSURE ADEQUATE
WIRE BENDING SPACE TO LUG SURFACE WHEN
MINIMUM TO WALL OR BARRIER TO INSURE ADEQUATE

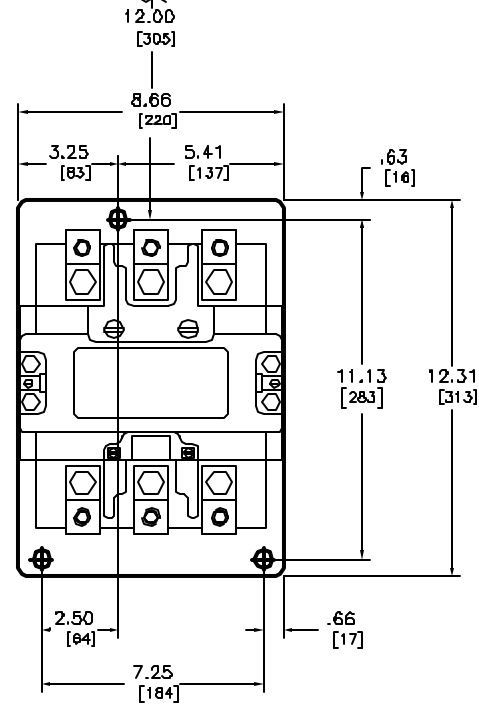

Catalog Number: B502-SG02(1)
 Ratings: SEE CHART
 UL File/CCN: E78351/NLX
 CSA File/Class: LR80905/3211 0
 Meets Standards: -
 Weight: 45.80 lbs
 Wire Size: POWER - #4-500MCM | CONTROL - #16-#12
 Terminal torque: 375 LB-IN
 Mounting Hwd.: (3) 1/2" screws

DUAL DIMENSIONS: INCHES
MILLIMETERS

NEMA SIZE 5 CONTACTOR
CLASS B502 TYPE SG02(1)



DWG# E0300701-01
NO.