







Altivar

VW3 A9 503 ... 505

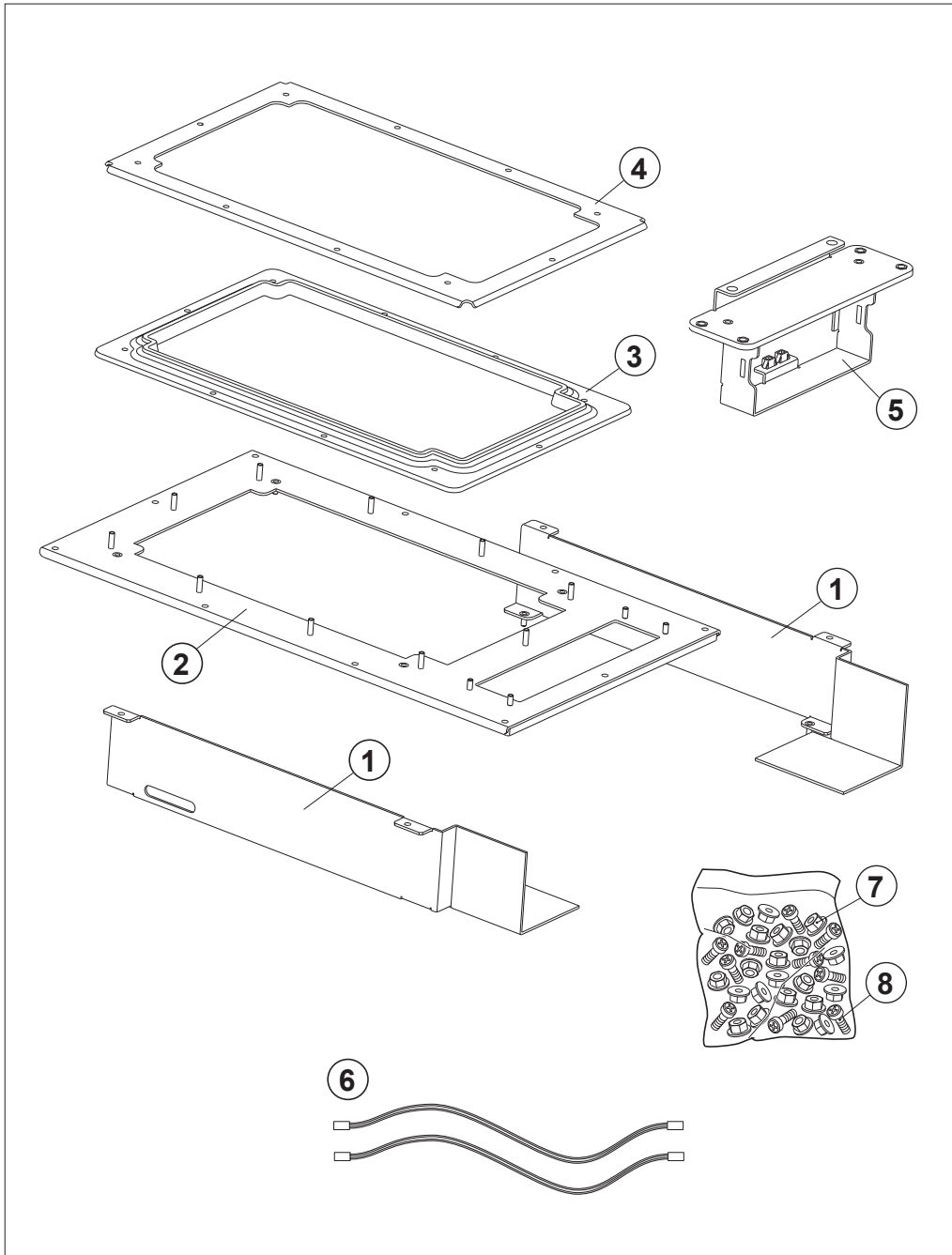


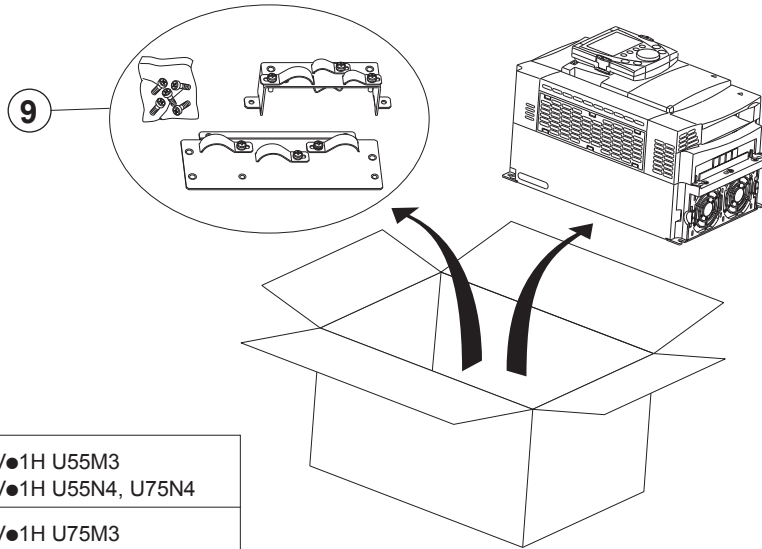


VW3A9503	ATV●1H U55M3 ATV●1H U55N4, U75N4
VW3A9504	ATV●1H U75M3 ATV●1H D11N4
VW3A9505	ATV●1H D11M3X, D15M3X ATV●1H D15N4, D18N4

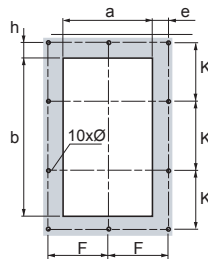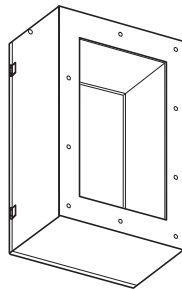


	a		b		F		K		h		e		Ø	
	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.
VW3 A9 503	215	8.46	419	16.50	125	4.92	149,5	5.89	14,5	0.57	17,5	0.69	3,6	0.14
VW3 A9 504	250	9.84	438	17.24	142,5	5.61	155	6.10	13	0.51	17,5	0.69	3,6	0.14
VW3 A9 505	270	10.63	537,5	21.16	152,5	6.00	189,5	7.46	15,5	0.61	17,5	0.69	3,6	0.14

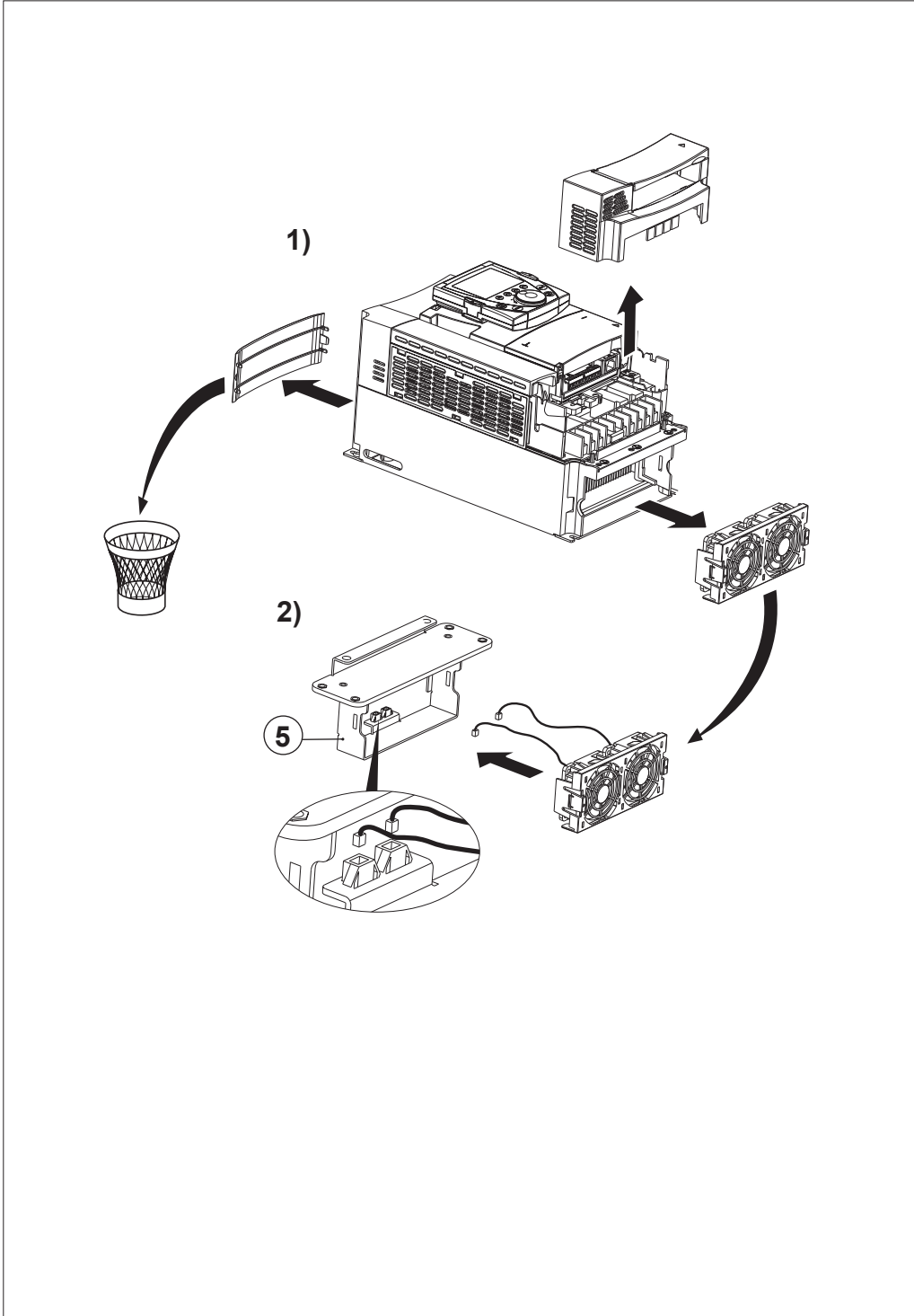


3)

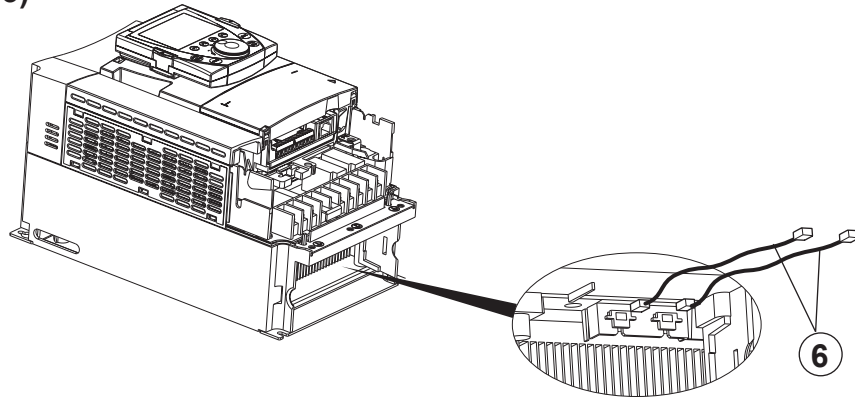


4)

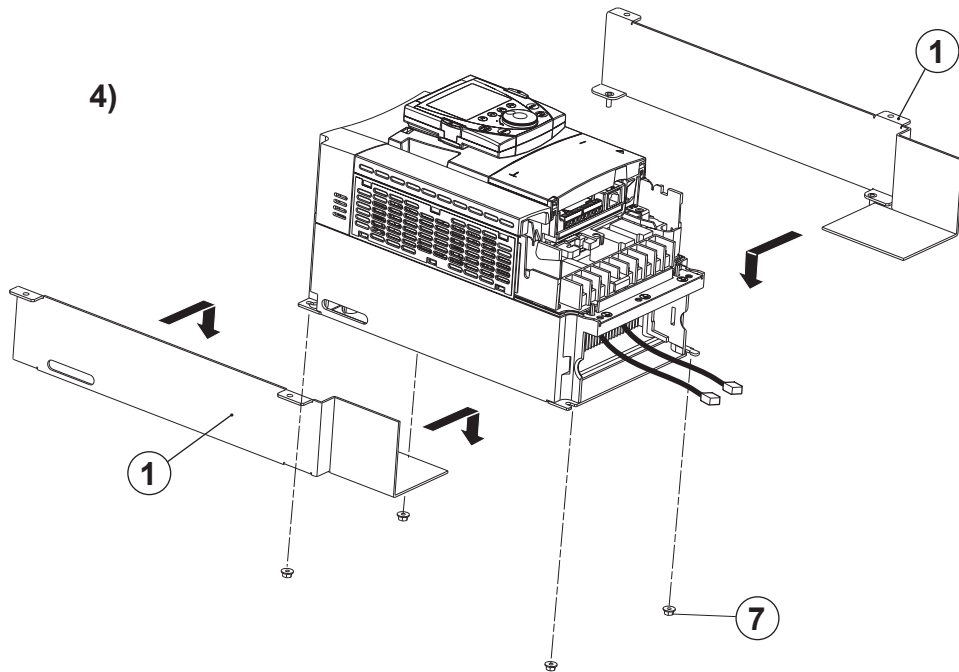


5)

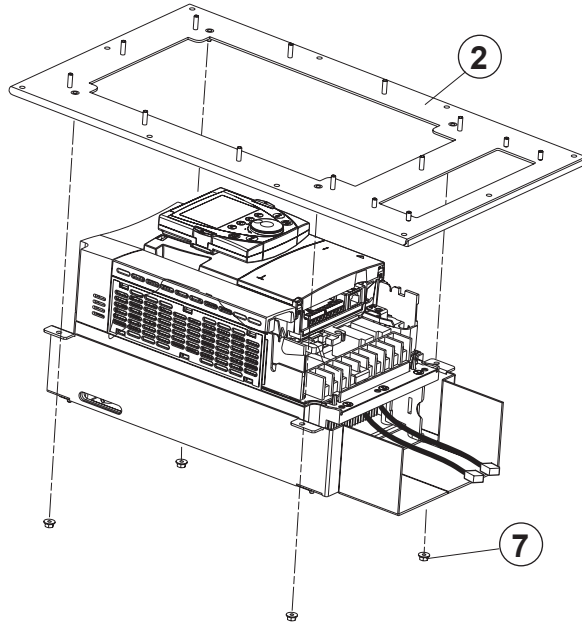


6)

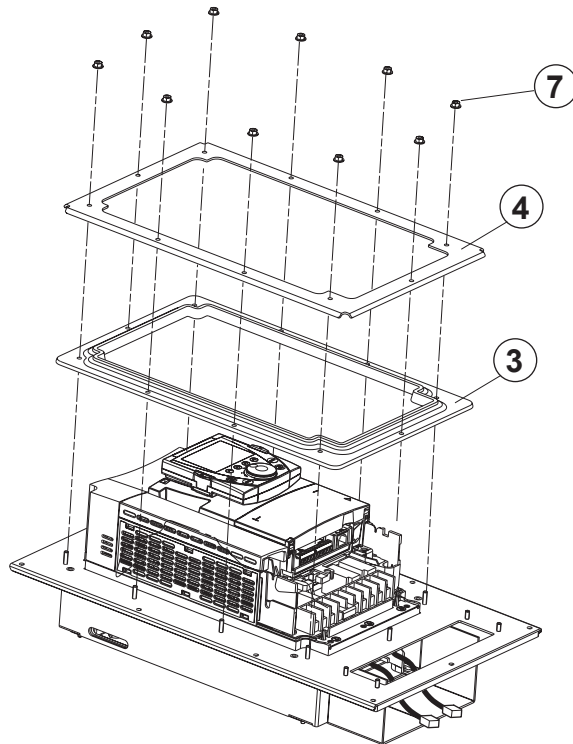

7)

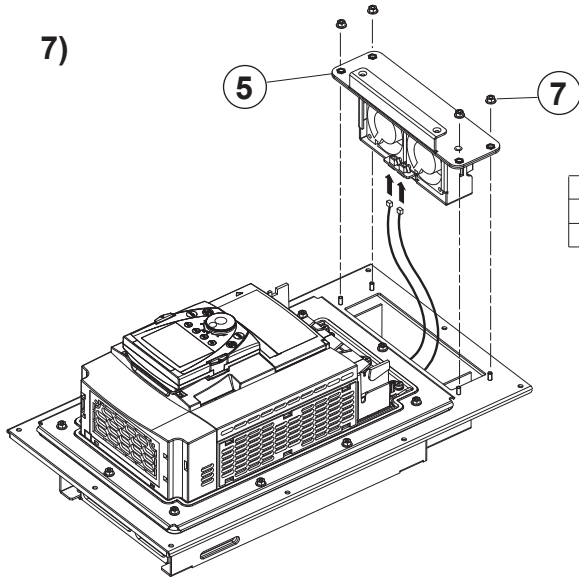

	A	B
VW3 A9 503	96 (3.76)	70 (2.76)
VW3 A9 504	99 (3.88)	90 (3.54)
VW3 A9 505	96 (3.76)	90 (3.54)

 

8)

