 

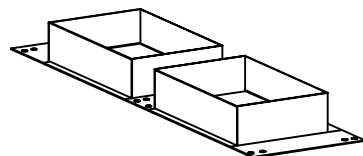
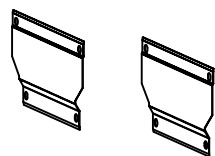





Ident.:	Material	Quantity
	A M8 x 20 hexagon screw, spring lock washer, plain washer	8
	B M10 x 30 hexagon screw, plain washer	16
	C M6 x 20 hexagon comby screw	16
	D M6 flat head screw SAREL type cross recessed	—
	E M10 nut, plain washer	2
	F M6 comby nut	26
	G M8 x 12 Threaded Plug H5	4
	H Plug 27 x 24 x 11	4
	I M8 x 20 Countersunk Flat Head hexalobular recessed screw	—
	J M6 x 16 pan head screw cross recessed thru slot	8
	P M16 crane eye, plain washer	2
	Q M8 nut, plain washer	4

Ident.:	Material	Quantity
	K M8 comby nut (screwed to the drive when delivered)	4
	L M6 x 12 phillips slotted comby screw (screwed to the drive when delivered)	13
	M M6 comby nut (screwed to the drive when delivered)	22
	N M6 x 16 comby screw hexalobular recessed (screwed to the DC box when delivered)	—
	O M12 crane eye, plain washer (screwed to the enclosure when delivered)	4


	type 1 ● M5 / T25 2.7 Nm 23.9 lb-in		type 2 ● M6 / T30 4.5 Nm 39.82 lb-in		type 3 ● M8 / T40 4.5 Nm 39.82 lb-in		type 4 ● M12 / EXAG8 10 Nm 88.50 lb-in		type 5 ● M6 / T30 4.5 Nm 39.82 lb-in
	type 6 M6		type 7 M6		type 8 M8		type 9 M6		type 10 M8
	type 11 M8 4.5 Nm 39.82 lb-in		type 12 M 8		type 13 M8 4.5 Nm 39.825 lb-in		type 14 M12 10 Nm 88.50 lb-in		type 15 diam. 6
	type 16 diam. 13		type 17 diam. 13 / PA 6.6						

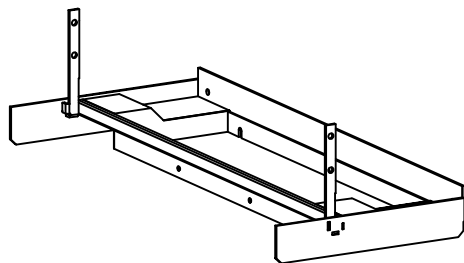



Ident.:	Material	Reference
1	drive support	ENNA06009
2	hard paper for rails	ENNA06019
3	EMC connection	ENNA06180
4	upper air duct	ENNA06202

 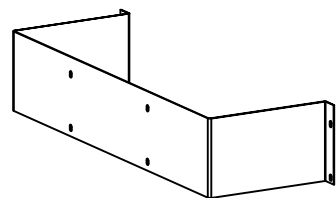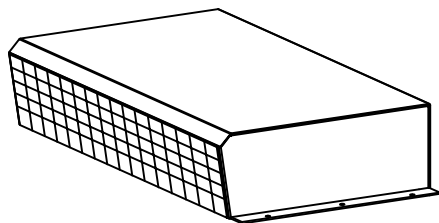

Ident.:	Material	Reference
5	roof extension	ENNA06216
6	sealing tape 20x3	ENNA06036
7	sealing tape 15x8	ENNA06035
8	connection lower airduct	ENNA06173






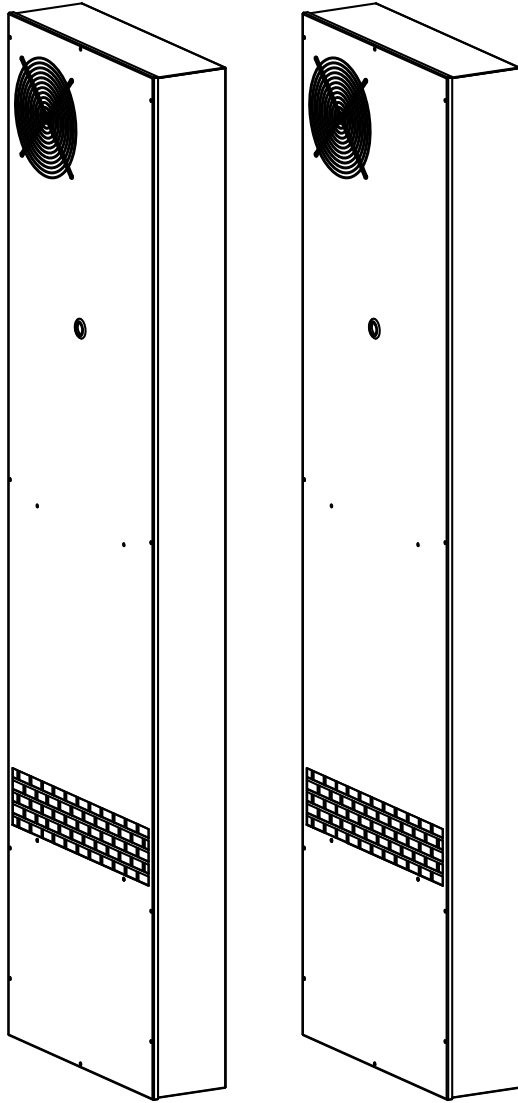


Ident.:	Material	Reference
9	air/air heat exchanger fan type R2E250-AS47-09	ENNA06044

 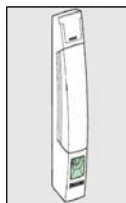


Ident.:	Material	Reference
10	door mounting kit	VW3 A1 102 VW3 A1 103 VW3 A1 104 R30
11	handle bar (U.E.)	NSYSSFHS1
12	sheet bag (U.E.)	NSYDPA44
13	Schneider logo	ENNA 10146

 

Enclosure : Universal Enclosure SF
cubicle frame size 2000x1000x600

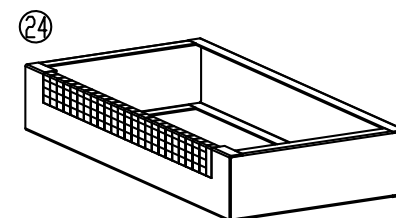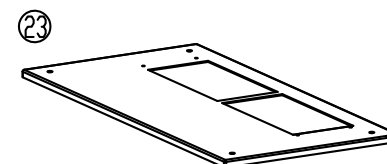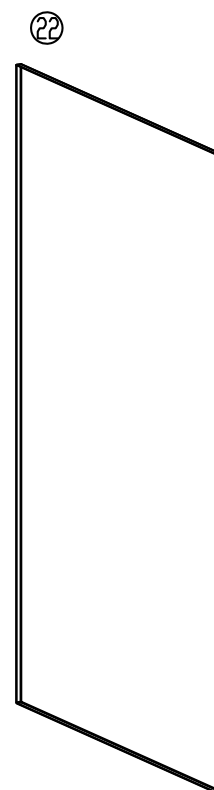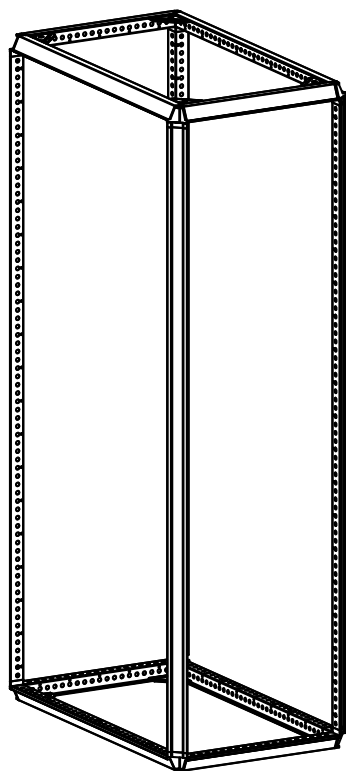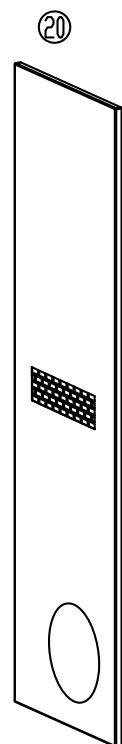



1


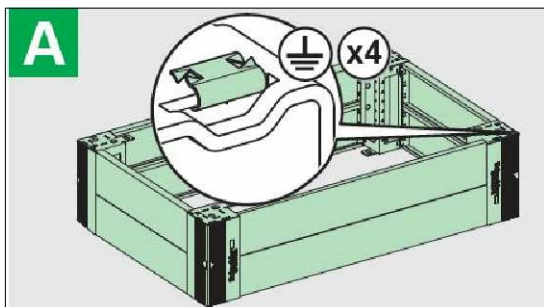


3

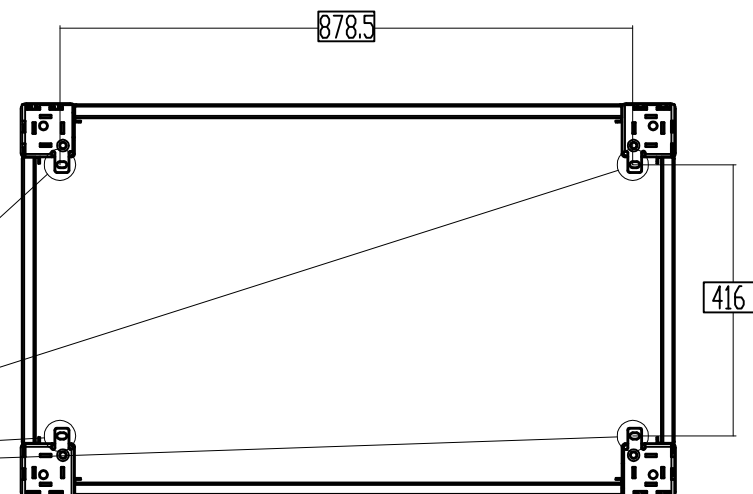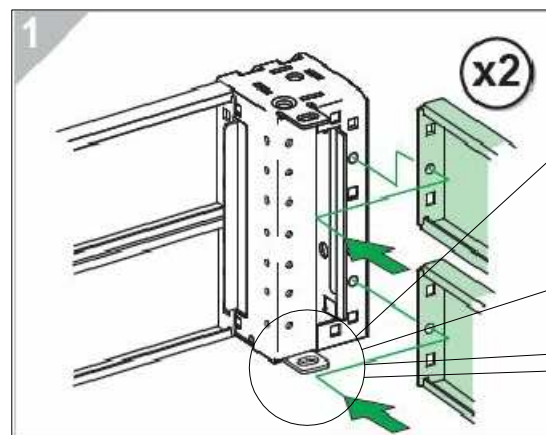



2

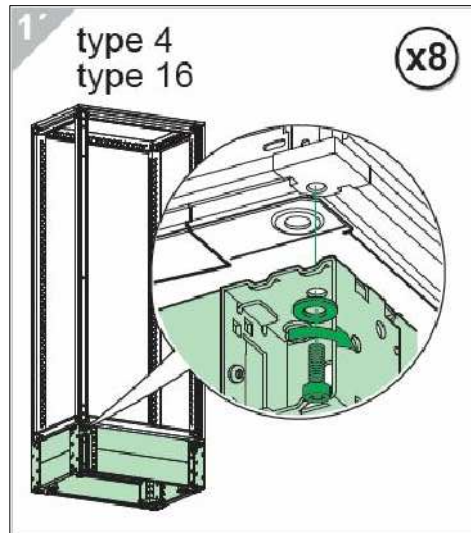
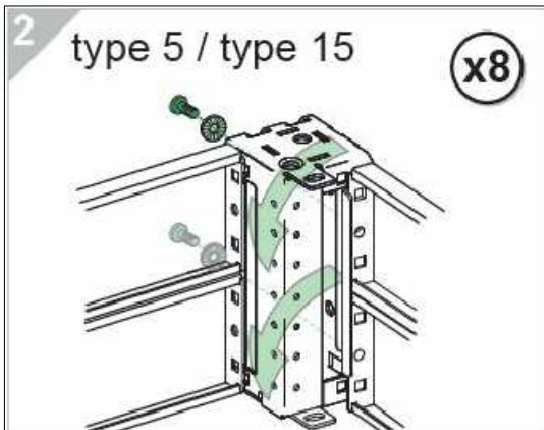


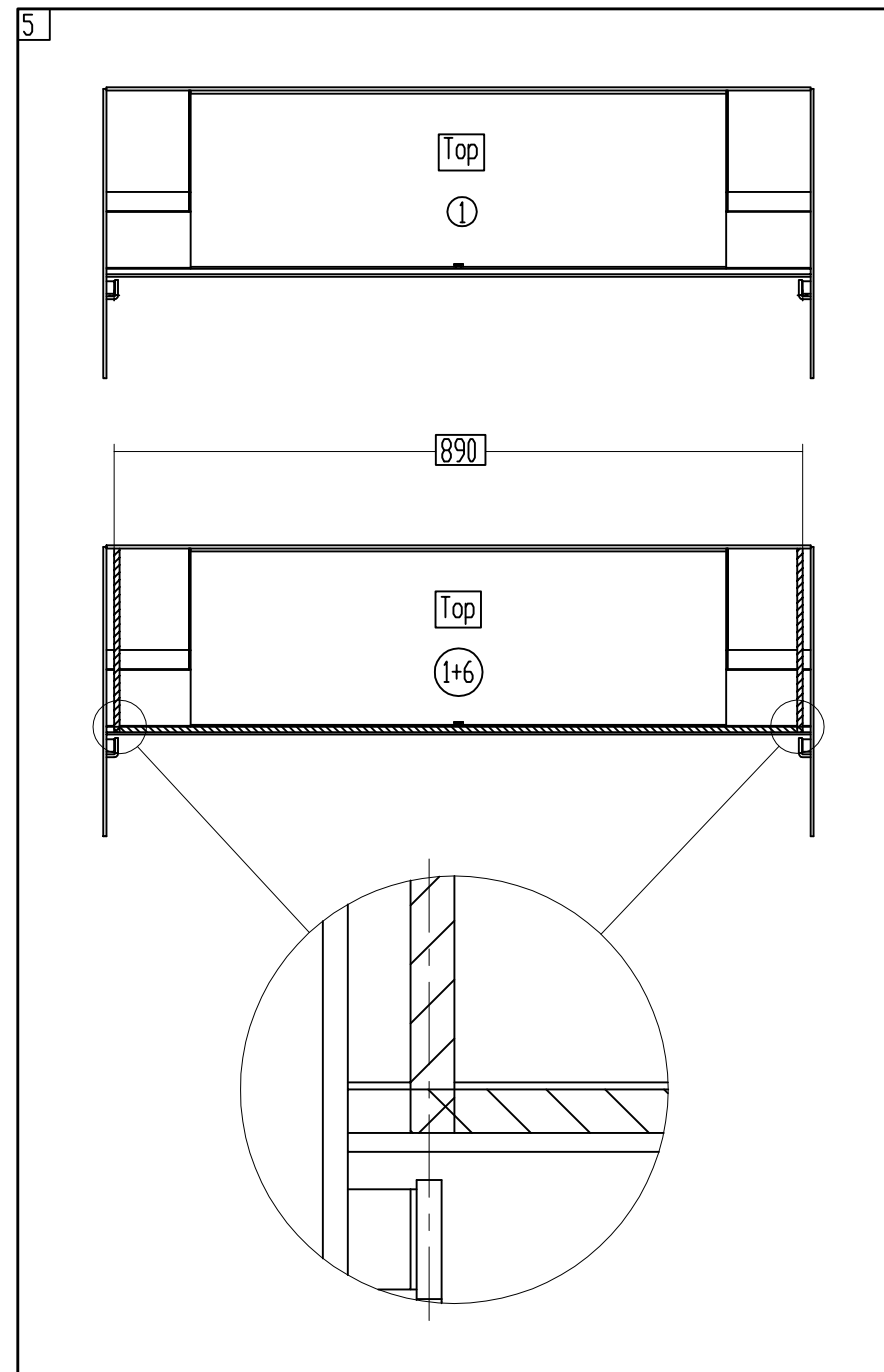
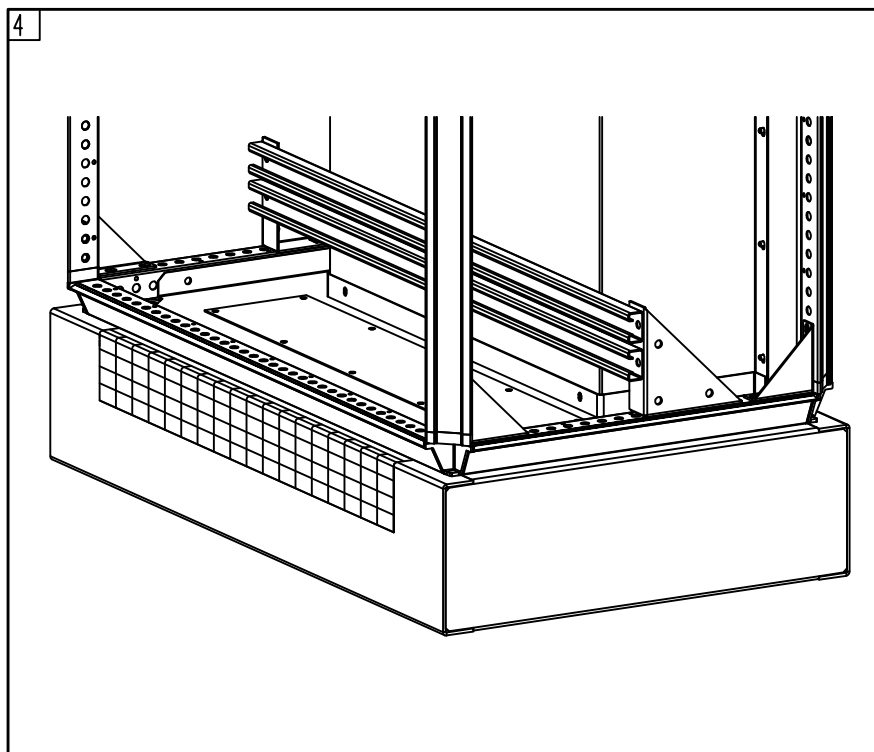


6

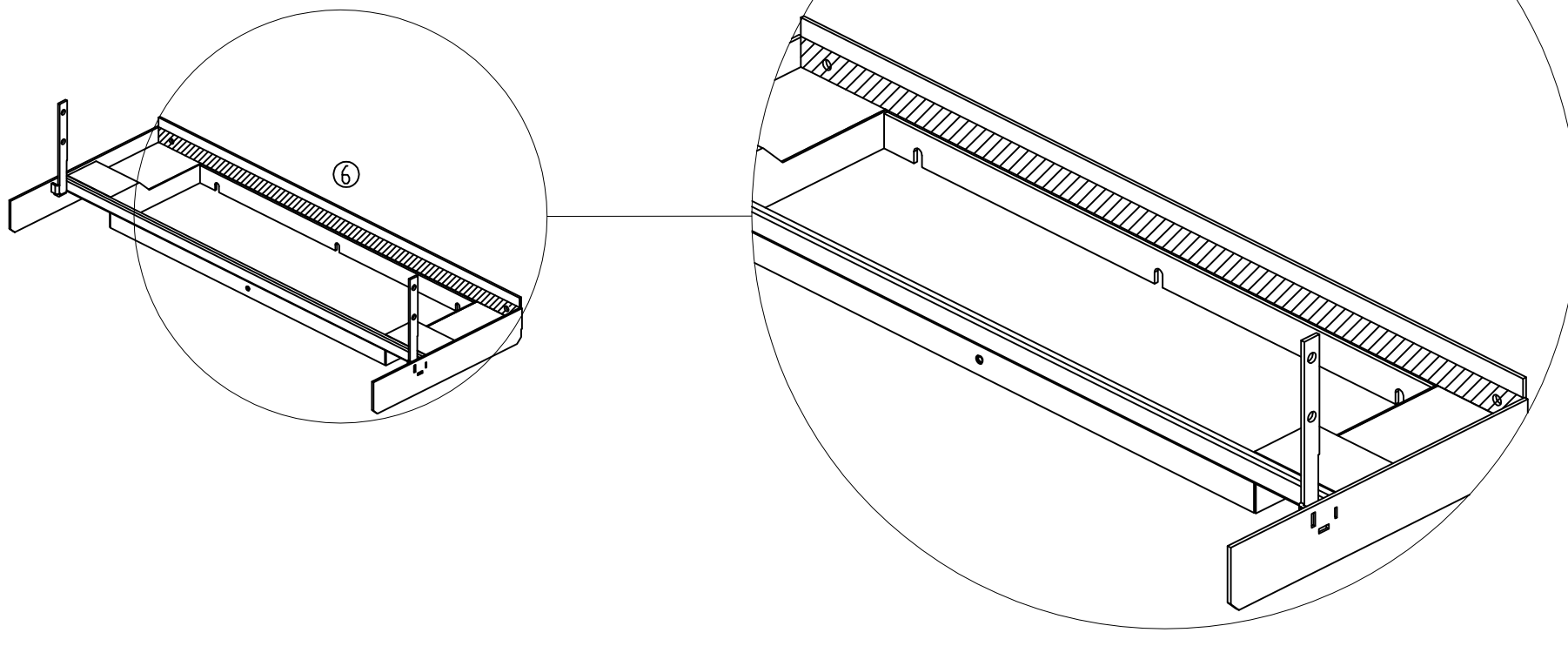


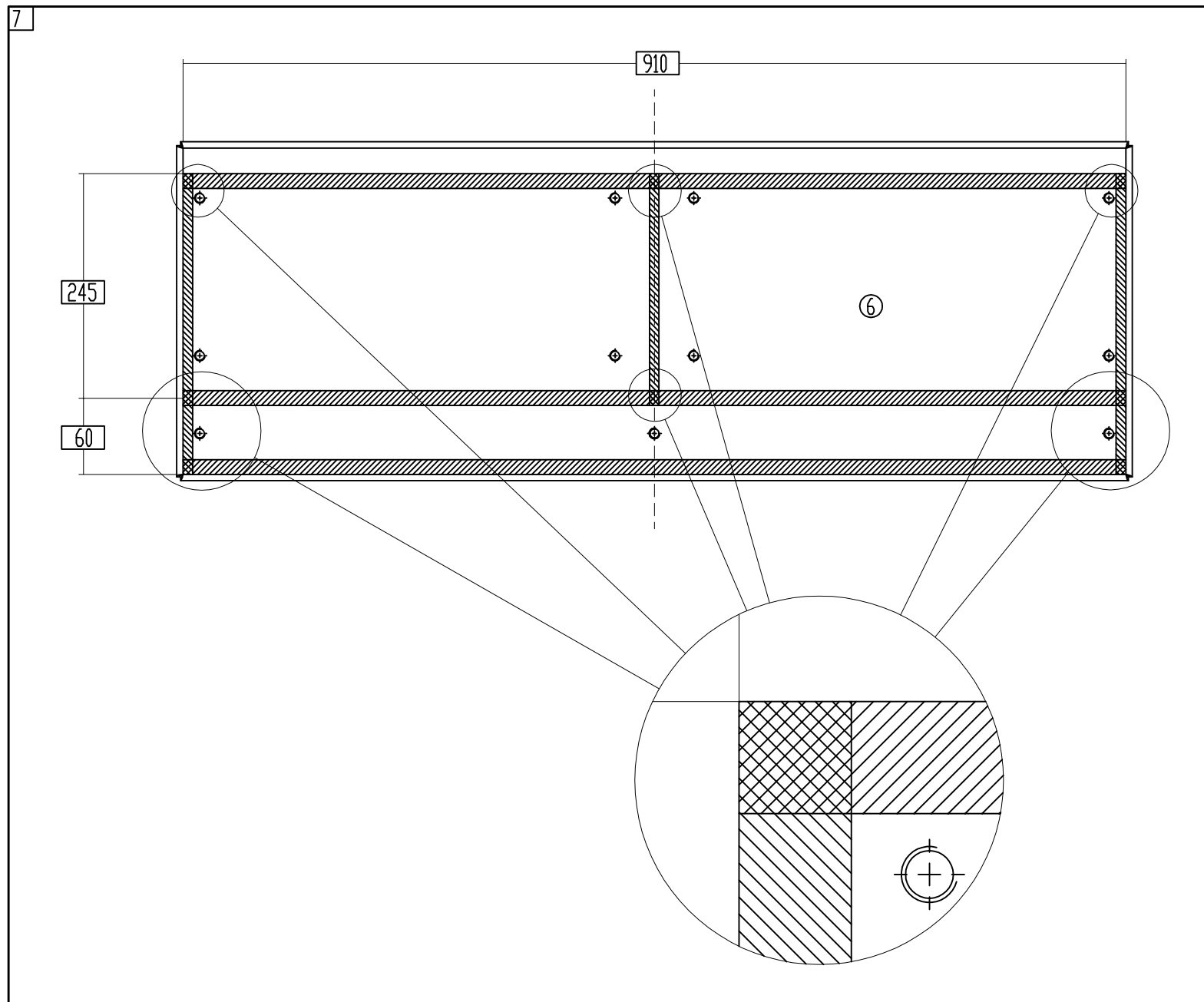

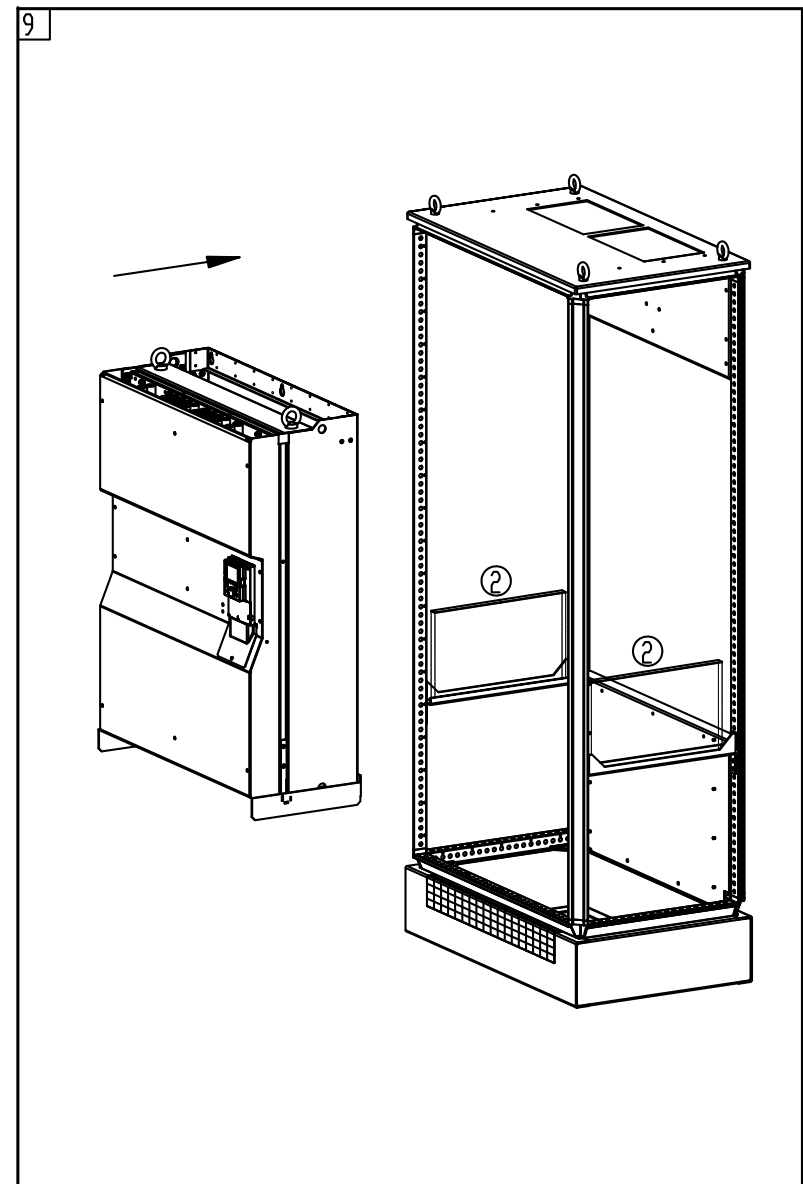
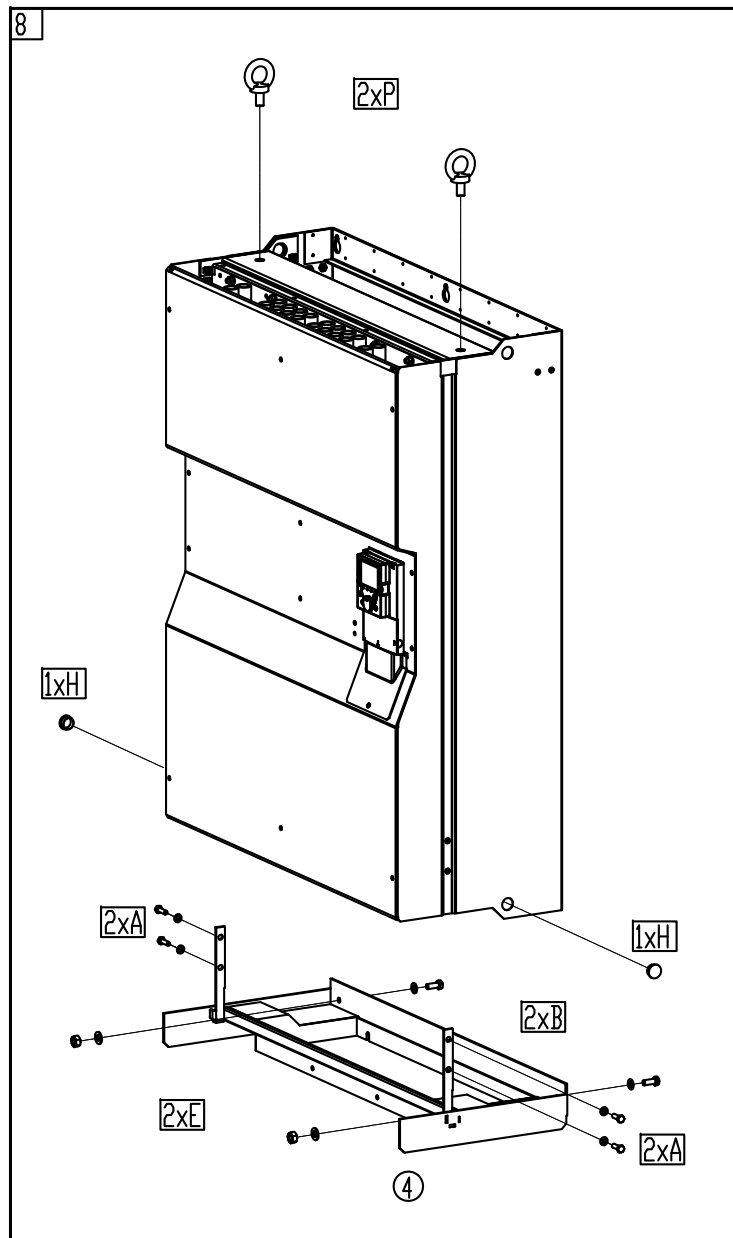


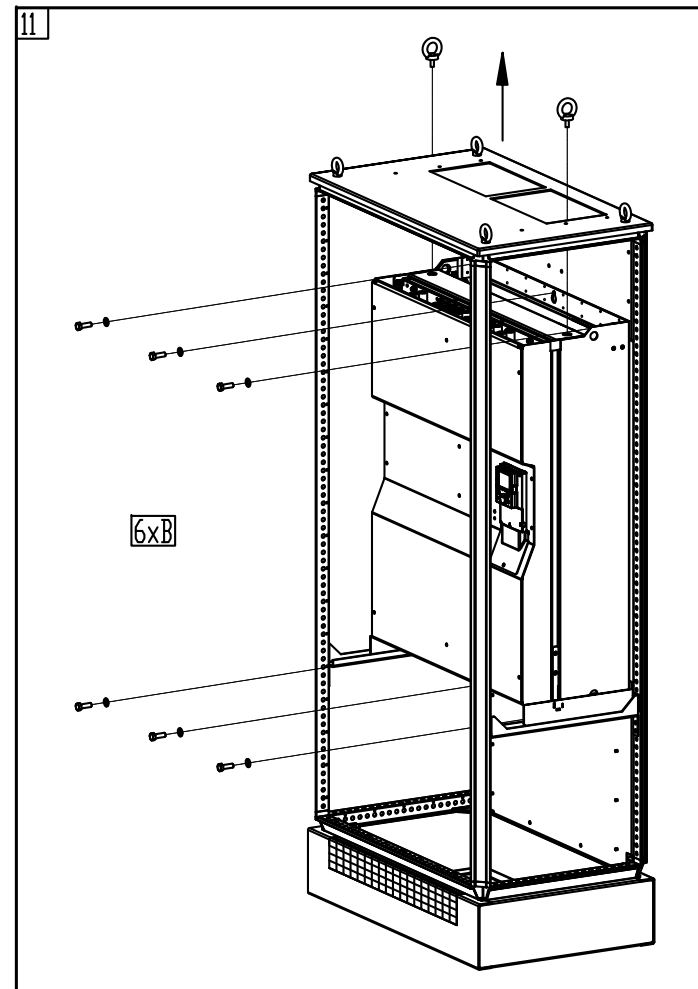
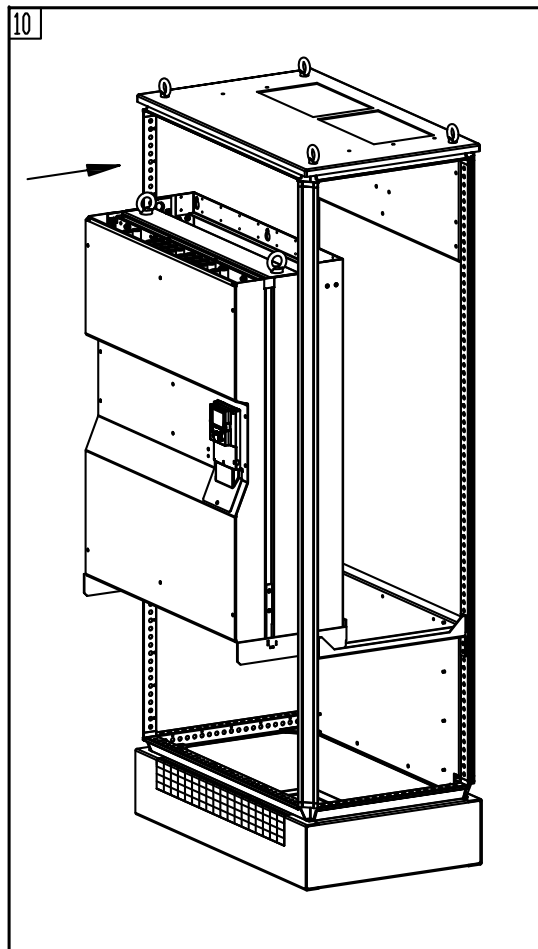


12

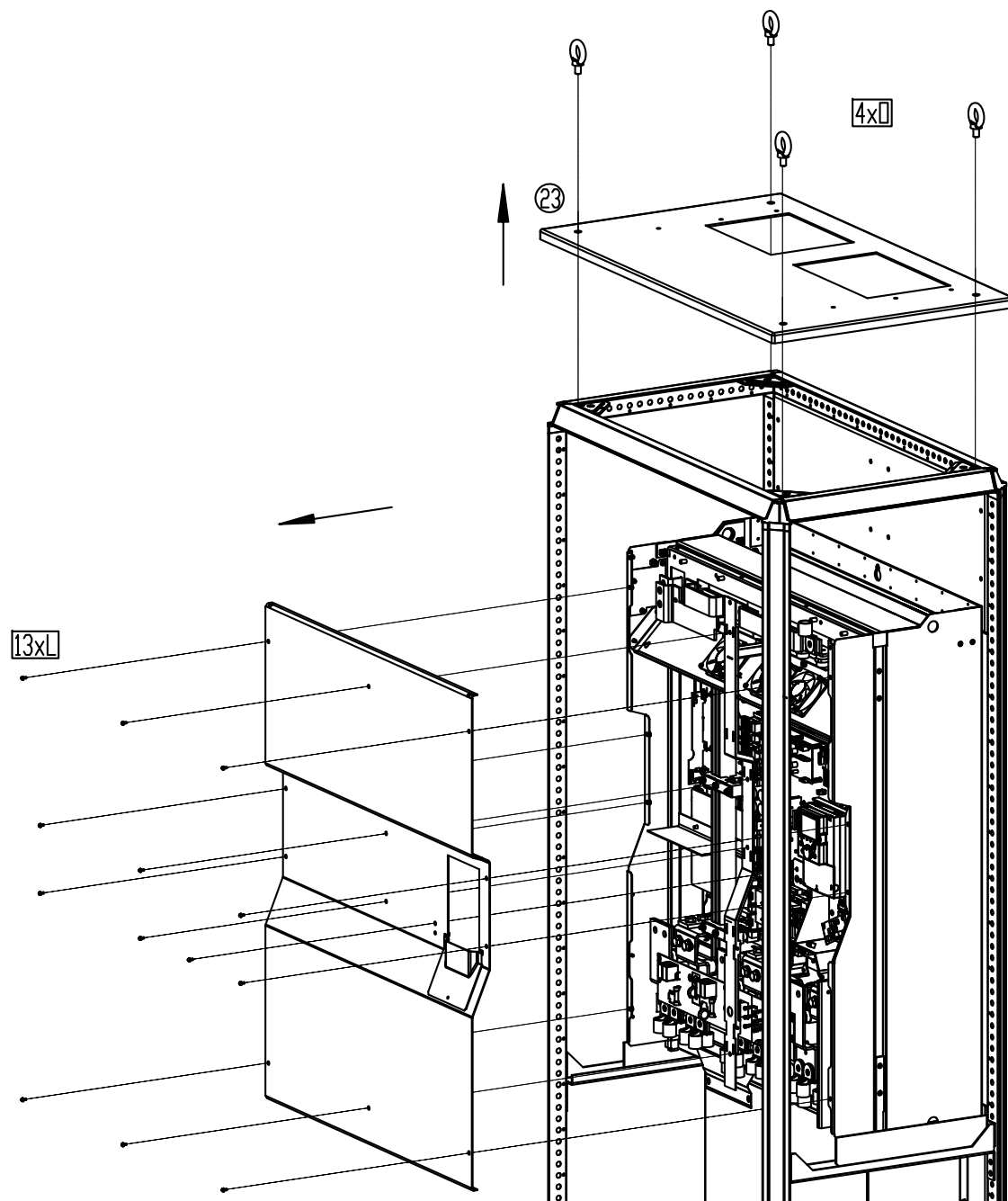


13

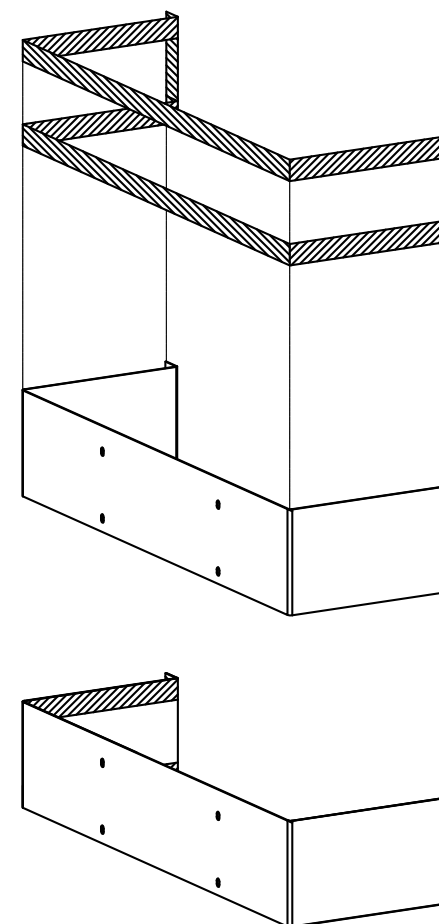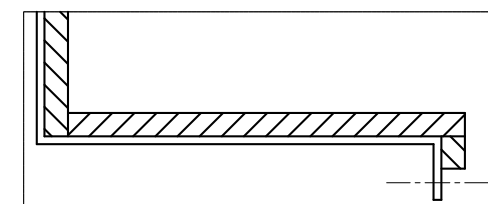


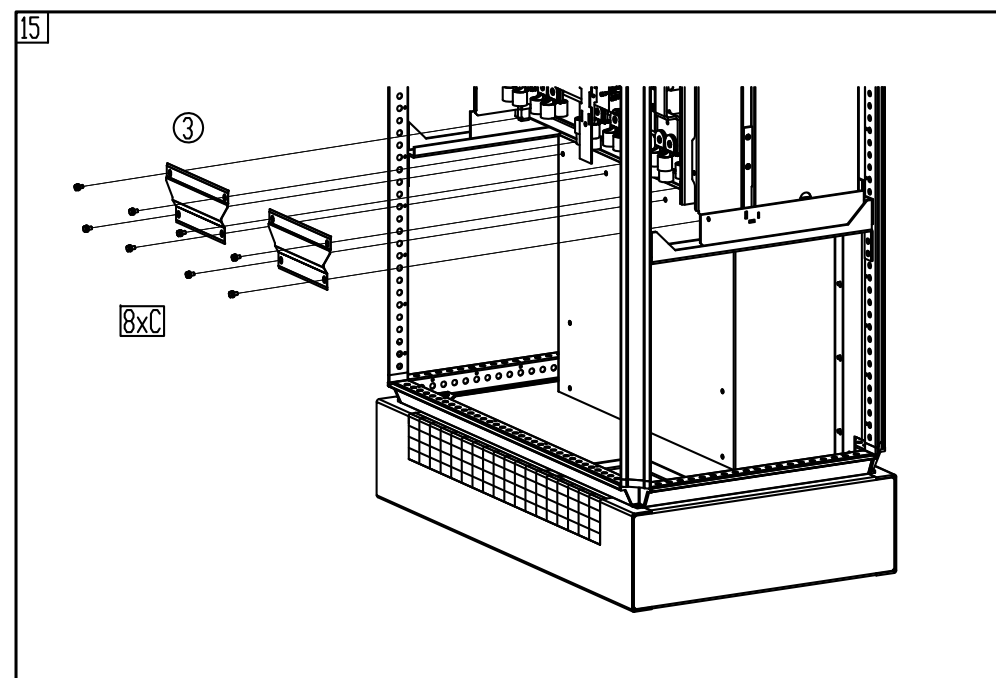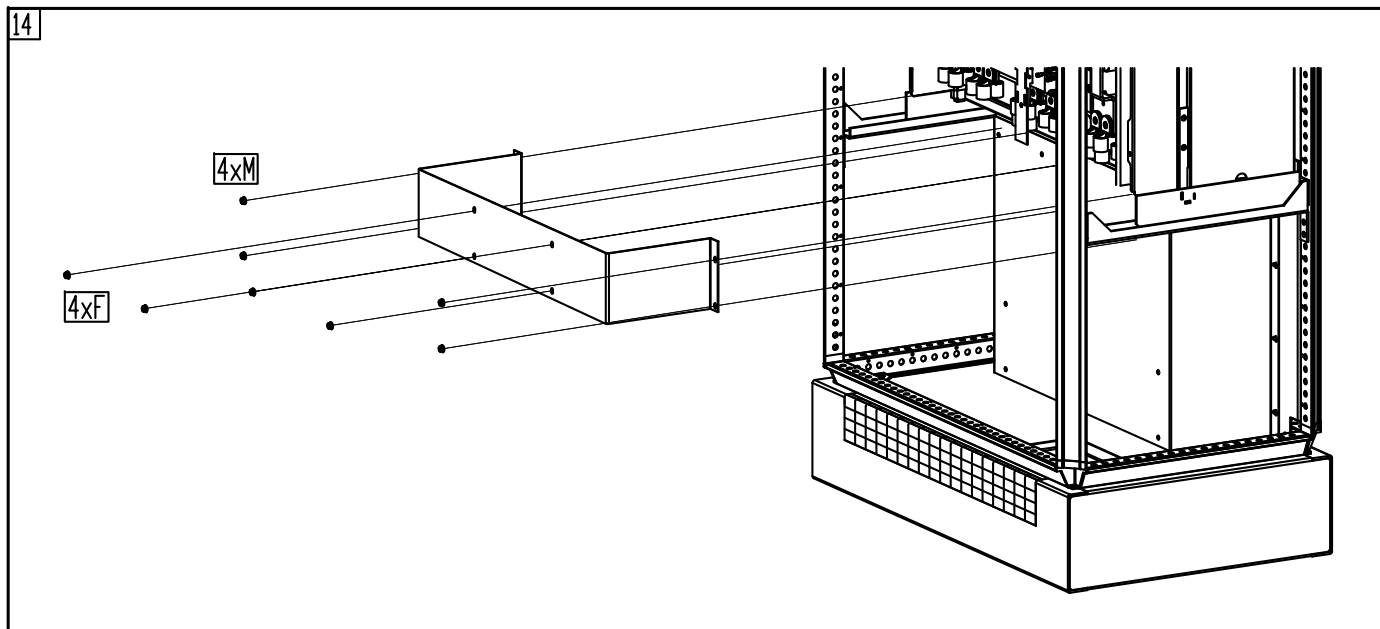


16




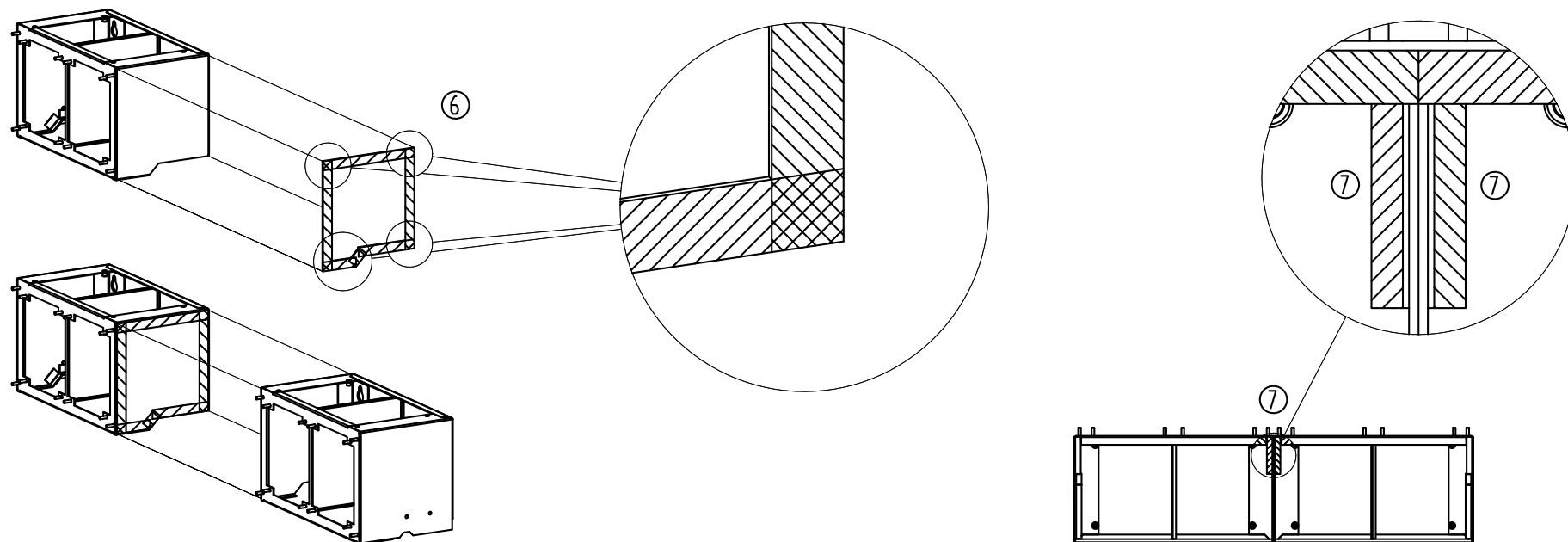


17

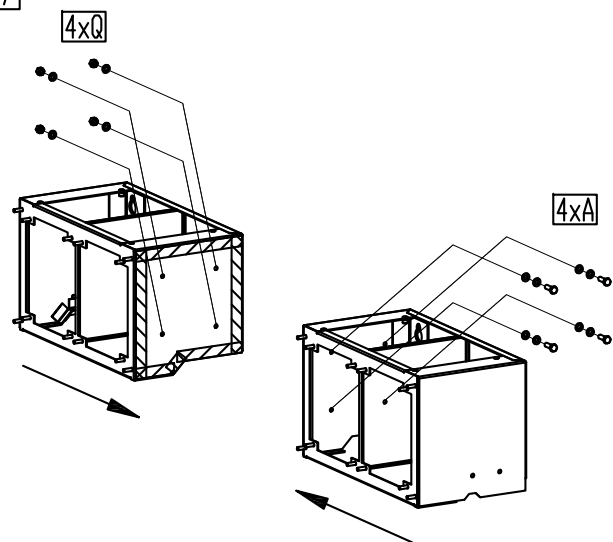


18

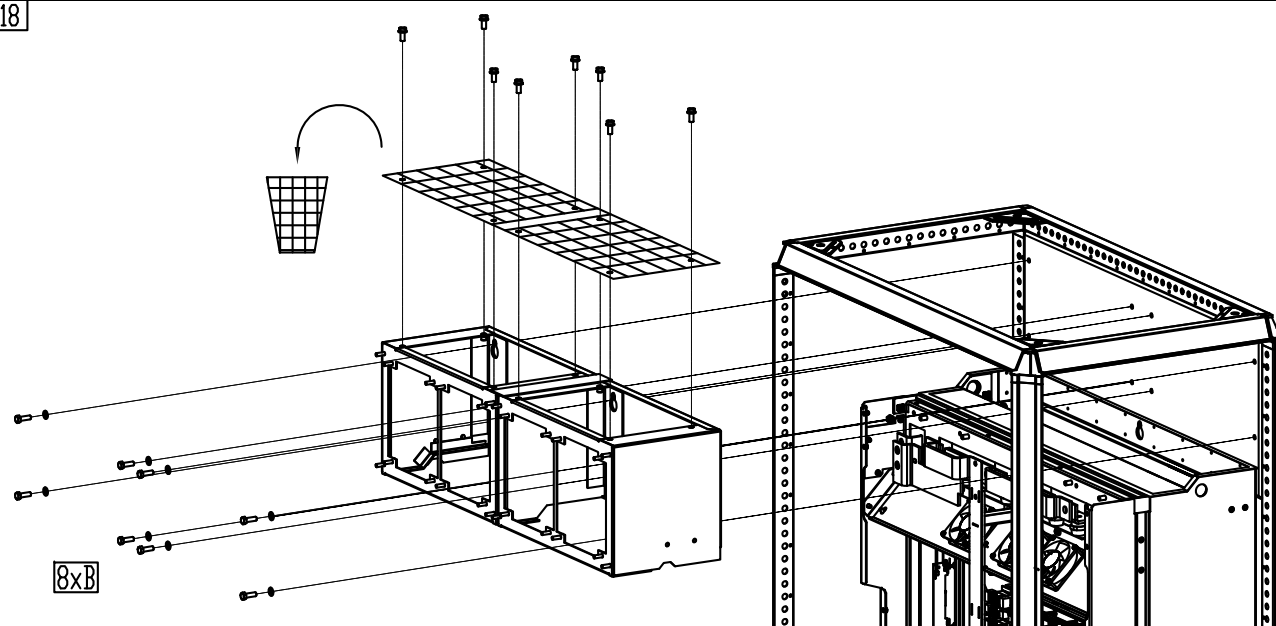


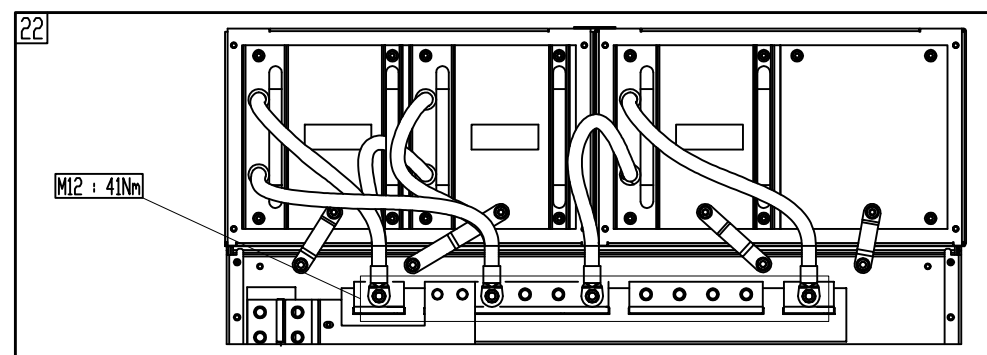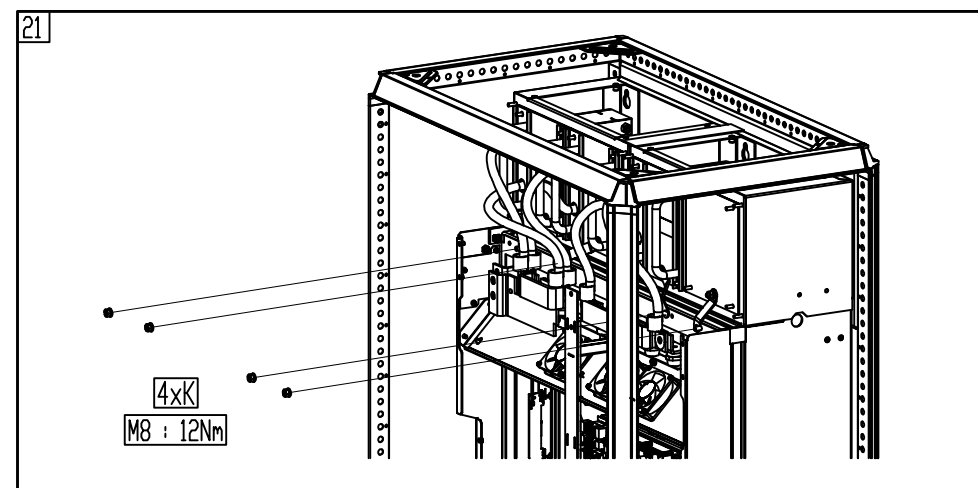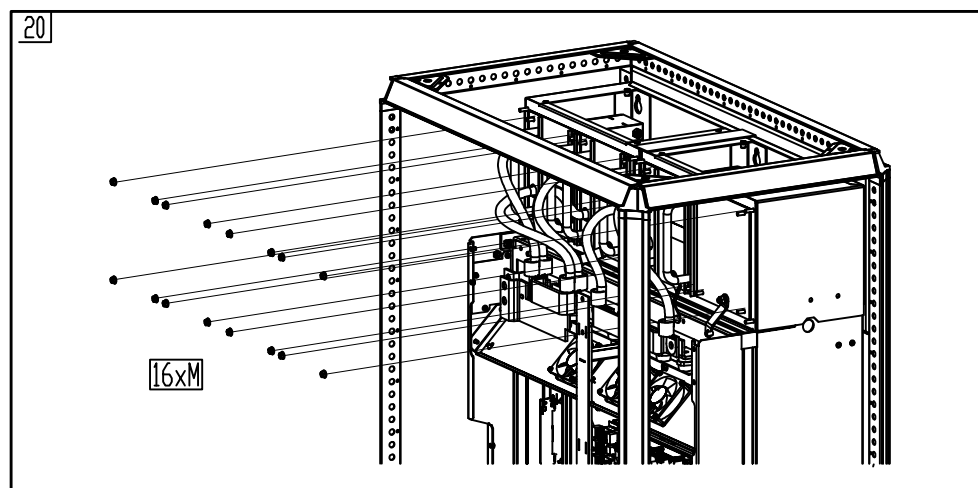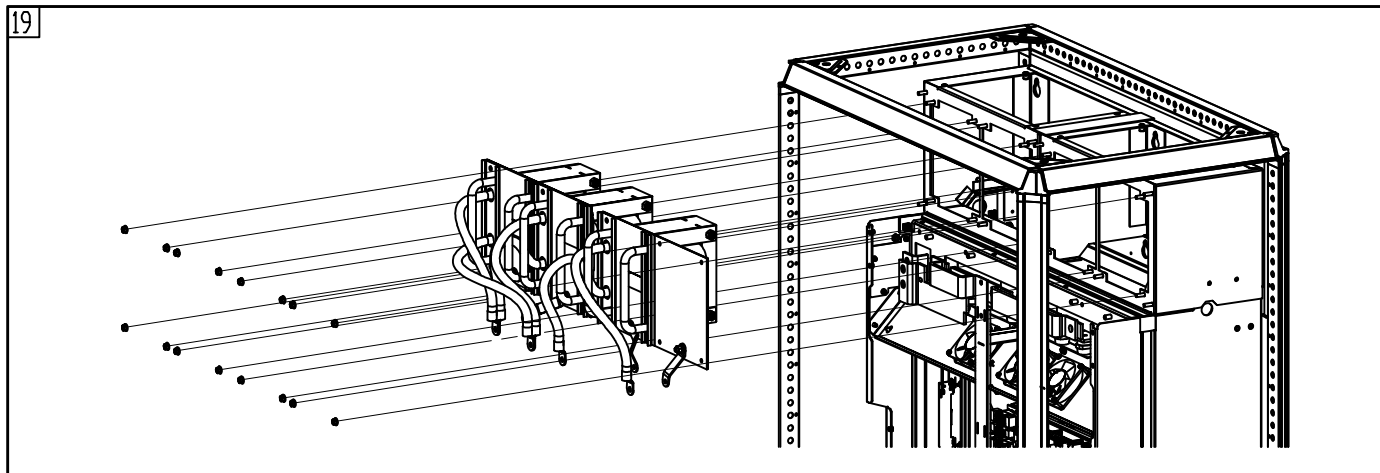


23

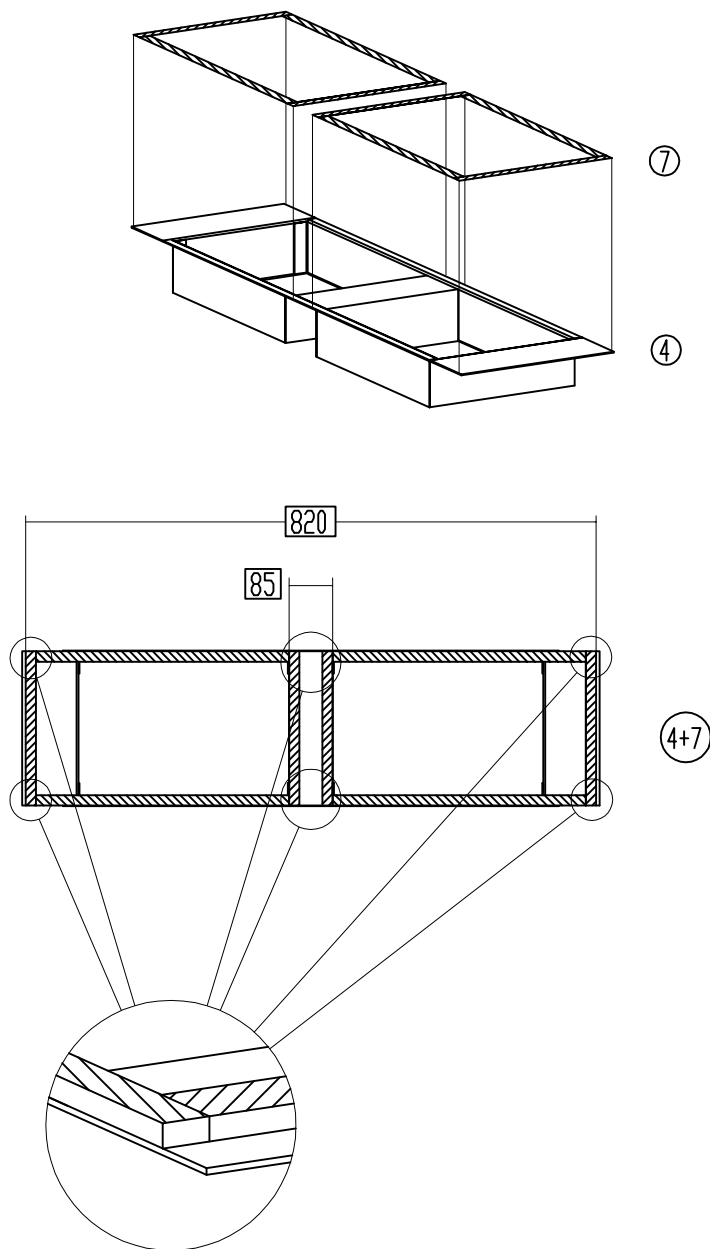


24



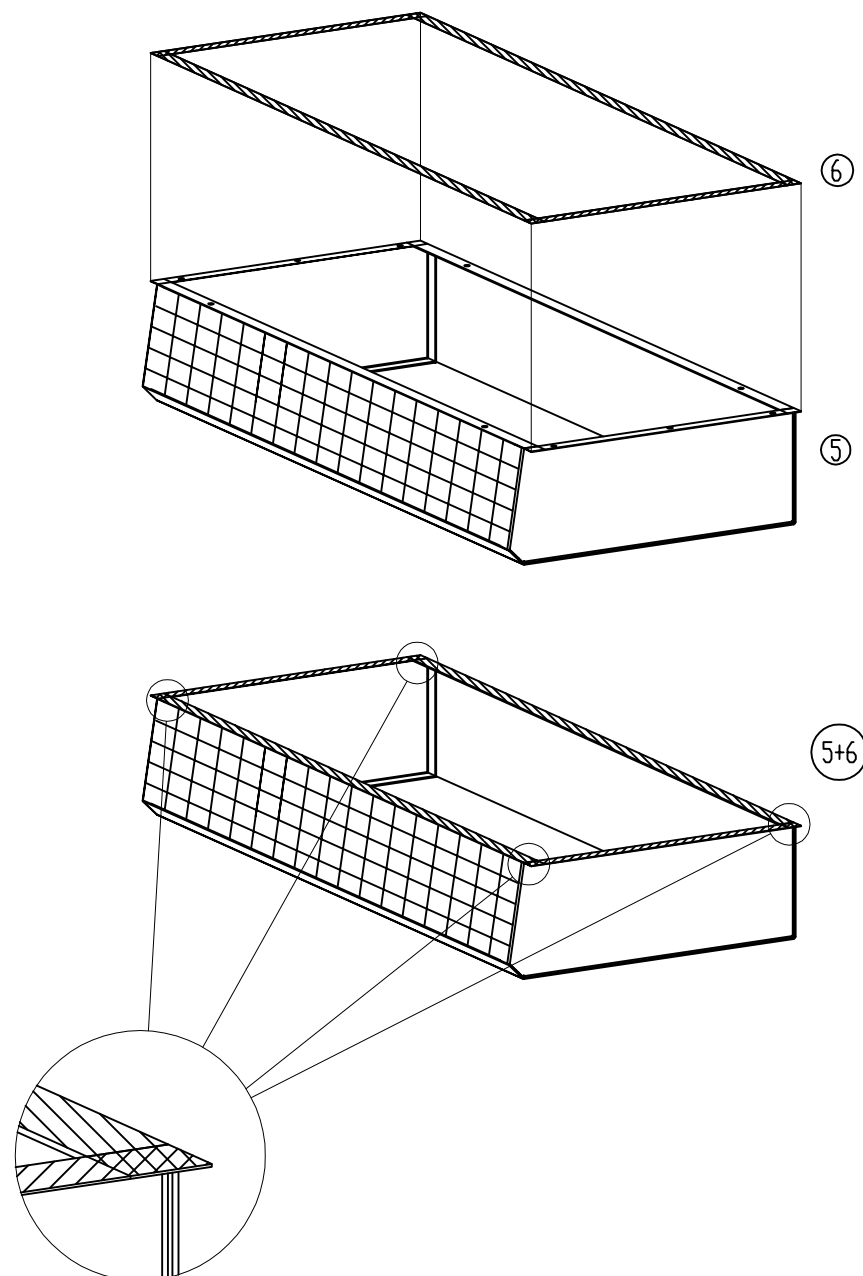



25

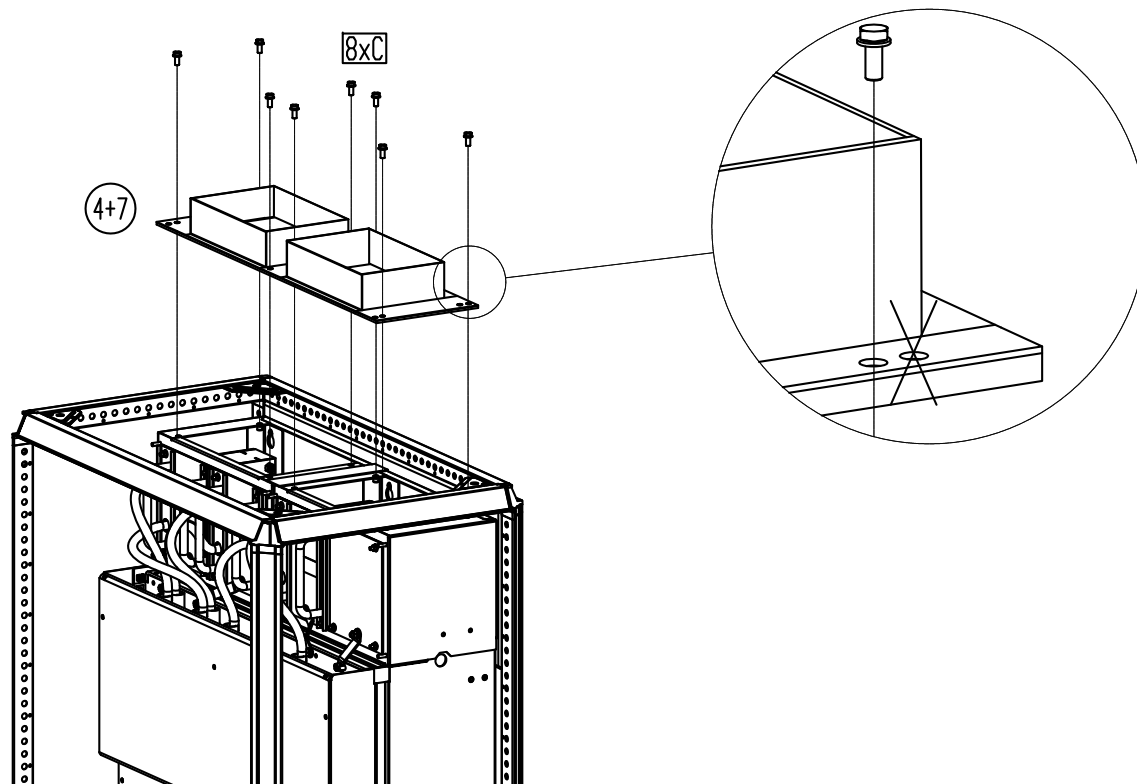


26

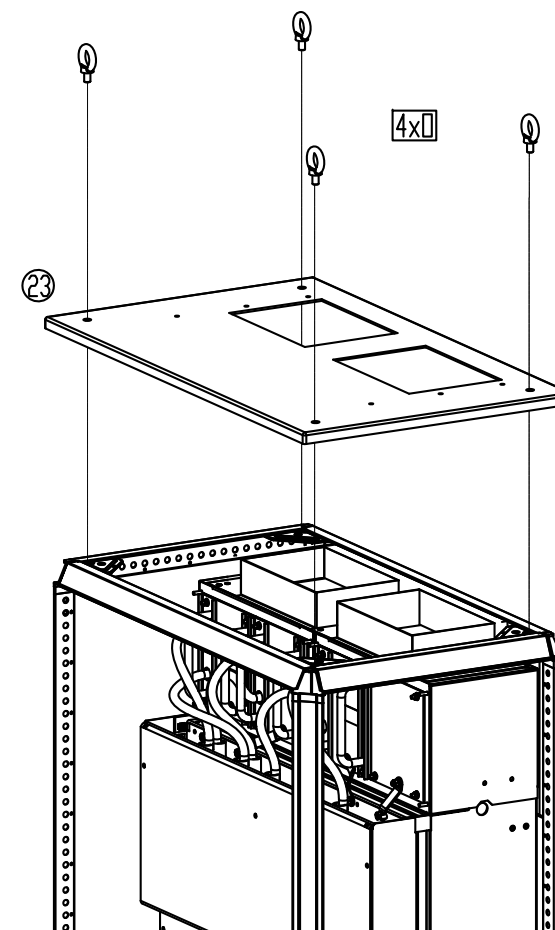


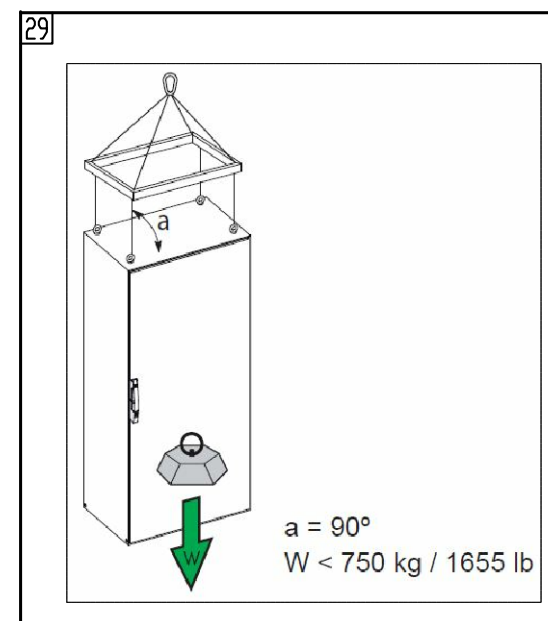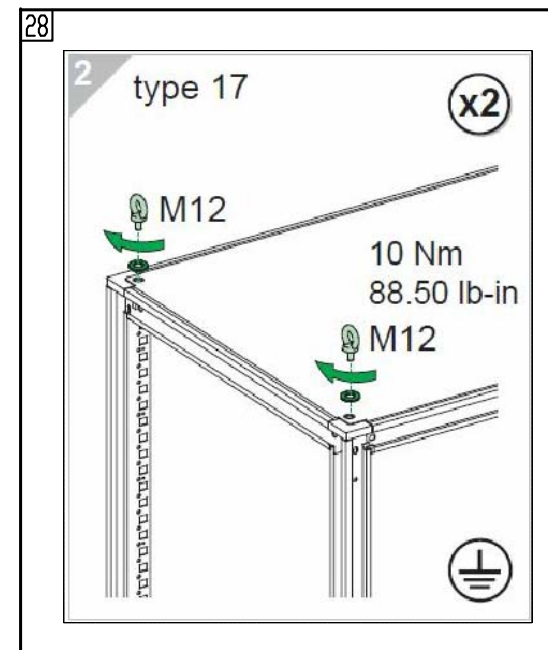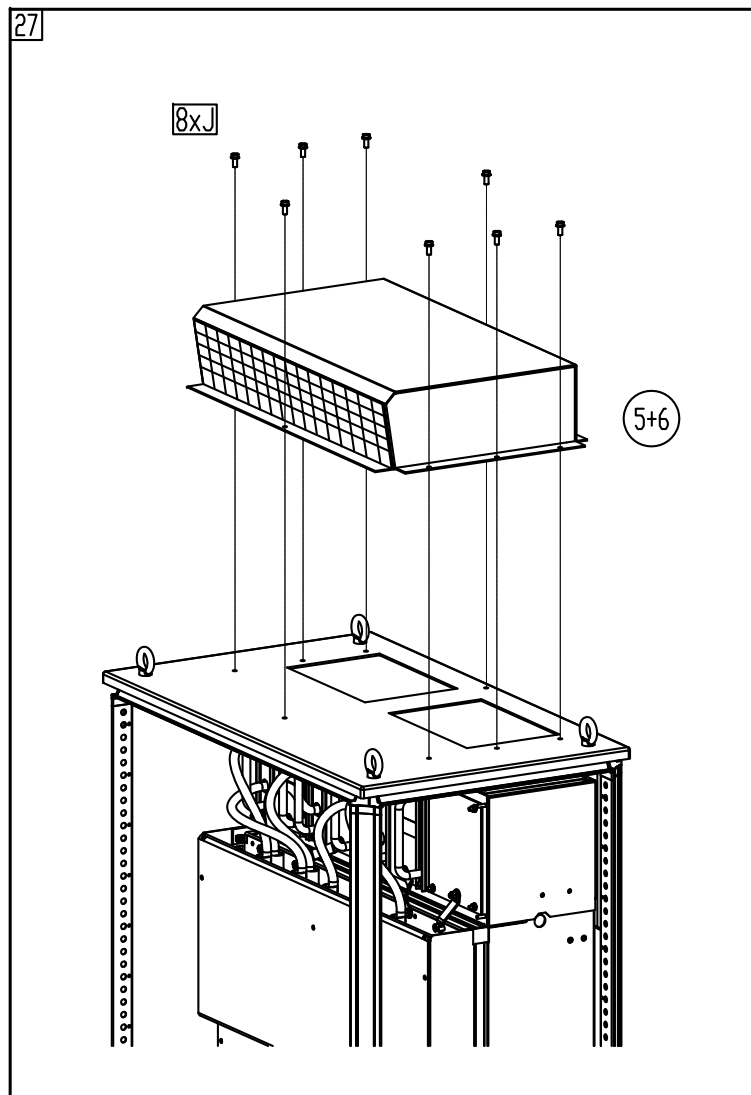

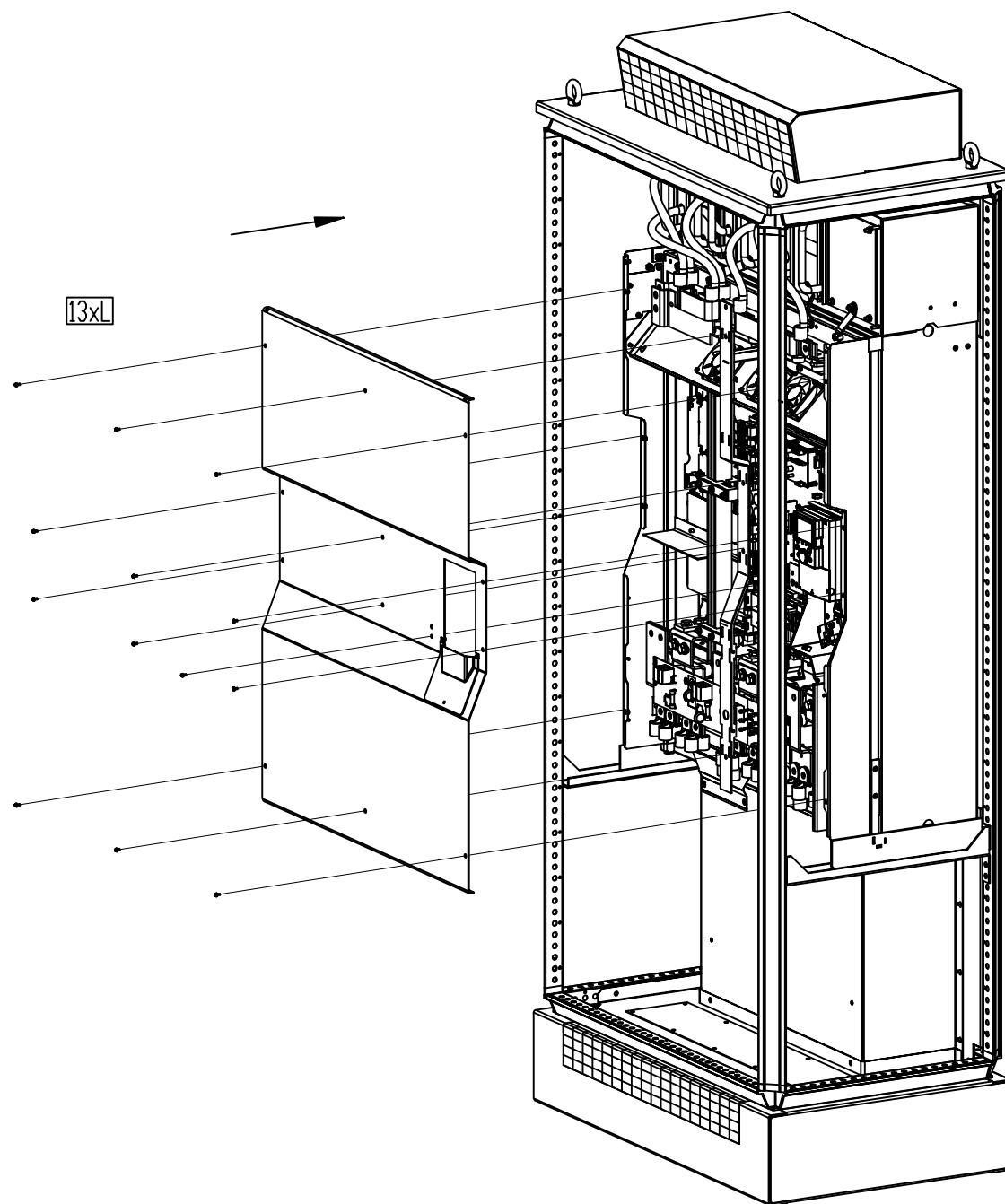


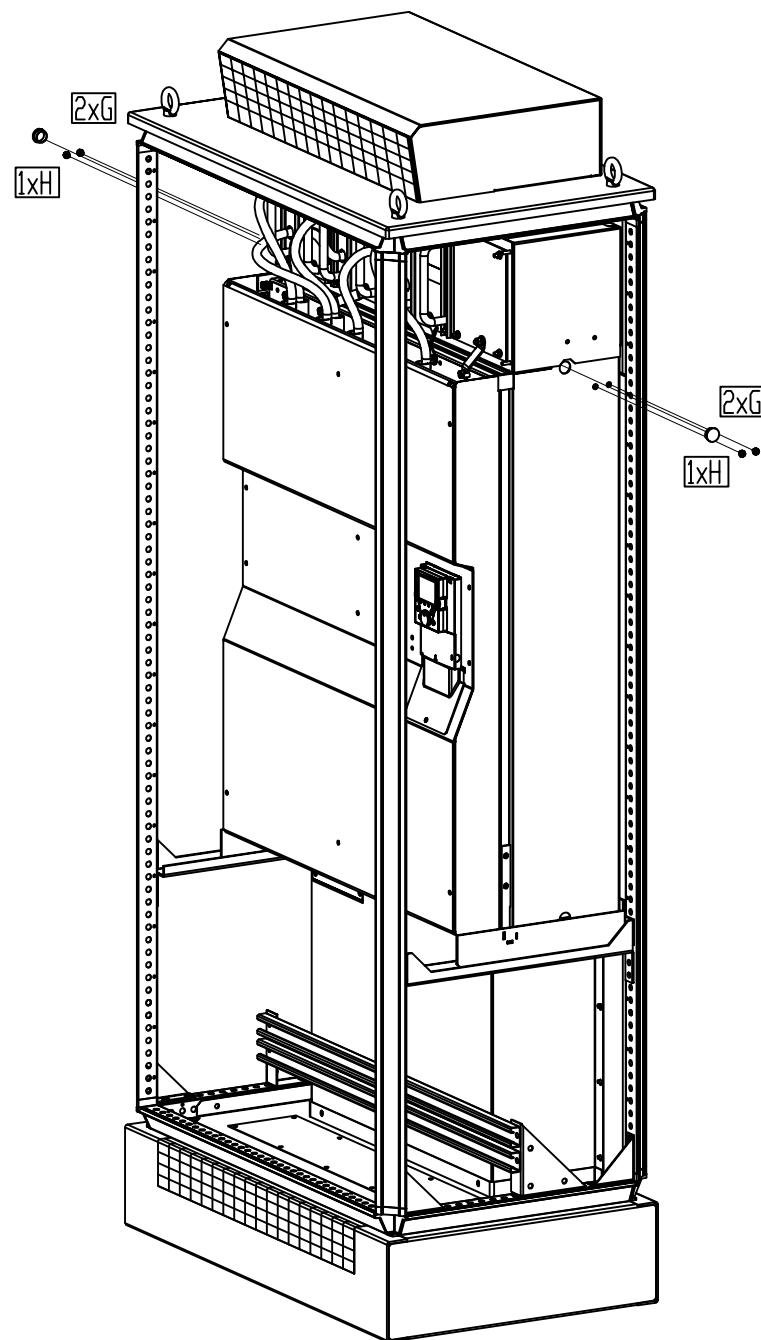


32

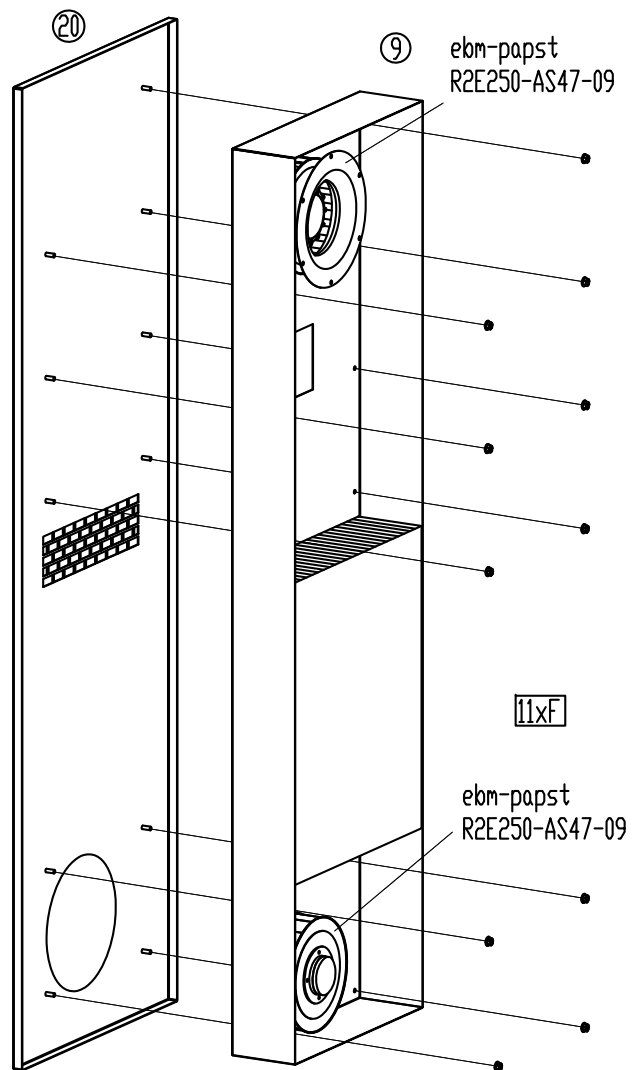


33

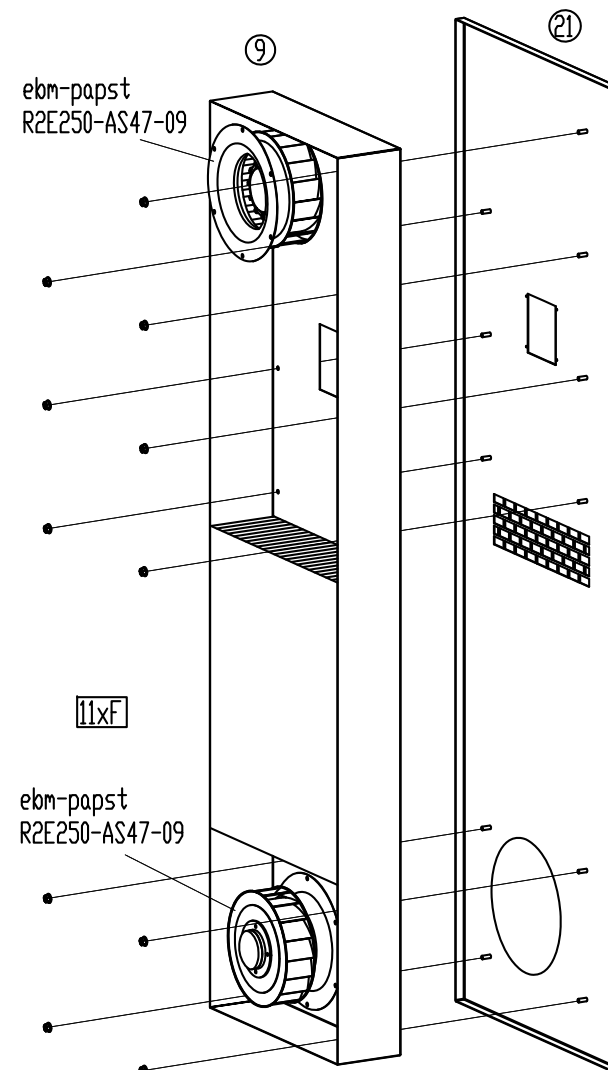


34

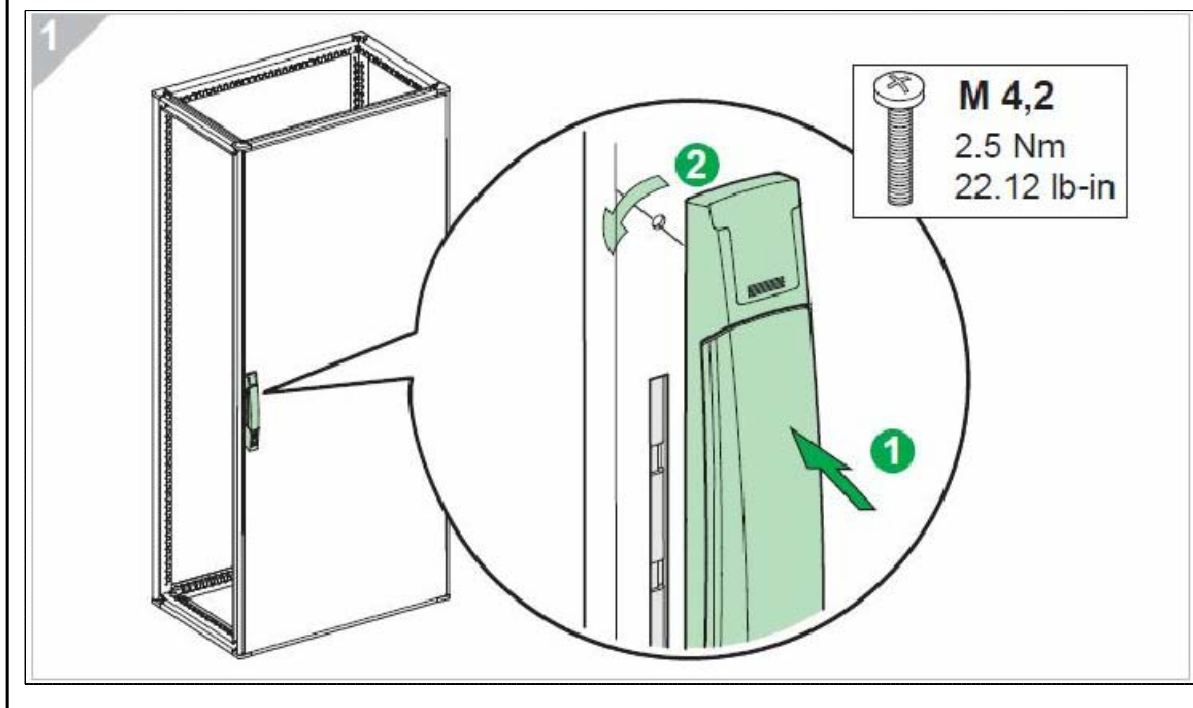


35

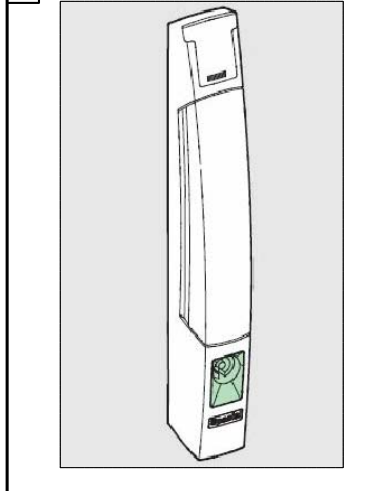


36

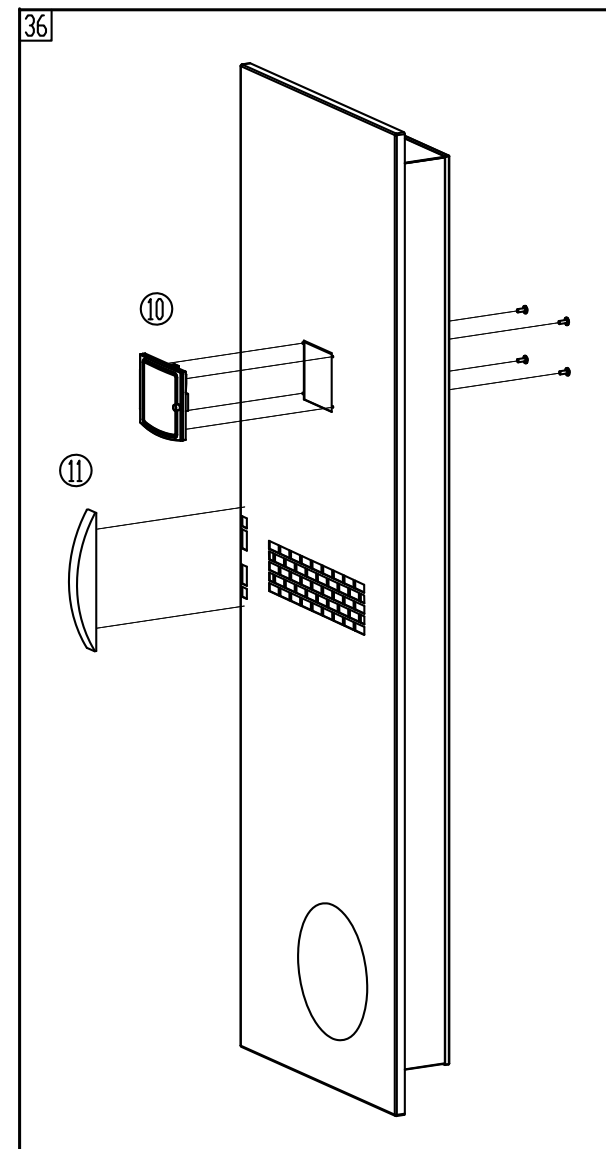




37

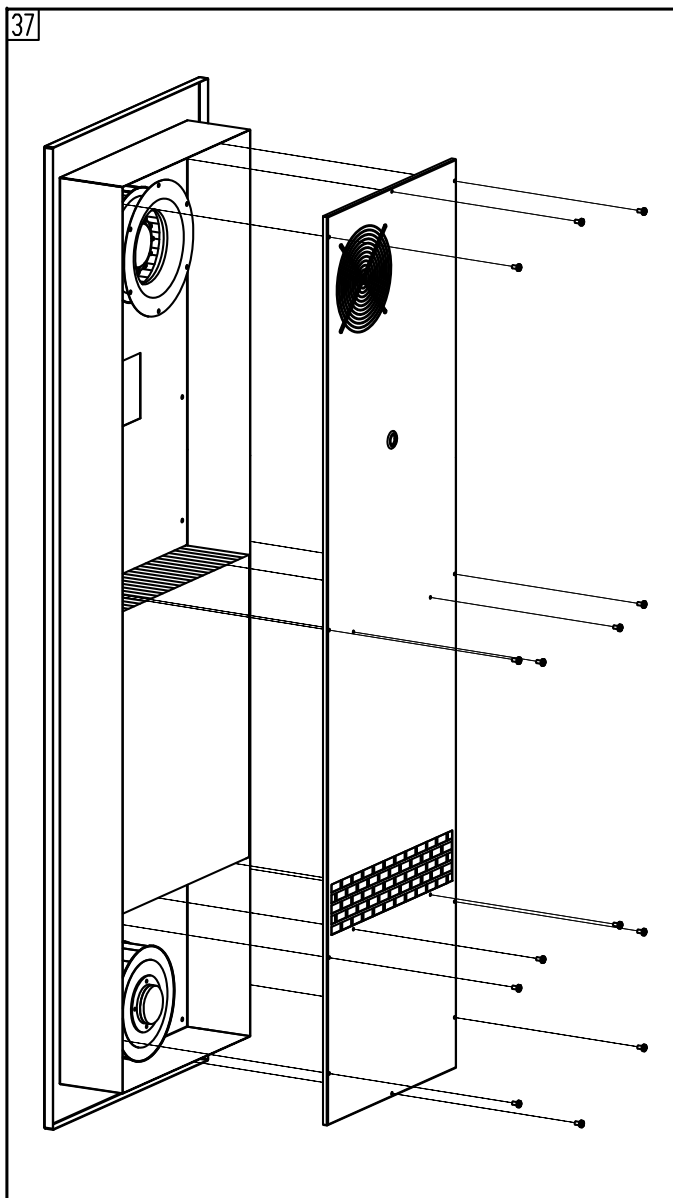



38



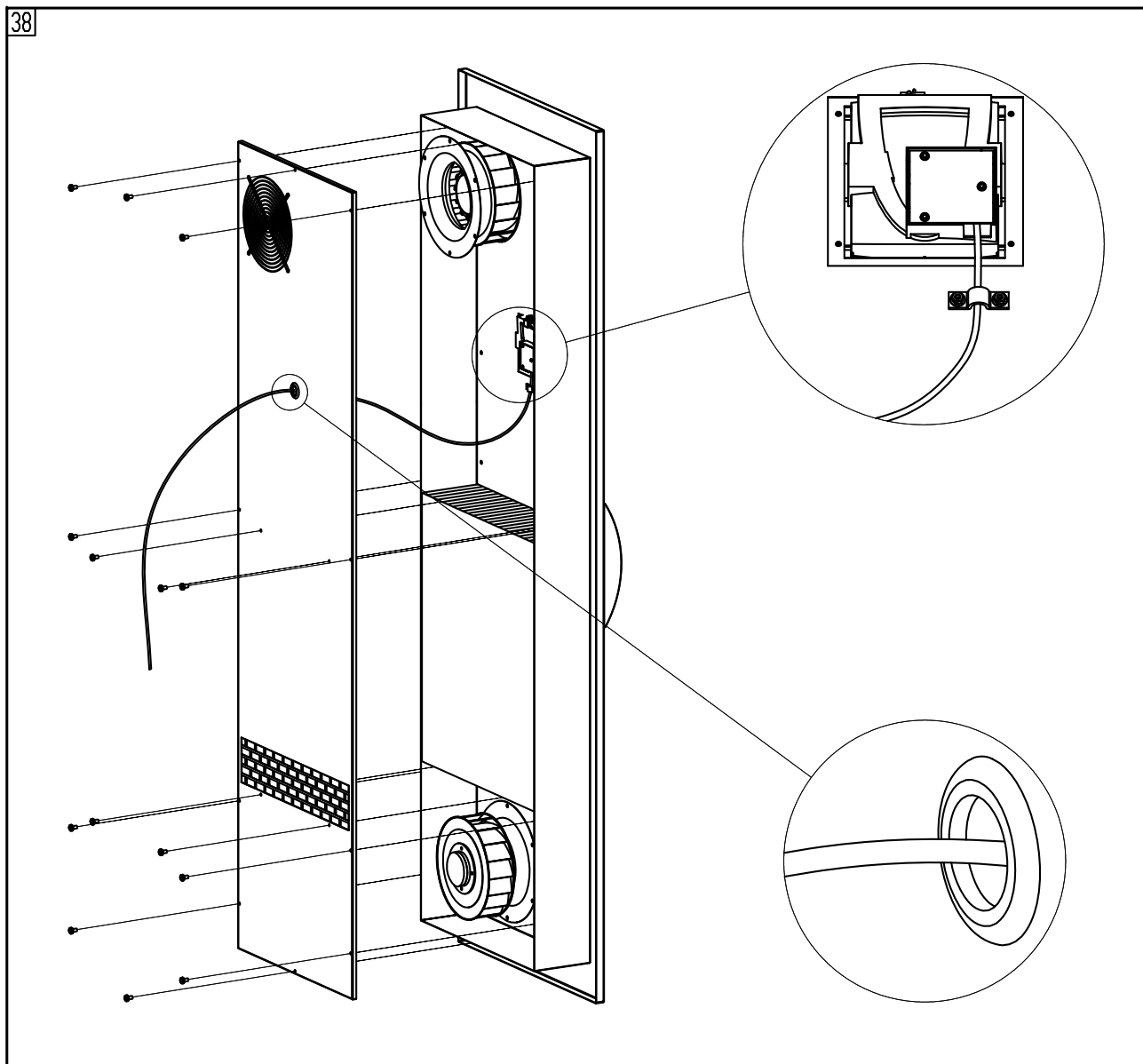





39

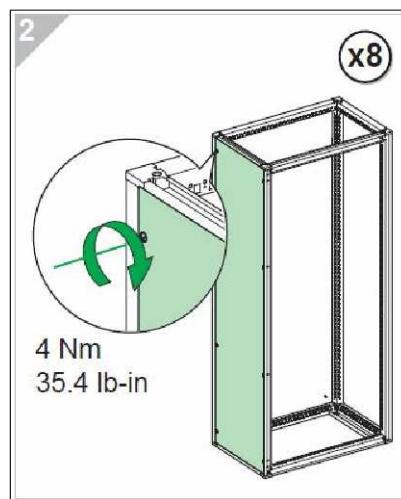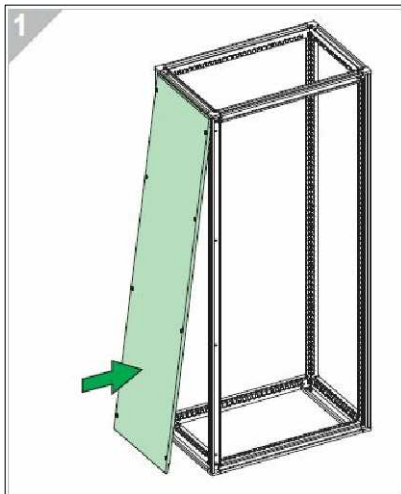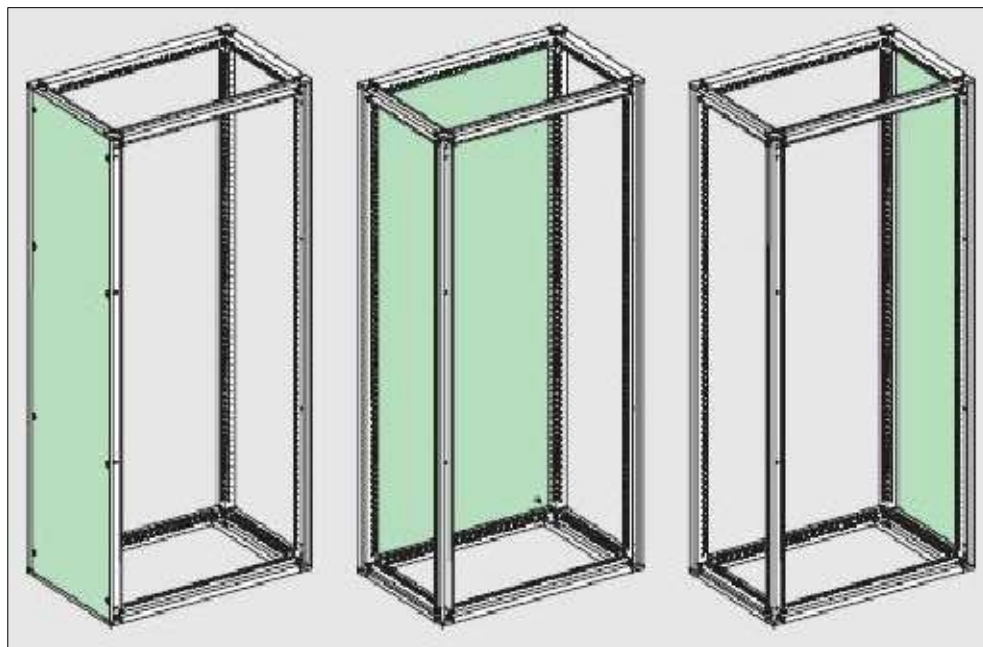



40

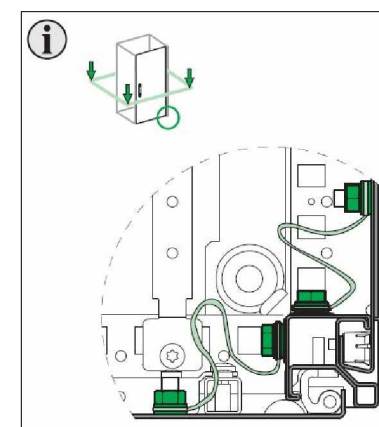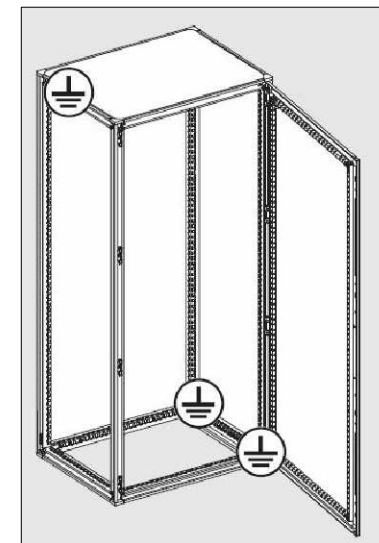

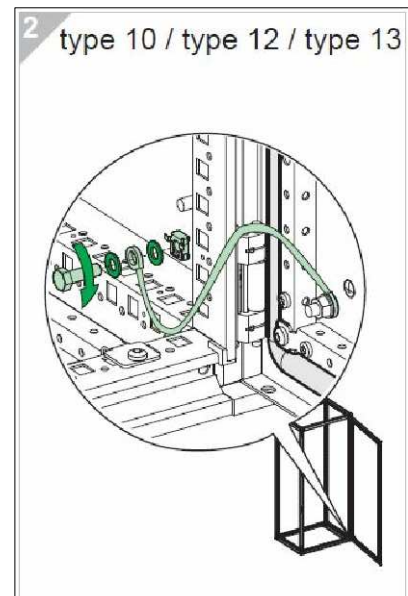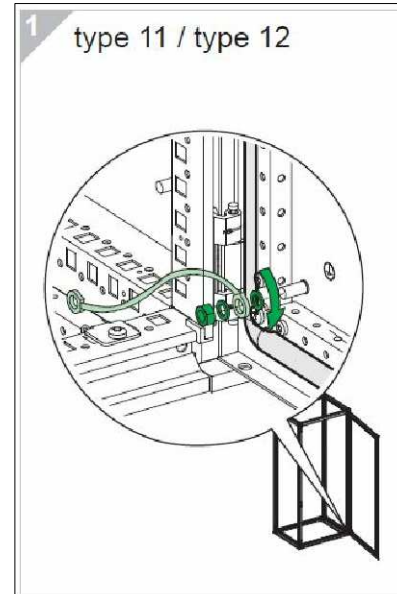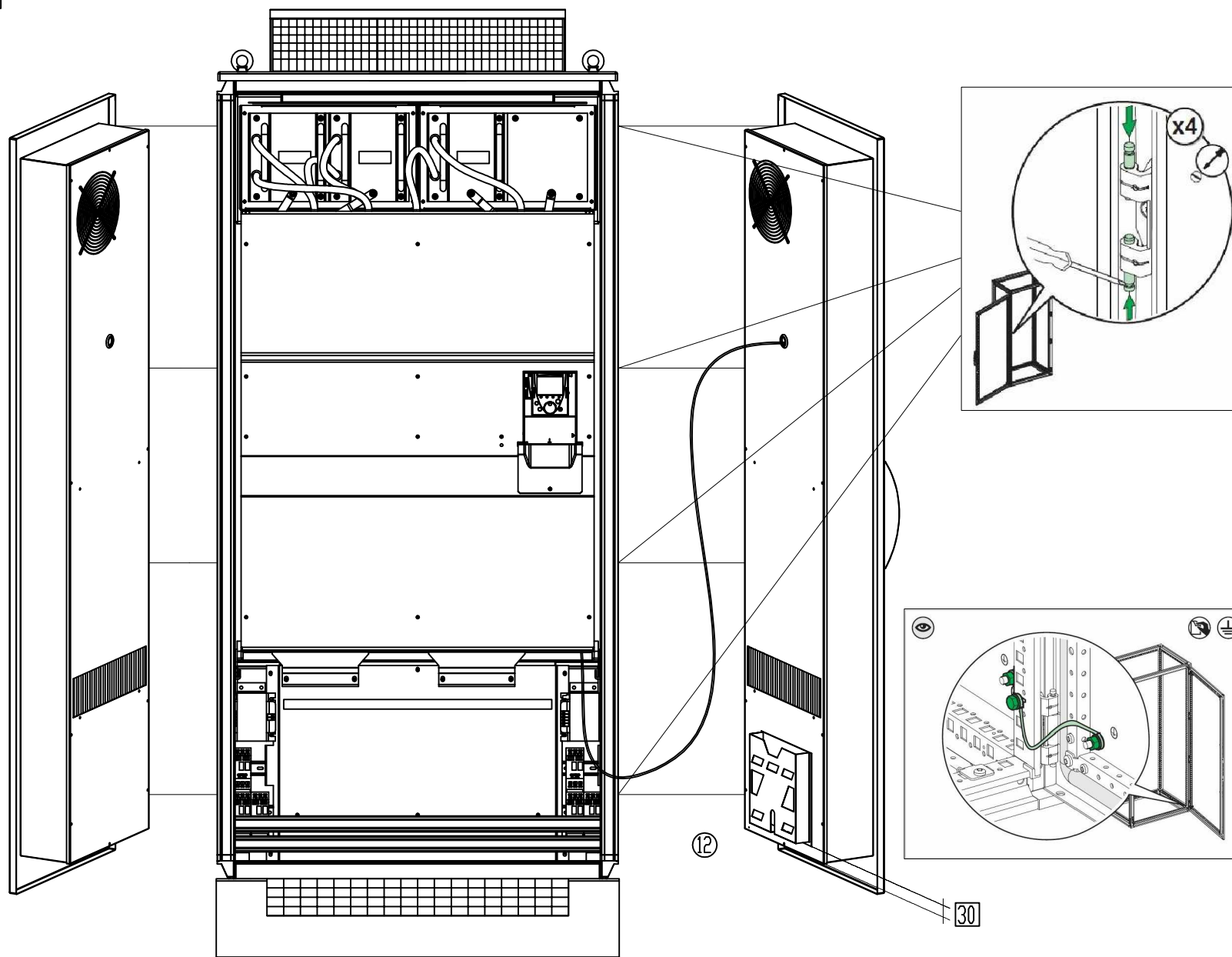


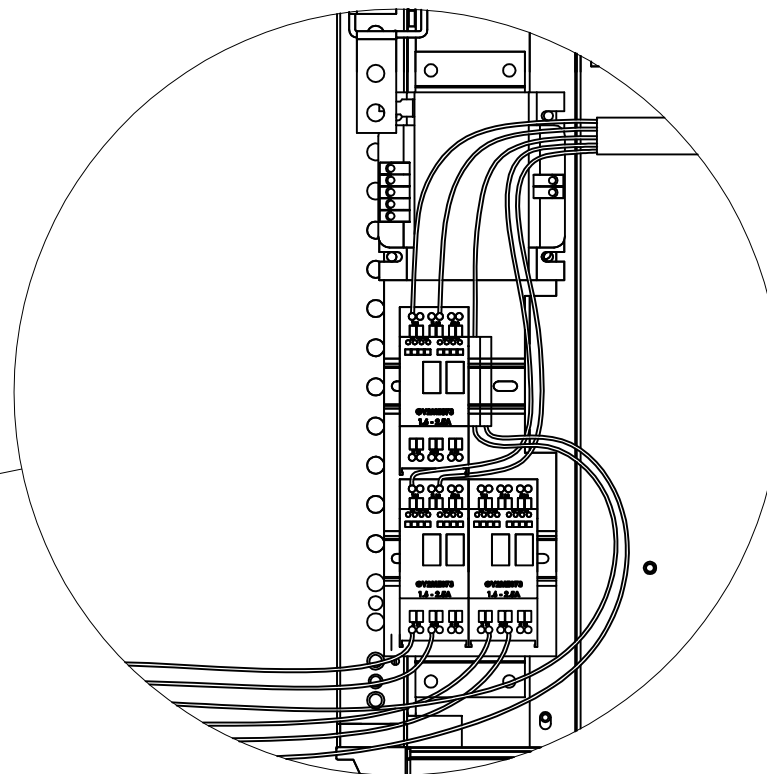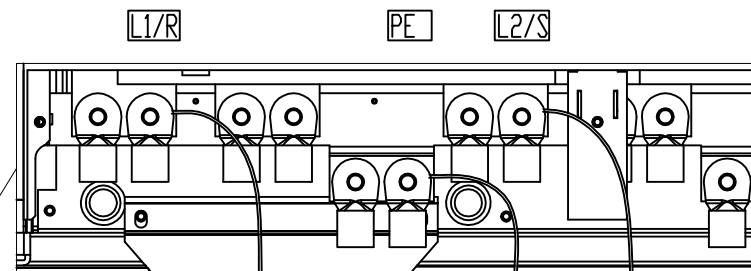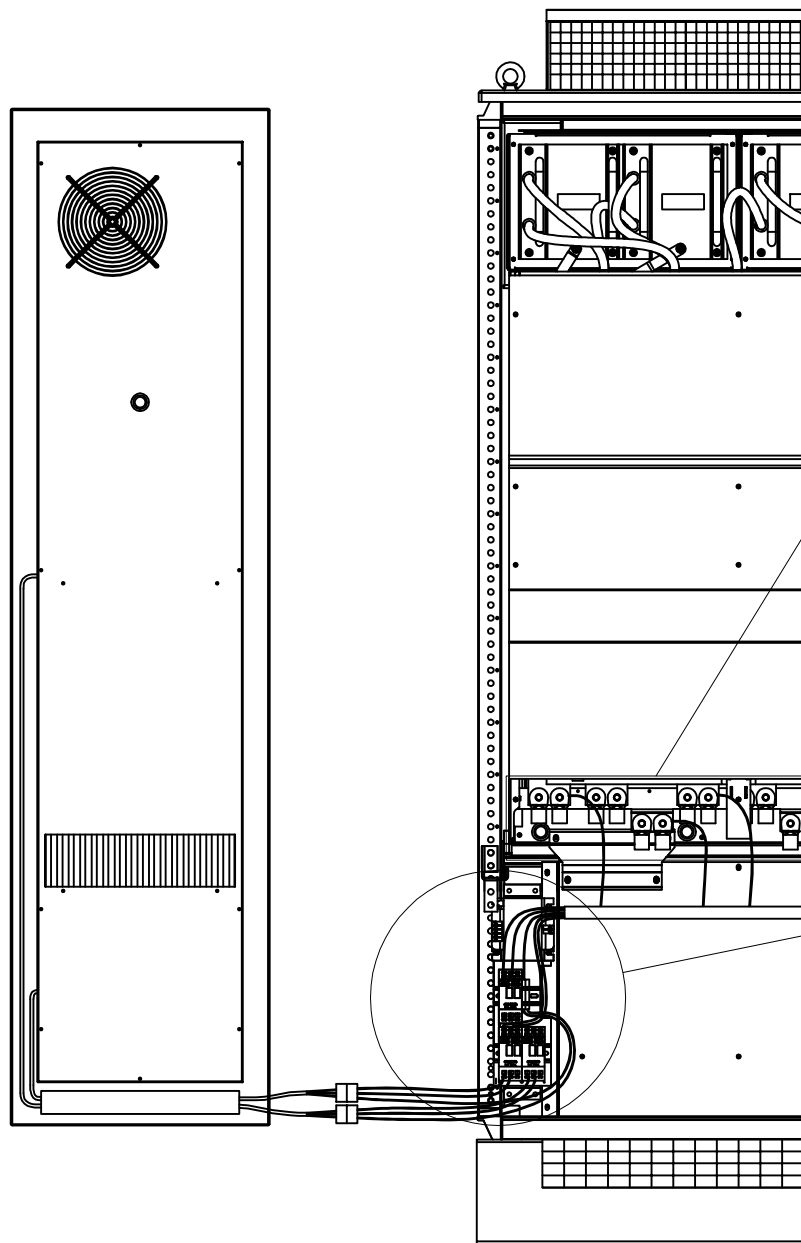

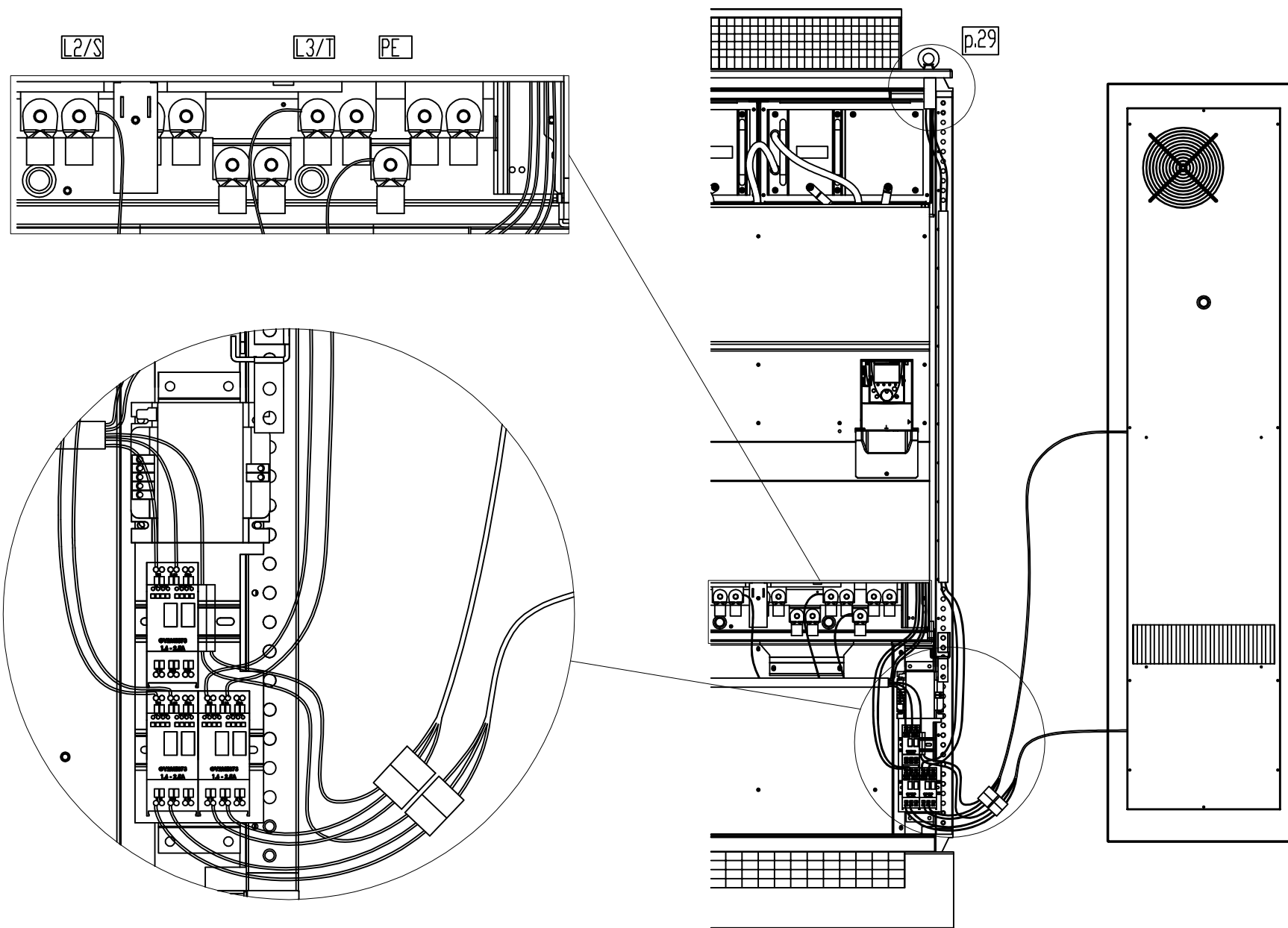


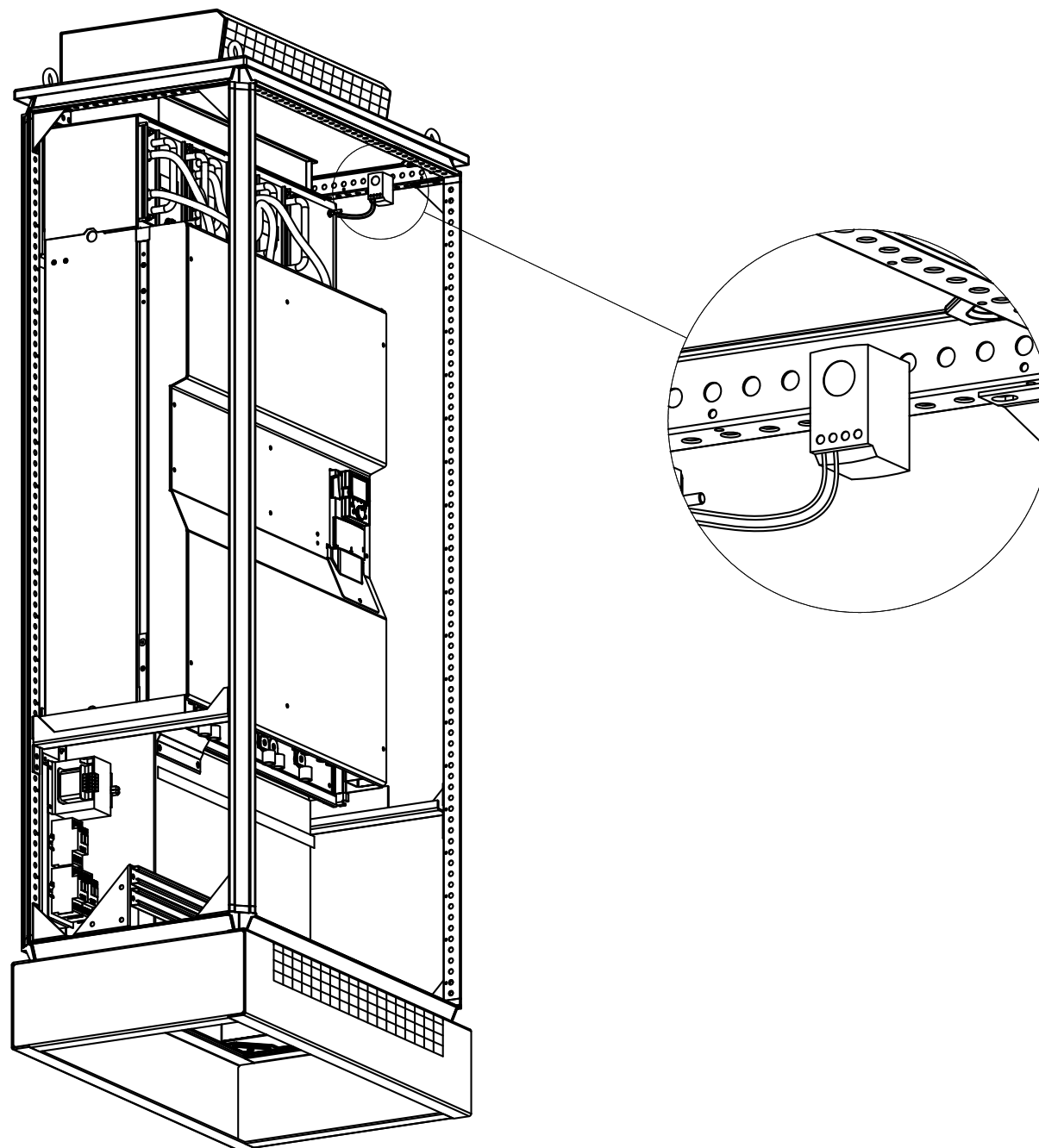


45

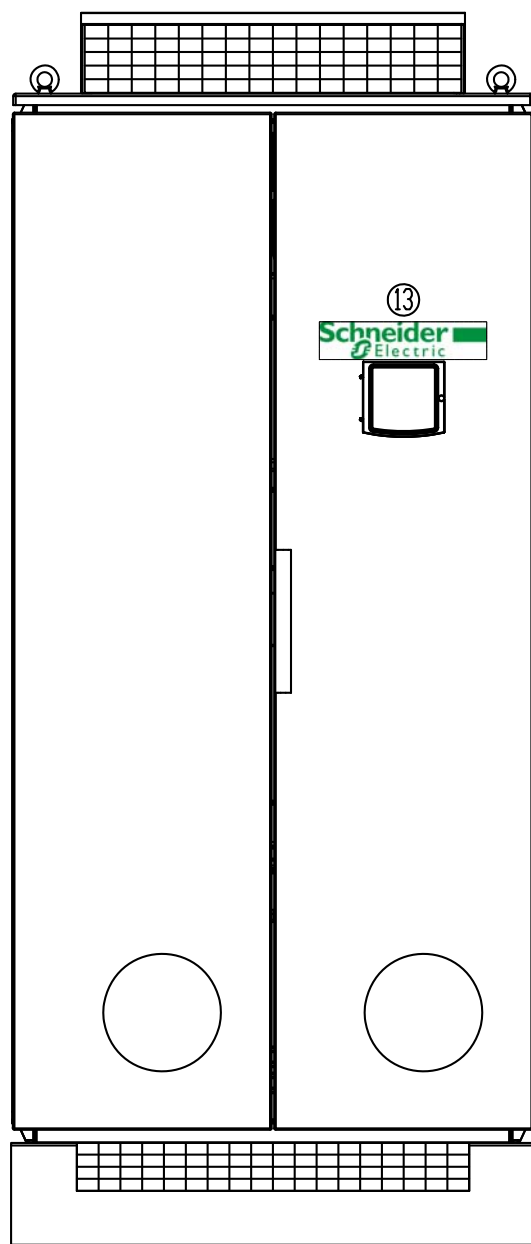


1

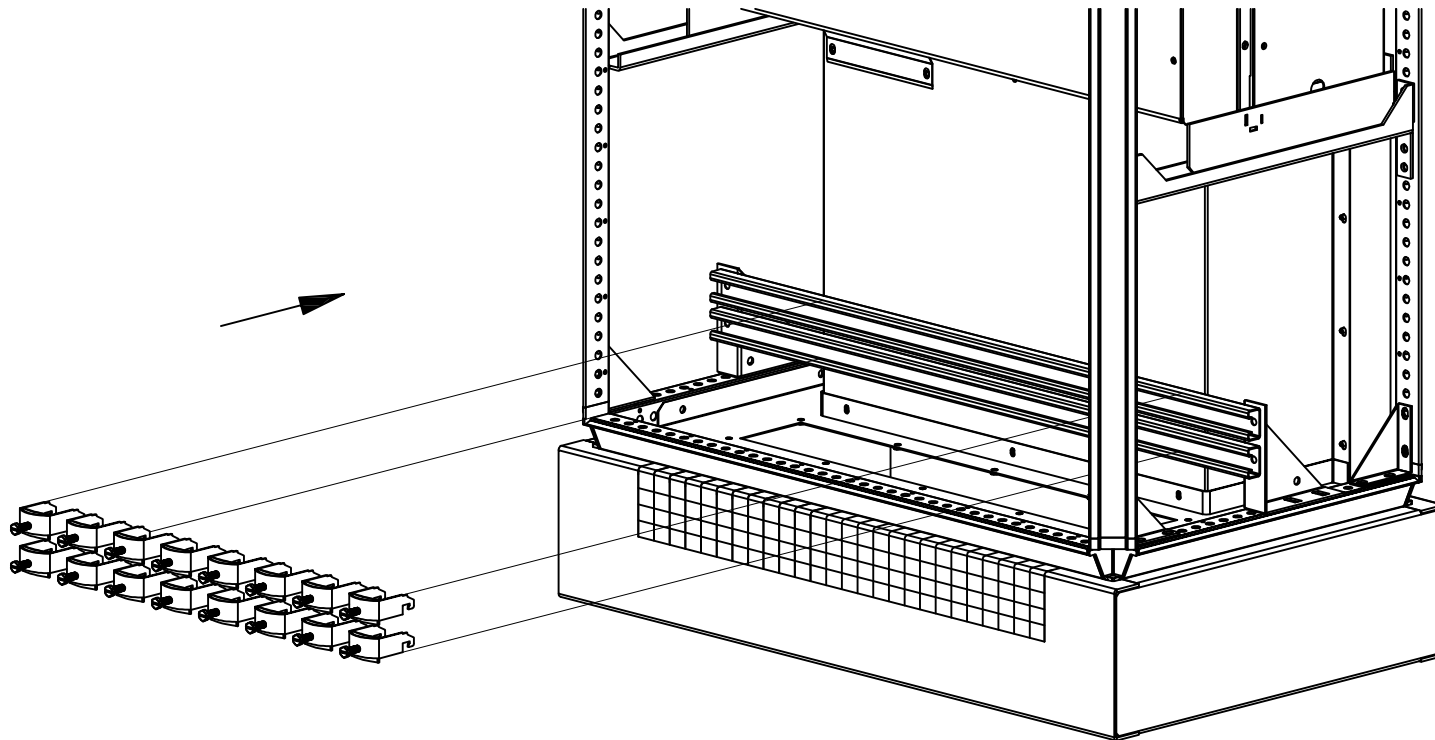


2

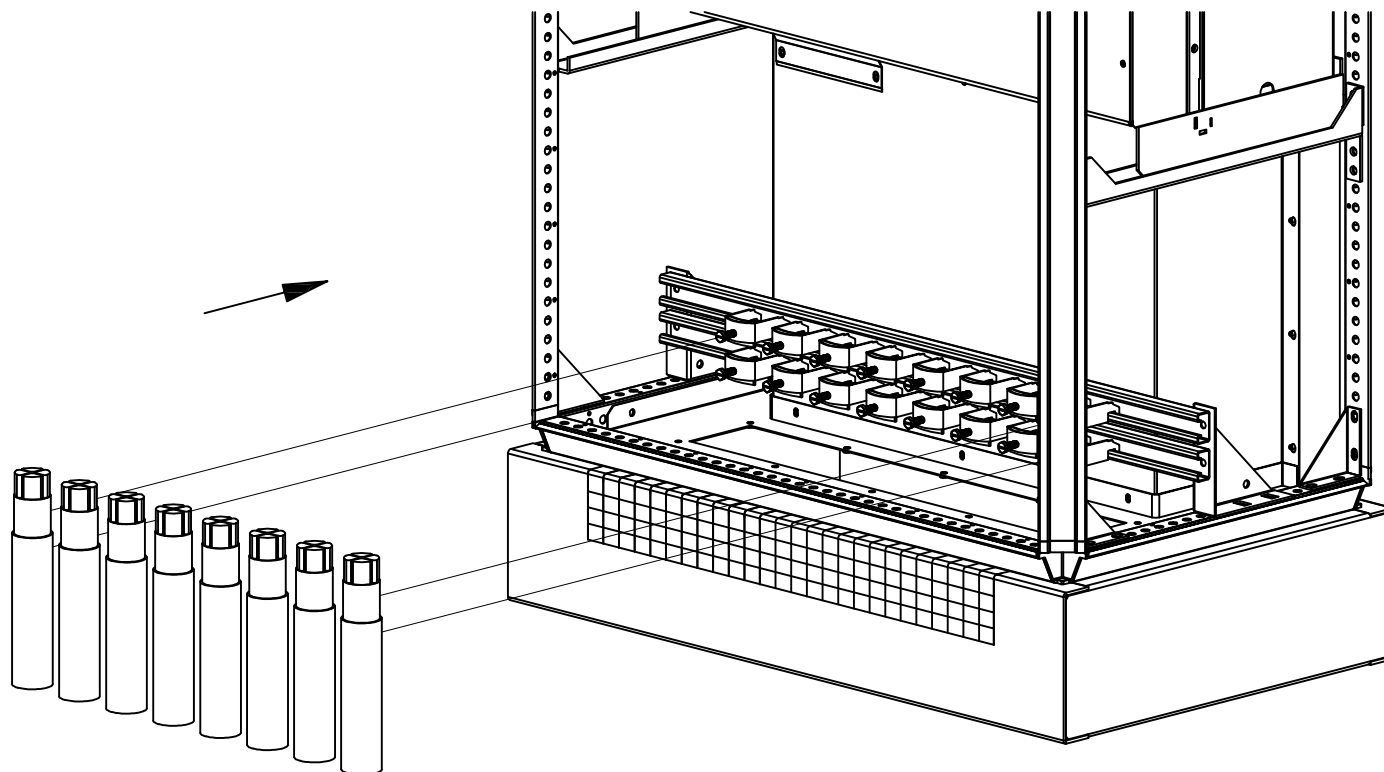


3

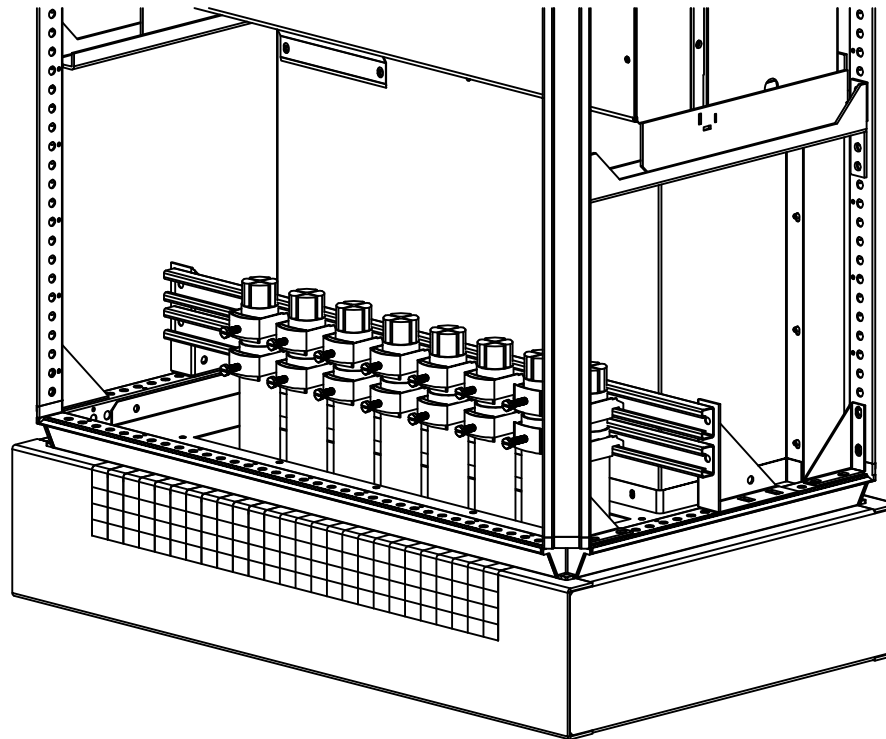


5

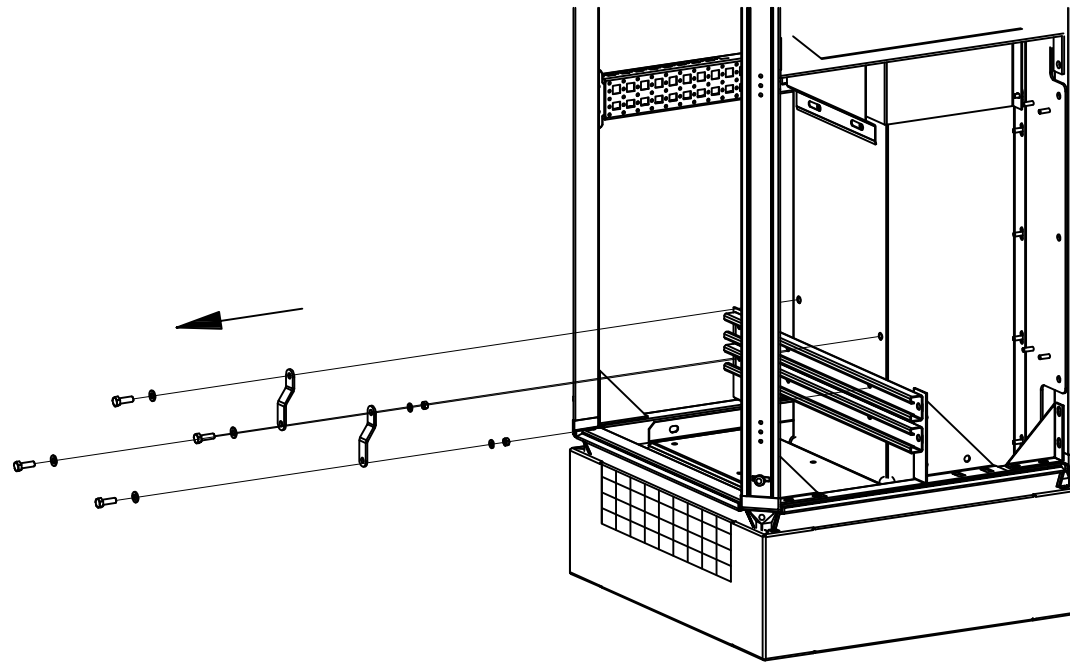


5

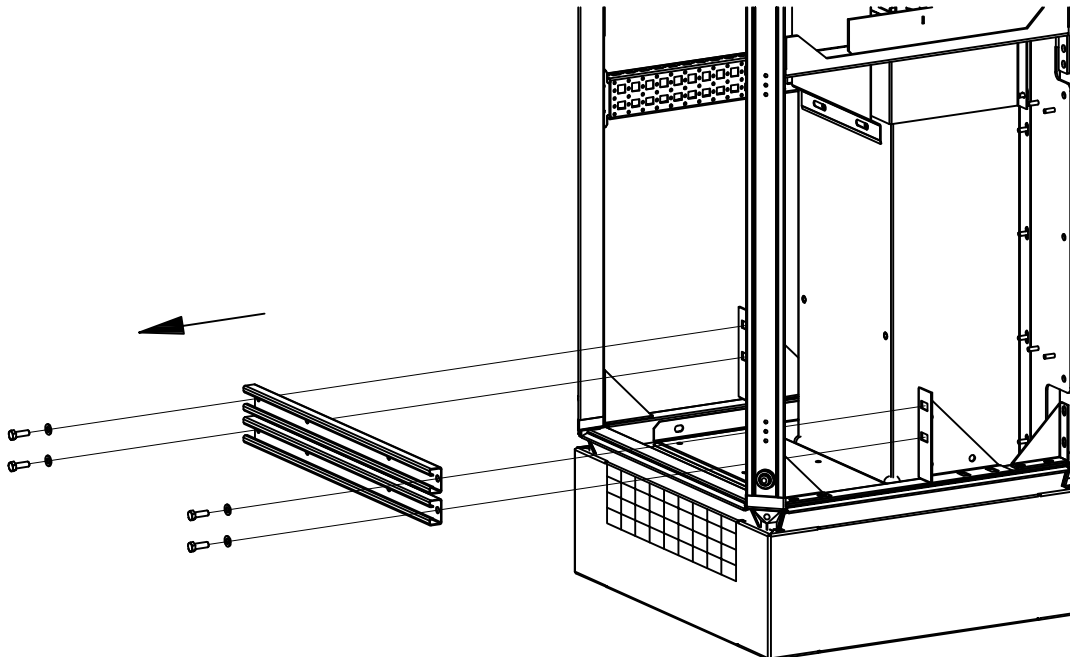


6


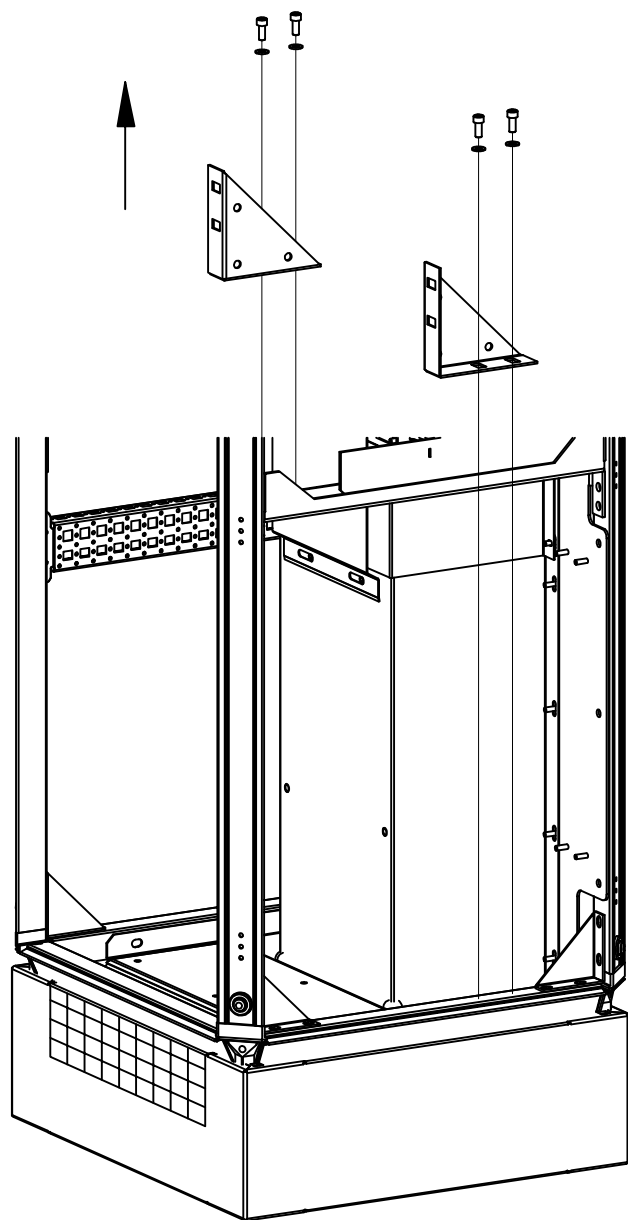


7

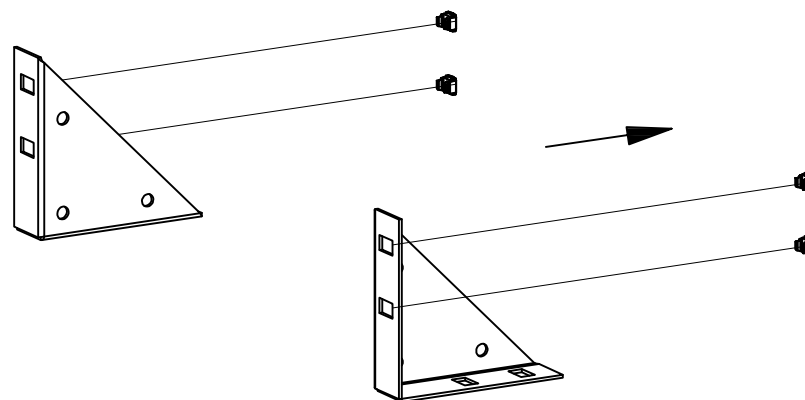


8

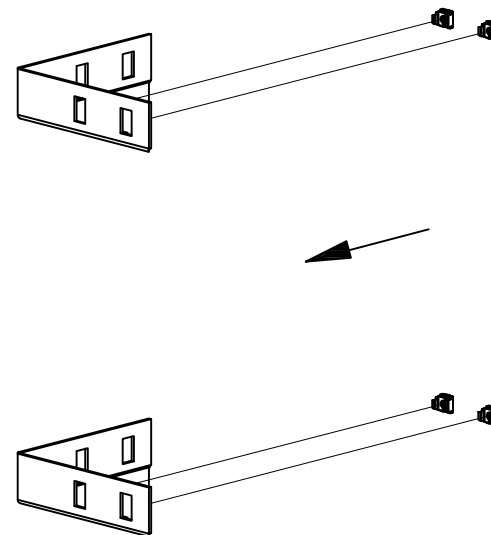


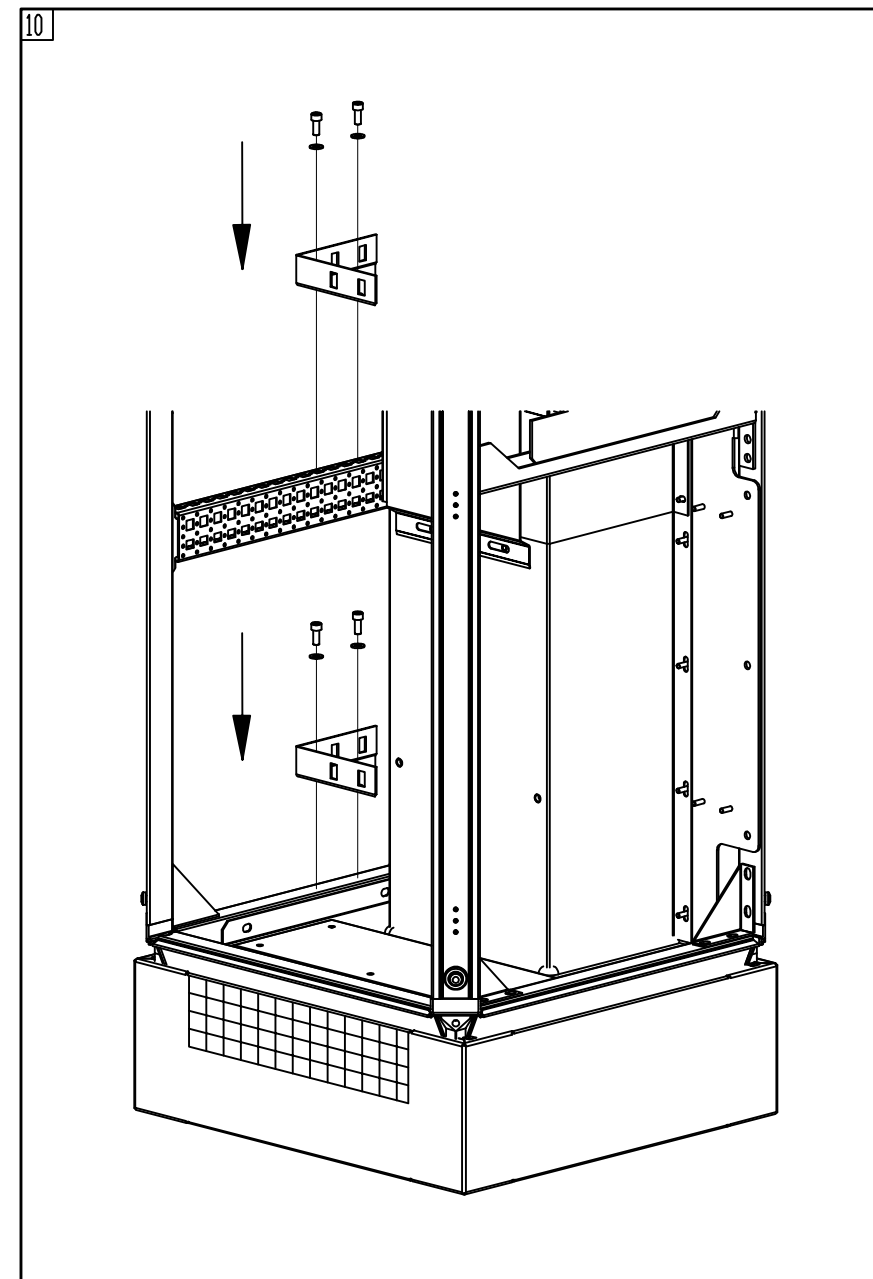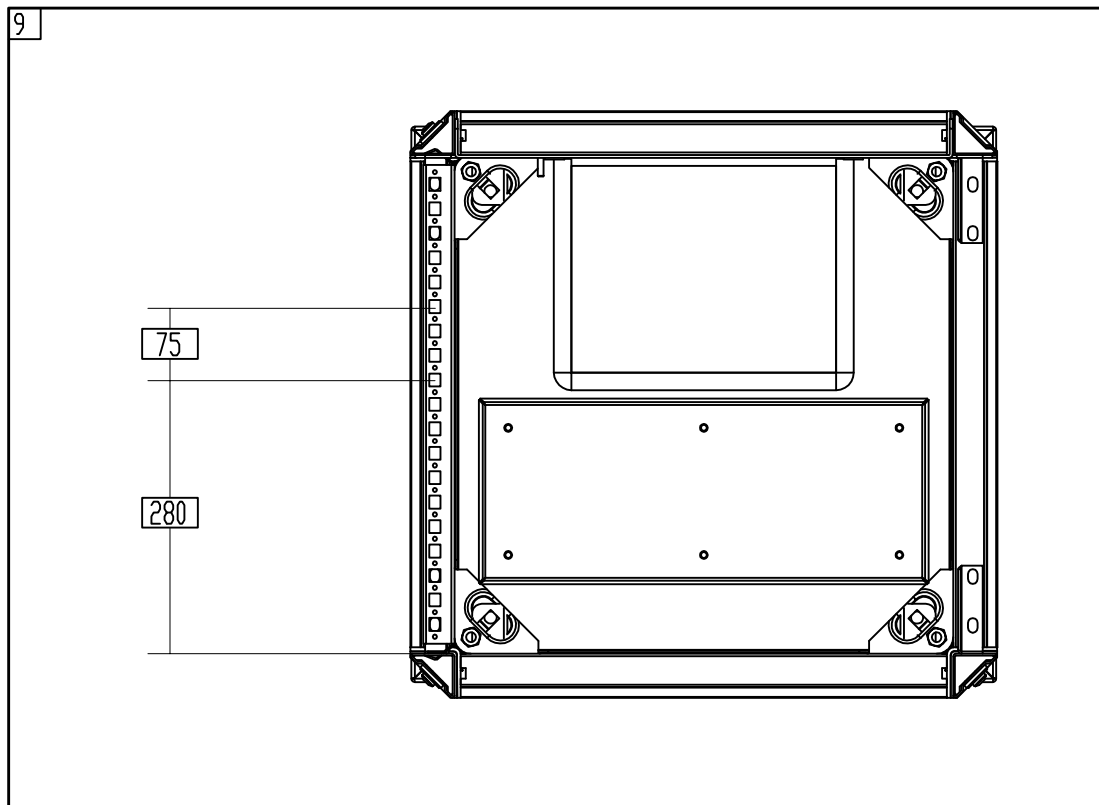


11

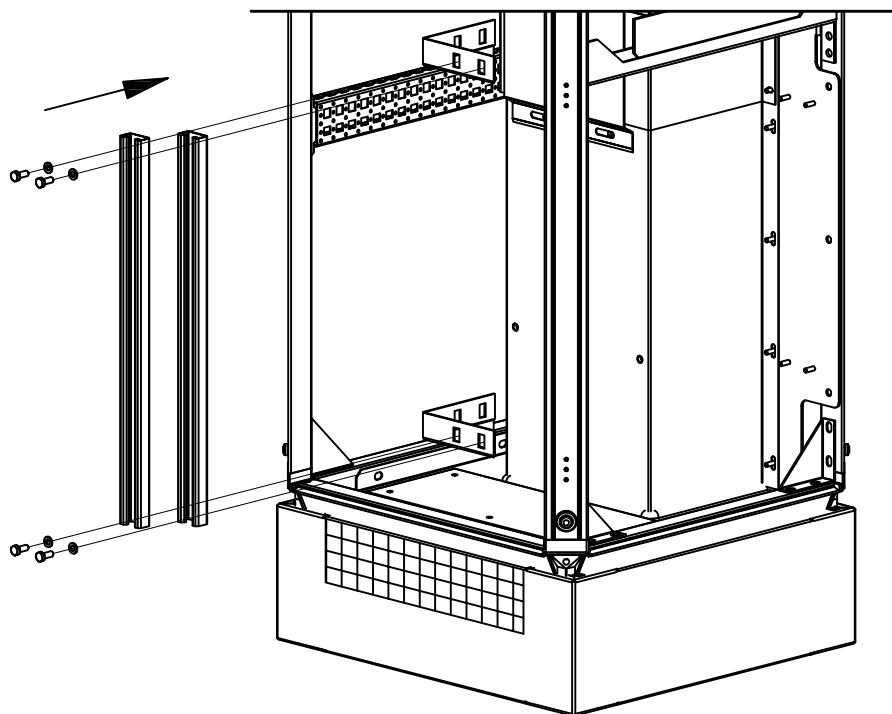


12

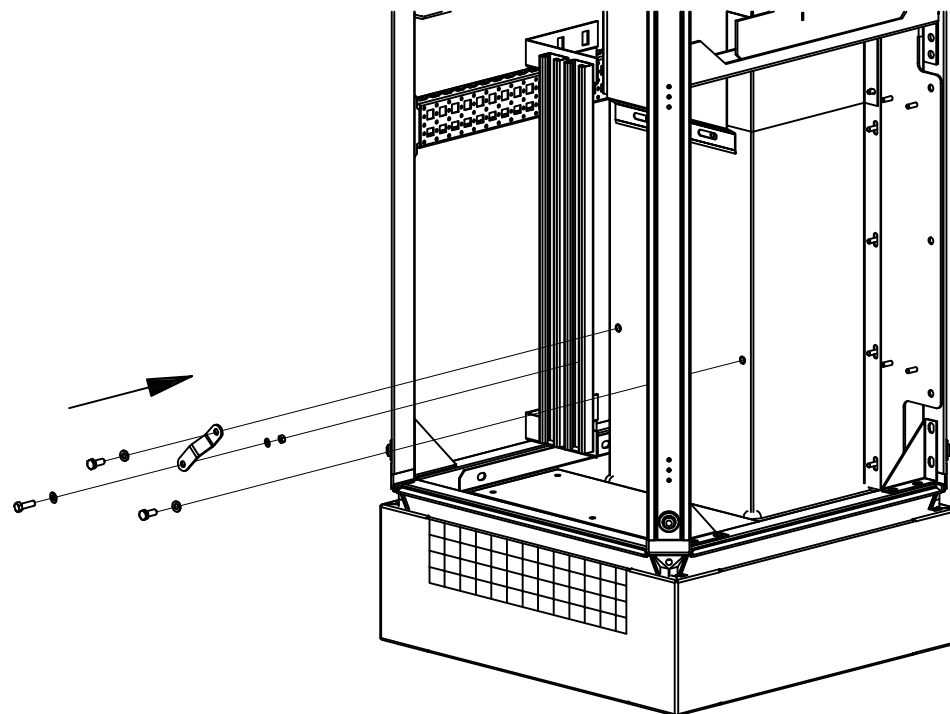

13

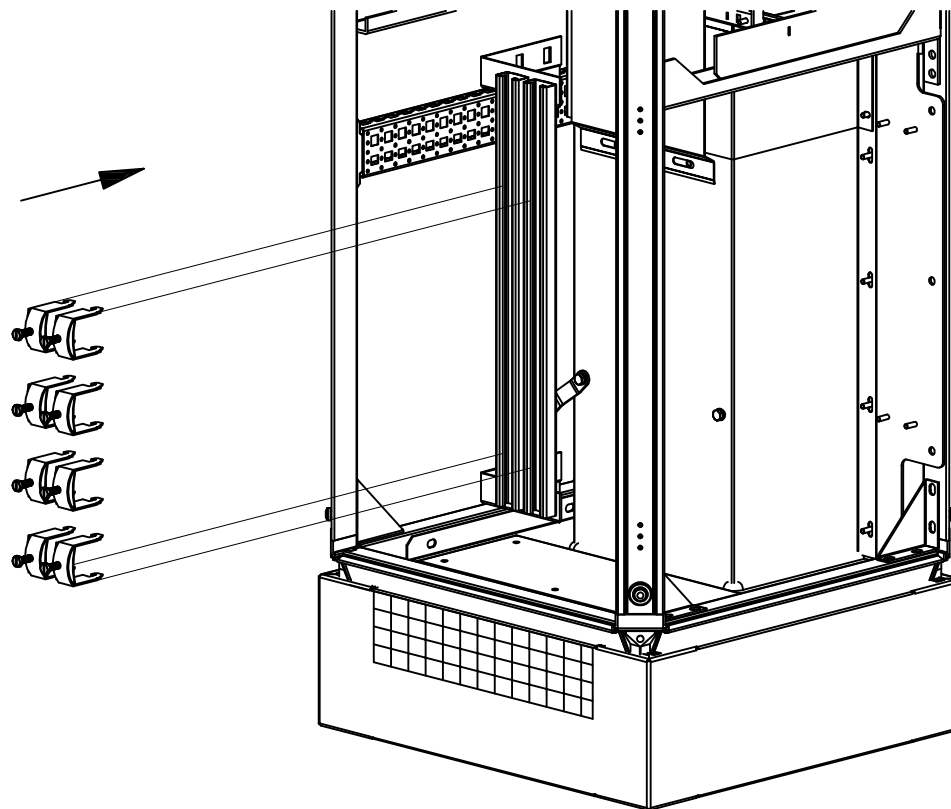

14

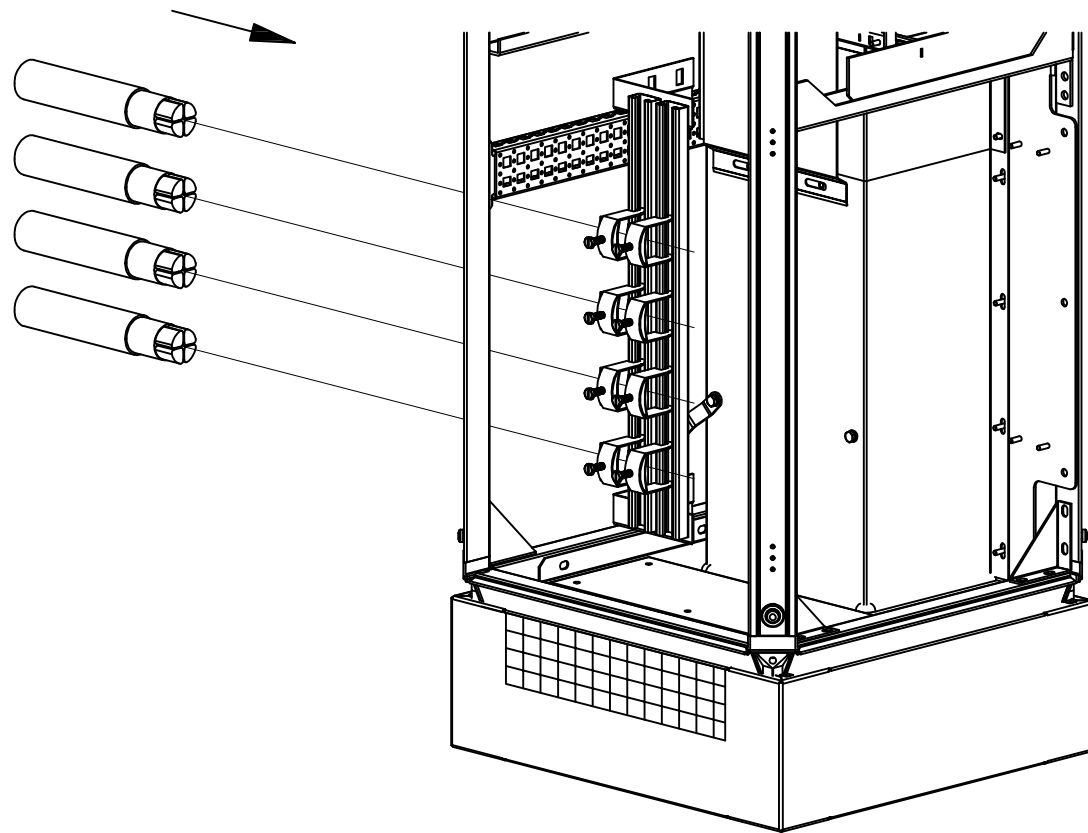

15

