
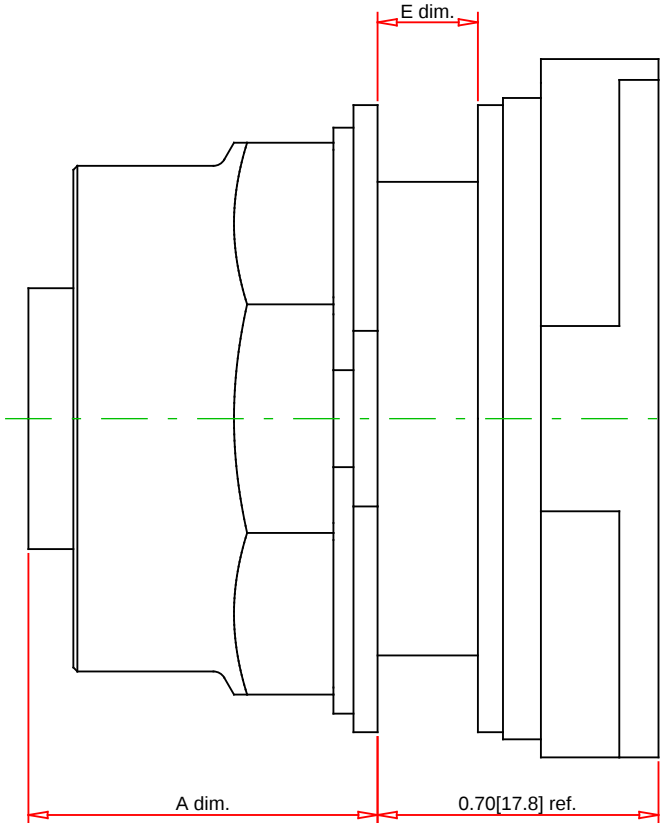


Panel Thickness E dim. inches (mm)	Number of Gasket
1/16 (1.6)	4
1/8 (3.2)	3
3/16 (4.8)	2
1/4 (6.4)	1

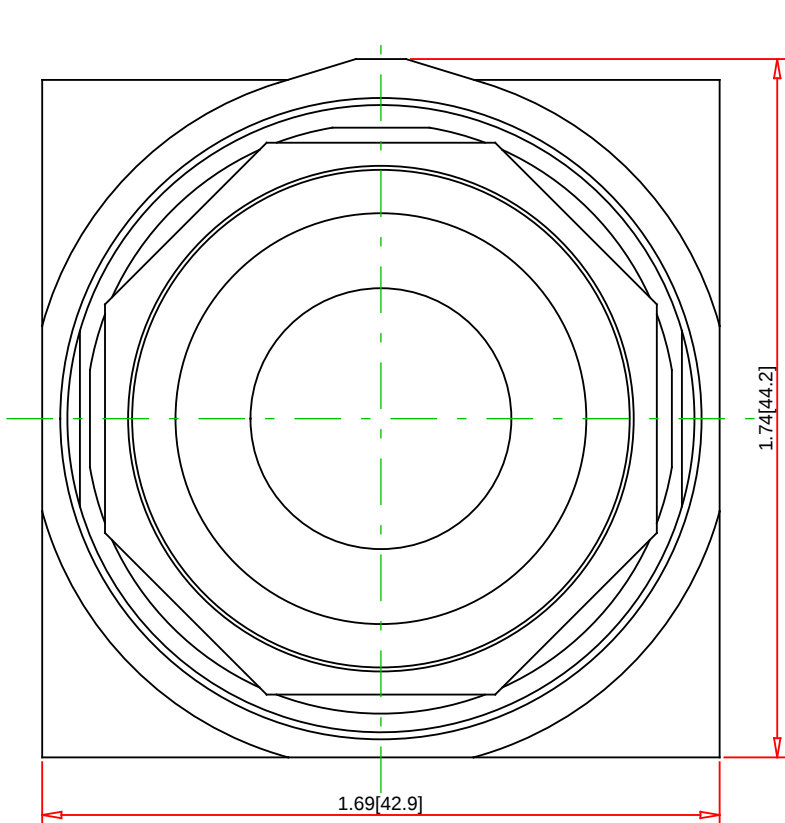


A dim. inches (mm)		
Depressed (Stop)	Midway (Neutral)	Extended (Start)
0.87 (22.1)	1.06 (27.0)	1.25 (31.8)

Note:
- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

9001SKR8

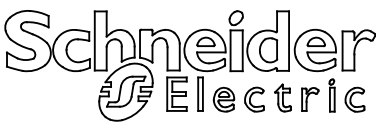

Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone:+1 8773425173
Email: CCC@us.schneider-electric.com

Technical Information:

UL File:	E78403 CCN NKCR
CSA File:	LR24590 Class 3211-03
CE Marked:	Yes
RoHS:	Yes
NEMA / IP Rating:	NEMA 1/2/3/3R/4/4X/6/12/13 Water tight, Dust tight, Oil tight and Corrosion Resistant (Industrial Use)
Key Number:	n/a
Key Removal:	n/a
Light Module Supply Voltage:	not applicable
Light Module Type:	not applicable
Number of Operators:	1

Description:
Ring Nut Material:
Operator Type:
Operator Action:
Button Type:
Guard Type:
Button/Cap Color:
Lens Type:
Lens Color:
Knob Type:
Knob Color:
Number of Positions:

30mm Push Button
Black Plastic
Non-Illuminated
Momentary (Push/Pull) - Maintained (Neutral)
Screw-On Mushroom Operator (mushroom head not included)
No Guard
No Button
not applicable
not applicable
not applicable
n/a
3

Specification: