



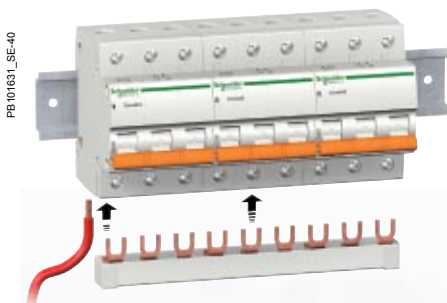

Distribution of electrical power supply in an enclosure. Quick assembly and disassembly of the devices connected.

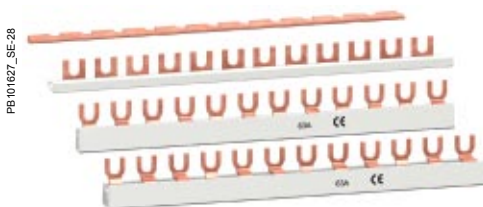

| CBB1V1012...CBB3U1057 | | 10355...10660 |
|------------------------------|------------------|-------------------------|
| Technical data | | |
| Compliance with standards | | IEC 60439-1, EN 60439-1 |
| Rated current | | 63 A |
| Voltage rating | Phase-to-neutral | 230 V AC |
| | Phase-to-phase | 400 V AC |

These comb busbars can only be mounted on Domae devices of the biconnect type.

| Power supply | | |
|---|--|--|
| The comb busbars are supplied directly in the tunnel terminals provided on the device (25 mm ² rigid or 16 mm ² flexible cable) | | |

Pre-cut comb busbars

| Type | Rating (A) | Width in mod. of 9 mm | Description | Cat. no. |
|------|------------|-----------------------|---|------------------------|
| 1 Ph | 63 | 24 | 1 x 12-module comb busbar 1 x 10 mm ² | 10355 CBB1V1012 |
| | | | 1 x 12-module bare comb busbar 1 x 10 mm ² | 10655 CBB1T1012 |
| 2 Ph | 63 | 24 | 1 x 12-module comb busbar 2 x 10 mm ² | 10358 CBB2U1012 |
| 3 Ph | 63 | 24 | 1 x 12-module comb busbar 3 x 10 mm ² | 10656 CBB3U1012 |

1 m long comb busbars

| Type | Rating (A) | Length (m) | Description | Cat. no. |
|------|------------|------------|--|------------------------|
| 1 Ph | 63 | 1 | 1 recuttable 1 m bar 1 x 10 mm ² | 10357 CBB1V1057 |
| | | | 1 bare recuttable 1 m bar 1 x 10 mm ² | 10645 CBB1T1057 |
| 2 Ph | 63 | 1 | 1 recuttable 1 m bar 2 x 10 mm ² | 10281 CBB2U1057 |
| 3 Ph | 63 | 1 | 1 recuttable 1 m bar 3 x 10 mm ² | 10660 CBB3U1057 |

| Accessories | | Cat. no. |
|---|--|-----------------------|
| 1 set of four 35 mm ² connectors | | 10397 CBB1C35A |
| 1 set of 10 bar end pieces (2 phases) | | 10398 CBB2GA |
| 1 set of 10 bar end-pieces (3 phases) | | 10399 CBB3GA |
| 1 set of 10 tooth shields | | 10396 CBB1EA |



⁽¹⁾ For information only. To cancel when you create your local catalogue.