



Produce ergonomic, practical and attractive electrical switchboards.



066137-45



066124HD-55

13366...13370, 13922...13923, 13376...13380, 13912...13913

Technical data


Compliance with standards	IEC 60439-3 (EN 60439-3)	
Rated current (In)	4-module enclosure	50 A
	6- to 36-module enclosures	63 A
Rated insulation voltage (Ui)	< 690 V	
Insulation	Class 2 (with plugs on fastening screws), as per IEC 60439-3	
Degree of protection	IP 40	
Materials	Self-extinguishing plastic: abnormal heat and fire withstand at 650°C as per IEC 60695-2-11	
Colour	Enclosure and opaque door	White RAL 9003

Number of rows	Capacity in modules of		Outside dimensions (mm)			Delivered with terminal blocks (1) nb x nb of points	Cat. no. enclosure	
	9 mm	18 mm	H	W	D		opaque door	transparent smoked door
1	8	4	200	112	94	2 x 4	13376	13366
	12	6	200	148	94	2 x 4	13377	13367
	16	8	200	184	94	2 x 8	13378	13368
	24	12	200	256	94	(2 x 4) + (2 x 8)	13379	13369
	36	18	221	364	100	2 x 16	13380	13370
2	48 (2 x 24)	24 (2 x 12)	326	256	96	2 x 16	13912	13922
3	72 (3 x 24)	36 (3 x 12)	451	256	96	2 x 22	13913	13923

066156-35



Exploded view

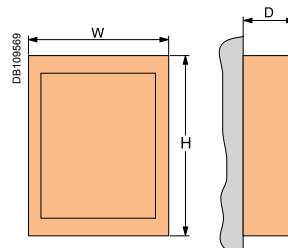

Outside dimensions

Accessories delivered with each enclosure

2 earth/neutral connection terminal blocks with supports (1)

066148



Insulating plugs for fastening screws

1 identification label per row

Connection accessories

Type	Width (mm)	For enclosures with number of modules	Cat. no.
Terminal block support	90	4	13361
	105	6	13362
	140	8	13363
	210	12	13364
	320	18	13381
	210	24 (2 x 12)	13364
Terminal blocks	210	36 (3 x 12)	13364
	Number of points	4	10235
		8	10236

PB101628



13663

PB101623



10236