

Pragma UP enclosures

Flush-mounted

Produce ergonomic, practical and attractive electrical switchboards.




PRAUP112...PRAUP412 10935...10938

Technical data		
Compliance with standards	IEC 60439-3 et DIN 43871	
Rated current (In)	63 A	
Rated insulation voltage (Ui)	< 690 V	
Insulation	Class 2 as per IEC 60439-3	
Degree of protection	IP 40	
Materials	Back and front plate	Self-extinguishing plastic: abnormal heat and fire withstand at 650°C as per IEC 60695-2-11
	Door and door frame	Electrolytic galvanised steel plate with lead-free and cadmium-free painting
Colour	Of enclosure and door	White RAL 9010


Number of rows	Capacity in modules of		Dimensions (mm)						Cat. no.	
	9 mm	18 mm	flush mnt			outside				
			H1	W	D	H2	W	D		
1	24	12	290	333	92	311	361	7	10935	PRAUP112
2	48 (2 x 24)	24 (2 x 12)	415	333	92	436	361	7	10936	PRAUP212
3	72 (3 x 24)	36 (3 x 12)	560	333	92	581	361	7	10937	PRAUP312
4	96 (3 x 24)	48 (3 x 12)	685	333	92	706	361	7	10938	PRAUP412




Exploded view

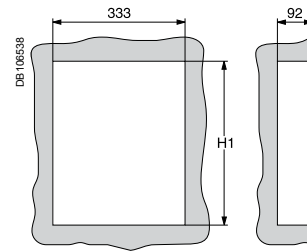

Flush mounting dimensions

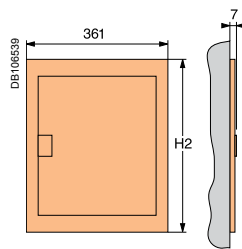

Outside dimensions

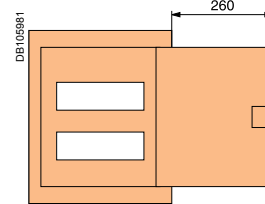

Accessories delivered with each enclosure

2 x 10 mm ² earth/neutral connection terminal blocks with supports	1- and 2-row enclosures	16 points (12 x 4 mm ² + 4 x 25 mm ²)
	3- and 4-row enclosures	24 points (18 x 4 mm ² + 6 x 25 mm ²)
1 identification label		



Optional accessories for connection

Type		Cat. no.
36-point terminal block	(30 x 4 mm ² + 6 x 16 mm ²)	10950 PRAUPTB36



4-point neutral terminal block	(3 x 4 mm ² + 1 x 25 mm ²)	10955 PRAUPTB4
--------------------------------	---	----------------



for installation

Type	Cat. no.
Association kit	10939 PRAUPAS



Gypsum board mounting kit	10960 PRAUPGB
---------------------------	---------------



Mounting lugs	10965 PRAUPLUG
---------------	----------------



for finishing

Type	Cat. no.
Splittable blanking plate strip	10945 PRAUPBLP



Lock + key	10940 PRAUPKEY
------------	----------------



See catalogue page 93032