



by Schneider Electric

## Basic Rack PDU


### Overview

The APC by Schneider Electric Basic Rack PDU distributes power to devices in the rack.

**Outlets.** The Rack PDU has twenty-one (21) NEMA 5-20 outlets and six (6) NEMA L6-20 outlets.

**Power cord.** The 3-foot (0.91-meter) power cord terminates with a NEMA L21-20 connector.

### AP7563

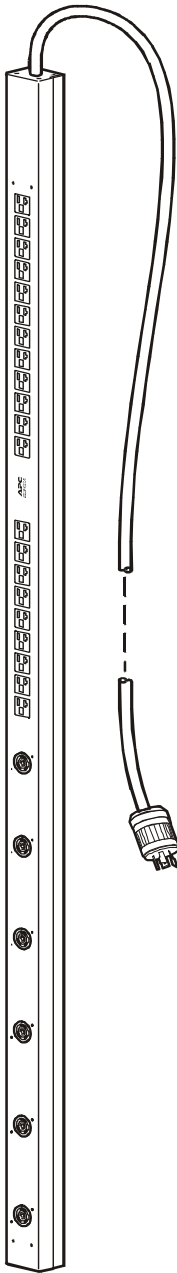

# Specifications for AP7563

---

## Electrical

---

Input connector	NEMA L21-20 plug
Output connectors	(21) NEMA 5-20 outlets (6) NEMA L6-20 outlets
Nominal input voltage	120/208 VAC, 3-phase
Acceptable input voltage	± 10% of nominal voltage
Input frequency	47–63 Hz

---

## Physical

---

Dimensions (H × W × D)	70.00 × 2.19 × 1.73 in (177.80 × 5.56 × 4.39 cm)
Shipping dimensions (H × W × D)	84.00 × 6.00 × 5.00 in (213.36 × 15.24 × 12.7 cm)
Weight	12lb (5.44kg)
Shipping weight	19.5lb (8.85kg)

---

## Environmental

---

Maximum elevation (above MSL)	
Operating	15,000 ft (4500 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	–5 to 45° C (23 to 115° F)
Storage	–25 to 65° C (–13 to 149° F)
Humidity	
Operating	5–95% RH non-condensing
Storage	5–95% RH non-condensing

---

## Compliance

---

Safety verification	cULus
---------------------	-------

---

You can find customer support and warranty information on the APC website, [www.apc.com](http://www.apc.com).

© 2021 APC by Schneider Electric. All rights reserved.