


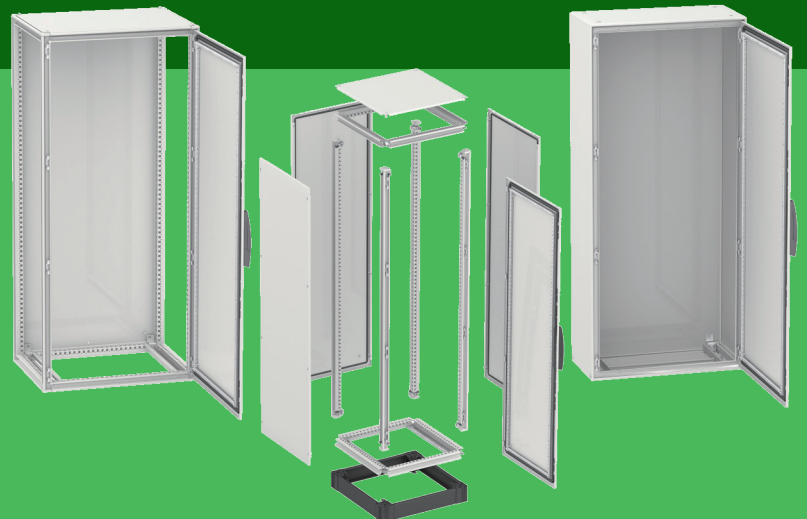


Spacial steel SF and SM enclosures

The flexible, robust, and easy-to-assemble steel floor standing enclosure



schneider-electric.us

 Life Is On



Spacial SF steel floor-standing enclosures


Multi-purpose IP55 modular steel enclosure.



Adapts to all your needs. Assembled delivery for a ready-to-use solution.




Adapts to customer needs. Delivered as kit, with up to 600 different possible configurations.

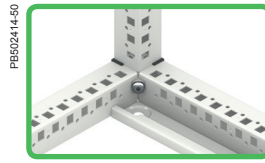


Robust

- Structure formed from a single 15/10°-mm galvanised-steel section, with a high rigidity.
- Vertical uprights screwed with connections of full steel. Placement and screwing at the corners of top and bottom frames. Mounting by 8 screws at each corner.
- Capable of withstanding 1000 kg distributed in its volume.

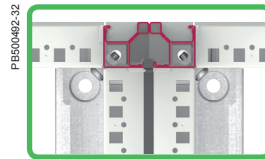

Reliable

- The design of the profile creates a double protective barrier against the entry of water and dust when coupling two enclosures.
- The first barrier is the metal connection of the sections, and the second barrier is the EPaDM gasket that guarantees the sealing.

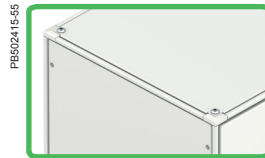

Aesthetics

- The built-in panels and handle with new design give the enclosure a new appearance.




Comfort

- Handle with robust design for easily activating the locking system, allowing the installation of any shape insert and any cylindrical combination key.
- Panels with captive screws for easier assembly and dismantling.




Practical

- Suspension of the rear panel using a self-centering piece to facilitate screwing.

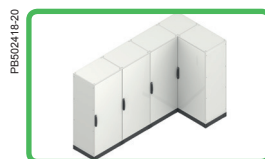


Simple

- The new design allows enclosures to be coupled in any direction, adapting to all installation surfaces.

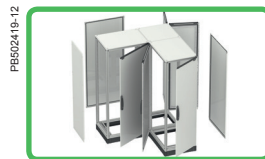

Accessible

- The symmetric design of the profile allows doors to be installed on any side of the enclosure, opening to right or left, providing full accessibility to the enclosure.

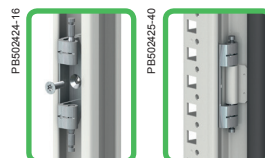

Fast

- The double system of cut-outs on the structure allows most accessories to be installed using self-tapping TORX T30 M6 screws or nuts.
- Clip-on quick-mounting cross rails, fixed with self-tapping screws.
- Door installation inserting the captive pins of the hinge in their housing in the door.

Spacial SM steel floor-standing enclosures


SM

Multi-purpose IP55 compact steel enclosure for fast and simple solutions.



Robust

- Body made as a single piece with welded rear panel.
- Front part forming a rigid frame with welded corners.

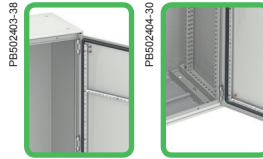

Practical

- Door rails, which can be height-adjustable and used for mounting cables.
- The adaptation profile installed in the front of the enclosure and the universal 40-mm cross rail (1 row) in the rear provide the same mounting points as the modular enclosure.



Protection

- IP guaranteed by the rigidity of the enclosure, the expanded-polyurethane sealing gasket of the enclosure and the subsequent welding.
- Double-door enclosures with inner lock on the left door.



Comfort

- Handle with sturdy design for easily activating the locking system, allowing the installation of any shape insert and any cylindrical combination key.
- Easily interchangeable insert with one click.

This range can be configured according to your needs

4 different services available:



Assemble to order



Mounting of standard accessories





Painting



Machining

Spacial SF and SM floor-standing enclosures

Characteristics

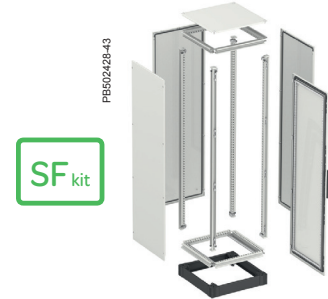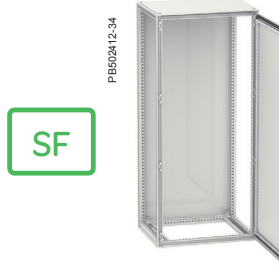


Characteristics	Compact enclosures Spacial SM	Suitable enclosures Spacial SF - Assembled supply	Suitable enclosures Spacial SF - Supplied as a kit
	<p>Compact body with a front rigid frame with welded corners and rear panel 4 supports installed in depth to adjust and fix the equipment with a pitch of 25 mm</p> <p>Basic composition</p> <ul style="list-style-type: none"> • Front door with a reinforcement frame (horizontal rails height-adjustable) • The double doors are overlapping, with system for mounting the left door • Door reversible, 120° opening • Welded rear panel • 4 locking points system with handle 5 mm double-bar insert • Cable-gland plate 1 entry • Mounting plate support brackets <p>Versions / Configurations</p> <ul style="list-style-type: none"> • Compact enclosure with plain door and mounting plate • Compact enclosure with plain door and without mounting plate • Compact enclosure with transparent Securit® glass door and without mounting plate <p>Protection of personnel Earthing accessories needed to ensure the grounding continuity</p>	<p>Structure made up of vertical uprights joined with top and bottom frames Panels and doors built into the structure Formed from a single section and perforated structure with a pitch of 25 mm</p> <p>Basic composition</p> <ul style="list-style-type: none"> • Front door with a reinforcement frame (horizontal rails height-adjustable) and a trim plate • The double doors are overlapping, with system for mounting the left door • Door reversible, 120° opening • Rear panel screwed on with captive screws • Removable roof • 4 locking points system with handle 5 mm double-bar insert • Mounting plate support brackets • Mounting plate sliding rails • 2 quick mounting cross rails <p>Versions / Configurations</p> <ul style="list-style-type: none"> • Modular enclosure with plain door and mounting plate • Modular enclosure with plain door and without mounting plate • Modular enclosure with transparent Securit® glass door and without mounting plate <p>Protection of personnel Earthing accessories needed to ensure the grounding continuity</p>	<p>Structure made up of vertical uprights joined with top and bottom frames Panels and doors built into the structure Formed from a single section and perforated structure with a pitch of 25 mm</p> <p>Basic composition</p> <ul style="list-style-type: none"> • Front door with a reinforcement frame (horizontal rails height-adjustable) • The double doors are overlapping, with system for mounting the left door • Door reversible, 120° opening • Rear panel to be screwed on with captive screws • Removable roof delivered with top frame • 4 locking points system with handle 5 mm double-bar insert • Mounting plate support brackets delivered with top & bottom frames kit • Mounting plate sliding rails delivered with top & bottom frames kit • 2 quick mounting cross rails delivered with top & bottom frames kit <p>Versions / Configurations</p> <ul style="list-style-type: none"> • Uprights kit • Top and bottom frames kit • Rear panel kit • Door kit (plain or transparent) <p>Protection of personnel Earthing accessories needed to ensure the grounding continuity, see page 300</p>
Material	Sheet steel	Sheet steel	
Finish	Textured finish with epoxy-polyester powder	Textured finish with epoxy-polyester powder	
Colour	RAL 7035 grey	RAL 7035 grey	
Ingress protection rating	IP55 according to IEC 60529	IP55 according to IEC 60529	IP55 according to IEC 60529
Mechanical protection rating	IK10 for plain door and IK08 for transparent door according to IEC 62262	IK10 for plain door and IK08 for transparent door according to IEC 62262	IK10 for plain door and IK08 for transparent door according to IEC 62262
Standards	Compliance with enclosure standard IEC 62208 and the RoHS directive	Compliance with enclosure standard IEC 62208 and the RoHS directive	
Certifications	BV, DNV, UL * and cUL *1 door: 1, 2, 3R, 4, 5, 12K and 13 *2 doors: 1, 12, 12K	BV, DNV, UL and cUL* *1 door: 1, 3R, 12, 12K *2 doors: 1, 3R, 12, 12K	BV, DNV, UL and cUL* *1 door: 1, 3R, 12, 12K *2 doors: 1, 3R, 12, 12K
Installation	Indoor / Outdoor* installation * Compliant with IEC 62208 regarding type tests specified in §9.12 (resistance to UV radiation) and §9.13 (resistance to corrosion) Outdoor installation: canopy needed to avoid water stagnation on the upper part of the enclosure	Indoor / Outdoor* installation * Compliant with IEC 62208 regarding type tests specified in §9.12 (resistance to UV radiation) and §9.13 (resistance to corrosion) Outdoor installation: canopy needed to avoid water stagnation on the upper part of the enclosure	Indoor / Outdoor* installation * Compliant with IEC 62208 regarding type tests specified in §9.12 (resistance to UV radiation) and §9.13 (resistance to corrosion) Outdoor installation: canopy needed to avoid water stagnation on the upper part of the enclosure
Maximum load	700	1000	1000
Options	<ul style="list-style-type: none"> • Plinths, heights 100 mm and 200 mm • Lifting eyebolts • Internal door • Door accessories • Other locking options • Mounting plates and Telequick system 	<ul style="list-style-type: none"> • Side panels options • Enclosure suites options • Plinths, heights 100 mm and 200 mm • Cable-gland plates • Lifting systems • Roof options • Door accessories • Other locking options • Mounting plates and Telequick system 	<ul style="list-style-type: none"> • Door trim plates • Side panels options • Enclosure suites options • Plinths, heights 100 mm and 200 mm, • Cable-gland plates • Lifting systems • Roof options • Other locking options • Mounting plates and Telequick system

Wide range of accessories

We offer many accessories to ease all the interactions with the enclosure, especially during installation.

Composition accessories

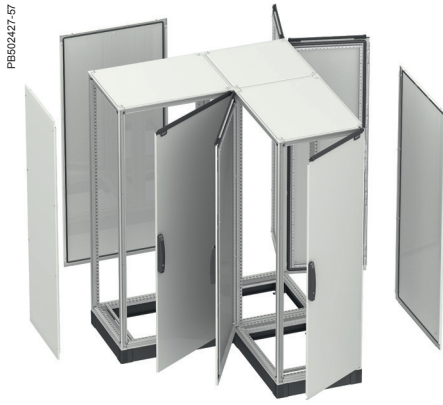


Panels




Coupling accessories



Roofs

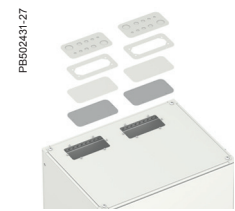

Wall-mounting

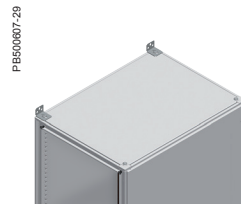


Floor



Cable entry



Lifting systems

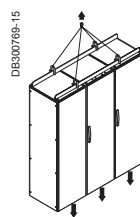


Doors




Locking systems




Installation accessories

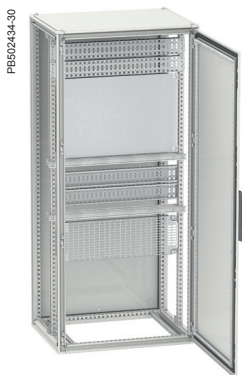

Mounting accessories

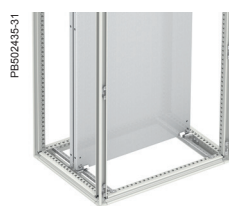


Telequick system

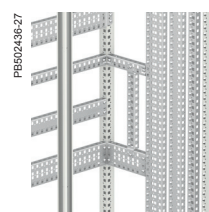


See catalog for specific accessories

Selection Guide

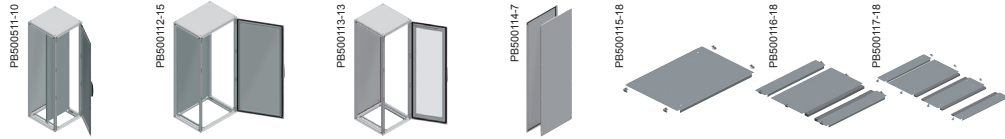

Nominal dimensions - mm (in)			No. of Door doors	Plain			Transparent	Side panels	Cable-entry plate		
Height (A)	Width (B)	Depth (C)		With mounting plate	Without mounting plate	Without mounting plate		Plain	1 entry	2 entries	
1200 (47.2)	600 (23.6)	400 (15.6)	1	NSYSF12640P	NSYSF12640	-	NSY2SP124	NSYEC64	NSYEC641	-	
		600 (23.6)	1	NSYSF12660P	NSYSF12660	-	NSY2SP126	NSYEC66	NSYEC661	NSYEC662	
	800 (31.5)	400 (15.6)	1	NSYSF12840P	NSYSF12840	-	NSY2SP124	NSYEC84	NSYEC841	-	
		600 (23.6)	1	NSYSF12860P	NSYSF12860	-	NSY2SP126	NSYEC86	NSYEC861	NSYEC862	
1400 (55.1)	600 (23.6)	400 (15.6)	1	NSYSF14640P	NSYSF14640	-	NSY2SP144	NSYEC64	NSYEC641	-	
	800 (31.5)	400 (15.6)	1	NSYSF14840P	NSYSF14840	-	NSY2SP144	NSYEC84	NSYEC841	-	
1600 (63.0)	600 (23.6)	600 (23.6)	1	NSYSF16660P	NSYSF16660	-	NSY2SP166	NSYEC66	NSYEC661	NSYEC662	
		800 (31.5)	1	NSYSF16680P	NSYSF16680	-	NSY2SP168	NSYEC68	NSYEC681	NSYEC682	
		600 (23.6)	1	NSYSF16860P	NSYSF16860	-	NSY2SP166	NSYEC86	NSYEC861	NSYEC862	
		800 (31.5)	1	NSYSF16880P	NSYSF16880	-	NSY2SP168	NSYEC88	NSYEC881	NSYEC882	
1800 (70.9)	400 (15.6)	400 (15.6)	1	-	NSYSF18440	-	NSY2SP184	NSYEC44	NSYEC441	-	
		500 (19.7)	1	-	NSYSF18450	-	NSY2SP185	NSYEC45	NSYEC451	-	
		600 (23.6)	1	-	NSYSF18460	-	NSY2SP186	-	NSYEC461	-	
		400 (15.6)	1	NSYSF18640P	NSYSF18640	NSYSF18640T	NSY2SP184	NSYEC64	NSYEC641	-	
	600 (23.6)	500 (19.7)	1	NSYSF18650P	NSYSF18650	NSYSF18650T	NSY2SP185	NSYEC65	NSYEC651	-	
		600 (23.6)	1	NSYSF18660P	NSYSF18660	-	NSY2SP186	NSYEC66	NSYEC661	NSYEC662	
		800 (31.5)	1	-	-	NSYSF18680T	NSY2SP188	NSYEC68	NSYEC681	NSYEC682	
		400 (15.6)	1	NSYSF18840P	NSYSF18840	NSYSF18840T	NSY2SP184	NSYEC84	NSYEC841	-	
	800 (31.5)	500 (19.7)	1	NSYSF18850P	NSYSF18850	NSYSF18850T	NSY2SP185	NSYEC85	NSYEC851	-	
		600 (23.6)	1	NSYSF18860P	NSYSF18860	NSYSF18860T	NSY2SP186	NSYEC86	NSYEC861	NSYEC862	
		600 (23.6)	2	NSYSF188602DP	NSYSF188602D	-	NSY2SP186	NSYEC86	NSYEC861	NSYEC862	
		400 (15.6)	1	NSYSF181040P	NSYSF181040	-	NSY2SP184	NSYEC104	NSYEC1041	-	
	1000 (39.4)	400 (15.6)	2	NSYSF1810402DP	NSYSF1810402D	-	NSY2SP184	NSYEC104	NSYEC1041	-	
		500 (19.7)	1	NSYSF181050P	NSYSF181050	-	NSY2SP185	NSYEC105	NSYEC1051	-	
		600 (23.6)	1	NSYSF181060P	NSYSF181060	-	NSY2SP186	NSYEC106	NSYEC1061	NSYEC1062	
		600 (23.6)	2	NSYSF1810602DP	NSYSF1810602D	-	NSY2SP186	NSYEC106	NSYEC1061	NSYEC1062	
1200 (47.2)	400 (15.6)	2	NSYSF1812402DP	NSYSF1812402D	-	NSY2SP184	NSYEC124	NSYEC1241	-		
	500 (19.7)	2	NSYSF1812502DP	NSYSF1812502D	-	NSY2SP185	NSYEC125	NSYEC1251	-		
	600 (23.6)	2	NSYSF1812602DP	NSYSF1812602D	-	NSY2SP186	NSYEC126	NSYEC1261	NSYEC1262		
	500 (19.7)	1	-	NSYSF20350	-	NSY2SP205	NSYEC35	NSYEC351	-		
2000 (78.7)	300 (11.8)	600 (23.6)	1	-	NSYSF20360	-	NSY2SP206	NSYEC36	NSYEC361	-	
		800 (31.5)	1	-	NSYSF20380	-	NSY2SP208	-	NSYEC381	-	
		400 (15.6)	1	-	NSYSF20440	-	NSY2SP204	NSYEC44	NSYEC441	-	
	400 (15.6)	500 (19.7)	1	-	NSYSF20450	-	NSY2SP205	NSYEC45	NSYEC451	-	
		600 (23.6)	1	-	NSYSF20460	-	NSY2SP206	NSYEC64	NSYEC461	-	
		800 (31.5)	1	-	NSYSF20480	-	NSY2SP208	NSYEC84	NSYEC481	-	
		400 (15.6)	1	NSYSF20640P	NSYSF20640	NSYSF20640T	NSY2SP204	NSYEC64	NSYEC641	-	
	600 (23.6)	500 (19.7)	1	NSYSF20650P	NSYSF20650	NSYSF20650T	NSY2SP205	NSYEC65	NSYEC651	-	
		600 (23.6)	1	NSYSF20660P	NSYSF20660	-	NSY2SP206	NSYEC66	NSYEC661	NSYEC662	
		800 (31.5)	1	NSYSF20680P	NSYSF20680	-	NSY2SP208	NSYEC68	NSYEC681	NSYEC682	
		400 (15.6)	1	NSYSF20840P	NSYSF20840	NSYSF20840T	NSY2SP204	NSYEC84	NSYEC841	-	
	800 (31.5)	500 (19.7)	1	NSYSF20850P	NSYSF20850	NSYSF20850T	NSY2SP205	NSYEC85	NSYEC851	-	
		600 (23.6)	1	NSYSF20860P	NSYSF20860	NSYSF20860T	NSY2SP206	NSYEC86	NSYEC861	NSYEC862	
		600 (23.6)	2	NSYSF208602DP	NSYSF208602D	-	NSY2SP206	NSYEC86	NSYEC861	NSYEC862	
		800 (31.5)	1	NSYSF20880P	NSYSF20880	NSYSF20880T	NSY2SP208	NSYEC88	NSYEC881	NSYEC882	
	1000 (39.4)	400 (15.6)	1	NSYSF201040P	NSYSF201040	NSYSF201040T	NSY2SP204	NSYEC104	NSYEC1041	-	
400 (15.6)		2	NSYSF2010402DP	NSYSF2010402D	-	NSY2SP204	NSYEC104	NSYEC1041	-		
500 (19.7)		1	NSYSF201050P	NSYSF201050	NSYSF201050T	NSY2SP205	NSYEC105	NSYEC1051	-		
500 (19.7)		2	NSYSF2010502DP	NSYSF2010502D	-	NSY2SP205	NSYEC105	NSYEC1051	-		
600 (23.6)		1	NSYSF201060P	NSYSF201060	NSYSF201060T	NSY2SP206	NSYEC106	NSYEC1061	NSYEC1062		
600 (23.6)		2	NSYSF2010602DP	NSYSF2010602D	-	NSY2SP206	NSYEC106	NSYEC1061	NSYEC1062		
800 (31.5)		1	NSYSF201080P	NSYSF201080	-	NSY2SP208	NSYEC108	NSYEC1081	NSYEC1082		
400 (15.6)		2	NSYSF2012402DP	NSYSF2012402D	-	NSY2SP204	NSYEC124	NSYEC1241	-		
1200 (47.2)	500 (19.7)	2	NSYSF2012502DP	NSYSF2012502D	-	NSY2SP205	NSYEC125	NSYEC1251	-		
	600 (23.6)	2	NSYSF2012602DP	NSYSF2012602D	-	NSY2SP206	NSYEC126	NSYEC1261	NSYEC1262		
	800 (31.5)	2	NSYSF2012802DP	NSYSF2012802D	-	NSY2SP208	NSYEC128	NSYEC1281	NSYEC1282		
	400 (15.6)	2	NSYSF2016402DP	NSYSF2016402D	-	NSY2SP204	NSYEC164	NSYEC1641	-		
1600 (63.0)	500 (19.7)	2	NSYSF2016502DP	NSYSF2016502D	-	NSY2SP205	NSYEC165	NSYEC1651	-		
	600 (23.6)	2	NSYSF2016602DP	NSYSF2016602D	-	NSY2SP206	NSYEC166	NSYEC1661	NSYEC1662		
	600 (23.6)	1	-	NSYSF22460	-	NSY2SP226	-	NSYEC461	-		
	600 (23.6)	1	NSYSF22660P	NSYSF22660	-	NSY2SP226	NSYEC66	NSYEC661	NSYEC662		
800 (31.5)	800 (31.5)	1	NSYSF22680P	NSYSF22680	-	NSY2SP228	NSYEC68	NSYEC681	NSYEC682		
	600 (23.6)	1	NSYSF22860P	NSYSF22860	-	NSY2SP226	NSYEC86	NSYEC861	NSYEC862		
	800 (31.5)	1	NSYSF22880P	NSYSF22880	NSYSF22880T	NSY2SP228	NSYEC88	NSYEC881	NSYEC882		
	600 (23.6)	1	NSYSF221060P	NSYSF221060	-	NSY2SP226	NSYEC106	NSYEC1061	NSYEC1062		
1000 (39.4)	600 (23.6)	2	NSYSF2212602DP	NSYSF2212602D	-	NSY2SP226	NSYEC126	NSYEC1261	NSYEC1262		
	800 (31.5)	2	NSYSF2212802DP	NSYSF2212802D	-	NSY2SP228	NSYEC128	NSYEC1281	NSYEC1282		

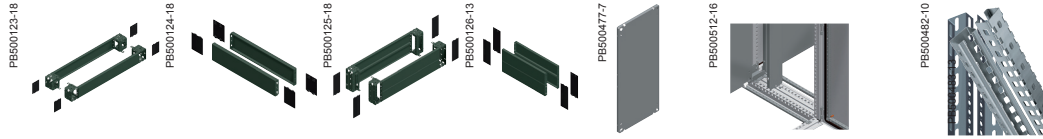


Nominal dimension- mm (in)			Plinth				Mounting plate	Intermediate mounting plate	Vertical uprights		
Height (A)	Width (B)	Depth (C)	Height 100 mm		Height 200 mm				Standard	Technical	
			Front kit (corners + front panels)	Side panels, 2 u.	Front kit (corners + front panels)	Side panels, 4 u.					
1200 (47.2)	600 (23.6)	400 (15.6)	NSYSPF6100	NSYSPS4100	NSYSPF6200	NSYSPS4200	NSYMP126	NSYSIMP12	-	NSYTVR12	
		600 (23.6)	NSYSPF6100	NSYSPS6100	NSYSPF6200	NSYSPS6200	NSYMP126	NSYSIMP12	-	NSYTVR12	
	800 (31.5)	400 (15.6)	NSYSPF8100	NSYSPS4100	NSYSPF8200	NSYSPS4200	NSYMP128	NSYSIMP12	-	NSYTVR12	
		600 (23.6)	NSYSPF8100	NSYSPS6100	NSYSPF8200	NSYSPS6200	NSYMP128	NSYSIMP12	-	NSYTVR12	
1400 (55.1)	600 (23.6)	400 (15.6)	NSYSPF6100	NSYSPS4100	NSYSPF6200	NSYSPS4200	NSYMP146	NSYSIMP14	-	NSYTVR14	
	800 (31.5)	400 (15.6)	NSYSPF8100	NSYSPS4100	NSYSPF8200	NSYSPS4200	NSYMP148	NSYSIMP14	-	NSYTVR14	
1600 (63.0)	600 (23.6)	600 (23.6)	NSYSPF6100	NSYSPS6100	NSYSPF6200	NSYSPS6200	NSYMP166	NSYSIMP16	-	NSYTVR16	
		800 (31.5)	NSYSPF6100	NSYSPS8100	NSYSPF6200	NSYSPS8200	NSYMP166	NSYSIMP16	-	NSYTVR16	
	800 (31.5)	600 (23.6)	NSYSPF8100	NSYSPS6100	NSYSPF8200	NSYSPS6200	NSYMP168	NSYSIMP16	-	NSYTVR16	
		800 (31.5)	NSYSPF8100	NSYSPS8100	NSYSPF8200	NSYSPS8200	NSYMP168	NSYSIMP16	-	NSYTVR16	
1800 (70.9)	400 (15.6)	400 (15.6)	NSYSPF4100	NSYSPS4100	NSYSPF4200	NSYSPS4200	-	-	NSYVR18	NSYTVR18	
		500 (20.0)	NSYSPF4100	NSYSPS5100	NSYSPF4200	NSYSPS5200	-	-	NSYVR18	NSYTVR18	
		600 (23.6)	NSYSPF4100	NSYSPS6100	NSYSPF4200	NSYSPS6200	-	-	NSYVR18	NSYTVR18	
		400 (15.6)	NSYSPF6100	NSYSPS4100	NSYSPF6200	NSYSPS4200	NSYMP186	NSYSIMP18	NSYVR18	NSYTVR18	
	600 (23.6)	500 (20.0)	NSYSPF6100	NSYSPS5100	NSYSPF6200	NSYSPS5200	NSYMP186	NSYSIMP18	NSYVR18	NSYTVR18	
		600 (23.6)	NSYSPF6100	NSYSPS6100	NSYSPF6200	NSYSPS6200	NSYMP186	NSYSIMP18	NSYVR18	NSYTVR18	
		800 (31.5)	NSYSPF6100	NSYSPS8100	NSYSPF6200	NSYSPS8200	NSYMP186	NSYSIMP18	NSYVR18	NSYTVR18	
		400 (15.6)	NSYSPF8100	NSYSPS4100	NSYSPF8200	NSYSPS4200	NSYMP188	NSYSIMP18	NSYVR18	NSYTVR18	
	500 (20.0)	NSYSPF8100	NSYSPS5100	NSYSPF8200	NSYSPS5200	NSYMP188	NSYSIMP18	NSYVR18	NSYTVR18		
		600 (23.6)	NSYSPF8100	NSYSPS6100	NSYSPF8200	NSYSPS6200	NSYMP188	NSYSIMP18	NSYVR18	NSYTVR18	
		600 (23.6)	NSYSPF8100	NSYSPS6100	NSYSPF8200	NSYSPS6200	NSYMP188	NSYSIMP18	NSYVR18	NSYTVR18	
		400 (15.6)	NSYSPF10100	NSYSPS4100	NSYSPF10200	NSYSPS4200	NSYMP1810	NSYSIMP18	NSYVR18	NSYTVR18	
	1000 (39.4)	400 (15.6)	NSYSPF10100	NSYSPS4100	NSYSPF10200	NSYSPS4200	NSYMP1810	NSYSIMP18	NSYVR18	NSYTVR18	
		500 (20.0)	NSYSPF10100	NSYSPS5100	NSYSPF10200	NSYSPS5200	NSYMP1810	NSYSIMP18	NSYVR18	NSYTVR18	
		600 (23.6)	NSYSPF10100	NSYSPS6100	NSYSPF10200	NSYSPS6200	NSYMP1810	NSYSIMP18	NSYVR18	NSYTVR18	
		600 (23.6)	NSYSPF10100	NSYSPS6100	NSYSPF10200	NSYSPS6200	NSYMP1810	NSYSIMP18	NSYVR18	NSYTVR18	
	1200 (47.2)	400 (15.6)	NSYSPF12100	NSYSPS4100	NSYSPF12200	NSYSPS4200	NSYMP1812	NSYSIMP18	NSYVR18	NSYTVR18	
		500 (20.0)	NSYSPF12100	NSYSPS5100	NSYSPF12200	NSYSPS5200	NSYMP1812	NSYSIMP18	NSYVR18	NSYTVR18	
		600 (23.6)	NSYSPF12100	NSYSPS6100	NSYSPF12200	NSYSPS6200	NSYMP1812	NSYSIMP18	NSYVR18	NSYTVR18	
		600 (23.6)	NSYSPF12100	NSYSPS6100	NSYSPF12200	NSYSPS6200	NSYMP1812	NSYSIMP18	NSYVR18	NSYTVR18	
	2000 (78.7)	300 (11.8)	500 (20.0)	NSYSPF3100	NSYSPS5100	NSYSPF3200	NSYSPS5200	-	-	NSYVR20	NSYTVR20
			600 (23.6)	NSYSPF3100	NSYSPS6100	NSYSPF3200	NSYSPS6200	-	-	NSYVR20	NSYTVR20
			800 (31.5)	NSYSPF3100	NSYSPS8100	NSYSPF3200	NSYSPS8200	-	-	NSYVR20	NSYTVR20
		400 (15.6)	400 (15.6)	NSYSPF4100	NSYSPS4100	NSYSPF4200	NSYSPS4200	-	-	NSYVR20	NSYTVR20
500 (20.0)			NSYSPF4100	NSYSPS5100	NSYSPF4200	NSYSPS5200	-	-	NSYVR20	NSYTVR20	
600 (23.6)			NSYSPF4100	NSYSPS6100	NSYSPF4200	NSYSPS6200	-	-	NSYVR20	NSYTVR20	
800 (31.5)			NSYSPF4100	NSYSPS8100	NSYSPF4200	NSYSPS8200	-	-	NSYVR20	NSYTVR20	
600 (23.6)		400 (15.6)	NSYSPF6100	NSYSPS4100	NSYSPF6200	NSYSPS4200	NSYMP206	NSYSIMP20	NSYVR20	NSYTVR20	
		500 (20.0)	NSYSPF6100	NSYSPS5100	NSYSPF6200	NSYSPS5200	NSYMP206	NSYSIMP20	NSYVR20	NSYTVR20	
		600 (23.6)	NSYSPF6100	NSYSPS6100	NSYSPF6200	NSYSPS6200	NSYMP206	NSYSIMP20	NSYVR20	NSYTVR20	
		800 (31.5)	NSYSPF6100	NSYSPS8100	NSYSPF6200	NSYSPS8200	NSYMP206	NSYSIMP20	NSYVR20	NSYTVR20	
800 (31.5)		400 (15.6)	NSYSPF8100	NSYSPS4100	NSYSPF8200	NSYSPS4200	NSYMP208	NSYSIMP20	NSYVR20	NSYTVR20	
		500 (20.0)	NSYSPF8100	NSYSPS5100	NSYSPF8200	NSYSPS5200	NSYMP208	NSYSIMP20	NSYVR20	NSYTVR20	
		600 (23.6)	NSYSPF8100	NSYSPS6100	NSYSPF8200	NSYSPS6200	NSYMP208	NSYSIMP20	NSYVR20	NSYTVR20	
		800 (31.5)	NSYSPF8100	NSYSPS8100	NSYSPF8200	NSYSPS8200	NSYMP208	NSYSIMP20	NSYVR20	NSYTVR20	
1000 (39.4)		400 (15.6)	NSYSPF10100	NSYSPS4100	NSYSPF10200	NSYSPS4200	NSYMP2010	NSYSIMP20	NSYVR20	NSYTVR20	
		400 (15.6)	NSYSPF10100	NSYSPS4100	NSYSPF10200	NSYSPS4200	NSYMP2010	NSYSIMP20	NSYVR20	NSYTVR20	
		500 (20.0)	NSYSPF10100	NSYSPS5100	NSYSPF10200	NSYSPS5200	NSYMP2010	NSYSIMP20	NSYVR20	NSYTVR20	
		500 (20.0)	NSYSPF10100	NSYSPS5100	NSYSPF10200	NSYSPS5200	NSYMP2010	NSYSIMP20	NSYVR20	NSYTVR20	
		600 (23.6)	NSYSPF10100	NSYSPS6100	NSYSPF10200	NSYSPS6200	NSYMP2010	NSYSIMP20	NSYVR20	NSYTVR20	
		600 (23.6)	NSYSPF10100	NSYSPS6100	NSYSPF10200	NSYSPS6200	NSYMP2010	NSYSIMP20	NSYVR20	NSYTVR20	
		800 (31.5)	NSYSPF10100	NSYSPS8100	NSYSPF10200	NSYSPS8200	NSYMP2010	NSYSIMP20	NSYVR20	NSYTVR20	
		800 (31.5)	NSYSPF10100	NSYSPS8100	NSYSPF10200	NSYSPS8200	NSYMP2010	NSYSIMP20	NSYVR20	NSYTVR20	
1200 (47.2)		400 (15.6)	NSYSPF12100	NSYSPS4100	NSYSPF12200	NSYSPS4200	NSYMP2012	NSYSIMP20	NSYVR20	NSYTVR20	
	500 (20.0)	NSYSPF12100	NSYSPS5100	NSYSPF12200	NSYSPS5200	NSYMP2012	NSYSIMP20	NSYVR20	NSYTVR20		
	600 (23.6)	NSYSPF12100	NSYSPS6100	NSYSPF12200	NSYSPS6200	NSYMP2012	NSYSIMP20	NSYVR20	NSYTVR20		
	800 (31.5)	NSYSPF12100	NSYSPS8100	NSYSPF12200	NSYSPS8200	NSYMP2012	NSYSIMP20	NSYVR20	NSYTVR20		
1600 (63.0)	400 (15.6)	NSYSPF16100	NSYSPS4100	NSYSPF16200	NSYSPS4200	NSYMP2016	NSYSIMP20	NSYVR20	NSYTVR20		
	500 (20.0)	NSYSPF16100	NSYSPS5100	NSYSPF16200	NSYSPS5200	NSYMP2016	NSYSIMP20	NSYVR20	NSYTVR20		
	600 (23.6)	NSYSPF16100	NSYSPS6100	NSYSPF16200	NSYSPS6200	NSYMP2016	NSYSIMP20	NSYVR20	NSYTVR20		
2200 (86.6)	400 (15.6)	600 (23.6)	NSYSPF4100	NSYSPS6100	NSYSPF4200	NSYSPS6200	-	-	NSYVR22	NSYTVR22	
		600 (23.6)	NSYSPF6100	NSYSPS6100	NSYSPF6200	NSYSPS6200	NSYMP226	NSYSIMP22	NSYVR22	NSYTVR22	
	600 (23.6)	800 (31.5)	NSYSPF6100	NSYSPS8100	NSYSPF6200	NSYSPS8200	NSYMP226	NSYSIMP22	NSYVR22	NSYTVR22	
		800 (31.5)	NSYSPF8100	NSYSPS6100	NSYSPF8200	NSYSPS6200	NSYMP228	NSYSIMP22	NSYVR22	NSYTVR22	
	800 (31.5)	600 (23.6)	NSYSPF8100	NSYSPS8100	NSYSPF8200	NSYSPS8200	NSYMP228	NSYSIMP22	NSYVR22	NSYTVR22	
		800 (31.5)	NSYSPF8100	NSYSPS8100	NSYSPF8200	NSYSPS8200	NSYMP228	NSYSIMP22	NSYVR22	NSYTVR22	
	1000 (39.4)	600 (23.6)	NSYSPF10100	NSYSPS6100	NSYSPF10200	NSYSPS6200	NSYMP2210	NSYSIMP22	NSYVR22	NSYTVR22	
	1200 (47.2)	600 (23.6)	NSYSPF12100	NSYSPS6100	NSYSPF12200	NSYSPS6200	NSYMP2212	NSYSIMP22	NSYVR22	NSYTVR22	
		800 (31.5)	NSYSPF12100	NSYSPS8100	NSYSPF12200	NSYSPS8200	NSYMP2212	NSYSIMP22	NSYVR22	NSYTVR22	

Selection Guide



Nominal dimensions- mm (in)			No. of doors	Vertical uprights	Bottom frame and top frame with roof	Rear panel	Side panels	Plain door (1)	Transparent door (Securit® glass) (1)	Door Trim plate	Mounting plate	
Height (A)	Width (B)	Depth (C)										
1200 (47.2)	600 (23.6)	400 (15.6)	1	NSYSFV12	NSYSFC64	NSYBP126	NSY2SP124	NSYSFD126	NSYSFD126T	NSYTRIM6SF	NSYMP126	
		500 (19.7)	1	NSYSFV12	NSYSFC65	NSYBP126	NSY2SP125	NSYSFD126	NSYSFD126T	NSYTRIM6SF	NSYMP126	
		600 (23.6)	1	NSYSFV12	NSYSFC66	NSYBP126	NSY2SP126	NSYSFD126	NSYSFD126T	NSYTRIM6SF	NSYMP126	
		800 (31.5)	1	NSYSFV12	NSYSFC68	NSYBP126	NSY2SP128	NSYSFD126	NSYSFD126T	NSYTRIM6SF	NSYMP126	
	800 (31.5)	400 (15.6)	1	NSYSFV12	NSYSFC84	NSYBP128	NSY2SP124	NSYSFD128	NSYSFD128T	NSYTRIM8SF	NSYMP128	
		500 (19.7)	1	NSYSFV12	NSYSFC85	NSYBP128	NSY2SP125	NSYSFD128	NSYSFD128T	NSYTRIM8SF	NSYMP128	
		600 (23.6)	1	NSYSFV12	NSYSFC86	NSYBP128	NSY2SP126	NSYSFD128	NSYSFD128T	NSYTRIM8SF	NSYMP128	
		800 (31.5)	1	NSYSFV12	NSYSFC88	NSYBP128	NSY2SP128	NSYSFD128	NSYSFD128T	NSYTRIM8SF	NSYMP128	
1400 (55.1)	600 (23.6)	400 (15.6)	1	NSYSFV14	NSYSFC64	NSYBP146	NSY2SP144	NSYSFD146	NSYSFD146T	NSYTRIM6SF	NSYMP146	
		500 (19.7)	1	NSYSFV14	NSYSFC65	NSYBP146	NSY2SP145	NSYSFD146	NSYSFD146T	NSYTRIM6SF	NSYMP146	
		600 (23.6)	1	NSYSFV14	NSYSFC66	NSYBP146	NSY2SP146	NSYSFD146	NSYSFD146T	NSYTRIM6SF	NSYMP146	
		800 (31.5)	1	NSYSFV14	NSYSFC68	NSYBP146	NSY2SP148	NSYSFD146	NSYSFD146T	NSYTRIM6SF	NSYMP146	
	800 (31.5)	400 (15.6)	1	NSYSFV14	NSYSFC84	NSYBP148	NSY2SP144	NSYSFD148	NSYSFD148T	NSYTRIM8SF	NSYMP148	
		500 (19.7)	1	NSYSFV14	NSYSFC85	NSYBP148	NSY2SP145	NSYSFD148	NSYSFD148T	NSYTRIM8SF	NSYMP148	
		600 (23.6)	1	NSYSFV14	NSYSFC86	NSYBP148	NSY2SP146	NSYSFD148	NSYSFD148T	NSYTRIM8SF	NSYMP148	
		800 (31.5)	1	NSYSFV14	NSYSFC88	NSYBP148	NSY2SP148	NSYSFD148	NSYSFD148T	NSYTRIM8SF	NSYMP148	
1600 (63.0)	600 (23.6)	400 (15.6)	1	NSYSFV16	NSYSFC64	NSYBP166	NSY2SP164	NSYSFD166	NSYSFD166T	NSYTRIM6SF	NSYMP166	
		500 (19.7)	1	NSYSFV16	NSYSFC65	NSYBP166	NSY2SP165	NSYSFD166	NSYSFD166T	NSYTRIM6SF	NSYMP166	
		600 (23.6)	1	NSYSFV16	NSYSFC66	NSYBP166	NSY2SP166	NSYSFD166	NSYSFD166T	NSYTRIM6SF	NSYMP166	
		800 (31.5)	1	NSYSFV16	NSYSFC68	NSYBP166	NSY2SP168	NSYSFD166	NSYSFD166T	NSYTRIM6SF	NSYMP166	
	800 (31.5)	400 (15.6)	1	NSYSFV16	NSYSFC84	NSYBP168	NSY2SP164	NSYSFD168	NSYSFD168T	NSYTRIM8SF	NSYMP168	
		500 (19.7)	1	NSYSFV16	NSYSFC85	NSYBP168	NSY2SP165	NSYSFD168	NSYSFD168T	NSYTRIM8SF	NSYMP168	
		600 (23.6)	1	NSYSFV16	NSYSFC86	NSYBP168	NSY2SP166	NSYSFD168	NSYSFD168T	NSYTRIM8SF	NSYMP168	
		800 (31.5)	1	NSYSFV16	NSYSFC88	NSYBP168	NSY2SP168	NSYSFD168	NSYSFD168T	NSYTRIM8SF	NSYMP168	
1800 (70.9)	400 (15.6)	400 (15.6)	1	NSYSFV18	NSYSFC44	NSYBP184	NSY2SP184	NSYSFD184	-	NSYTRIM4SF	-	
		500 (19.7)	1	NSYSFV18	NSYSFC45	NSYBP184	NSY2SP185	NSYSFD184	-	NSYTRIM4SF	-	
		600 (23.6)	1	NSYSFV18	NSYSFC46	NSYBP184	NSY2SP186	NSYSFD184	-	NSYTRIM4SF	-	
		800 (31.5)	1	NSYSFV18	NSYSFC48	NSYBP184	NSY2SP188	NSYSFD184	-	NSYTRIM4SF	-	
	600 (23.6)	400 (15.6)	1	NSYSFV18	NSYSFC64	NSYBP186	NSY2SP184	NSYSFD186	NSYSFD186T	NSYTRIM6SF	NSYMP186	
		500 (19.7)	1	NSYSFV18	NSYSFC65	NSYBP186	NSY2SP185	NSYSFD186	NSYSFD186T	NSYTRIM6SF	NSYMP186	
		600 (23.6)	1	NSYSFV18	NSYSFC66	NSYBP186	NSY2SP186	NSYSFD186	NSYSFD186T	NSYTRIM6SF	NSYMP186	
		800 (31.5)	1	NSYSFV18	NSYSFC68	NSYBP186	NSY2SP188	NSYSFD186	NSYSFD186T	NSYTRIM6SF	NSYMP186	
	800 (31.5)	400 (15.6)	1	NSYSFV18	NSYSFC84	NSYBP188	NSY2SP184	NSYSFD188	NSYSFD188T	NSYTRIM8SF	NSYMP188	
		500 (19.7)	1	NSYSFV18	NSYSFC85	NSYBP188	NSY2SP185	NSYSFD188	NSYSFD188T	NSYTRIM8SF	NSYMP188	
		600 (23.6)	2	NSYSFV18	NSYSFC86	NSYBP188	NSY2SP186	NSYSFD188	NSYSFD188T	NSYTRIM8SF2D	NSYMP188	
		800 (31.5)	1	NSYSFV18	NSYSFC88	NSYBP188	NSY2SP188	NSYSFD188	NSYSFD188T	NSYTRIM8SF	NSYMP188	
	1000 (39.4)	400 (15.6)	400 (15.6)	1	NSYSFV18	NSYSFC104	NSYBP1810	NSY2SP184	NSYSFD1810	NSYSFD1810T	NSYTRIM10SF	NSYMP1810
			400 (15.6)	2	NSYSFV18	NSYSFC104	NSYBP1810	NSY2SP184	NSYSFD1810	NSYSFD1810T	NSYTRIM10SF2D	NSYMP1810
		500 (19.7)	1	NSYSFV18	NSYSFC105	NSYBP1810	NSY2SP185	NSYSFD1810	NSYSFD1810T	NSYTRIM10SF	NSYMP1810	
		600 (23.6)	1	NSYSFV18	NSYSFC106	NSYBP1810	NSY2SP186	NSYSFD1810	NSYSFD1810T	NSYTRIM10SF	NSYMP1810	
1200 (47.2)	400 (15.6)	400 (15.6)	2	NSYSFV18	NSYSFC106	NSYBP1810	NSY2SP186	NSYSFD1810	NSYSFD1810T	NSYTRIM10SF2D	NSYMP1810	
		800 (31.5)	1	NSYSFV18	NSYSFC108	NSYBP1810	NSY2SP188	NSYSFD1810	NSYSFD1810T	NSYTRIM10SF	NSYMP1810	
	800 (31.5)	2	NSYSFV18	NSYSFC108	NSYBP1810	NSY2SP188	NSYSFD1810	NSYSFD1810T	NSYTRIM10SF2D	NSYMP1810		
	400 (15.6)	2	NSYSFV18	NSYSFC124	NSYBP1812	NSY2SP184	NSYSFD1812	NSYSFD1812D	NSYTRIM12SF2D	NSYMP1812		
500 (19.7)	2	NSYSFV18	NSYSFC125	NSYBP1812	NSY2SP185	NSYSFD1812	NSYSFD1812D	NSYTRIM12SF2D	NSYMP1812			
600 (23.6)	2	NSYSFV18	NSYSFC126	NSYBP1812	NSY2SP186	NSYSFD1812	NSYSFD1812D	NSYTRIM12SF2D	NSYMP1812			
800 (31.5)	2	NSYSFV18	NSYSFC128	NSYBP1812	NSY2SP188	NSYSFD1812	NSYSFD1812D	NSYTRIM12SF2D	NSYMP1812			

(1) Hinges, locking bar catches and handle with 5-mm double-bar insert included.

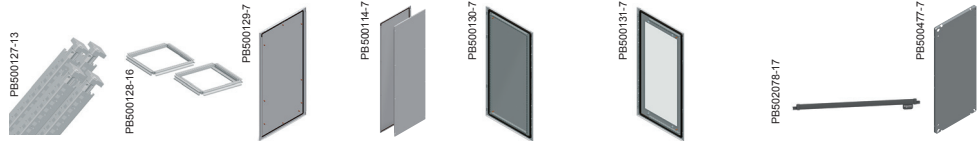


Nominal dimensions (mm)			No. of doors	Vertical uprights	Bottom frame and top frame with roof	Rear panel	Side panels	Plain door (1)	Transparent door (Securit® glass) (1)	Door Trim plate	Mounting plate
Height (A)	Width (B)	Depth (C)									
2000 (78.7)	300 (11.8)	500 (19.7)	1	NSYSFV20	NSYSFC35	NSYBP203	NSY2SP205	NSYSFD203	-	NSYTRIM3SF	-
		600 (23.6)	1	NSYSFV20	NSYSFC36	NSYBP203	NSY2SP206	NSYSFD203	-	NSYTRIM3SF	-
	400 (15.6)	400 (15.6)	1	NSYSFV20	NSYSFC44	NSYBP204	NSY2SP204	NSYSFD204	-	NSYTRIM4SF	-
		500 (19.7)	1	NSYSFV20	NSYSFC45	NSYBP204	NSY2SP205	NSYSFD204	-	NSYTRIM4SF	-
		600 (23.6)	1	NSYSFV20	NSYSFC46	NSYBP204	NSY2SP206	NSYSFD204	-	NSYTRIM4SF	-
		800 (31.5)	1	NSYSFV20	NSYSFC48	NSYBP204	NSY2SP208	NSYSFD204	-	NSYTRIM4SF	-
	600 (23.6)	400 (15.6)	1	NSYSFV20	NSYSFC64	NSYBP206	NSY2SP204	NSYSFD206	NSYSFD206T	NSYTRIM6SF	NSYMP206
		500 (19.7)	1	NSYSFV20	NSYSFC65	NSYBP206	NSY2SP205	NSYSFD206	NSYSFD206T	NSYTRIM6SF	NSYMP206
		600 (23.6)	1	NSYSFV20	NSYSFC66	NSYBP206	NSY2SP206	NSYSFD206	NSYSFD206T	NSYTRIM6SF	NSYMP206
		800 (31.5)	1	NSYSFV20	NSYSFC68	NSYBP206	NSY2SP208	NSYSFD206	NSYSFD206T	NSYTRIM6SF	NSYMP206
	800 (31.5)	400 (15.6)	1	NSYSFV20	NSYSFC84	NSYBP208	NSY2SP204	NSYSFD208	NSYSFD208T	NSYTRIM8SF	NSYMP208
		500 (19.7)	1	NSYSFV20	NSYSFC85	NSYBP208	NSY2SP205	NSYSFD208	NSYSFD208T	NSYTRIM8SF	NSYMP208
		600 (23.6)	1	NSYSFV20	NSYSFC86	NSYBP208	NSY2SP206	NSYSFD208	NSYSFD208T	NSYTRIM8SF	NSYMP208
		600 (23.6)	2	NSYSFV20	NSYSFC86	NSYBP208	NSY2SP206	NSYSFD2082D	-	NSYTRIM8SF2D	NSYMP208
		800 (31.5)	1	NSYSFV20	NSYSFC88	NSYBP208	NSY2SP208	NSYSFD208	NSYSFD208T	NSYTRIM8SF	NSYMP208
		800 (31.5)	2	NSYSFV20	NSYSFC88	NSYBP208	NSY2SP208	NSYSFD2082D	-	NSYTRIM8SF2D	NSYMP208
	1000 (39.4)	400 (15.6)	1	NSYSFV20	NSYSFC104	NSYBP2010	NSY2SP204	NSYSFD2010	NSYSFD2010T	NSYTRIM10SF	NSYMP2010
		400 (15.6)	2	NSYSFV20	NSYSFC104	NSYBP2010	NSY2SP204	NSYSFD20102D	-	NSYTRIM10SF2D	NSYMP2010
		500 (19.7)	1	NSYSFV20	NSYSFC105	NSYBP2010	NSY2SP205	NSYSFD2010	NSYSFD2010T	NSYTRIM10SF	NSYMP2010
		500 (19.7)	2	NSYSFV20	NSYSFC105	NSYBP2010	NSY2SP205	NSYSFD20102D	-	NSYTRIM10SF2D	NSYMP2010
		600 (23.6)	1	NSYSFV20	NSYSFC106	NSYBP2010	NSY2SP206	NSYSFD2010	NSYSFD2010T	NSYTRIM10SF	NSYMP2010
		600 (23.6)	2	NSYSFV20	NSYSFC106	NSYBP2010	NSY2SP206	NSYSFD20102D	-	NSYTRIM10SF2D	NSYMP2010
		800 (31.5)	1	NSYSFV20	NSYSFC108	NSYBP2010	NSY2SP208	NSYSFD2010	NSYSFD2010T	NSYTRIM10SF	NSYMP2010
		800 (31.5)	2	NSYSFV20	NSYSFC108	NSYBP2010	NSY2SP208	NSYSFD20102D	-	NSYTRIM10SF2D	NSYMP2010
1200 (47.2)	400 (15.6)	2	NSYSFV20	NSYSFC124	NSYBP2012	NSY2SP204	NSYSFD20122D	NSYSFD20122DT	NSYTRIM12SF2D	NSYMP2012	
	500 (19.7)	2	NSYSFV20	NSYSFC125	NSYBP2012	NSY2SP205	NSYSFD20122D	NSYSFD20122DT	NSYTRIM12SF2D	NSYMP2012	
	600 (23.6)	2	NSYSFV20	NSYSFC126	NSYBP2012	NSY2SP206	NSYSFD20122D	NSYSFD20122DT	NSYTRIM12SF2D	NSYMP2012	
	800 (31.5)	2	NSYSFV20	NSYSFC128	NSYBP2012	NSY2SP208	NSYSFD20122D	NSYSFD20122DT	NSYTRIM12SF2D	NSYMP2012	
1600 (63.0)	400 (15.6)	2	NSYSFV20	NSYSFC164	NSYBP2016	NSY2SP204	NSYSFD20162D	-	NSYTRIM16SF2D	NSYMP2016	
	500 (19.7)	2	NSYSFV20	NSYSFC165	NSYBP2016	NSY2SP205	NSYSFD20162D	-	NSYTRIM16SF2D	NSYMP2016	
	600 (23.6)	2	NSYSFV20	NSYSFC166	NSYBP2016	NSY2SP206	NSYSFD20162D	-	NSYTRIM16SF2D	NSYMP2016	
	800 (31.5)	2	NSYSFV20	NSYSFC168	NSYBP2016	NSY2SP208	NSYSFD20162D	-	NSYTRIM16SF2D	NSYMP2016	
2200 (86.6)	400 (15.6)	400 (15.6)	1	NSYSFV22	NSYSFC44	NSYBP224	NSY2SP224	NSYSFD224	-	NSYTRIM4SF	-
		500 (19.7)	1	NSYSFV22	NSYSFC45	NSYBP224	NSY2SP225	NSYSFD224	-	NSYTRIM4SF	-
		600 (23.6)	1	NSYSFV22	NSYSFC46	NSYBP224	NSY2SP226	NSYSFD224	-	NSYTRIM4SF	-
		800 (31.5)	1	NSYSFV22	NSYSFC48	NSYBP224	NSY2SP228	NSYSFD224	-	NSYTRIM4SF	-
	600 (23.6)	400 (15.6)	1	NSYSFV22	NSYSFC64	NSYBP226	NSY2SP224	NSYSFD226	NSYSFD226T	NSYTRIM6SF	NSYMP226
		500 (19.7)	1	NSYSFV22	NSYSFC65	NSYBP226	NSY2SP225	NSYSFD226	NSYSFD226T	NSYTRIM6SF	NSYMP226
		600 (23.6)	1	NSYSFV22	NSYSFC66	NSYBP226	NSY2SP226	NSYSFD226	NSYSFD226T	NSYTRIM6SF	NSYMP226
		800 (31.5)	1	NSYSFV22	NSYSFC68	NSYBP226	NSY2SP228	NSYSFD226	NSYSFD226T	NSYTRIM6SF	NSYMP226
	800 (31.5)	400 (15.6)	1	NSYSFV22	NSYSFC84	NSYBP228	NSY2SP224	NSYSFD228	NSYSFD228T	NSYTRIM8SF	NSYMP228
		500 (19.7)	1	NSYSFV22	NSYSFC85	NSYBP228	NSY2SP225	NSYSFD228	NSYSFD228T	NSYTRIM8SF	NSYMP228
		600 (23.6)	1	NSYSFV22	NSYSFC86	NSYBP228	NSY2SP226	NSYSFD228	NSYSFD228T	NSYTRIM8SF	NSYMP228
		800 (31.5)	1	NSYSFV22	NSYSFC88	NSYBP228	NSY2SP228	NSYSFD228	NSYSFD228T	NSYTRIM8SF	NSYMP228
	1000 (39.4)	400 (15.6)	1	NSYSFV22	NSYSFC104	NSYBP2210	NSY2SP224	NSYSFD2210	NSYSFD2210T	NSYTRIM10SF	NSYMP2210
		500 (19.7)	1	NSYSFV22	NSYSFC105	NSYBP2210	NSY2SP225	NSYSFD2210	NSYSFD2210T	NSYTRIM10SF	NSYMP2210
		600 (23.6)	1	NSYSFV22	NSYSFC106	NSYBP2210	NSY2SP226	NSYSFD2210	NSYSFD2210T	NSYTRIM10SF	NSYMP2210
		800 (31.5)	1	NSYSFV22	NSYSFC108	NSYBP2210	NSY2SP228	NSYSFD2210	NSYSFD2210T	NSYTRIM10SF	NSYMP2210
	1200 (47.2)	400 (15.6)	2	NSYSFV22	NSYSFC124	NSYBP2212	NSY2SP224	NSYSFD22122D	NSYSFD22122DT	NSYTRIM12SF2D	NSYMP2212
		500 (19.7)	2	NSYSFV22	NSYSFC125	NSYBP2212	NSY2SP225	NSYSFD22122D	NSYSFD22122DT	NSYTRIM12SF2D	NSYMP2212
		600 (23.6)	2	NSYSFV22	NSYSFC126	NSYBP2212	NSY2SP226	NSYSFD22122D	NSYSFD22122DT	NSYTRIM12SF2D	NSYMP2212
		800 (31.5)	2	NSYSFV22	NSYSFC128	NSYBP2212	NSY2SP228	NSYSFD22122D	NSYSFD22122DT	NSYTRIM12SF2D	NSYMP2212

(1) Hinges, locking bar catches and handle with 5-mm double-bar insert included.



Selection Guide

SM

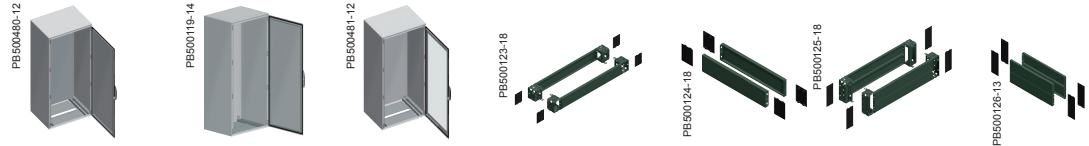

Characteristics			Door			Plinth					
Dimensions - mm (in)			No. of doors	Plain		Transparent	Height 100 mm (3.9 in)		Height 200 mm (7.9 in)		
Height (A)	Width (B)	Depth (C)		With mounting plate	Without mounting plate	Without mounting plate	Front kit (corners + front panels)	Side panels, 2 u.	Front kit (corners + front panels)	Side panels, 4 u.	
1200 (47.2)	800 (31.5)	300 (11.8)	1	NSYSM12830P	NSYSM12830	-	NSYSPF8100	NSYSPS3100	NSYSPF8200	NSYSPS3200	
	1000 (39.4)	300 (11.8)	2	NSYSM1210302DP	NSYSM1210302D	-	NSYSPF10100	NSYSPS3100	NSYSPF10200	NSYSPS3200	
	1200 (47.2)	400 (15.6)	2	NSYSM1212402DP	NSYSM1212402D	-	NSYSPF12100	NSYSPS4100	NSYSPF12200	NSYSPS4200	
1400 (55.1)	600 (23.6)	300 (11.8)	1	NSYSM14630P	NSYSM14630	-	NSYSPF6100	NSYSPS3100	NSYSPF6200	NSYSPS3200	
		400 (15.6)	1	NSYSM14640P	NSYSM14640	-	NSYSPF6100	NSYSPS4100	NSYSPF6200	NSYSPS4200	
	800 (31.5)	300 (11.8)	1	NSYSM14830P	NSYSM14830	-	NSYSPF8100	NSYSPS3100	NSYSPF8200	NSYSPS3200	
		400 (15.6)	1	NSYSM14840P	NSYSM14840	NSYSM14840T	NSYSPF8100	NSYSPS4100	NSYSPF8200	NSYSPS4200	
	1000 (39.4)	400 (15.6)	2	NSYSM1410402DP	NSYSM1410402D	-	NSYSPF10100	NSYSPS4100	NSYSPF10200	NSYSPS4200	
	1200 (47.2)	400 (15.6)	2	NSYSM1412402DP	NSYSM1412402D	-	NSYSPF12100	NSYSPS4100	NSYSPF12200	NSYSPS4200	
1600 (63.0)	600 (23.6)	300 (11.8)	1	NSYSM16630P	NSYSM16630	-	NSYSPF6100	NSYSPS3100	NSYSPF6200	NSYSPS3200	
		400 (15.6)	1	NSYSM16640P	NSYSM16640	NSYSM16640T	NSYSPF6100	NSYSPS4100	NSYSPF6200	NSYSPS4200	
	800 (31.5)	300 (11.8)	1	NSYSM16830P	NSYSM16830	NSYSM16830T	NSYSPF8100	NSYSPS3100	NSYSPF8200	NSYSPS3200	
		400 (15.6)	1	NSYSM16840P	NSYSM16840	NSYSM16840T	NSYSPF8100	NSYSPS4100	NSYSPF8200	NSYSPS4200	
	1000 (39.4)	300 (11.8)	2	NSYSM1610302DP	NSYSM1610302D	-	NSYSPF10100	NSYSPS3100	NSYSPF10200	NSYSPS3200	
		400 (15.6)	2	NSYSM1610402DP	NSYSM1610402D	-	NSYSPF10100	NSYSPS4100	NSYSPF10200	NSYSPS4200	
	1200 (47.2)	300 (11.8)	2	NSYSM1612302DP	NSYSM1612302D	-	NSYSPF12100	NSYSPS3100	NSYSPF12200	NSYSPS3200	
		400 (15.6)	2	NSYSM1612402DP	NSYSM1612402D	-	NSYSPF12100	NSYSPS4100	NSYSPF12200	NSYSPS4200	
	1800 (70.9)	600 (23.6)	300 (11.8)	1	NSYSM18630P	NSYSM18630	-	NSYSPF6100	NSYSPS3100	NSYSPF6200	NSYSPS3200
			400 (15.6)	1	NSYSM18640P	NSYSM18640	NSYSM18640T	NSYSPF6100	NSYSPS4100	NSYSPF6200	NSYSPS4200
500 (19.7)			1	NSYSM18650P	NSYSM18650	-	NSYSPF6100	NSYSPS5100	NSYSPF6200	NSYSPS5200	
800 (31.5)		300 (11.8)	1	NSYSM18830P	NSYSM18830	NSYSM18830T	NSYSPF8100	NSYSPS3100	NSYSPF8200	NSYSPS3200	
		400 (15.6)	1	NSYSM18840P	NSYSM18840	NSYSM18840T	NSYSPF8100	NSYSPS4100	NSYSPF8200	NSYSPS4200	
		500 (19.7)	1	NSYSM18850P	NSYSM18850	NSYSM18850T	NSYSPF8100	NSYSPS5100	NSYSPF8200	NSYSPS5200	
600 (23.6)		1	NSYSM18860P	NSYSM18860	-	NSYSPF8100	NSYSPS6100	NSYSPF8200	NSYSPS6200		
		400 (15.6)	1	NSYSM181040P	NSYSM181040	-	NSYSPF10100	NSYSPS4100	NSYSPF10200	NSYSPS4200	
1000 (39.4)		400 (15.6)	2	NSYSM1810402DP	NSYSM1810402D	-	NSYSPF10100	NSYSPS4100	NSYSPF10200	NSYSPS4200	
		500 (19.7)	2	NSYSM1810502DP	NSYSM1810502D	-	NSYSPF10100	NSYSPS5100	NSYSPF10200	NSYSPS5200	
		400 (15.6)	2	NSYSM1812402DP	NSYSM1812402D	-	NSYSPF12100	NSYSPS4100	NSYSPF12200	NSYSPS4200	
1200 (47.2)		400 (15.6)	2	NSYSM1812502DP	NSYSM1812502D	-	NSYSPF12100	NSYSPS5100	NSYSPF12200	NSYSPS5200	
		500 (19.7)	2	NSYSM1816402DP	NSYSM1816402D	-	NSYSPF16100	NSYSPS4100	NSYSPF16200	NSYSPS4200	
1600 (63.0)		400 (15.6)	2	NSYSM1816502DP	NSYSM1816502D	-	NSYSPF16100	NSYSPS5100	NSYSPF16200	NSYSPS5200	
	500 (19.7)	2	NSYSM1816502DP	NSYSM1816502D	-	NSYSPF16100	NSYSPS5100	NSYSPF16200	NSYSPS5200		
2000 (78.7)	600 (23.6)	300 (11.8)	1	NSYSM20630P	NSYSM20630	-	NSYSPF6100	NSYSPS3100	NSYSPF6200	NSYSPS3200	
		400 (15.6)	1	NSYSM20640P	NSYSM20640	NSYSM20640T	NSYSPF6100	NSYSPS4100	NSYSPF6200	NSYSPS4200	
		500 (19.7)	1	NSYSM20650P	NSYSM20650	-	NSYSPF6100	NSYSPS5100	NSYSPF6200	NSYSPS5200	
	800 (31.5)	300 (11.8)	1	NSYSM20830P	NSYSM20830	NSYSM20830T	NSYSPF8100	NSYSPS3100	NSYSPF8200	NSYSPS3200	
		400 (15.6)	1	NSYSM20840P	NSYSM20840	NSYSM20840T	NSYSPF8100	NSYSPS4100	NSYSPF8200	NSYSPS4200	
		500 (19.7)	1	NSYSM20850P	NSYSM20850	NSYSM20850T	NSYSPF8100	NSYSPS5100	NSYSPF8200	NSYSPS5200	
	600 (23.6)	1	NSYSM20860P	NSYSM20860	NSYSM20860T	NSYSPF8100	NSYSPS6100	NSYSPF8200	NSYSPS6200		
		400 (15.6)	2	NSYSM2010402DP	NSYSM2010402D	-	NSYSPF10100	NSYSPS4100	NSYSPF10200	NSYSPS4200	
	500 (19.7)	2	NSYSM2010502DP	NSYSM2010502D	-	NSYSPF10100	NSYSPS5100	NSYSPF10200	NSYSPS5200		
		400 (15.6)	2	NSYSM2012402DP	NSYSM2012402D	-	NSYSPF12100	NSYSPS4100	NSYSPF12200	NSYSPS4200	
	500 (19.7)	2	NSYSM2012502DP	NSYSM2012502D	-	NSYSPF12100	NSYSPS5100	NSYSPF12200	NSYSPS5200		
		600 (23.6)	2	NSYSM2012602DP	NSYSM2012602D	-	NSYSPF12100	NSYSPS6100	NSYSPF12200	NSYSPS6200	
	1600 (63.0)	400 (15.6)	2	NSYSM2016402DP	NSYSM2016402D	-	NSYSPF16100	NSYSPS4100	NSYSPF16200	NSYSPS4200	
		500 (19.7)	2	NSYSM2016502DP	NSYSM2016502D	-	NSYSPF16100	NSYSPS5100	NSYSPF16200	NSYSPS5200	
		600 (23.6)	2	NSYSM2016602DP	NSYSM2016602D	-	NSYSPF16100	NSYSPS6100	NSYSPF16200	NSYSPS6200	
		600 (23.6)	2	NSYSM2016602DP	NSYSM2016602D	-	NSYSPF16100	NSYSPS6100	NSYSPF16200	NSYSPS6200	

 SM

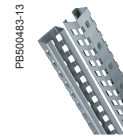

Characteristics			Inner door	Mounting plate	Vertical uprights		Off-centre 19" swing rack	Centred 19" swing rack
Dimensions - mm (in)			No. of doors		Standard	Technical		
Height (A)	Width (B)	Depth (C)						
1200 (47.2)	800 (31.5)	300 (11.8)	1	-	NSYMP128	-	NSYTVR12	-
	1000 (39.4)	300 (11.8)	2	-	NSYMP1210	-	NSYTVR12	-
	1200 (47.2)	400 (15.6)	2	-	NSYMP1212	-	NSYTVR12	-
1400 (55.1)	600 (23.6)	300 (11.8)	1	-	NSYMP146	-	NSYTVR14	-
		400 (15.6)	1	-	NSYMP146	-	NSYTVR14	-
	800 (31.5)	300 (11.8)	1	-	NSYMP148	-	NSYTVR14	NSYRSW27
		400 (15.6)	1	-	NSYMP148	-	NSYTVR14	NSYRSW27
	1000 (39.4)	400 (15.6)	2	-	NSYMP1410	-	NSYTVR14	-
	1200 (47.2)	400 (15.6)	2	-	NSYMP1412	-	NSYTVR14	-
1600 (63.0)	600 (23.6)	300 (11.8)	1	NSYID166	NSYMP166	-	NSYTVR16	-
		400 (15.6)	1	NSYID166	NSYMP166	-	NSYTVR16	-
	800 (31.5)	300 (11.8)	1	NSYID168	NSYMP168	-	NSYTVR16	NSYRSW31
		400 (15.6)	1	NSYID168	NSYMP168	-	NSYTVR16	NSYRSW31
	1000 (39.4)	300 (11.8)	2	-	NSYMP1610	-	NSYTVR16	-
		400 (15.6)	2	-	NSYMP1610	-	NSYTVR16	-
	1200 (47.2)	300 (11.8)	2	-	NSYMP1612	-	NSYTVR16	-
		400 (15.6)	2	-	NSYMP1612	-	NSYTVR16	-
1800 (70.9)	600 (23.6)	300 (11.8)	1	NSYID186	NSYMP186	NSYVR18	NSYTVR18	-
		400 (15.6)	1	NSYID186	NSYMP186	NSYVR18	NSYTVR18	-
		500 (19.7)	1	NSYID186	NSYMP186	NSYVR18	NSYTVR18	-
	800 (31.5)	300 (11.8)	1	NSYID188	NSYMP188	NSYVR18	NSYTVR18	NSYRSW36
		400 (15.6)	1	NSYID188	NSYMP188	NSYVR18	NSYTVR18	NSYRSW36
		500 (19.7)	1	NSYID188	NSYMP188	NSYVR18	NSYTVR18	NSYRSW36
		600 (23.6)	1	NSYID188	NSYMP188	NSYVR18	NSYTVR18	NSYRSW36
	1000 (39.4)	400 (15.6)	1	NSYID1810	NSYMP1810	NSYVR18	NSYTVR18	-
		400 (15.6)	2	NSYID1810	NSYMP1810	NSYVR18	NSYTVR18	-
		500 (19.7)	2	NSYID1810	NSYMP1810	NSYVR18	NSYTVR18	-
	1200 (47.2)	400 (15.6)	2	-	NSYMP1812	NSYVR18	NSYTVR18	-
		500 (19.7)	2	-	NSYMP1812	NSYVR18	NSYTVR18	-
	1600 (63.0)	400 (15.6)	2	-	NSYMP1816	NSYVR18	NSYTVR18	-
		500 (19.7)	2	-	NSYMP1816	NSYVR18	NSYTVR18	-
2000 (78.7)	600 (23.6)	300 (11.8)	1	NSYID206	NSYMP206	NSYVR20	NSYTVR20	-
		400 (15.6)	1	NSYID206	NSYMP206	NSYVR20	NSYTVR20	-
		500 (19.7)	1	NSYID206	NSYMP206	NSYVR20	NSYTVR20	-
	800 (31.5)	300 (11.8)	1	NSYID208	NSYMP208	NSYVR20	NSYTVR20	NSYRSW40
		400 (15.6)	1	NSYID208	NSYMP208	NSYVR20	NSYTVR20	NSYRSW40
		500 (19.7)	1	NSYID208	NSYMP208	NSYVR20	NSYTVR20	NSYRSW40
		600 (23.6)	1	NSYID208	NSYMP208	NSYVR20	NSYTVR20	NSYRSW40
	1000 (39.4)	400 (15.6)	2	NSYID2010	NSYMP2010	NSYVR20	NSYTVR20	-
		500 (19.7)	2	NSYID2010	NSYMP2010	NSYVR20	NSYTVR20	-
	1200 (47.2)	400 (15.6)	2	-	NSYMP2012	NSYVR20	NSYTVR20	-
		500 (19.7)	2	-	NSYMP2012	NSYVR20	NSYTVR20	-
		600 (23.6)	2	-	NSYMP2012	NSYVR20	NSYTVR20	-
	1600 (63.0)	400 (15.6)	2	-	NSYMP2016	NSYVR20	NSYTVR20	-
		500 (19.7)	2	-	NSYMP2016	NSYVR20	NSYTVR20	-
600 (23.6)		2	-	NSYMP2016	NSYVR20	NSYTVR20	-	

Digital tools




Digital rules

The fast enclosure's components selector: it is the software assistant to help you to define the enclosure range, compatible accessories and thermal management solutions in a matter of minutes.




ProClima Software

To accurately size your fans, heaters, and air conditioning units for more reliability and cost effectiveness of your thermal management solutions.

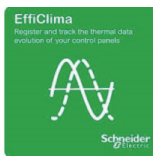

EffiClima Software

This thermal tracking software can provide a complete diagnosis in 3 simple steps.

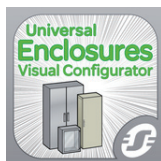

Universal Enclosures Visual Configurator

The Universal Enclosures Visual Product Configurator is an interactive tool which simplifies the selection of Schneider Electric™ wall-mounting and floor-standing universal enclosures, industrial boxes and available accessories.



EZ Selector

EZ Selector tools are designed to assist you through the product selection process. Click-to-Answer questions guide you through selecting the right product for your application.

For more information visit:

schneider-electric.com/us/en/work/campaign/spacial-sf

Schneider Electric USA, Inc.

8001 Knightdale Blvd.
Knightdale, NC 27545
Phone: 919-266-3671

schneider-electric.us/en/product-category/53800

November 2019
Document Number 9991BE1901

©2019 Schneider Electric. All Rights Reserved. Schneider Electric | Life Is On is a trademark and the property of Schneider-Electric SE, its subsidiaries, and affiliated companies.

Life Is On

Schneider
Electric