
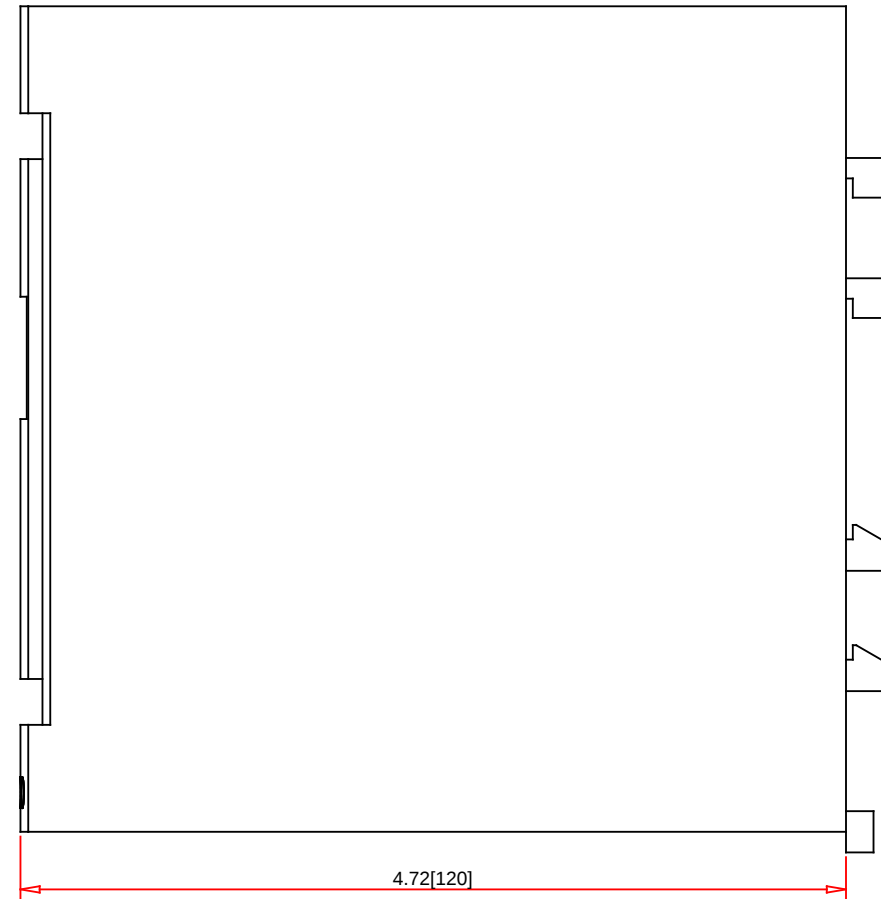


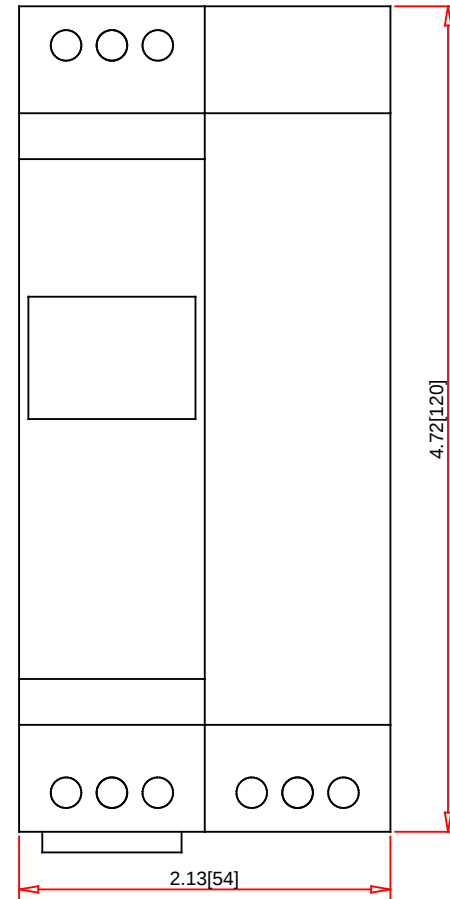


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

ABL7RP1205

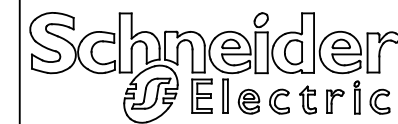

Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 877 342 5173
Email: CCC@us.schneider-electric.com

Technical Information:

Wire Range: #14 - #26
Tightening Torque: 5.4 lb-in (0.6 Nm)
Mounting: DIN Rail
Screw for Panel Mtg.: N/A
Weight: 2.20 lb (1.00 kg)
UL File: E164867 NMTR
CSA File: 204701 5311-03
Conform to EN61000-3-2: Yes
CE: Yes
RoHS: Yes

Description: Optimum Power Supplies
Type: Power Supply 12Vdc 5 Amp
Input Voltage: 100-240 -15/+10% 50/60Hz, single phase
Output Voltage: 12Vdc
Nominal Power: 60 Watts
Nominal Current: 5 Amp
Reset: Automatic or Manual

Specification: