
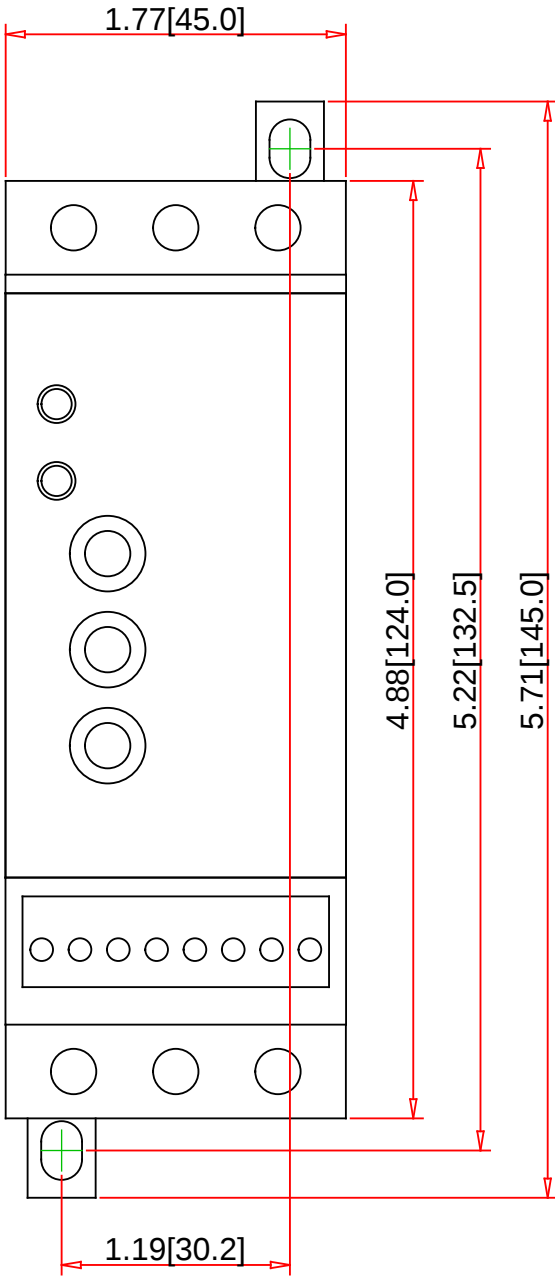


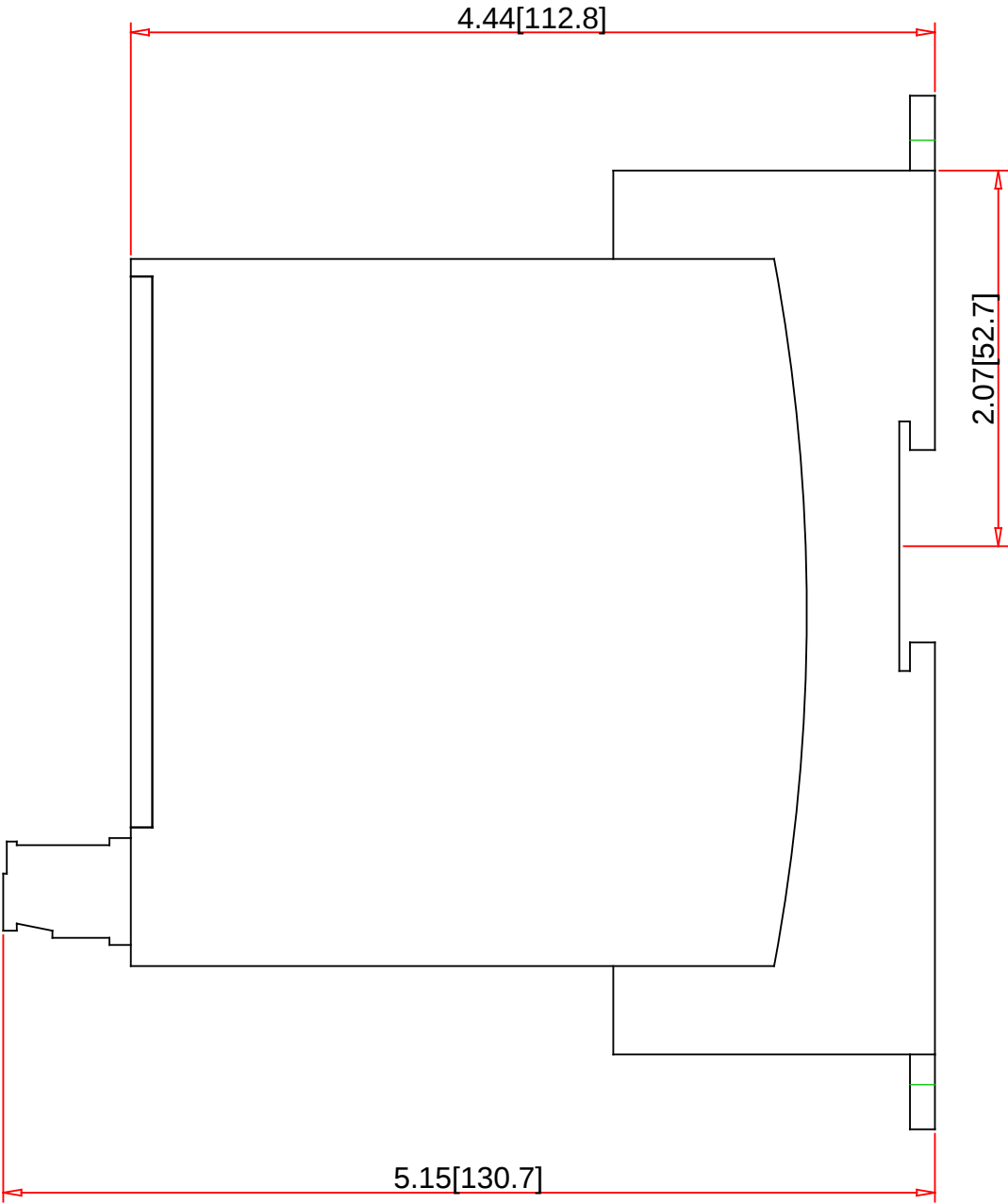

Note:
- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:
ATS01N206RT

Schneider Electric
Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 8773425173
Email: CCC@us.schneider-electric.com

Technical Information:

Control Voltage: 110 - 240 Vac
Weight [lb]/[kg]: 0.93/0.42
UL File No.: E184727
CSA File: 224330
Other: IEC/EN 60947-4-2 CE,UL,CSA,C-Tick and CCC

Specification:

Description:
Family: Altistart 01
Product Line: Soft Starters
Application: Constant & Variable Torque
Output Ampere Rating: 6
hp rating 110V Single Phase: n/a
hp rating 208V Single Phase: n/a
kW rating 230V Single Phase: n/a
hp rating 230V Single Phase: n/a
kW rating 230V three Phase: —
hp rating 230V three Phase: —
kW Rating 400V three phase: —
hp rating 460V three phase: 2 / 3 hp
Enclosure Rating: IP20