


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

ATSU01N206LT

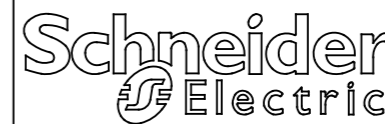

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Control Voltage: 24 VDC
 Weight [lb]/[kg]: 0.75/0.34
 UL File No.: E184727
 CSA File: 224330
 Other: IEC/EN 60947-4-2 CE,UL,CSA,C-Tick and CCC

Specification:

Description:
 Family: Altistart 01
 Product Line: Soft Starters
 Application: Constant & Variable Torque
 Output Ampere Rating: 6
 hp rating 110V Single Phase: n/a
 hp rating 208V Single Phase: n/a
 kW rating 230V Single Phase: n/a
 hp rating 230V Single Phase: n/a
 kW rating 230V three Phase: 0.75 - 1.1 kW
 hp rating 230V three Phase: 1 - 1.5 hp
 kW Rating 400V three phase: 1.5, 2.2, 3 kW
 hp rating 460V three phase: 2 - 3 hp
 Enclosure Rating: IP20