



Depth C inches (mm)		
	With Keypad	Without Keypad
No option card	14.84[377.0]	14.84[377.0]
With 1 option card	14.84[377.0]	14.84[377.0]
With 2 options cards	15.43[392.0]	14.84[377.0]

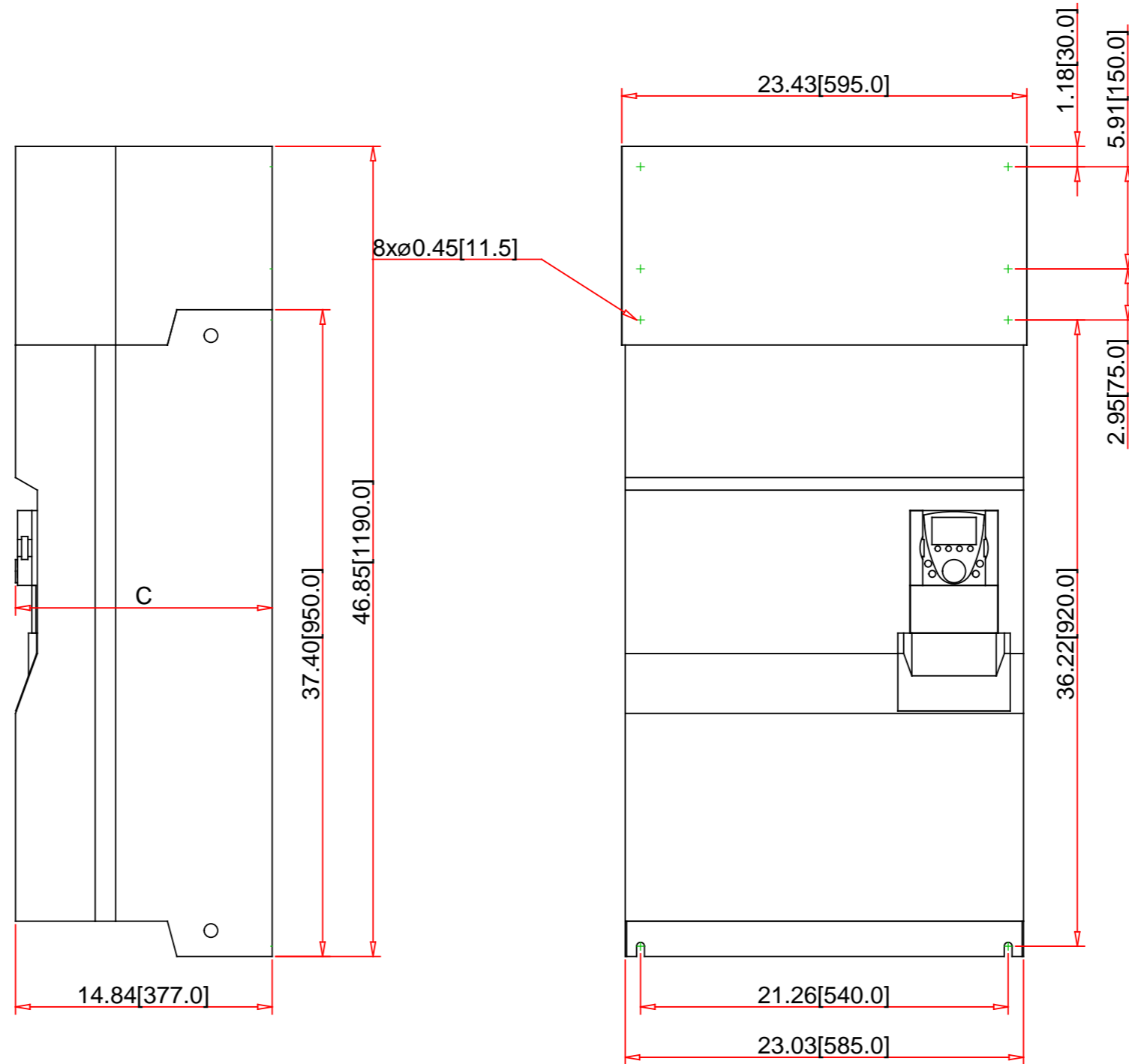

Note:
- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]
- Inch Dimensions are derived from the metric.

Part No.:

ATV61HC31N4

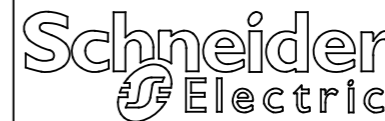

Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 8773425173
Email: CCC@us.schneider-electric.com

Technical Information:

Control Voltage: 24Vdc
Logic Input: 6
Analog Input: 2
Analog Output: 1
Communication: Modbus and CANopen
Logic/Relay Output: 1 NO/NC, 1 NO
Weight [lb/kg]: 455 / 207
UL File No.: E116875
CSA File: 1650725
Other: CE, ABS, DNV, GOST, RoHS, WEEE, C-Tick, NOM 117

Specification:

Description:
Family: Altivar 61
Product Line: AC Drives
Application: Variable Torque
Voltage Rating: 400/480VAC
HP Rating / kW Rating: 500 / 315
Output Ampere Rating: 616A
Enclosure Rating: IP20
Frame Size: 13
Input Phase / Output Phase: 3-Phase / 3-Phase