


Depth C inches (mm)		
	With Keypad	Without Keypad
No option card	9.29[236.0]	8.27[210.0]
With 1 option card	10.20[259.0]	9.17[233.0]
With 2 options cards	11.10[282.0]	10.08[256.0]

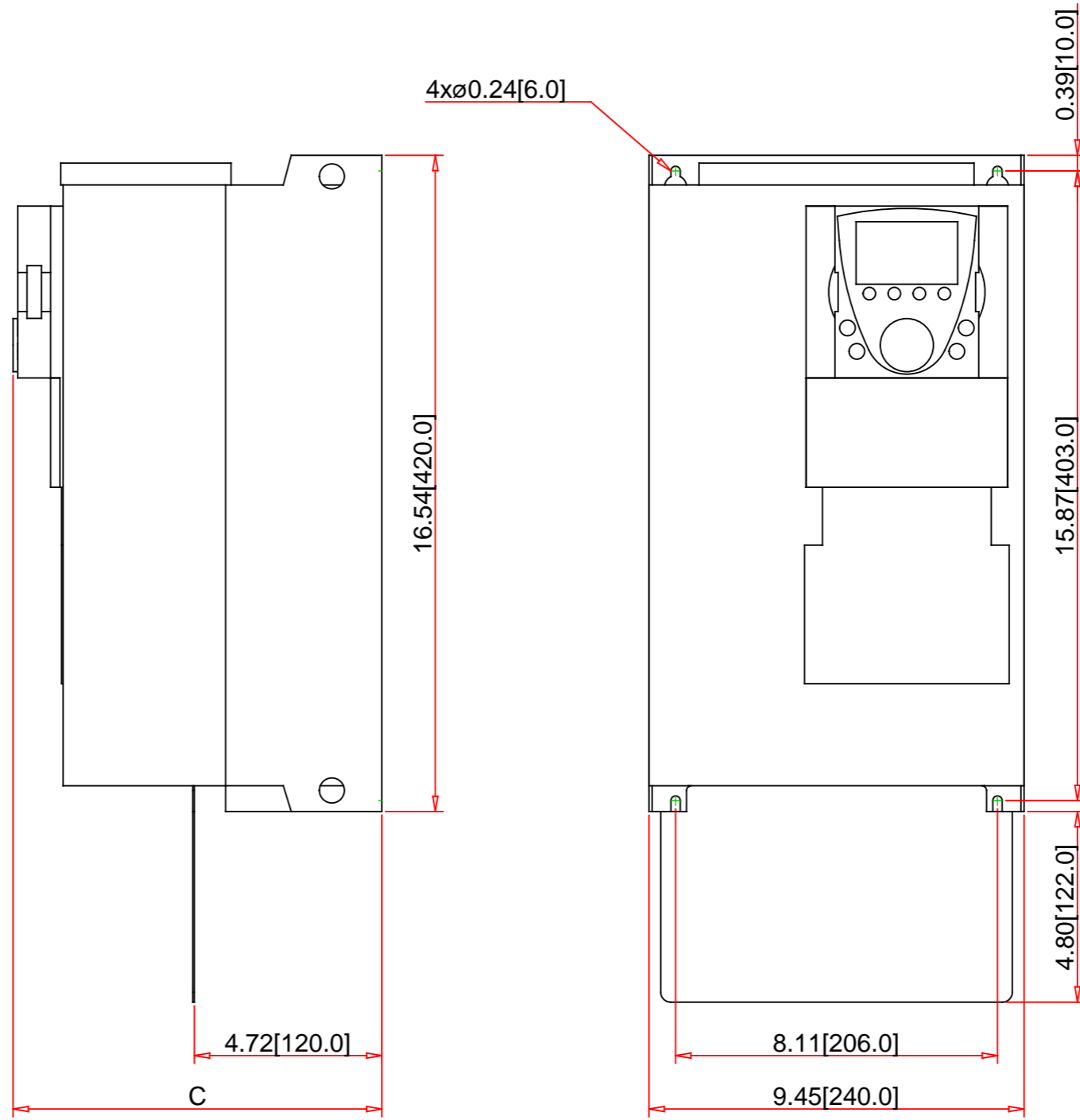

Optional EMC grounding plate is shown, it may be removed if not needed in the application.

Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]
 - Inch Dimensions are derived from the metric.

Part No.:
ATV71HD18Y

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com



Technical Information:

Control Voltage: 24Vdc
 Logic Input: 6
 Analog Input: 2
 Analog Output: 1
 Communication: Modbus and CANopen
 Logic/Relay Output: 1 NO/NC, 1 NO
 Weight [lb/kg]: 66.14 / 30
 UL File No.: E116875
 CSA File: 1650725
 Other: CE, ABS, DNV, GOST, RoHS, WEEE, C-Tick, NOM 117

Specification:

Description:
 Family: Altivar 71
 Product Line: AC Drive
 Application: Constant Torque
 Voltage Rating: 575/690VAC
 HP Rating / kW Rating: 20 / 18.5
 Output Ampere Rating: 22A / 24A
 Enclosure Rating: IP20
 Frame Size: 6
 Input Phase / Output Phase: 3-Phase / 3-Phase