



VW3 A4 405, VW3 A4 409

VW3 A4 401 ... 404

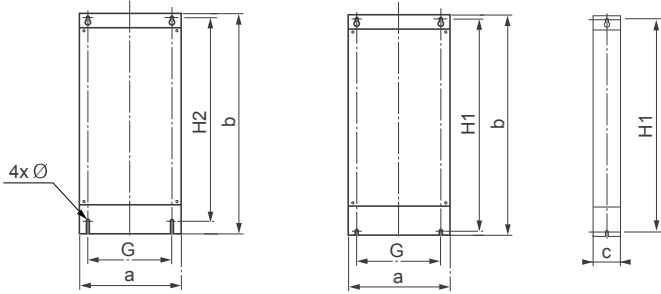

	a		b		c		G		H1		H2		Ø	
	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in
VW3 A4 401	130	5.12	290	11.42	40	1.57	105	4.13	275	10.83	-	-	4,50	0.18
VW3 A4 402	155	6.10	324	12.76	50	1.97	130	5.12	309	12.17	-	-	4,50	0.18
VW3 A4 403	175	6.89	370	14.57	60	2.36	150	5.91	355	13.98	-	-	5,50	0.22
VW3 A4 404	210	8.27	380	14.96	60	2.36	190	7.48	365	14.37	-	-	5,50	0.22
VW3 A4 405	230	9.06	498,5	19.63	62	2.44	190	7.48	479	18.86	460	18.11	6,6	0.26
VW3 A4 409	230	9.06	498,5	19.63	62	2.44	190	7.48	479	18.86	460	18.11	6,6	0.26

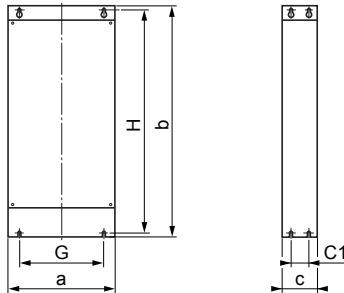

	a		b		c		C1		G		H		Ø	
	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in
VW3 A4 406	240	9.45	522	20.53	79	3.11	40	1.57	200	7.87	502,5	19.78	6,6	0.26
VW3 A4 407	240	9.45	650	25.59	79	3.11	40	1.57	200	7.87	631	24.84	6,6	0.26
VW3 A4 408	320	12.60	750	29.53	119	4.69	80	3.15	280	11.02	725	28.54	9,0	0.35

