

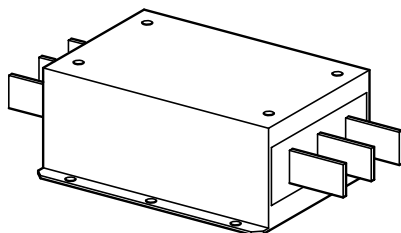
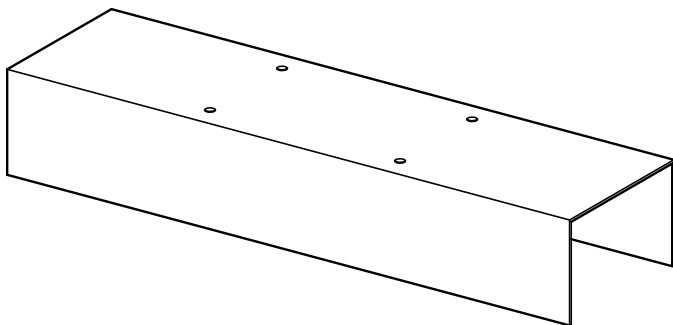


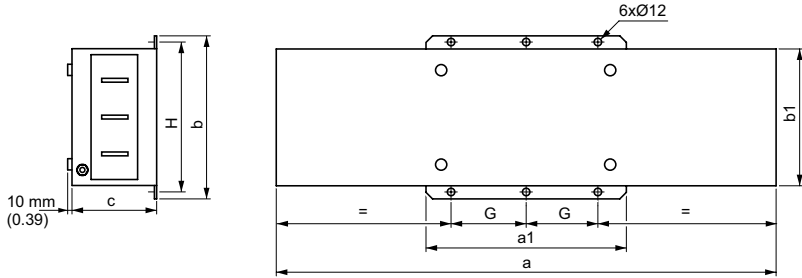

00175555712026

**Altivar****VW3 A4 410 ... 413**

|            |   |   |
|------------|---|---|
| VW3 A4 410 | ATV61 HD55M3X, ATV61 HD75M3X<br>ATV61 HD90N4 ... HC16N4 | ATV71 HD55M3X, ATV71 HD75M3X<br>ATV71 HD90N4 ... HC13N4 |
| VW3 A4 411 | ATV61 HD90M3X<br>ATV61 HC22N4 ... HC31N4                | ATV71 HC16N4 ... HC28N4                                 |
| VW3 A4 412 | ATV61 HC40N4, HC50N4                                    | ATV71 HC31N4 ... HC40N4                                 |
| VW3 A4 413 | ATV61 HC63N4  | ATV71 HC50N4  |

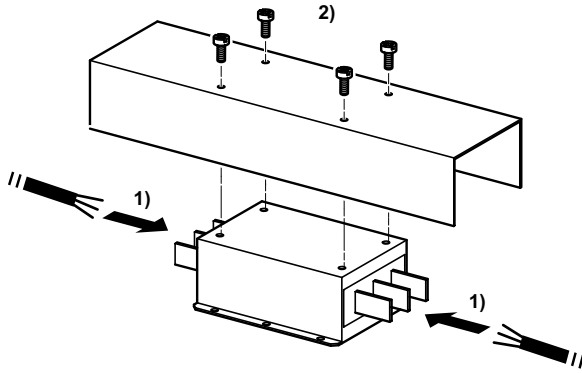

|                    | a    |       | a1  |       | b   |       | b1  |       | c   |      | G   |      | H   |       |
|--------------------|------|-------|-----|-------|-----|-------|-----|-------|-----|------|-----|------|-----|-------|
|                    | mm   | in.   | mm  | in.   | mm  | in.   | mm  | in.   | mm  | in.  | mm  | in.  | mm  | in.   |
| VW3 A4 410 ... 411 | 800  | 31.50 | 302 | 11.90 | 261 | 10.28 | 219 | 8.62  | 139 | 5.47 | 120 | 4.72 | 235 | 9.25  |
| VW3 A4 412         | 900  | 35.43 | 352 | 13.86 | 281 | 11.06 | 239 | 9.41  | 174 | 6.85 | 145 | 5.71 | 255 | 10.04 |
| VW3 A4 413         | 1000 | 39.37 | 401 | 15.79 | 301 | 11.85 | 259 | 10.20 | 164 | 6.46 | 170 | 6.69 | 275 | 10.83 |

