

# CERTIFICATE FI 29031 A1



Our Ref. 279816

**Product** Distribution box

**Type** Mureva U56

**Trade mark** Schneider Electric

**Certificate Holder** Schneider Electric Sverige AB  
CMS product department, Box 1009, SE-61129 NYKÖPING  
SWEDEN

**Manufacturer** Schneider Electric Sverige AB  
CMS product department, Tillverkarvägen 2, SE-61129 NYKÖPING  
SWEDEN

**Technical information** 440V~, IP65, 3-6 terminals, conductor area 1,5-2,5 mm<sup>2</sup>

**Other information** Junction box of white insulation material, flame class V-0, for surface mounting.  
10 inlets for grommet allowing a cable diam. up to 16mm.  
For floating terminals or 5-pole screw connecting terminal board (100733), 6-pole screw connecting terminal board (KS 2,5/6), 6-pole screwless connecting terminal board (MC 2,5/6) and a cable anchorage (100513). May also be mounted on a fixing steel plate.  
Lid with screw fixing, alternative lid with non-screw-type fixing  
Alternative box of white thermoplastic material (glow wire 650 °C)

**The product is certified according to the following standard(s)** EN 60670-1:2005 + A1:2013

**Validity** This certificate is valid until 11 March 2020 unless the standard in question has been amended or superseded with significant changes in requirements, in which case, SGS Fimko has the right to shorten the validity of the certificate based on the legislation of the European Union. This certificate includes the right to use the FI mark under the condition that changes (if any) will be checked at SGS Fimko before the product is brought onto market and that the conditions for FI certification are met.

**Directive information** The product(s) fulfils the essential safety requirements for CE conformity marking according to the Low Voltage Directive (2006/95/EC) at the date of issue of the certificate.


**Date of issue** 26 February 2016

**SGS Fimko Ltd**

**Signature**

Matti Huttunen  
Certification Engineer

**This certificate has 1 appendix**

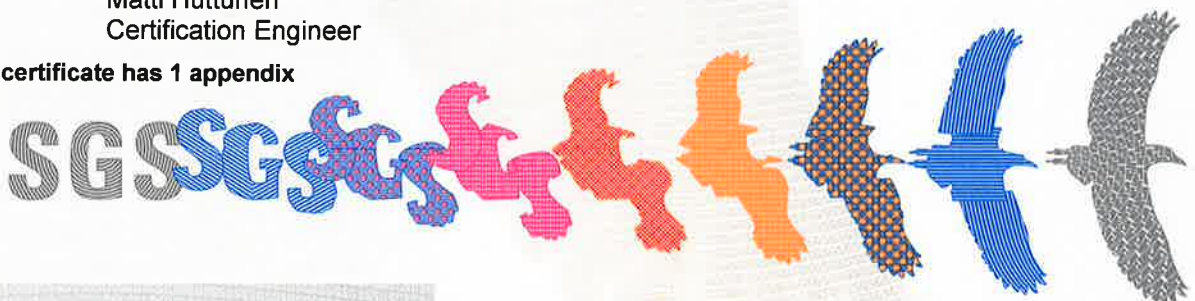

This certificate is issued by the company under its General Conditions for Certification Services accessible at <http://www.sgs.fi/en/Terms-and-Conditions.aspx>. Attention is drawn to the limitations of liability defined therein and in the Test Report here above mentioned which findings are reflected in this certificate. Any unauthorized alteration, forgery or falsification of the content or appearance of this document is unlawful and offenders may be prosecuted to the fullest extent of the law.

Appendix to Certificate: FI 29031 A1

**Manufacturing sites**

ELSO GmbH  
Frankenhäuser strasse 64, D-99706 SONDRSHAUSEN,  
GERMANY

**Additional information**

The product has certificate 1607303 issued by Intertek Semko AB in accordance with the Nordic Certification Service system.



This certificate replaces previous certificate FI 29031, dated 11 March 2015. The manufacturing site has been changed.

**Our ref. no.**

279816-2