


Part No.:

BMH0701T02A2A

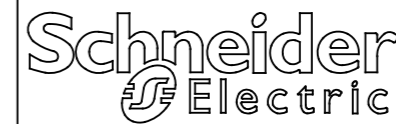

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Technical Information:

Frame Size (mm):	70
Degree of Protection (Shaft / housing):	IP54 / IP65
Maximum Current (Arms):	9.56
Holding brake:	No
Encoder Type:	ABS Multi turn 128 Sin/Cos period
Torque Constant (Nm/A):	0.49
CSA:	Yes
RoHS:	Yes
Weight without brake (kg / lb):	3.53 / 1.6

Description:

Family:	BMH
Maximum Permissible Speed (rpm):	8000
Continuous Stall Torque (Nm / lbs-in):	1.4 / 12.4
Peak Torque (Nm / lbs-in):	4.2 / 37.2

Specification: