


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

CA2KN223B7

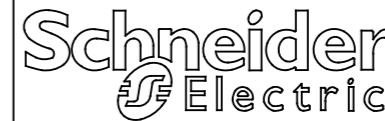

Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 8773425173
Email: CCC@us.schneider-electric.com

Technical Information:

Rating: A600, Q600 10A
UL File/CCN: E164353 / NKCR
CSA File: LR43364 3211 03
Meets Standards: IEC 60647-1-1
Weight: 0.40 lb (0.18 kg)
Termination Method: Spring Terminal
Wire Size: #16 - #18 AWG
Terminal torque: N/A
Mounting Hwd.: 35mm DIN Rail, 4mm screw

Specification:

Description: TeSys K IEC Control Relay - 2NO,2NC
Type: TeSys K IEC Control Relay - 10A - 24Vac Coil
Voltages Code: B7 at 24Vac 50/60 Hz
Coil Consumption: Inrush 30 VA
Sealed 4.5 VA