


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

CA2KN22Q7

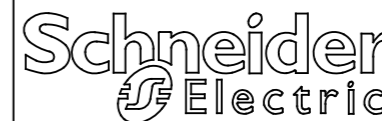

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Rating: A600, Q600 10A
 UL File/CCN: E164353 / NKCR
 CSA File: LR43364 3211 03
 Meets Standards: IEC 60647-1-1
 Weight: 0.40 lb (0.18 kg)
 Termination Method: Screw Clamp
 Wire Size: #12 - #18 AWG
 Terminal torque: 7 lb-in (0.8 Nm)
 Mounting Hwd.: 35mm DIN Rail, 4mm screw

Specification:

Description: TeSys K IEC Control Relay - 2NO,2NC
 Type: TeSys K IEC Control Relay - 10A - 380Vac Coil
 Voltages Code: Q7 at 380Vac 50/60 Hz
 Coil Consumption: Inrush 30 VA
 Sealed 4.5 VA