
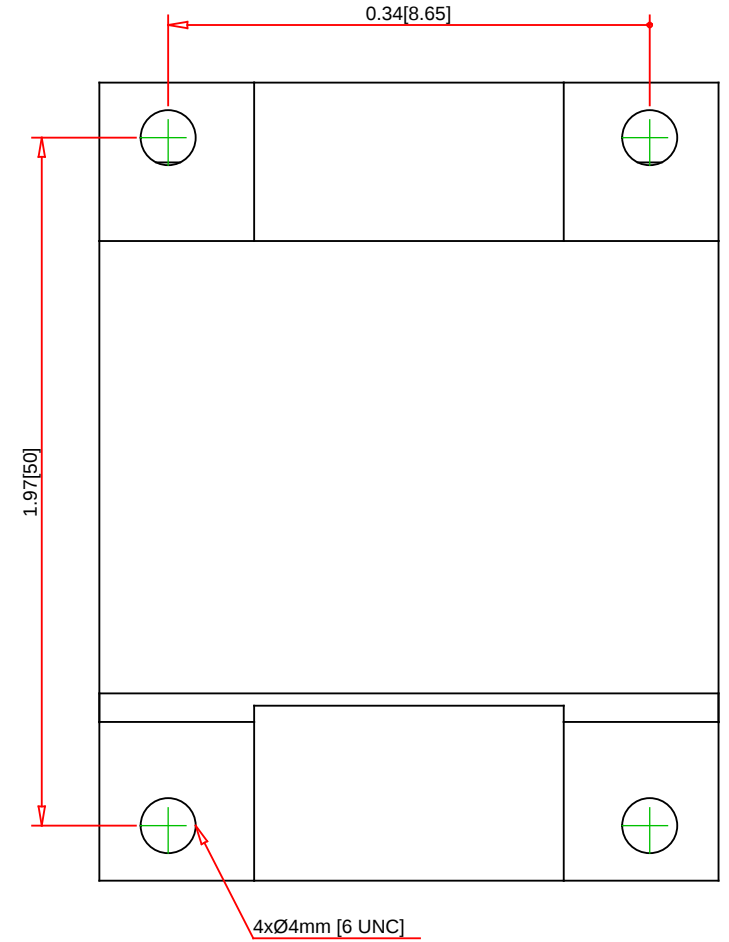
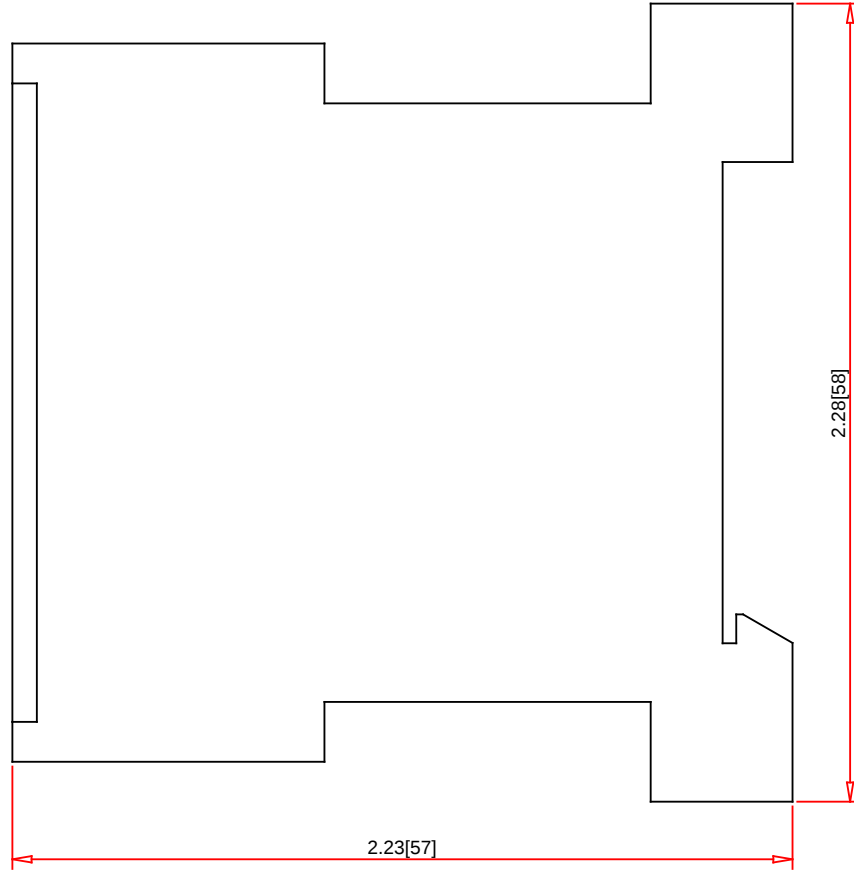


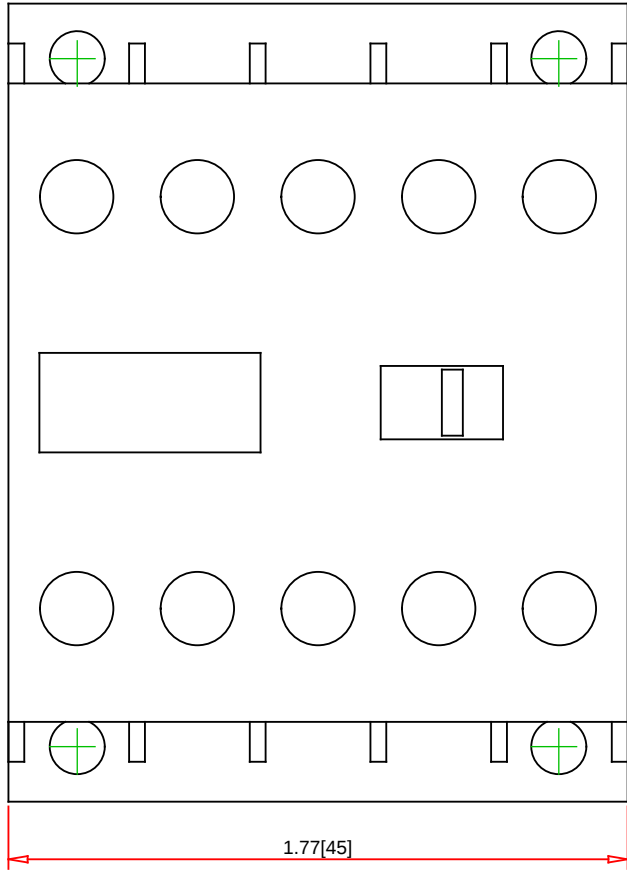

Note:
- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:
CA2KN40F7

Schneider Electric
Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 8773425173
Email: CCC@us.schneider-electric.com

Technical Information:
Rating: A600, Q600 10A
UL File/CCN: E164353 / NKCR
CSA File: LR43364 3211 03
Meets Standards: IEC 60647-1-1
Weight: 0.40 lb (0.18 kg)
Termination Method: Screw Clamp
Wire Size: #12 - #18 AWG
Terminal torque: 7 lb-in (0.8 Nm)
Mounting Hwd.: 35mm DIN Rail, 4mm screw

Specification:
Description: TeSys K IEC Control Relay - 4NO,0NC
Type: TeSys K IEC Control Relay - 10A - 110Vac Coil
Voltages Code: F7 at 110Vac 50/60 Hz
Coil Consumption: Inrush 30 VA
Sealed 4.5 VA