


**Note:**

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

**CA4KN313BW3**

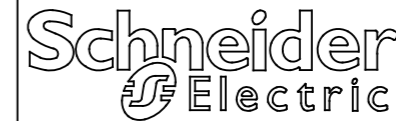

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Rating: A600, Q600 10A  
 UL File/CCN: E164353 / NKCR  
 CSA File: LR43364 3211 03  
 Meets Standards: IEC 60647-1-1  
 Weight: 0.40 lb (0.18 kg)  
 Termination Method: Spring Terminal  
 Wire Size: #16 - #18 AWG  
 Terminal torque: N/A  
 Mounting Hwd.: 35mm DIN Rail, 4mm screw

**Specification:**

Description: TeSys K IEC Control Relay - 3NO,1NC  
 Type: TeSys K IEC Control Relay - 10A - 24Vdc Coil  
 Voltages Code: BW3 at 24VDC  
 Coil Consumption: Inrush 1.8 W  
 Sealed 1.8W