


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

CAD326GD

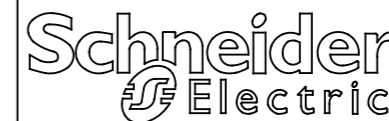

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Rating: A600, Q600 10A
 UL File/CCN: E164862 / NKCR
 CSA File: LR43364 3211 03
 Meets Standards: IEC 60647-5
 Weight: 1.28 lb (0.58 kg)
 Termination Method: Ring Tongue
 Wire Size: Lug Size 0.32 in (8mm)
 Terminal torque: 15 lb-in (1.7 Nm)
 Mounting Hwd.: 35mm DIN Rail, #8 screw

Specification:

Description: TeSys D IEC Control Relay - 3NO,2NC - Vdc Coil
 Type: TeSys D IEC Control Relay - 3NO,2NC - 125Vdc Coil
 Voltages Code: GD at 125Vdc
 Coil Consumption: Inrush 5.4 W
 Sealed 5.4 W