



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

CERTIFICATE NO.: 2024010307702035

NAME AND ADDRESS OF THE APPLICANT

Schneider Shanghai Power Distribution Elec.Co.,Ltd.
No.833 Kangqiao Road, Kangqiao Industrial Development Zone,Pudong Distrcit, Shanghai, P.R.China

NAME AND ADDRESS OF THE MANUFACTURER

Schneider Electric Industries SAS
35 Rue Joseph Monier 92500 Rueil-Malmaison, France

NAME AND LOCATION OF THE FACTORY

SCHNEIDER ELECTRIC FRANCE
70 RUE DE LA GRANGE BATIE, PARC D'ACTIVITES DE CENTR'ALP,38430
MOIRANS,FRANCE

PRODUCT NAME,MODEL AND SPECIFICATION

Air Circuit Breaker

Masterpact NW10/NW20/NW40 N/H DC;Ui: 1000V;Uimp: 12kV;Ue: DC500V,DC750V,DC900V;In:
1000A,2000A,4000A;Overcurrent release:Electronic;Ics=Icu: Masterpact NW10/20/40 N DC-C:
DC500V/35kA;Masterpact NW10/20/40 H DC-C: DC500V/85kA, DC750V/50kA, DC900V/35kA;Masterpact
NW10/20/40 H DC-D: DC500V/85kA, DC750V/50kA, DC900V/35kA;Masterpact NW10/20/40 H DC-E: DC500V/85kA,
DC750V/50kA, DC900V/35kA;Selectivity category:A; Poles:3P style,4P style, See the connection diagram;Applicable for
isolation;See the appendix

STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS

GB/T 14048.2-2020

This is to certify that the above mentioned product(s) complies with the requirements of
implementation rules for compulsory certification(REFNO. CNCA-C03-02:2024).

Valid from: Feb.10,2026

Valid until: Oct.08,2029

Date of original issued: Oct.09,2024

The certificate information and validity could be checked by scanning the QR code below or logging in to
the website of the issuing authority, or on the website of the CNCA (www.cnca.gov.cn).



SIGNATURE:

谢肇煦



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE



CHINA QUALITY CERTIFICATION CENTRE CO., LTD.



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

CERTIFICATE NO. : 2024010307702035

Appendix: Page 1 of 2

NW 40 N/H DC - E
(1) (2) (3) (4) (5)

(1) 型号

(2) 电流等级

10----1000A
20----2000A
40----4000A

(3) 分断能力

N 型: 500V: 35kA

H 型: 500V: 85kA

750V: 50kA

900V: 35kA

(4) 直流型

(5) 端子联接类型

C----C 型连接方式，见下图；
D----D 型连接方式，见下图；
E----E 型连接方式，见下图；

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心

CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.




CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

CERTIFICATE NO. : 2024010307702035

Appendix : Page 2 of 2

本翻译文件不具有法律效力，不得单独使用
This translated document does not have legal validity and cannot be used in isolation

直流接线图:

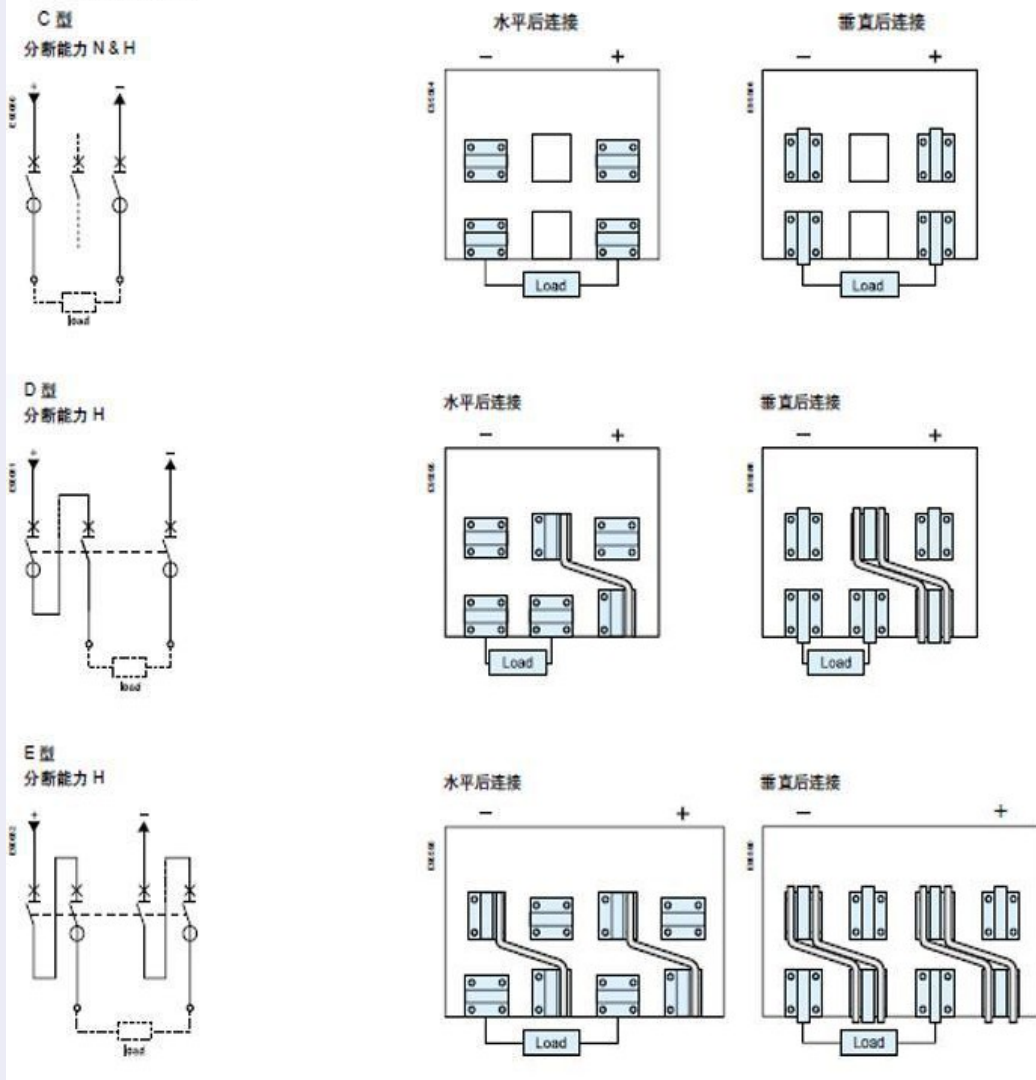

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.