



Year round comfort with the flick of a switch.


This summer, bring the gentle cooling breeze of a tropical island into your home with Airflow Reversible Ceiling Fans.

Ideal for living areas and bedrooms, the blades gently circulate air to keep your family comfortably cool, while the fan motor is whisper quiet to help ensure a peaceful night's sleep.


In winter, simply flicking the switch located just above the blades reverses the fan direction so that the warm air that rises towards the ceiling from your heater, is directed back down to where it's needed most.

As warm air is better circulated around the room, you'll find that you can usually turn your heating to a lower setting to help reduce your winter heating bills.

Airflow Reversible Ceiling Fans are so economical that they use less power than a light globe.

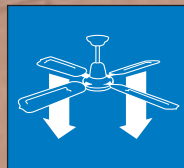

Air is forced back into the room in winter

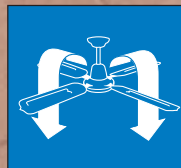

Air is gently swirled down in summer

Contemporary styling

Airflow Reversible Ceiling Fans perfectly combine functionality with fashion.

Their streamlined, contemporary design makes them the perfect choice for any style of home.

All Airflow fans are supplied with Clipsal's popular 2000 Series switchplates which complement other 2000 Series switches and sockets.

A range of accessories is also available, including mounting kits for installing fans on raked ceilings, and Oyster light kits.

Fashion Series

4 Rattan/Timber Blades

These beautiful timber and rattan look blade fans will turn any home into your own piece of paradise. With quiet and efficient performance they're a stylish addition to living areas and bedrooms.

Features

- Four reversible timber/rattan look blades.
- Three speed capacitor controller.
- Light adaptable.
- Sealed top and bottom bearings.
- Reversing switch on fan motor.
- Pre-wired and part assembled.



Product Range				
Cat. No.	Diameter	Colours	Power 240V~ 50Hz	Fan Speed (RPM)
AFLR48	1200mm (48")	White (WE)	60W	High 240, Med 140, Low 100
AFLR48	1200mm (48")	Beige (BG)	60W	High 240, Med 140, Low 100

Please specify colour when ordering.



3 Speed Controller



Reversible Blades



Distinctive Brass Trim



Reversing Switch

High Performance Series

3 Aluminium Blades

The aluminium blades of Airflow's High Performance Series offer outstanding corrosion resistance in harsh environments such as coastal regions and areas of high humidity.

A range of sizes is available as well as two mounting versions - j hook mounting for easy installation on flat ceilings and hangsure mounting for raked ceilings.

Features

- Three heavy gauge aluminium blades.
- Three speed capacitor controller.
- Light adaptable.
- Sealed top and bottom bearings.
- Reversing switch on fan motor.
- Pre-wired and part assembled.



Product Range - with J Hook mounting				
Cat. No.	Diameter	Colours	Power 240V~ 50Hz	Fan Speed (RPM)
ACES36JAL	900mm (36")	White (WE)	65W	High 370, Med 220, Low 125
ACES48JAL	1200mm (48")	White (WE)	65W	High 280, Med 200, Low 130
ACES56JAL	1400mm (56")	White (WE)	65W	High 260, Med 180, Low 120


Product Range - with Hangsure mounting				
Cat. No.	Diameter	Colours	Power 240V~ 50Hz	Fan Speed (RPM)
ACES36AL	900mm (36")	White (WE)	65W	High 370, Med 220, Low 125
ACES48AL	1200mm (48")	White (WE)	65W	High 280, Med 200, Low 130
ACES56AL	1400mm (56")	White (WE)	65W	High 260, Med 180, Low 120



3 Speed Controller



J Hook Mounting Kit

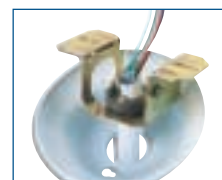

Hangsure Mounting Kit



Reversing Switch



Accessories

The following accessories can be used to customise your Airflow fan to suit your individual requirements.



Down Rod

Down Rods

Cat. No.	Description	Colours
DR30X1/2	Hangsure 760mm Down Rod	White (WE)
DR30X1/2	Hangsure 760mm Down Rod	Beige (BG)
DR30X1/2J	J Hook 760mm Down Rod	White (WE)

Please specify colour when ordering.



Mounting Kit

Mounting Kit

Cat. No.	Description	Colours
HSMK	Hangsure Mounting Kit	White (WE)
HSMK	Hangsure Mounting Kit	Beige (BG)
HSMK	Hangsure Mounting Kit	Brown (BR)

Please specify colour when ordering.



Light Kit

Light Kit

Cat. No.	Description	Colours
OYWHT	Oyster Light Kit	White (WE)
OYBEI	Oyster Light Kit	Beige (WE)

Products of Gerard Industries Pty Ltd

ABN 27 007 873 529

Head Office

12 Park Terrace, Bowden
South Australia 5007
Telephone (08) 8269 0511
Facsimile (08) 8340 1724
Internet clipsal.com
E-Mail plugin@clipsal.com.au

Offices in all States

NSW	Sydney	(02) 9794 9200
	Albury	(02) 6041 2377
VIC	Melbourne	(03) 9207 3200
	Country Areas	1800 653 893
QLD	Brisbane	(07) 3244 7444
	Townsville	(07) 4729 3333
SA	Adelaide	(08) 8268 0400
WA	Perth	(08) 9442 4444

TAS Hobart (03) 6272 3177
Launceston (03) 6343 5900

NT Darwin (08) 8947 0278

International Enquiries

Head Office Export Department

Telephone + 61 8 8269 0587
Facsimile + 61 8 8340 7350
E-Mail export@clipsal.com.au

New Zealand

Clipsal Industries (NZ) Ltd (Auckland)

Telephone (09) 576 3403
Facsimile (09) 576 1015
E-Mail headoffice@clipsal.co.nz

Customer Service

Free Fax (0508) 250 305
Auckland/Mobile Phone (09) 572 0014
Free Phone (0508) CLIPSAL
2547725

You can find this brochure and many others online in PDF format at:
clipsal.com

Follow the links off the home page or access the following page directly:
clipsal.com/wat_lib_pdf.cfm

clipsal.com

Gerard Industries Pty Ltd reserves the right to change specifications, modify designs and discontinue items without incurring obligation and whilst every effort is made to ensure that descriptions, specifications and other information in this catalogue are correct, no warranty is given in respect thereof and the company shall not be liable for any error therein.

©Copyright Gerard Industries Pty Ltd
Printed by Custom Press Pty Ltd (08) 8346 7999