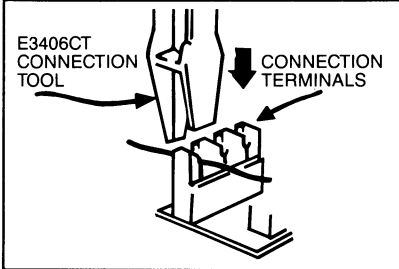
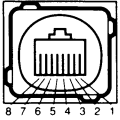
 
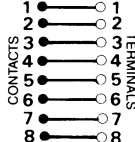
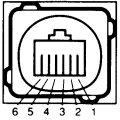
 
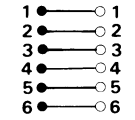
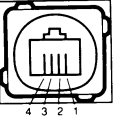
 
 
 
 
 
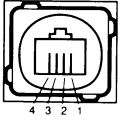
 
 
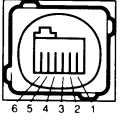
 
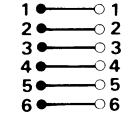
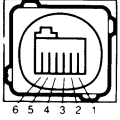
 
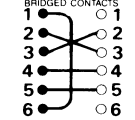


CLIPSAL 30RJ SERIES INSTALLATION INSTRUCTION

	CAT. No.	FRONT VIEW (CONTACT)	REAR VIEW (TERMINAL)	CIRCUIT/CONTACTS	SCHEMATIC WIRING DIAGRAM	MARKING	WIRING DETAIL CONNECTION OF THESE SOCKET MECHS. IS BY THE IDC (INSULATION DISPLACEMENT CONNECTION) METHOD. —ALLOWS ONE OR TWO EQUAL SIZE CABLES (BETWEEN 0.4mm & 0.68mm) TO BE TERMINATED PER CONNECTION TERMINAL. —'E3406CT' CONNECTION TOOL USED TO MAKE TERMINATION (as per illustration below).  —ALLOW 50mm CABLE 'TAILS' AT EACH CONNECTION TERMINAL. —PUSH HOME IN DIRECTION OF ARROW WITH CONNECTION TOOL. —EXCESS CABLE MAY BE TRIMMED USING WIRE CUTTERS. COLOURS: 30RJ SERIES White Electric, Soft Grey, Desert Sand, Cream, Black 31VRJ & 2031VRJ SERIES White Electric Soft Grey Desert Sand Cream
RJ45 SERIES	30RJ88SM 30RJ88SMD 30RJ88SMT			8 WAY/8 CONTACTS (Equivalent to RJ45)		NONE 'DATA' ↔ 'TELEPHONE' ↻	
RJ12 ALTERNATE	30RJ86SM			8 WAY/6 CONTACTS		NONE	
RJ11 ALTERNATE	30RJ84SM			8 WAY/4 CONTACTS		NONE	
RJ12 SERIES	30RJ66SM			6 WAY/6 CONTACTS (Equivalent to RJ12)		NONE	
RJ11 SERIES	30RJ64SM 30RJ64SMT			6 WAY/4 CONTACTS (Equivalent to RJ11)		NONE ↻	
RJ12K SERIES (VERSION 1)	30RJ66SM11 30RJ66SM11D		 BLUE DOT	6 WAY/6 CONTACTS "KEYED" (Equivalent to RJ12K)		NONE 'DATA' ↔	
RJ12K SERIES (VERSION 2)	30RJ66SM12		 RED DOT	6 WAY/6 CONTACTS "KEYED" CIRCUIT SUIT DEC DIGITAL SYSTEMS		'DATA' ↔	

VERTICAL ASSEMBLED 2000 SERIES

- 2031VRJ Single gang gridplate fitted with 30RJ88SM. Complete with curved surround 116 x 76mm
- 2031VRJT Single gang gridplate fitted with 30RJ88SMT. Complete with curved surround 116 x 76mm
- 2031VRJD Single gang gridplate fitted with 30RJ88SMD. Complete with curved surround 116 x 76mm
- 2032VRJ Two gang gridplate fitted with 2 x 30RJ88SM. Complete with curved surround 116 x 76mm
- 2032VRJTD Two gang gridplate fitted with 30RJ88SMT & 30RJ66SMD. Complete with curved surround 116 x 76mm

VERTICAL ASSEMBLED STD. PTN. SERIES

- 31VRJ Single gang flushplate fitted with 30RJ88SM 115 x 73mm
- 32VRJ Two gang flushplate fitted with 2 x 30RJ88SM 115 x 73mm