




Cat 901 Plug SIDE ENTRY

Recommended for use with 0.75mm² to 1.5mm²
PVC insulated ordinary duty 3 core circular flexible cords


STRIPPING DETAIL (FULL SIZE)

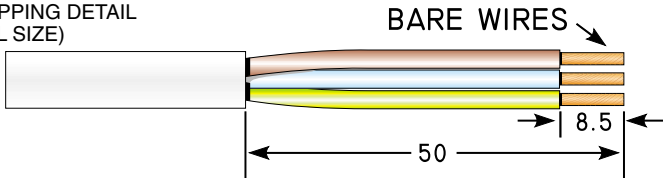

WIRING INSTRUCTIONS

1. Strip insulation as illustrated and twist bare conductor strands.
2. Connect the Earth wire (Green/Yellow or Green) to the terminal marked '⏏'.
3. Connect the Active (Live) wire (Brown or Red) to the terminal marked 'L'.
4. Connect the Neutral wire (Blue or Black) to the terminal marked 'N'.
5. Tighten cord clamp around outer sheath of flexible cord.
6. **Check the wires are in their correct position as illustrated and the terminal screws are tight.**
7. Put plug cover into place and ensure the fixing screws are fully tightened.

Note: When using 2 core (0.75mm) flexible cord on the 10A plug, fit the adaptor piece (located between phase & neutral terminals). The 15A plug is not suitable for use with 2 core (0.75mm) flexible core.

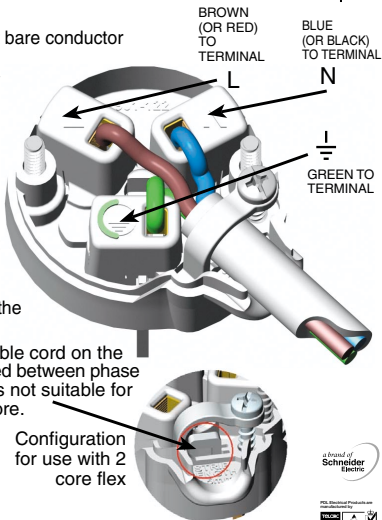

PDL

New Zealand Head Office: PO Box 15 355, New Lynn, Auckland, New Zealand
Telephone +64-9-829 0490, Fax +64-9-829 0491
www.pdl.co.nz



Electrical Products

PDL Industries Australia Pty Ltd
Locked Bag 5500, Baulkham Hills Business Centre,
Baulkham Hills NSW 2153, Australia
Freephone 1300 735 266, Freefax 1300 735 329
Telephone +61-29851 2666, Fax +61-29851 2695
www.pdl.com.au

