

# Cat 927 Pendant Connector

Recommended for use with 0.75mm<sup>2</sup> to 1.5mm<sup>2</sup>  
PVC insulated ordinary duty 3 core circular flexible cords


## STRIPPING DETAIL (FULL SIZE)



## WIRING INSTRUCTIONS

Note: Earth wire is clamped between the moving nuts and the fixed contact. **DO NOT** wrap wires under head of screw.

1. Strip insulation as illustrated and twist bare conductor strands.
2. Slide the Pendant connector cover over the flex.
3. Connect the Earth wire (Green/Yellow or Green) to the terminal on socket marked 'E'.
4. Connect the Active (Live) wire (Brown or Red) to the terminal on switch marked '3'.
5. Connect the Neutral wire (Blue or Black) to the terminal on switch marked '2'.
6. Place the Earth wire onto the slot as illustrated and tighten cord clamp around outer sheath of flexible cord. NOTE: 5mm of sheath minimum must be beyond the end of the cord clamp.
7. Check the wires are in their correct position as illustrated and the terminal screws are tight.
8. Slide the Pendant connector cover into place and ensure the fixing screws are fully tightened.

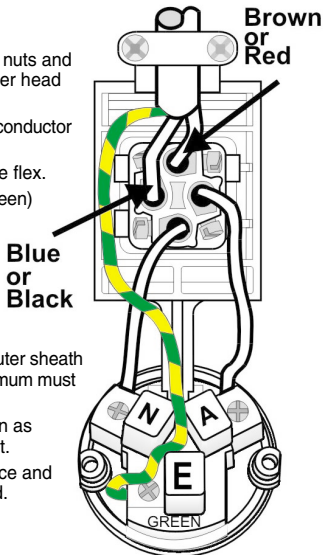

**PDL**

New Zealand Head Office: PO Box 15 355, Auckland, New Zealand  
Telephone +64-9-829 0490, Fax +64-9-829 0491  
[www.schneider-electric.co.nz](http://www.schneider-electric.co.nz)

Australia Head Office: Locked Bag 5500, Baulkham Hills Business Centre,  
NSW 2153, Australia  
Telephone +61-2-9851 2800, Fax +61-2-9629 8340  
[www.schneider-electric.com.au](http://www.schneider-electric.com.au)

brand of  
**Schneider  
Electric**

