


Wall Plug, Single-Phase, 3-Pin Heavy Duty 425HD

Wiring Details


Recommended Cables

Product Reference	Cable
425HD	3-core 2.5mm ² (50/0.25) 250 volt PVC insulated and sheathed heavy duty flexible cord.

Stripping Detail

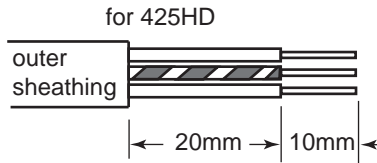

Wiring Instructions

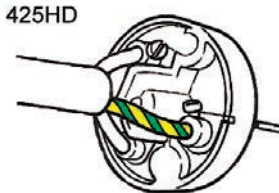

Must be installed by a suitably licenced and qualified electrician only. Use eye protection when stripping wires.

1. Strip the recommended cable to length as shown in 'Stripping Detail' and then twist the wire strands together.
2. Slip the cover over the flexible cable. (If the cord grip is used, it may require loosening).
3. Connect the Earth wire with green/yellow stripe (or all green) to the Earth terminal marked 'E', 'Earth' or green.
4. Connect the brown or red wire to the Active terminal marked 'A.'
5. Connect the blue or black wire to the Neutral terminal marked 'N.'
6. Double check that the Earth wire is connected to the Earth terminal.
7. Fit the cover and tighten the screws. Ensure that the cable is pushed into the base. Make sure that the base and cover are aligned properly using the key and notch.
8. Tighten the cord grip to provide strain relief.