



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

CERTIFICATE NO.: 2024010305659849

NAME AND ADDRESS OF THE APPLICANT

Schneider Electric (China) Co. Ltd. Shanghai Branch
No. 669, Suid Road, Putuo District, Shanghai, P.R.China

NAME AND ADDRESS OF THE MANUFACTURER

Schneider Electric Industries SAS
35 Rue Joseph Monier 92500 Rueil-Malmaison, France

NAME AND LOCATION OF THE FACTORY

Schneider Electric a. s.
Cizovska 447 - 39701 Pisek - Czech Republic

PRODUCT NAME,MODEL AND SPECIFICATION

Illuminated Beacon

XVB : Ui:250V; Uimp:4kV; Filament Lamp:Ue: AC12-48V,AC48-230V; LED:Ue:AC/DC24V, AC120V,AC230V;
Discharging Tube:Ue:AC/DC24V,AC120V,AC230V,AC48V,DC48V; Buzzer:Ue:AC/DC12-48V,AC120-230V; IP65
(Installed on fixed base)、IP66 (Installed directly in the base unit)

STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS

GB/T 14048.5-2017

This is to certify that the above mentioned product(s) complies with the requirements of
implementation rules for compulsory certification(REFNO. CNCA-C03-02:2024).

Valid from: Jul.18,2024

Valid until: Jul.17,2029

The certificate information and validity could be checked by scanning the QR code below or logging in to
the website of the issuing authority, or on the website of the CNCA (www.cnca.gov.cn).



SIGNATURE:

谢肇煦



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.





CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

CERTIFICATE NO. : 2024010305659849

Appendix: Page 1 of 4

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

白炽灯型号规格解释

<u>XVB</u>	<u>L</u>	<u>3</u>	<u>B</u>	<u>3</u>
I	II	III	IV	V
I -	产品系列号 XVB			
II -	外形 L - 灯塔, 直径 70 mm			
III -	灯泡型式和信号型式 3 - 白炽灯, 恒定光(仅适用 L 型) 4 - 白炽灯, 闪烁光(仅适用 L 型)			
IV -	电源电压 (仅适用于闪烁型) B - 24...48 V DC M - 48...230 V AC			
V -	镜片颜色 3 - 绿色 4 - 红色 5 - 琥珀色 6 - 蓝色 7 - 透明 8 - 黄色			

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

CERTIFICATE NO. : 2024010305659849

Appendix: Page 2 of 4

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

LED 型和放电管型号规格解释				
XVB I	L II	0 III	B IV	3 V
I -	产品系列号 XVB			
II -	形状			
	L - 灯塔, 直径 70 mm			
	C - 镜片或 底座 + 外壳			
III -	灯泡型式和信号型式或其它			
	0 - LED 串, 恒定光 Waiting for MD confirm(仅适用 L 型)			
	1 - LED 串, 闪烁光 Waiting for MD confirm(仅适用 L 型)			
	6 - 内置式放电管 5J			
	8 - 内置式放电管 10J 为 XVB 型			
	21 - 底座+盖+垫圈			
	21A - 底座+盖+垫圈 侧面电缆插入 AS 界面			
	21B - 底座+盖+垫圈 底部电缆插入 M12 连接器 AS 界面			
IV -	电压			
	E - 48VAC/DC			
	G - 120 V AC			
	M - 230 V AC			
V -	镜片颜色			
	3 - 绿色			
	4 - 红色			
	5 - 琥珀色			
	6 - 蓝色			
	7 - 透明			
	8 - 黄色			
发声单元型号规格解释				
XVB I	C9 II	B III		
I -	产品系列号			
	XVB - 安装在 XVB 底座上			
II -	形状			
	C9 - 蜂鸣器元件			
III -	电源电压			
	B - 12...48 V AC/DC			
	M - 120...230 V AC			

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

CERTIFICATE NO. : 2024010305659849

Appendix: Page 3 of 4

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

Description of the series		Incandescent Pilot Light Models				
Explanation about the model		XVB	L	3	B	3
		I	II	III	IV	V
I	Series designation XVB					
II	Shape L - Beacon 70 mm diameter					
III	Type of bulb and type of signal or other 3 - Incandescent bulb, steady light (only for Shape L) 4 - Flashing with incandescent bulb (only for Shape L)					
IV	Supply Voltage (for flashing type only) B - 24...48 VDC M - 48...230 VAC					
V	Lens Color 3 - Green 4 - Red 5 - Amber 6 - Blue 7 - Clear 8 - Yellow					

Description of the series		LED Cluster models and built-in strobe models				
Explanation about the model		XVB	L	0	B	3
		I	II	III	IV	V
I	Series designation XVB					
II	Shape L - Beacon 70 mm diameter C - Lens or base + cover for bank					
III	Type of bulb and type of signal or other 0 - LED cluster, steady light (only for Shape L) 1 - LED cluster, flashing (only for Shape L) 6 - Built-in strobe 5J 8 - Built-in strobe 10J for XVB type 21 - Base + cover + gasket 21A - Base + cover + gasket with side cable entry for AS-Interface 21B - Base + cover + gasket with bottom entry, pre-cabled and fitted with M12 and connector for AS-Interface					
IV	Supply Voltage (for flashing type only) E - 48VAC/DC G - 120 VAC M - 230 VAC					
V	Lens Color 3 - Green 4 - Red 5 - Amber 6 - Blue 7 - Clear 8 - Yellow					

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.




CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

CERTIFICATE NO. : 2024010305659849

Appendix: Page 4 of 4

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

Description of the series Explanation about the model	Audible signal units		
	XVB	C9	B
I	I	II	III
I Series designation			
XVB - For mounting on XVB base			
II Shape			
C9 - Buzzer element			
III Supply voltage			
B - 12...48 VAC/DC			
M -120...230 VAC			

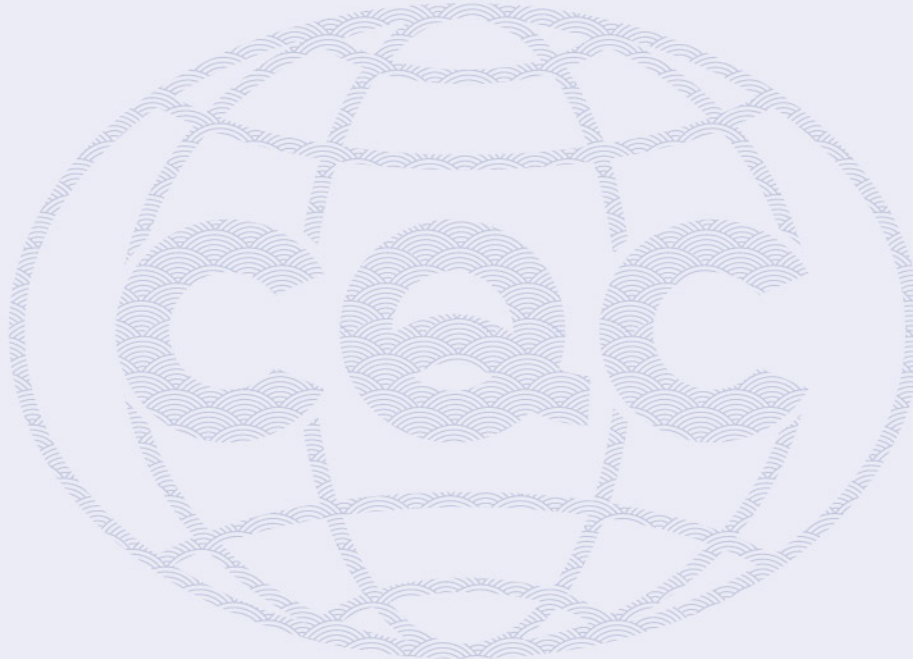

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.