

产品认证证书

II型自愿认证

证书编号: CQC2009010307369403

发证日期: 2021年09月22日

有效期至: 2031年09月22日

委托人名称 Schneider Electric Industries SAS
及注册地址 35 Rue Joseph Monier 92500 Rueil-Malmaison, France

制造商名称 Schneider Electric Industries SAS
及注册地址 35 Rue Joseph Monier 92500 Rueil-Malmaison, France

生产企业名称 Schneider Electric France
及生产地址 6-8, rue du Bailly - BP 97812 -21078- Dijon Cedex France

产品名称和系列、规格、型号 断路器
GV3L; 详见附件

产品标准和技术要求 GB/T 14048.2-2020

认证模式 产品型式试验+初次工厂检查+获证后监督

上述产品符合 CQC12-000001-2020 认证规则的要求, 特发此证。

本证书为变更证书, 证书首次颁发日期: 2020年09月28日

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

可通过扫描下方二维码或登录国家认监委网站(www.cnca.gov.cn)查验证书信息



授权签字人

签发

陈昕

谢肇煦



中国质量认证中心

产品认证证书

II型自愿认证

证书编号: CQC2009010307369403

第 1 页 共 3 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号:

GV3L

Ui:690V; Uimp:6kV,Ue:AC230/240V,400/415V,440V,500V,690V;

过电路脱扣器类型: 电磁式;

Ith=In:25A,32A,40A,50A,65A,73A,80A;

Icu:

GV3L25,GV3L32:

100kA(AC230/240V), 100kA(400/415V),50kA(AC440V),12kA(AC500V),
6kA(AC690V);

GV3L40,GV3L50, GV3L65, GV3L73:

100kA(AC230/240V), 50kA(400/415V),50kA(AC440V),12kA(AC500V),
6kA(AC690V);

GV3L80:

65kA(AC230/240V), 50kA(400/415V),50kA(AC440V),12kA(AC500V),
6kA(AC690V);

Ics:

GV3L25-GV3L65:

100%Icu(AC230/240V,400/415V,440V),50%Icu(AC500V,690V)

GV3L73-GV3L80: 100%Icu(AC230/240V), 60%Icu(AC400/415V,440V),
50%Icu(AC500V,690V);

使用类别:A 类; 极数: 3P;

配用的辅助触头: 2NO or1NO/1NC;Ith:2.5A;

AC-15:Ue/Ie:AC24V/2A,AC48V/1.25A,AC110V-127V/1.5A,
AC230V-240V/0.75A;

DC-13:Ue/Ie:DC 24V/1A,DC48V/0.3A,DC60V/0.15A.



中国质量认证中心

产品认证证书

II型自愿认证

证书编号：CQC2009010307369403

第 2 页 共 3 页

本证书及附件应同时使用，信息查验说明见证书页

纸号：

型号解释：

GV3	L	25	6
I	II	III	IV

I -	Designates Basic Model
II -	Designates actuation means L Magnetic tripping
III -	Designates trip setting range (A) 25 25A 32 32 A 40 40 A 50 50 A 65 65 A 73 73 A 80 80 A
IV -	Designates Type of Terminations (Power / Control) Blank - screws and clamp 1 - - without bottom connection (to be mounted directly up to a contactor) 6 - Ring lug terminals (must be used with IP20 cover reference LAD96570)



中国质量认证中心

产品认证证书

II型自愿认证


证书编号：CQC2009010307369403

第 3 页 共 3 页

本证书及附件应同时使用，信息查验说明见证书页

纸号：

(Except for GV3L80)

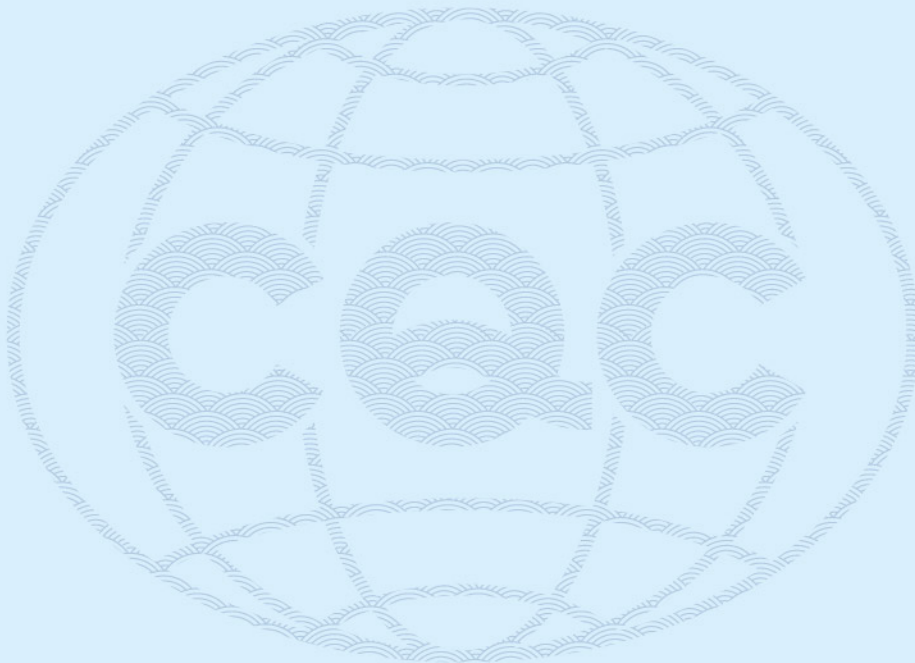

中国质量认证中心