



LICENCE

No.: 10228

Issued to:
Applicant:
Schneider MGTE N.V.-S.A.
Dieweg 3
BRUSSEL, Belgium

Manufacturer/Licensee:
Schneider MGTE N.V.-S.A.
Dieweg 3
BRUSSEL, Belgium

Product : modular switches
Trade name(s) : MERLIN GERIN
Type(s)/model(s) : 150xx

The product and any acceptable variation thereto is specified in the Annex to this licence and the documents therein referred to.

CEBEC Registered Quality hereby declares that the above-mentioned product has been certified on the basis of :

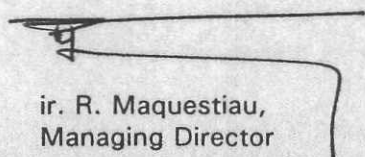
- a type test according to the standard EN 60699-1
- an inspection of the production location according to CCA Group Operational Document CCA 204
- a certification agreement with the number 12

CEBEC Registered Quality hereby grants the right to use the CEBEC certification mark



The CEBEC certification mark may be applied to the product as specified in this licence for the duration of the CEBEC certification agreement and under the conditions of the CEBEC certification agreement.

This licence is issued on: October 2, 1997


ir. R. Maquestiau,
Managing Director

© Integral publication of this certificate is allowed

SPECIFICATION OF THE CERTIFIED PRODUCTS**Product data**

product : modular switches
 trade name(s) : MERLIN GERIN
 type(s) : 15013, 15014, 15015, 15016,
 15019, 15020, 15023, 15024

 Rated current (In) : 40 and 63 A
 Rated voltage/ : 250 V for pattern 1
 Number of patterns : 415 V for pattern 2, 3, 03
 Nature of supply : AC
 Rated frequency : 50 Hz
 Method of mounting : DIN-RAIL

Additional information

<u>Reference number</u>	<u>Pattern number</u>	<u>Rated current (In)</u>
15024	1	40 A
15020	2	40 A
15023	3	40 A
15019	03	40 A
15013	1	63 A
15014	2	63 A
15015	3	63 A
15016	03	63 A

Product data - type 15024

Rated current (In) : 40 A
 Rated voltage (Un) : 250 V
 Pattern number : 1

Product data - type 15020

Rated current (In) : 40 A
 Rated voltage (Un) : 415 V
 Pattern number : 2

Product data - type 15023

Rated current (In) : 40 A
 Rated voltage (Un) : 415 V
 Pattern number : 3

Product data - type 15019

Rated current (In) : 40 A
Rated voltage (Un) : 415 V
Pattern number : 03

Product data - type 15013

Rated current (In) : 63 A
Rated voltage (Un) : 250 V
Pattern number : 1

Product data - type 15014

Rated current (In) : 63 A
Rated voltage (Un) : 415 V
Pattern number : 2

Product data - type 15015

Rated current (In) : 63 A
Rated voltage (Un) : 415 V
Pattern number : 3

Product data - type 15016

Rated current (In) : 63 A
Rated voltage (Un) : 415 V
Pattern number : 03

TESTS

Test requirements

NBN-EN
60699-1

Test results

The test results are laid down in CCA/B80/1997 and TRF Nos. 97001/00, 97001/01, 97001/02.

FACTORY-LOCATION(S)

Schneider MGTE N.V.-S.A.
Dieweg 3, BRUSSEL, Belgium