


ELECTRICAL CLEARANCE/WIRE BENDING SPACE

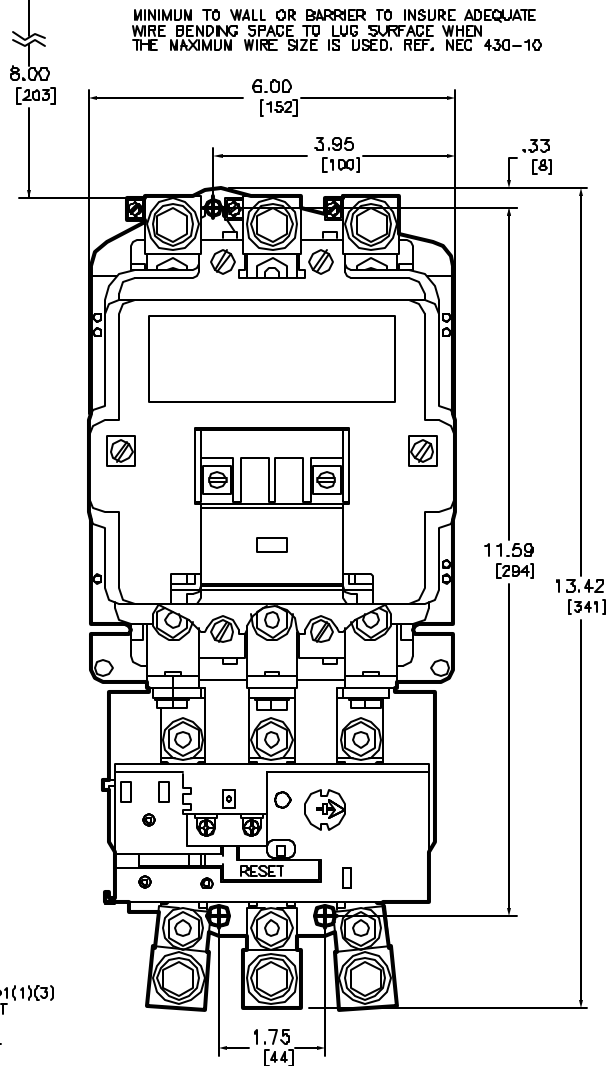

Catalog Number: 8536-SF01(1)(3)
 Ratings: SEE CHART
 UL File/CCN: NLDX
 CSA File/Class: 32011-04
 Meets Standards: -
 Weight: 25.08 lbs
 Wire Size: POWER - #8-25MCM, CONTROL - #16-#12
 Terminal torque: 200 lb./in.
 Mounting Hwd.: (3) #5/16 screws

NEMA SIZE 4 STARTER
 3-POLE POLYPHASE - 600 VAC, 50-60 HZ


| NEMA SIZE | CONTINUOUS CURRENT RATINGS |
|-----------|----------------------------|
| 4 | 135 |

| COIL VOLTAGE CODE (1) | VOLTAGE | |
|-----------------------|---------|---------|
| | 60 HZ | 50 HZ |
| V01 | 24 | - |
| V02S | 120# | 110 |
| V08 | 208 | - |
| V03 | 240 | 220 |
| V06 | 480 | 440 |
| V07 | 600 | 550 |
| V99 | SPECIFY | SPECIFY |

= 120 Volt Polyphase starters are wired for separate control.

| TYPE CODE (3) | SOLID STATE OVERLOAD RELAY PROTECTION |
|---------------|---------------------------------------|
| H10 | CLASS 10 |
| H20 | CLASS 20 |
| H30 | SELECTABLE CLASS 10/20 |

| MOTOR VOLTS | MAX. HP |
|-------------|---------|
| 200 | 40 |
| 230 | 50 |
| 460 | 100 |
| 675 | 100 |

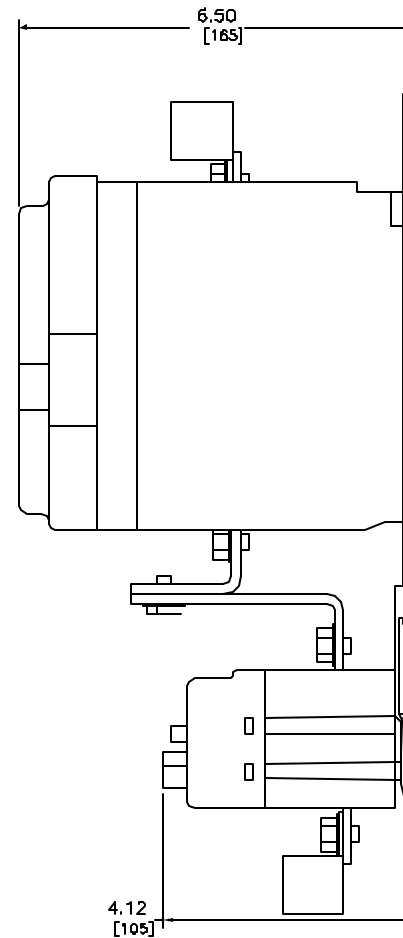

DUAL DIMENSIONS: INCHES
 MILLIMETERS

NEMA SIZE 4 STARTER W/SSOLR
 CLASS 8536 TYPE SF01 (1) (3)



DWG# E0320701-01
 NO.