




# CERTIFICATE FI/40878

Our Ref. HEL-CERT201200557-01



**Product** Socket-outlet  
**Type** 230/\*\* series  
**Trademark**  Schneider Electric  
**Certificate Holder** Schneider Electric Industries SAS  
35 Rue Joseph Monier, 92500, Rueil-Malmaison, France

**Technical information** 16 A, 250 V~, IP20, IP21, IP44

**Other information** Standard sheet III, 2P+E. One-fold flush-type fixed socket-outlet, with screwless terminals, with or without shutters.

**The product is certified according to the following standard(s)** IEC 60884-1:2002 + A1:2006 + A2:2013  
SFS 5610:2015 + A11:2016

**Validity** This certificate is valid until 2025-12-10 provided that the Conditions for FI certification are met. This certificate includes the right to use the FI mark under the condition that changes (if any) will be checked at SGS Fimko before the product is brought onto market and that the conditions for FI certification are met.

**Date of issue** 2020-12-10

**SGS Fimko Ltd**

**Signature**



Matti Huttunen  
Certification Engineer

Page 1 of 4

This document is issued by the Company under its General Conditions of Service accessible at [http://www.sgs.com/terms\\_and\\_conditions.htm](http://www.sgs.com/terms_and_conditions.htm). Attention is drawn to the limitation of liability, indemnification and jurisdiction issues defined therein.

Any holder of this document is advised that information contained hereon reflects the Company's findings at the time of its intervention only and within the limits of Client's instructions, if any. The Company's sole responsibility is to its Client and this document does not exonerate parties to a transaction from exercising all their rights and obligations under the transaction documents. Any unauthorized alteration, forgery or falsification of the content or appearance of this document is unlawful and offenders may be prosecuted to the fullest extent of the law.




**SGS Fimko Ltd**

Takomotie 8, FI-00380 Helsinki, Finland  
t. +358 9 696 361 [www.sgs.fi](http://www.sgs.fi)

Business ID 0978538-5

Member of the SGS Group (SGS SA)

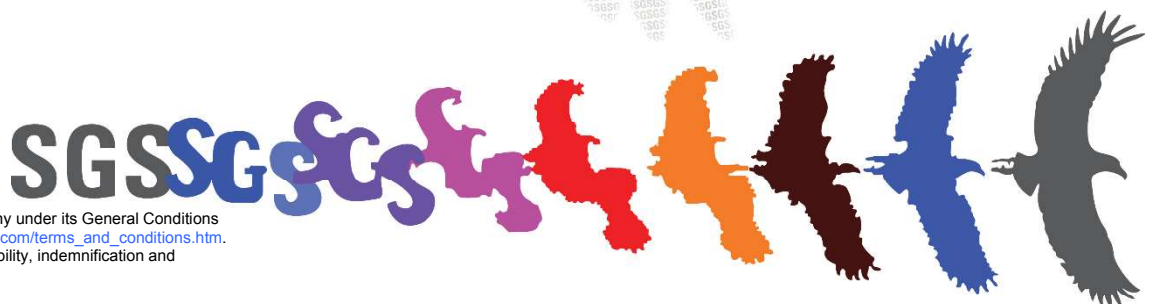

**Manufacturer** Schneider Electric Industries SAS  
35 Rue Joseph Monier, 92500, Rueil-Malmaison, France

**Manufacturing site** Merten GmbH  
Fritz-Kotz-Strasse 8, 51674, Wiehl, North Rhine-Westphalia, Germany

**Additional information** The products has certificate SE-S-2002559 issued by Intertek Semko AB in accordance with the Nordic Certification Service system.

Socket-outlet type list:

**Antivandalism (1-gang)**

230/S1B7217902

**System M-Creativ**

230/2300-35

**System M (Thermo/Duro)**

230/2371, 230/2373, 230/2376, 230/2374, 230/2300, 230/2301,

230/2309 with or without LED light module Mxx2003-0004

230/2474, 230/2485, 230/2496, 230/2470, 230/2471, 230/2472,

230/2473, 230/2315, 230/2334 with LED light module Mxx2334

**System Design (Thermo/Duro)**

230/2375, 230/2377, 230/2372, 230/2379 with or without LED light module Mxx2003-0004

230/2378, 230/2306, 230/2308, 230/2478, 230/2476, 230/2477

**System Design (Thermo/Metal)**

230/NHA5191702, 230/NHA5200102, 230/NHA2922902,

230/NHA2922002, 230/NHA5191902, 230/NHA5191802,

230/NHA5195702, 230/NHA5191902, 230/NHA5195702/PHA8168102,

230/NHA5195702/NHA5200202, 230/NHA2920902

**AQUADESIGN**

230/2330, 230/2335

**Renova**

230/EAV54699

Frame types:

**System M (Thermo+Duro)**

**M-Smart: (1 - 5 gang)**

4841, 4842, 4843, 4844, 4845

**1M: (1 - 5 gang)**

3891, 3892, 3893, 3894, 3895

**M-Plan II: (1 - 3 gang)**

4881, 5124, 4882, 5125, 4883, 5126

**M-Plan: (1 - 5 gang)**

4861, 4862, 4863, 4864, 4865

**M-Plan Metall: (1 - 5 gang)**

4751, 4752, 4753, 4754, 4755

**M-Plan real glas: (1 - 5 gang)**

4891, 4892, 4893, 4894, 4895

**Additional information**

- M-Plan real wood:** (1-5 gang)  
4051, 4052, 4053, 4054, 4055
- Atelier-M:** (1 - 5 gang)  
3881, 3882, 3883, 3884, 3885
- System M – Elegance:** (1 - 5 gang)  
4021, 4022, 4023, 4024, 4025, 4031, 4032, 4033, 4034, 4035,  
4041, 4042, 4043, 4044, 4045, 4051, 4052, 4053, 4054, 4055
- System M – Exxact (Thermo) Basic:** (1 - 5 gang)  
BBV49550, BBV49551, BBV49552, BBV49553, BBV49554
- Design:** (1 - 3 gang)  
BBV49558, BBV49559, BBV49561
- Solid:** (1 - 4 gang)  
BBV49558, BBV49559, BBV49561, BBV49589
- Solid Glass:** (1 - 4 gang)  
S1A45091, S1A45092, S1A45094, S1A45092
- Combi:** (1 - 5 gang)  
BBV49575, BBV49576, BBV49577, BBV49578, BBV49580
- Primo:** (1 - 6 gang)  
BBV49583, BBV49584, BBV49587, BBV49585, BBV49586,  
BBV54904, BBV54905
- Gasket for all IP44 frames:** (1 - 3 gang)  
BBV49557, S1A33102, S1A33103
- System M – Creative** (1 - 5 gang)  
4010-35, 4020-35, 4030-35, 4040-35, 4050-35, 4025-35, 4035-35
- System Design (Thermo + Duro)**  
**ARTEC, Antik, Fläche:** (1 - 5 gang)  
4811, 4812, 4813, 4814, 4815, 4831, 3981, 3982, 3983, 3984, 3985
- System M – M-Pure** (1 – 5 gang)  
4010-36, 4020-36, 4030-36, 4040-36, 4050-36
- System Design (Thermo + metal + glas/stone)**  
**D-Life** (1 – 5 gang)  
NHA2920502, NHA2920602, NHA5191402, NHA5191602,  
NHA2920702  
**D-Life metal** (1 – 5 gang)  
NHA2923102, 2xNHA2923302, 2xNHA2923302/1xNHA2923502,  
2xNHA2923302/2xNHA2923502, 2xNHA2923302/3xNHA2923502
- D-Life glas/basalt** (1 – 5 gang)  
NHA2922102, NHA2922402, NHA5195402, NHA5195502,  
NHA2922702
- AQUADESIGN:** (1 - 4 gang)  
4011, 4012, 4013, 4014

**Additional information**

**Antivandalism (1 – 3 gang)**  
4801, 4802, 4803  
**Renova**  
**Glass frame: (1 - 3 gang)**  
BBV28342, BBV28343, BBV28344  
**Plastic frame: (1 - 5 gang)**  
101370, 101371, 101372  
**Anti Vandalism: (1-gang)**  
S1B7217902

	Robust <b>Screwless (230/***)</b> Socket Outlets, IK class IK09.			Robuts: frame
	Insert	Center Cover	Center Cover Adapter	
Without Shutter	230/***	101363	101599	101600 (1-gang)
With Shutters		EAV54699		

Trend <b>Screwless (230/***)</b> Socket Outlets		
Insert	Center Cover (with Shutters)	Frames
230	NVE66783	100520 (1-gang) 100521 (2-gang) 100522 (3-gang) 100523 (4-gang) 101524 (5-gang)

This certificate replaces previous certificate FI 30013 dated 06 July 2017 due renewal of the certificate.

**As shown in the Test Report(s) No(s):** 2019700STO-001