


CERTIFICATE FI/41656/A1

Our Ref. HEL-CERT230300551-03



Product Shuttered socket-outlet
Type 101414-02, 101443-02, 101414
Trademark 
Certificate Holder Schneider Electric Industries SAS
35 Rue Joseph Monier, 92500, Rueil-Malmaison, France

Technical information 16 A, 250 V~, IP0, IP20, IP21, IP44, Class I, Class II

Other information Standard sheet III and I of SFS 5610
Standard sheet I of NF C 61-314:2017
Conductor area: 1,5 – 2,5 mm²

General:

In case the socket-outlet with unearthed fixing frame or plastic frame is to be installed in a metal box, the insulation p/n: BBV49557 shall be installed. In case the socket-outlet with earthed fixing frame is to be installed in a metal box (box earthed) a clearance of minimum 3 mm shall be met.

The product is certified according to the following standard(s) IEC 60884-1:2002 + A1:2006 + A2:2013
SFS 5610:2015 + A11:2016

Validity This certificate is valid until 12 April 2028 provided that the Conditions for FI certification are met. This certificate includes the right to use the FI mark under the condition that changes (if any) will be checked at SGS Fimko before the product is brought onto market and that the conditions for FI certification are met.


Date of issue 04 September 2024

SGS Fimko Ltd

Signature



Niklas Rönqvist
Certification Manager

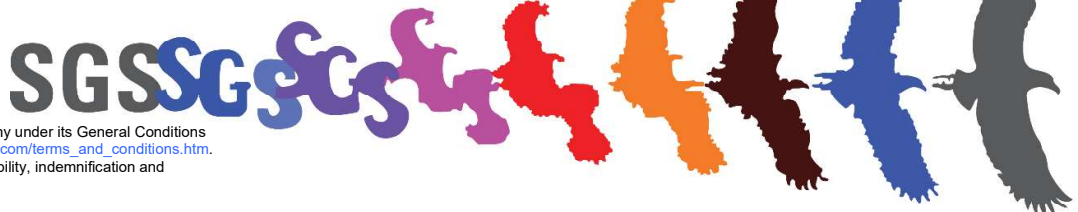

Manufacturer

Schneider Electric Industries SAS
35 Rue Joseph Monier, 92500, Rueil-Malmaison, France

Manufacturing site

Schneider Electric Elda S. A.
Bugno 1, 78-400, Szczecinek, Poland

Additional information

101414-02,101443-02,101414 Socket-outlets with Protective Earth (2P+E), available build of parts:

Part	Description
101414-02	insert base (Renova screw, Round screw)
101443-02	insert base (Exxact, Trend, Robust, Unica, new Unica, Odace, Ovalis)
101414	insert base (Exxact IP44 surface screwless / flush screw)
100977	insert cover & fixing part, screw-type (Exxact IP44), nature
101081	insert cover (Round), white
101366	insert cover & fixing part, screw-type, nature (Unica, Renova)
101415	insert cover (screw)(Exxact, Unica, Odace, Ovalis, Robust, Trend, Unica new)
101421	insert cover (screw + screwless) (Exxact)
101430	insert cover (screwless)(Exxact, Trend, System M, System Design, Robust)
100594	shutter slider natural / black
101037	shutter cassette body
101164	surface box (Exxact IP44), white
101164	surface box (Exxact IP44), black
101165	center plate SideE (Exxact IP44), white
101165	center plate SideE (Exxact IP44), black
101166/101167	lid (Exxact IP44), white
101166/101167	lid (Exxact IP44), black
101155	center plate SideE (Round), white
101367, 101364	center plate SideE (Renova), white
101367, 101364	center plate SideE (Renova), black
101392	center plate SideE (Trend)
101527	center plate SideE (Unica)
101531	center plate SideE (Unica)
101604	center plate SideE (Robust surface)
101610	center plate SideE (Robust flush)
BBV35087	center plate SideE (Exxact high, full-flush), white
BBV35087	center plate SideE (Exxact high, full-flush), black & black +painted
BBV35087	center plate SideE (Exxact low, semi flush), white
BBV35087	center plate SideE (Exxact low, semi flush), black & black +painted
BBV35087 + PHA2562402/ PHA2562502	center plate SideE (Exxact low, semi flush), white + Skirting box rear part/front part, white
BBV111557	center plate SideE (Exxact), white
BBV4013402	center plate SideE (Odace), white / + painted alu
BBV42390	center plate SideE (Exxact), white
NHA44968	center plate SideE (M-SMART, full-flush), white
NHA44968	center plate SideE (M-SMART, full-flush), active white & ivory
NHA44972	center plate SideE (M-SMART, semi flush), white
NHA44972	center plate SideE (M-SMART, semi flush), active white & ivory
S1B67876	center plate SideE (Exxact), white / painted met or anthr.
S1B13009	center plate unearthed / SideE (Exxact), white
BBV49557	Insulation

Additional information

101414-02,101443-02,101414 Socket-outlets with Protective Pin Earth (2P+E), available build of parts:

Part	Description
101414-02	insert base (Renova screw, Round screw)
101443-02	insert base (Exxact, Trend, Robust, Unica, new Unica, Odace, Ovalis)
101081	insert cover (Round)
101366	insert cover & fixing part, screw-type, nature (Unica, Renova)
101415	insert cover (screw) (Exxact, Unica, Odace, Ovalis, Robust, Trend, Unica new)
100594	shutter slider natural / black
101037	shutter cassette body
101530	center plate PinE PO/FR (Unica)
101533	center plate PinE CZ (Unica)
101535	center plate PinE CZ (Unica)
NVE8058402	center plate PinE FR (new Unica), white / painted alu/ graphite
S1A6508002	center plate PinE FR (Ovalis), white
BBV5354402	center plate PinE FR (Odace), white / + painted alu
BBV49557	Insulation

101414-02,101443-02 Socket-outlets without Protective Earth (2P), available build of parts:

Type number	Description
101414-02	insert base
101443-02	insert base
101366	insert cover & fixing part, screw-type, nature (Unica, Renova)
101415	insert cover (screw) (Exxact, Unica, Odace, Ovalis, Robust, Trend, Unica new)
101430	insert cover (screwless) (Exxact, Trend, System M, System Design, Robust)
100594	shutter slider natural / black
101037	shutter cassette body
BBV49557	Insulation
100465	center plate unearthed (Trend)
101528	center plate unearthed (Unica)
101365, 101364	center plate unearthed (Renova)
101532	center plate unearthed (Unica)
BBV42385	center plate unearthed (Exxact)
S1B13009	center plate unearthed / SideE (Exxact)

The products have certificate no. SE-S-2300261R3 issued by Intertek Semko AB in accordance with the Nordic Certification Service system.

This certificate replaces previous certificate FI/41656/M1, dated 2024-07-11, due to editorial corrections on the Certificate.

As shown in the Test Report(s) No(s): 2300701STO-001-003, 2404135STO-001-003, 2404135STO-001-003