
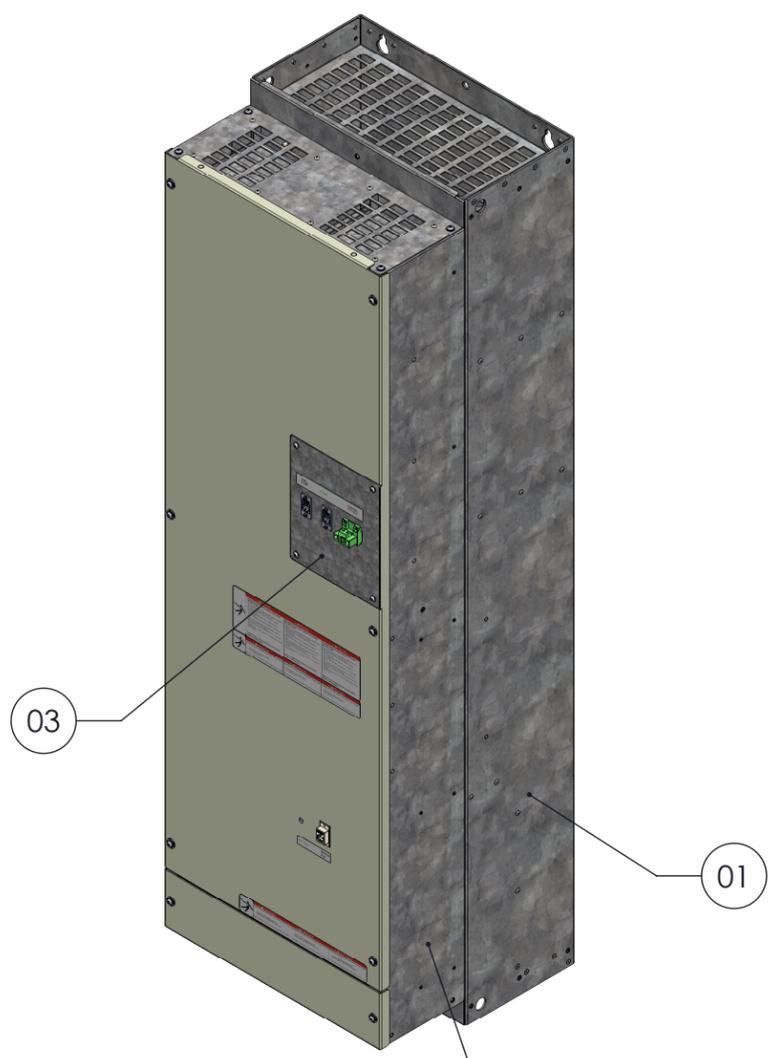
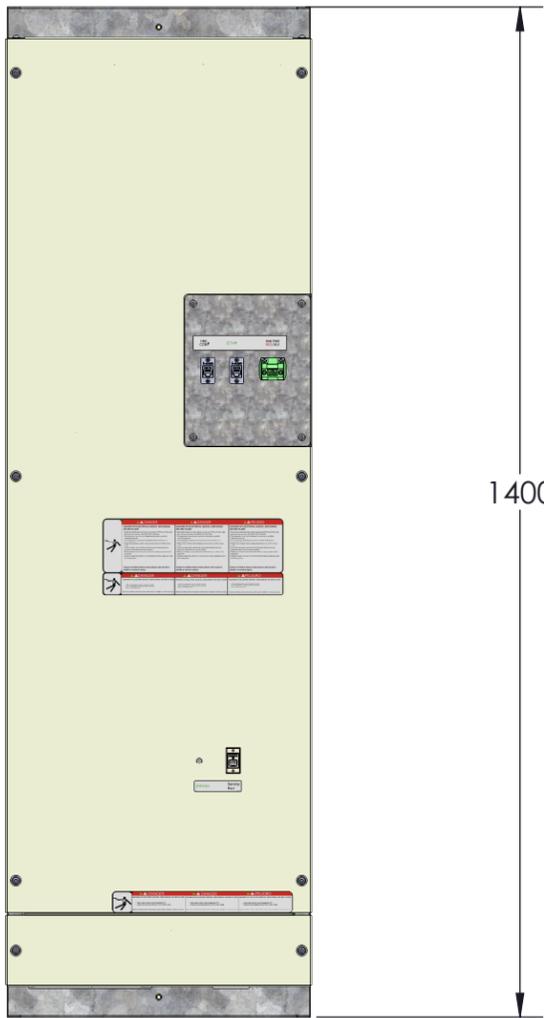
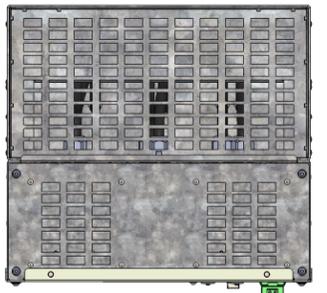


8 7 6 5 4 3 2 1

MOUNTING  
HARDWARE M10


AIR EXHAUST

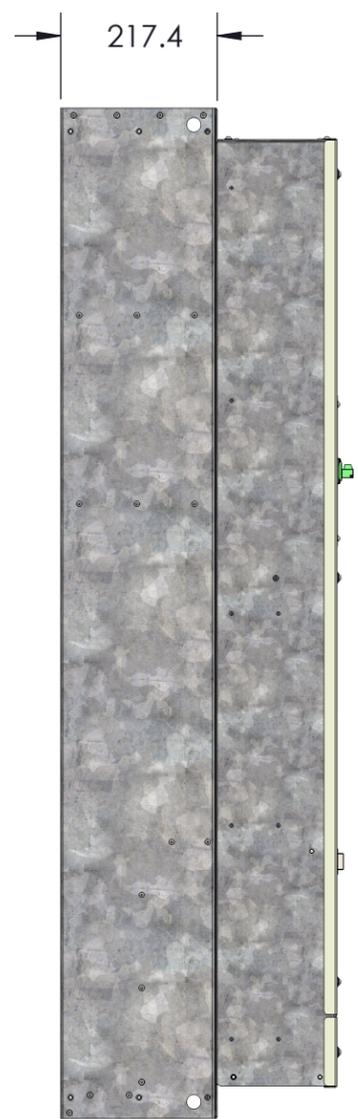

- NOTES:
1. IP00 TYPE ECLOSURE
  2. AMBIENT TEMP 0-40 C
  3. ALTITUDE 1000M(3300 FT)
  4. HUMIDITY 95% NON-CONDENSING
  5. INDOOR INSTALLATION IN CLEAN ENVIRONMENT
  6. MINIMUM CLEARANCES  
217 mm ABOVE FOR AIRLOW  
220 BELOW FOR AIRFLOW AND IMPELLER SERVICE
  7. COMMERCIAL REFERENCES INCLUDE HMI AND CABLES

CUSTOMER CONNECTIONS

AIR INLET

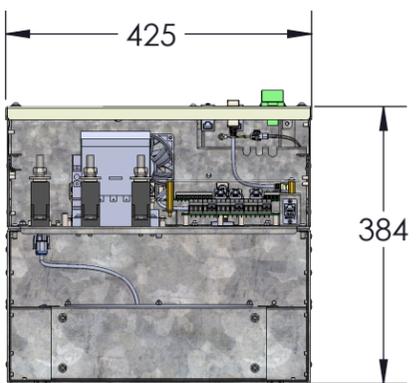

|                           |               |                                  |                         |
|---------------------------|---------------|----------------------------------|-------------------------|
|                           | Scale:<br>N/A | Tolerancing Standard:<br>ISO8015 | Units of Measure:<br>mm |
| <b>Schneider Electric</b> |               |                                  |                         |
| <b>FINISHED 120A IP00</b> |               | <b>FINISHED 120A IP00</b>        |                         |
| Number:<br>HRB4407202     |               | Revision:<br><b>00</b>           | Sheet:<br>1 OF 1        |

All information and data contained in this document are the exclusive property of Schneider Electric Industries SAS and may neither be used nor disclosed without its prior written consent.

State:

Released for Manufacturing  
Printed on 2015/07/09

8 7 6 5 4 3 2 1