


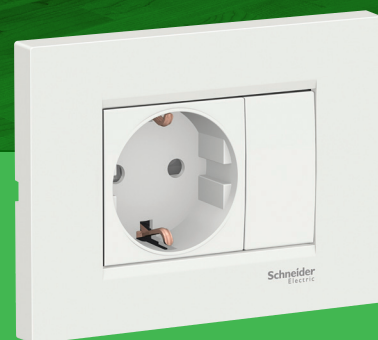

# Easy Style

Catalog 2021



[se.com](http://se.com)

Life Is On

**Schneider**  
Electric







# Content

5	Easy Styl presentation
19	Controls
23	Sockets
25	Data outlets - Communication outlets - Antenna outlets
27	Cover frames
31	Fixing frames and Installation boxes
33	Technical information
37	Reference numbers







# Designed to meet your clients' needs

The Easy Styl range blends form and function beautifully, offering quality solutions for everyone.

## The beauty of modularity

Easy Styl's modular design covers a wide range of applications and functions, offering up to seven modules per frame, and is supported with quality construction. It's now easier than ever to fulfill your customers' electrical installation needs, while offering them designs to suit their particular styles.

## Extensive functionalities

From homes to offices and all types of buildings in between, Easy Styl's extensive range of switches, socket outlets, dimmers and media outlets helps you find the right solution for every type of space.

## Switches and sockets

The new Easy Styl range of wiring devices includes modular switches and sockets that enhance your customers' homes. Each switch is beautifully designed with sleek lines, provides smooth operation and high protection against unexpected shocks, giving your customers greater peace of mind.



Socket outlet  
side-earth



Socket outlet  
pin-earth



Socket outlet  
EURO-US



Switch  
(also with  
LED indicator)



2-way switch  
(also with  
LED indicator)



Roller blind switch



Push-button  
(neutral, with bell symbol  
or with key symbol)  
Also with LED indicator




LED universal  
rotary dimmer



Convenient functionalities

Crafted to cater to your customers' comfort needs Easy Styl's extensive range includes dimmers and data sockets.

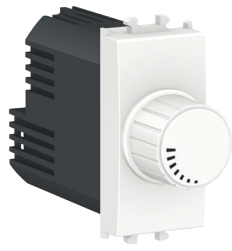

Rotary dimmer



Audio outlet



USB charger



SAT socket







TV-SAT socket



Tel. socket RJ11



Data socket RJ45



HDMI socket



USB data socket



Blind cover





# An intuitive design for easier installation

Easy Styl delivers elegant wiring devices that are simple to install, secure, and snap into place.


- Snap-on installation means modules are mounted at a click.
- Design frames are quickly installed by pressing them onto modules.
- Across all functions, same conical cable entry is used.
- Clear electrical wiring diagrams on the products.
- Interlock on fixing frames to easily align (for 2 modules).

Design frames can be installed on uneven walls thanks to its snapping feature.

## Switches with design


### Extra space

Mounting depth provides enough space for the wiring.

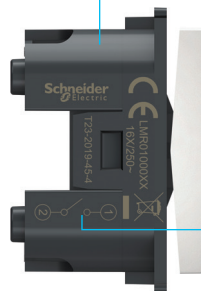

### Simple connection

A wiring diagram is printed on the side of the switch and push-button base to clearly identify connection options.

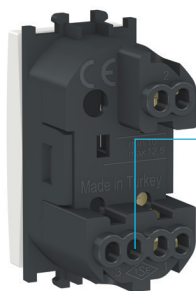

### Handy cable entries

Conical entries prove useful during installation of cables and provide good isolation between each of them.



### Lamp locator

This optional feature makes it easier for your customers to find switches and pushbuttons in the dark.





## Sockets with added convenience

### Extra space


A low mounting depth allows for extra wiring space.

### Easier cabling

Large entry sizes make it easier to fit 2.5mm<sup>2</sup> rigid and flexible cables.

### Quick wiring

Screw terminals have cable entries beside each other, so you can easily cut all wires to the same length.

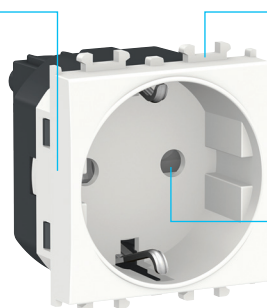

### Easy removal

Thanks to clearly visible notches on the fixing frames, the inserts can be easily removed from the front.

### Shock protection

Integrated shutters protect against accidental contact and insertion of objects by children.






## Modular frames are easier to install and fix

Thanks to clever features, such as snap-on mounting and modularity, installation of Easy Styl's frames is quick, easy, and intuitive.

### Fixing frames

Easy Styl offers a system with five types of fixing frames:

- Modular fixing frame, 2 modules, with claws
- Modular fixing frame, 2 modules, without claws
- Modular fixing frame, 3 modules, without claws
- Modular fixing frame, 4 modules, without claws
- Modular fixing frame, 7 modules, without claws

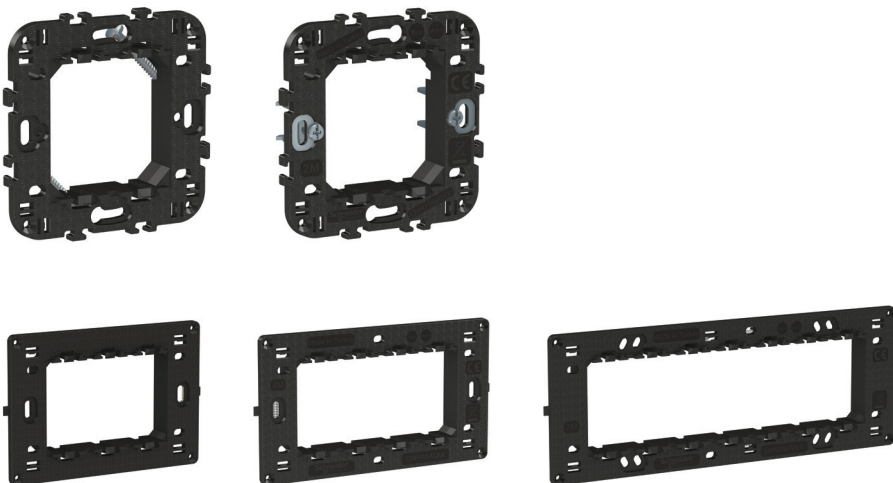



**Optimized for screw mounting:**

- Screws for installation come attached to the back of the fixing frame for fast installation.
- Highly-resistant, durable fixing frames ensure a tight screw support, with additional holes for various mounting possibilities.

**Strong connection**


Fine tolerances between the cover and fixing frame create a stronger connection for a more reliable installation.

**Flexible installation**

Symmetric fixing frame sides for easy adjustments.

**Secure fixing**

The insert is secured within the fixing frame to prevent dangling and achieve a strong hold.

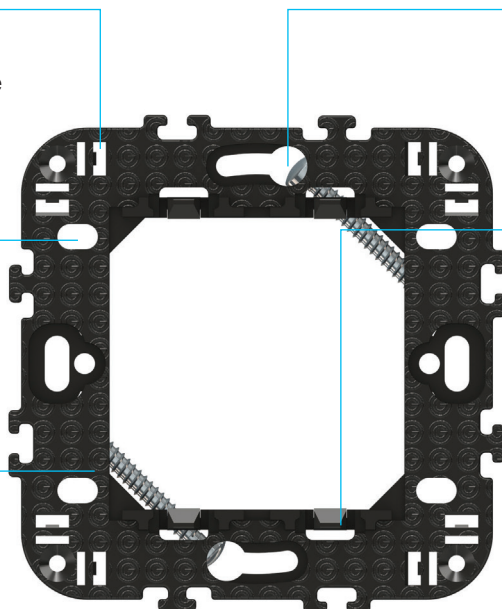

**Easy adjustment**

Screw slots allow rotation of the inserts to correct misaligned installation boxes. They're a perfect fit for flush mounted box standard screws, so fixing is easy and secure.

**Robust clipping**

The design of the clipping system secures the insert in the fixing frame.

**NOTE:** Easy Styl 2 modules fixing frames with claws and without claws can only be used with 2 modules Easy Styl frames without interlocking system.



# Two installation options


## Modular multifunctional, for flush boxes

Flush rectangular mounting boxes  
• 2M, 3M, 4M and 7M

1M, 2M or 3M inserts

Design cover frames  
• 2M, 3M, 4M, 7M  
• In different colors, shapes and materials

Rectangular plastic fixing frames  
• 2M, 3M, 4M and 7M

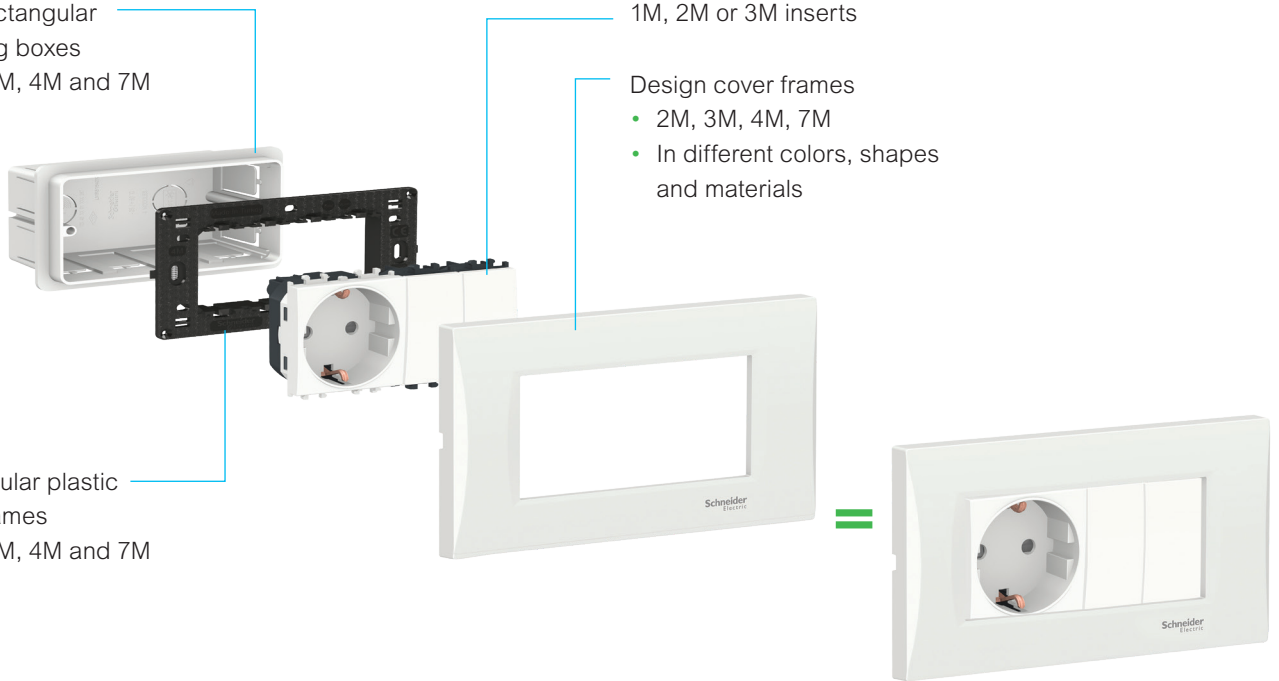


## Modular universal, for CE60 boxes

Flush CE60 boxes

2M plastic fixing frames with and without claws

2M product

Design cover frames  
• 2M  
• In different colors, shapes and materials

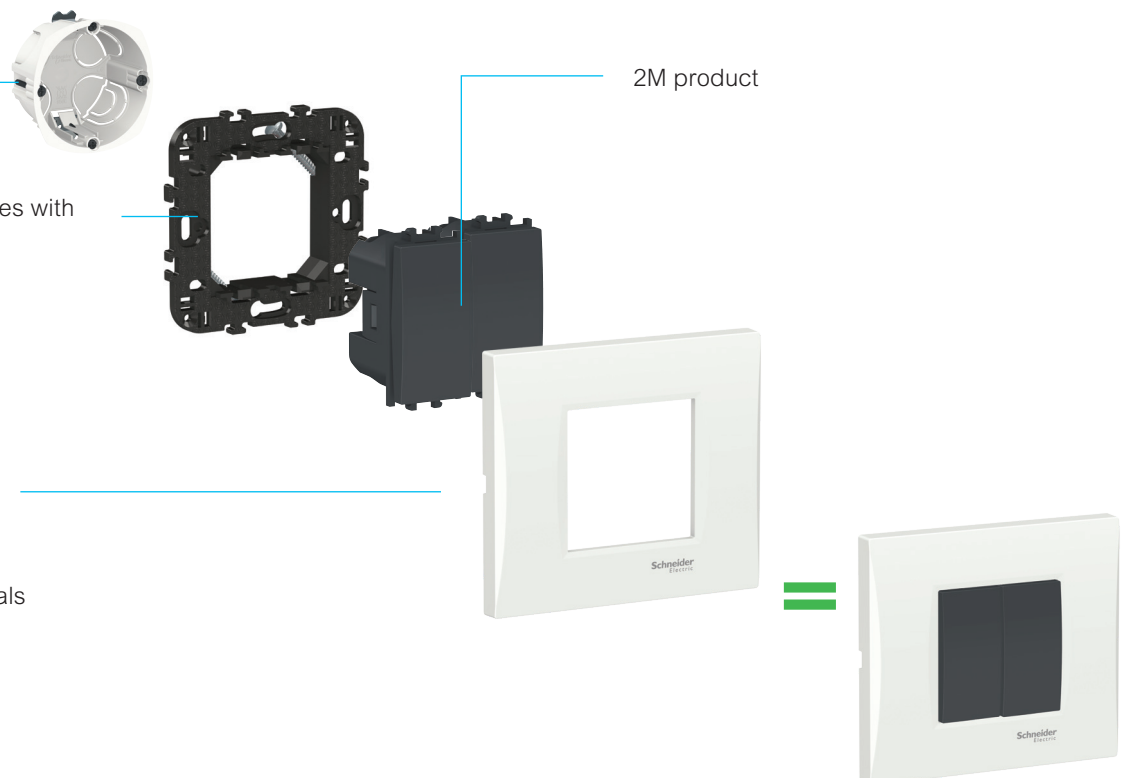





### Robust quality

At Schneider Electric, providing high quality across our entire range of devices remains our priority. For years, the robustness of our socket outlets has set the bar for the highest standards possible. Our sockets are CE-compliant and certified by VDE, the German Association for Electrical, Electronic and Information Technologies (for side earth socket outlets), as well as French NF (for pin earth socket outlets) and TSE, the Turkish Standards Institution. All our switches are also CE marked and comply with IEC 60669-1:2017.





# A range of modern designs, as stylish as your customers

The Easy Styl range of wiring devices blends form and function seamlessly, offering quality solutions for everyone.

The Easy Styl range combines sleek design with easy-to-assemble technology and it is designed to suit any building type and personal style.

## Find your look

Timeless and sturdy, our plastic design frames fit all spaces perfectly, with a choice of up to 6 different colors and 2 different styles.

For your boldest projects, you can select from a wider palette with refined finishes such as glass, inox, and wood, and find electrical accessories that will perfectly complement your project's esthetics.





Plastic frames


Flat




White



Cream

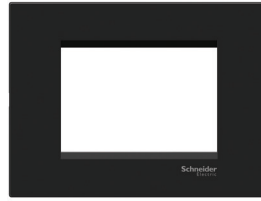

Metallic black

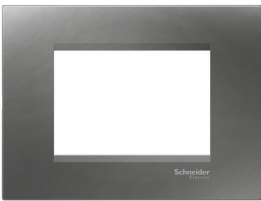

Smoked grey



Silver



Metallic beige

Mode



White



Cream



Metallic black



Smoked grey



Silver



Metallic beige



## Real material frames

### Inox



Bronze/chrome



Silver/chrome



Silver/black




Black/chrome

### Glass



White/chrome

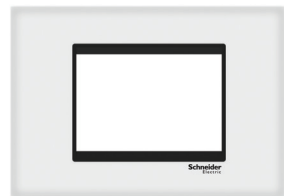

White/black



Sky blue/chrome



Light bronze/chrome



Black/chrome



## Wood



Walnut/chrome



Walnut/metallic beige



Bamboo/chrome



Bamboo/metallic beige



Venge/chrome



Venge/metallic beige



 
# Easy Styl Controls



# Controls

## Switches - Roller blind switches

### Switches – 16 AX – 250 V AC



#### 1 module



	1-way	2-way
□ white	LMR0100001	LMR0104001
■ cream	LMR0100002	LMR0104002
■ black	LMR0100003	LMR0104003
■ silver	LMR0100004	LMR0104004

#### 2 modules



	1-way	2-way
□ white	LMR0200001	LMR0124001
■ cream	LMR0200002	-
■ black	LMR0200003	LMR0124003
■ silver	LMR0200004	LMR0124004

### Switches with blue locator lamp 16 AX – 250 V AC



#### 1 module



	1-way	2-way
□ white	LMR1401001	LMR1404001
■ cream	LMR1401002	-
■ black	LMR1401003	LMR1404003
■ silver	LMR1401004	LMR1404004

#### 2 modules



	1-way	2-way
□ white	LMR1412001	LMR1422001
■ cream	LMR1412002	-
■ black	LMR1412003	LMR1422003
■ silver	LMR1412004	LMR1422004

The blue locator lamp is ON when the load is not powered (switch OFF).

### Roller blind switches 10 A – 250 V AC – 100 W SBL

 


#### 1 module



□ white	LMR0711001
■ black	LMR0711003
■ silver	LMR0711004

#### 2 modules




□ white	LMR0712001
■ black	LMR0712003
■ silver	LMR0712004

3 positions switch with middle position OFF.

### Intermediate switches 16 A – 250 V AC


 
#### 2 modules



□ white	LMR1901001
■ cream	LMR1901002
■ black	LMR1901003
■ silver	LMR1901004

### Switches with indicator lamp 16 A – 250 V AC



#### 1 module



□ white	LMR1501001
■ cream	LMR1501002
■ black	LMR1501003
■ silver	LMR1501004

# Controls

## Push-buttons

### Push-buttons – 10 A – 250 V AC

	1-way	1-way Bell Symbol	1-way Key Symbol
<b>1 module</b>			
<input type="checkbox"/> white	LMR0120001	LMR0130001	LMR0140001
<input checked="" type="checkbox"/> black	LMR0120003	LMR0130003	LMR0140003
<input type="checkbox"/> silver	LMR0120004	LMR0130004	LMR0140004

<b>2 modules</b>			
<input type="checkbox"/> white	LMR0220001	LMR0230001	
<input type="checkbox"/> cream	LMR0220002	-	
<input checked="" type="checkbox"/> black	LMR0220003	LMR0230003	
<input type="checkbox"/> silver	LMR0220004	-	

### Push-buttons with blue locator lamp – 10 A – 250 V AC

	1-way	1-way Bell Symbol	1-way Key Symbol
<b>1 module</b>			
<input type="checkbox"/> white	LMR1121001	LMR1490001	LMR1140001
<b>2 modules</b>			
<input type="checkbox"/> white	LMR1403001	LMR1402001	
<input checked="" type="checkbox"/> black	LMR1220003	LMR1432003	
<input type="checkbox"/> silver	LMR1220004	LMR1432004	

The blue locator lamp is ON when the load is not powered (switch OFF).






# Easy Styl

## Controls

### Rotary dimmers



 



### Rotary dimmers

Designed to switch and dim ohmic or capacitive loads (not CE certified).

		30-500 W
<b>1 module</b>		
		
<input type="checkbox"/> white		<b>LMR9331001</b>
<input checked="" type="checkbox"/> black		<b>LMR9331003</b>
<b>Loads</b>		
Incandescent lamp 230 V		30...500 W
Halogen lamp 230 V		30...500 W

### Universal rotary dimmers

 Designed to switch and dim ohmic, inductive or capacitive loads.

		5-200 W
<b>2 modules</b>		
		
<input type="checkbox"/> white		<b>LMR9341001</b>
<input checked="" type="checkbox"/> cream		<b>LMR9341002</b>
<input checked="" type="checkbox"/> black		<b>LMR9341003</b>
<input type="checkbox"/> silver		<b>LMR9341004</b>
<b>Loads</b>		
LED lamp 230 V		RC <sup>(1)</sup> : 5...100 VA RL <sup>(2)</sup> : 5...20 VA
Incandescent lamp 230 V		5...200 W
Halogen lamp 230 V		5...150 W
LV halogen lamps 12 V	electronic transformer  ferromagnetic transformer 	5...150 VA
<b>Characteristics</b>		
<ul style="list-style-type: none"> <li>• Automatic load detection</li> <li>• Remote control by unlimited number of auxiliary push-buttons</li> <li>• Brightness memory function</li> <li>• Minimum and maximum brightness settings</li> <li>• Wire configuration without neutral</li> <li>• Automatic overload protection, overheating protection, short-circuit protection</li> </ul>		
<sup>(1)</sup> RC = Resistive and Capacitive loads.		
<sup>(2)</sup> RL = Resistive and Inductive loads.		


# Easy Styl Sockets


 
# Sockets

## Socket-outlets and USB chargers


### Socket-outlets – 2P+E (side earth) – 16 A – 250 V AC

	Single with shutters	Single with shutters and lid IP20
<b>2 modules</b>		
		
<input type="checkbox"/> white	<b>LMR5210001</b>	<b>LMR5310001</b>
<input type="checkbox"/> cream	<b>LMR5210002</b>	<b>LMR5310002</b>
<input type="checkbox"/> black	<b>LMR5210003</b>	<b>LMR5310003</b>
<input type="checkbox"/> silver	<b>LMR5210004</b>	<b>LMR5310004</b>


### Socket-outlets – 2P+E (pin earth) – 16 A – 250 V AC

	Single with shutters
<b>2 modules</b>	
	
<input type="checkbox"/> white	<b>LMR5410001</b>

### Socket-outlets Euro-American – 2P – 16 A – 250 V AC

	Single
<b>1 module</b>	
	
<input type="checkbox"/> white	<b>LMR5510001</b>
<input type="checkbox"/> cream	<b>LMR5510002</b>
<input type="checkbox"/> black	<b>LMR5510003</b>
<input type="checkbox"/> silver	<b>LMR5510004</b>

### USB Chargers

	Type A + A
<b>2 modules</b>	
	
<input type="checkbox"/> white	<b>LMR9910001</b>
<input type="checkbox"/> cream	<b>LMR9910002</b>
<input type="checkbox"/> black	<b>LMR9910003</b>
<input type="checkbox"/> silver	<b>LMR9910004</b>
<b>Characteristics</b>	
<ul style="list-style-type: none"> <li>• Nominal input voltage: 100-240 V AC</li> <li>• USB output voltage: 5 V DC</li> <li>• Nominal output current: 1 x 2.1 A or 2 x 1.05 A (for 2 outputs)</li> </ul>	

Easy Styl

Data outlets






Communication  
outlets

Antenna outlets





# Data outlets - Communication outlets - Antenna outlets

## Data and communication outlets

 

	RJ11 Telephone Cat. 3	RJ45 Data Cat. 5e UTP	RJ45 Data Cat. 6 UTP	HDMI Video	USB Data Type A
<b>1 module</b>					
					
<input type="checkbox"/> white	LMR6231001	LMR6232001	LMR6233001	LMR6234001	LMR9810001
<input type="checkbox"/> cream	-	-	-	-	LMR9810002
<input type="checkbox"/> black	LMR6231003	LMR6232003	LMR6233003	LMR6234003	LMR9810003
<input type="checkbox"/> silver	-	-	-	LMR6234004	LMR9810004

UTP = Unshielded Twisted Pair

## Antenna outlets TV/SAT

	TV/SAT	SAT - F type
<b>1 module</b>		
		
<input type="checkbox"/> white	LMR6138001	LMR6128001
<input type="checkbox"/> cream	-	LMR6128002
<input type="checkbox"/> black	LMR6138003	LMR6128003
<input type="checkbox"/> silver	-	LMR6128004

## Audio outlets

	Single	Double
<b>1 module</b>		
		
<input type="checkbox"/> white	LMR6341001	LMR6342001
<input type="checkbox"/> black	LMR6341003	LMR6342003


# Easy Styl Cover frames



# Cover frames

## Plastic - Mode and Flat

### Mode cover frames IP20

		2 modules	3 modules	4 modules	7 modules
					
White		LMR7262001	LMR7263001	LMR7364001	LMR7367001
Cream		LMR7362002	LMR7263002	LMR7364002	LMR7367002
Metallic Black		LMR7362005	LMR7263003	LMR7364005	LMR7367005
Silver		LMR7362004	LMR7263005	LMR7364004	LMR7367004
Smoked Grey		LMR7362006	LMR7263006	LMR7364006	LMR7367006
Metallic Beige		LMR7362007	LMR7263008	LMR7364007	LMR7367007
Paper Bag		-	LMR7263009	-	-

### Flat cover frames IP20

		2 modules	3 modules	4 modules	7 modules
					
White		LMR7252001	LMR7253001	LMR7254001	LMR7257001
Cream		LMR7262002	LMR7253002	LMR7264002	LMR7267002
Metallic Black		LMR7262005	LMR7253005	LMR7264005	LMR7267005
Silver		LMR7262004	LMR7263004	LMR7264004	LMR7267004
Smoked Grey		LMR7262006	LMR7253006	LMR7264006	LMR7267006
Metallic Beige		LMR7262007	LMR7263007	LMR7264007	LMR7267007

# Cover frames

Real Materials – Glass, Inox, and Wood

## Glass cover frames IP20

		2 modules	3 modules	4 modules	7 modules
					
Sky Blue / Chrome		LMR7912038	LMR7913038	LMR7914038	LMR7917038
Sky Blue / Black		-	LMR7963034	-	-
Black / Chrome		LMR7932038	LMR7933038	LMR7934038	LMR7937038
Black / Black		-	LMR7963033	-	-
White / Chrome		LMR7962038	LMR7963038	LMR7964038	LMR7967038
White / Black		LMR7962031	LMR7963031	LMR7964031	LMR7967031
Light Brown / Chrome		LMR7922038	LMR7923038	LMR7924038	LMR7927038
Paper Bag / Black		-	LMR7963039	-	-

## Inox cover frames IP20










 



		2 modules	3 modules	4 modules	7 modules
					
Silver / Chrome		LMR7762038	LMR7763038	LMR7664038	LMR7667038
Silver / Black		LMR7762031	LMR7663035	LMR7664031	LMR7667031
Bronze / Chrome		LMR7722038	LMR7723038	LMR7724038	LMR7727038
Bronze / Black		-	LMR7663037	-	-
Black / Chrome		LMR7732038	LMR7733038	LMR7734038	LMR7737038
Black / Black		-	LMR7663033	-	-



# Cover frames

## Real Materials – Glass, Inox, and Wood (continued)

### Wood cover frames IP20

		2 modules	3 modules	4 modules	7 modules
					
Walnut / Chrome		LMR7822038	LMR7823038	LMR7824038	LMR7827038
Walnut / Metallic Beige		LMR7822039	LMR7823039	LMR7824039	LMR7827039
Walnut / Black		-	LMR8263083	-	-
Bamboo / Chrome		LMR7832038	LMR7833038	LMR7834038	LMR7837038
Bamboo / Metallic Beige		LMR7832039	LMR7833039	LMR7834039	LMR7837039
Bamboo / Black		-	LMR8263089	-	-
Venge / Chrome		LMR7842038	LMR7843038	LMR7844038	LMR7847038
Venge / Metallic Beige		LMR7842039	LMR7843039	LMR7844039	LMR7847039
Venge / Black		-	LMR8263086	-	-

Easy Styl


 
 
 
Fixing frames

Installation boxes







# Fixing frames and Installation boxes




## Fixing frames

	2 modules	3 modules	4 modules	7 modules
				
Without claws	LMR7062003	LMR7063003	LMR7064003	LMR7067003
With claws	LMR7162003	-	-	-


## Modular flush mounting boxes

	2 modules	3 modules	4 modules	7 modules
				
	LMR8162003	LMR8163003	LMR8164003	LMR8167003

## Modular installation boxes

	3 modules	4 modules	7 modules
			
	LMR8263003	LMR8264003	LMR8267003

## Blind covers

	1 module
	
White	LMR6020001
Black	LMR6020003


Easy Styl  
Technical  
information




# Technical information

## Switches and push-buttons


### Connection examples

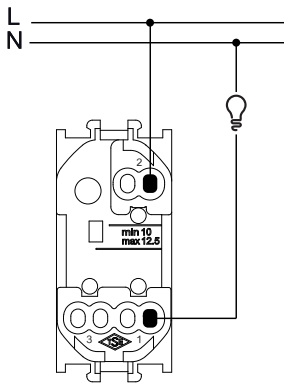

1-way switch (with or without locator lamp)

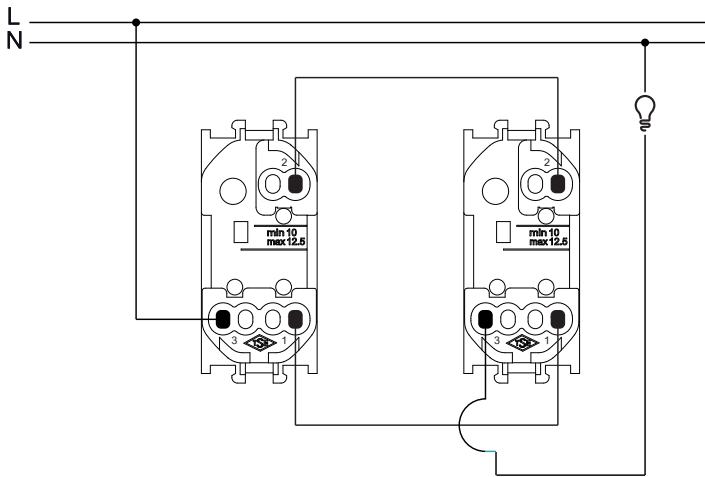

Two 2-way switches (with or without locator lamp)

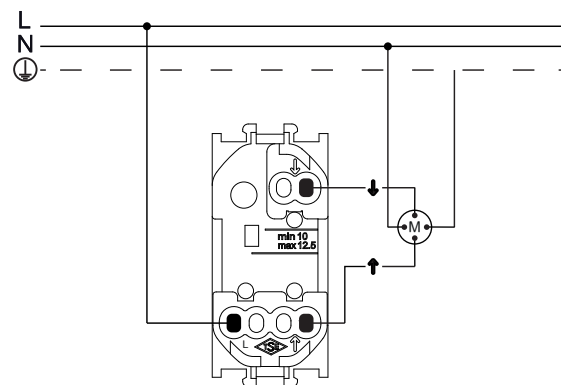


Roller blind switch

# Technical information

## USB chargers - Antenna TV/SAT outlets

### Use

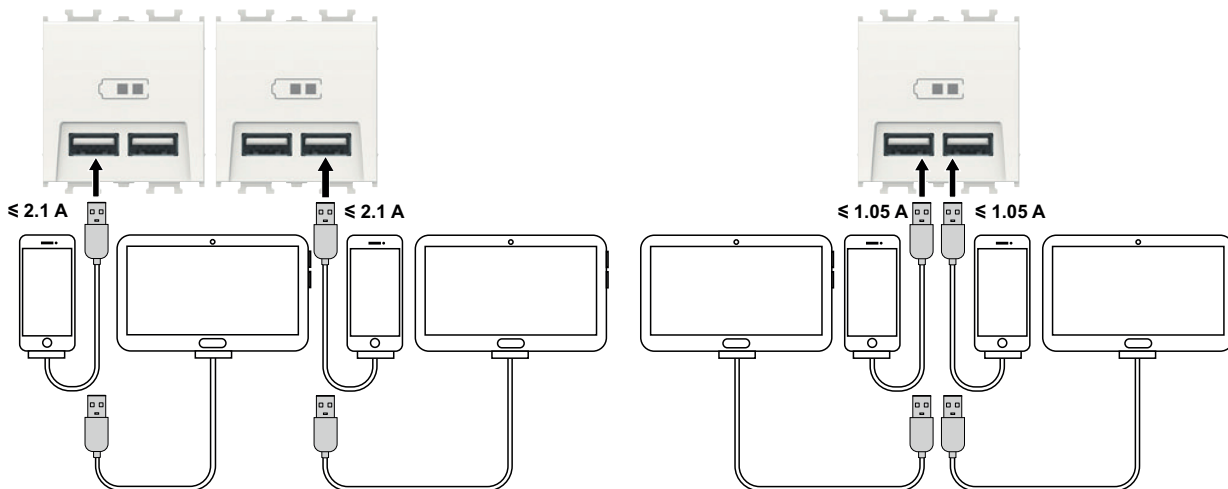


USB type A connection

### Connections

- Nominal input voltage: 100-240 V AC
- USB Output voltage: 5 V DC
- Nominal output current: 1 x 2.1 A or 2 x 1.05 A (for 2 outputs)

## Installation

### TV applications – Individual / Parallel installation insert end of line 1 dB

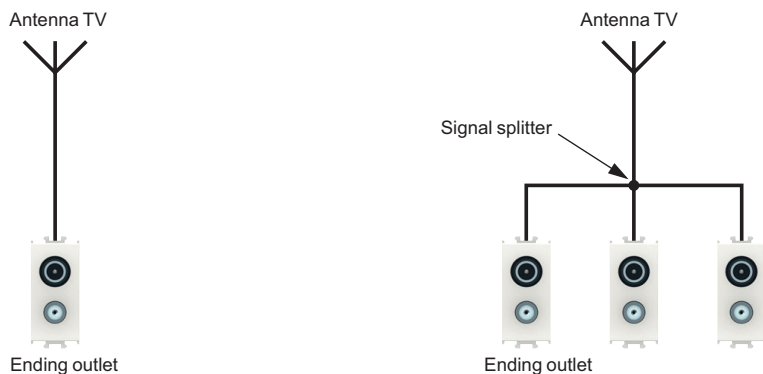

### SAT applications – Individual installation insert end of line 1 dB




# Technical information


## Cover frames dimension diagram

### Cover frames dimensions (mm)


#### Flat plastic cover frames

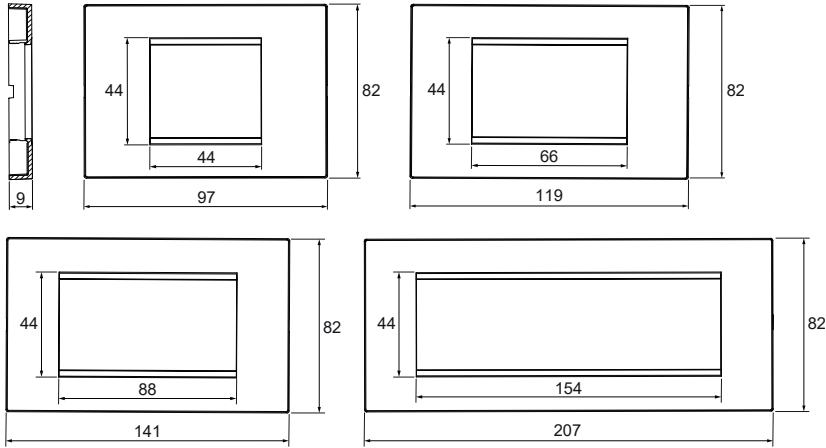

#### Mode plastic cover frames

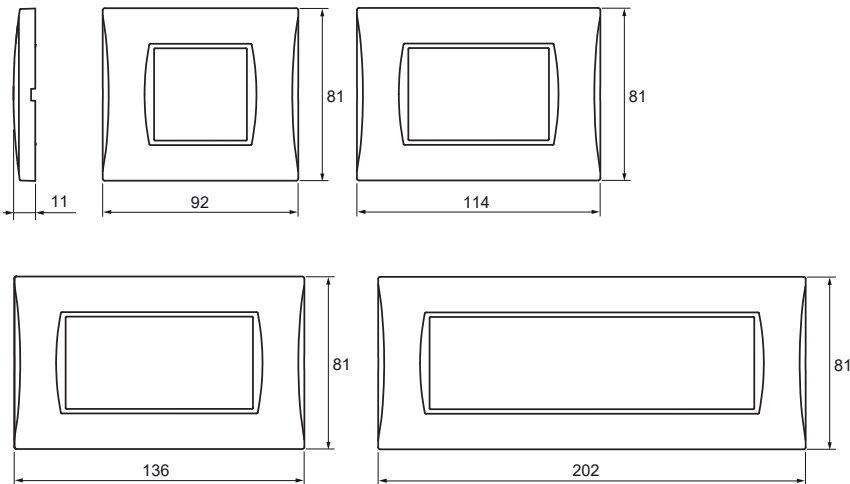

#### Glass / Inox / Wood cover frames

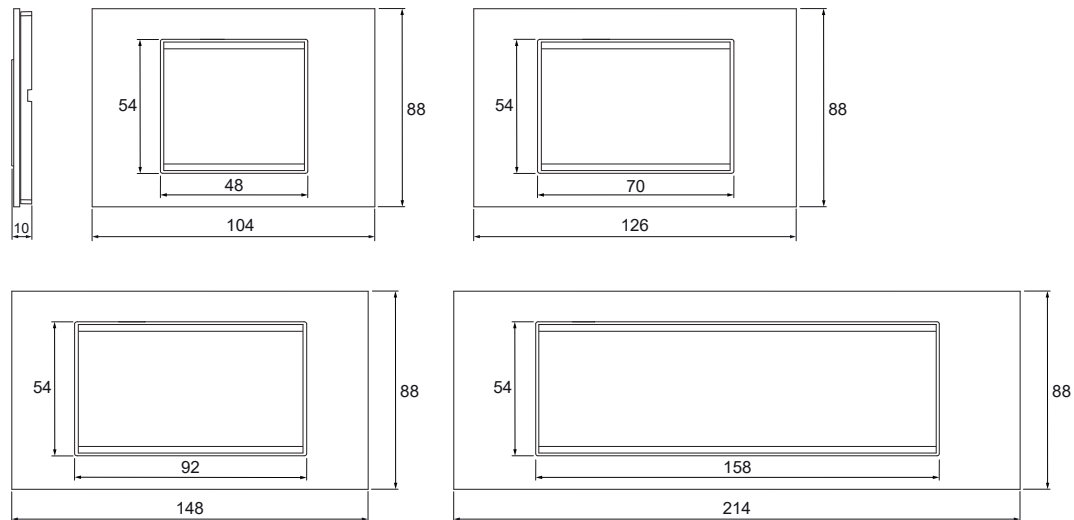




# Technical information


## Fixing frames and Installation boxes dimension diagram

### Fixing frames and Installation boxes dimensions (mm)


#### Fixing frames

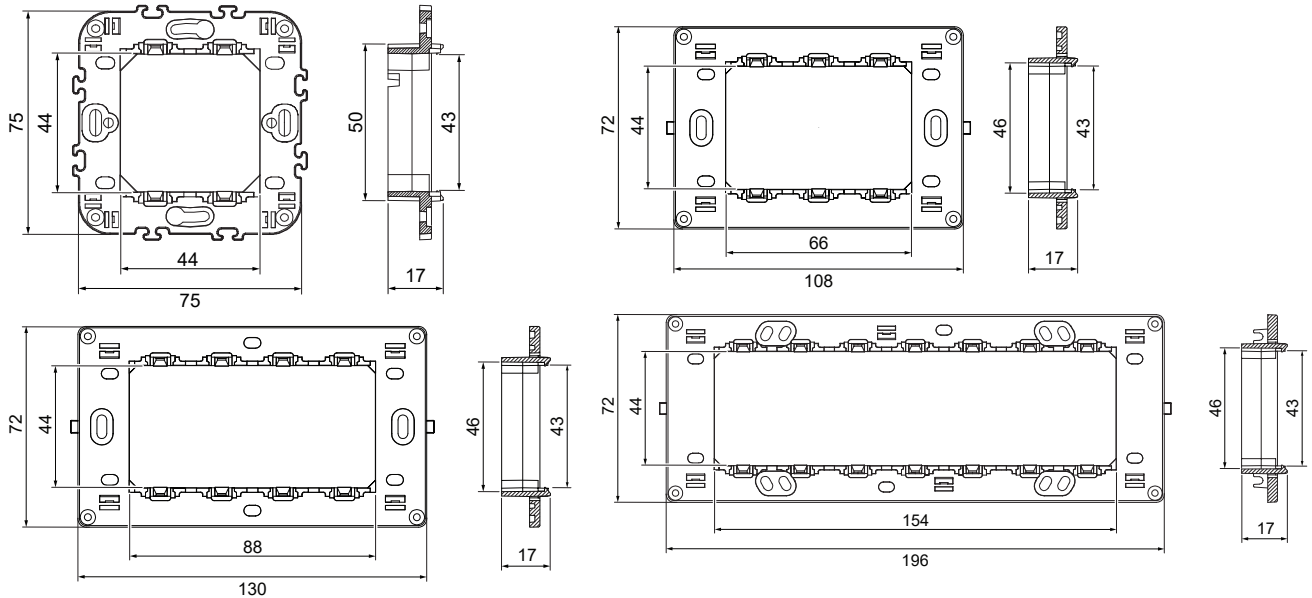

#### Modular flush mounting boxes

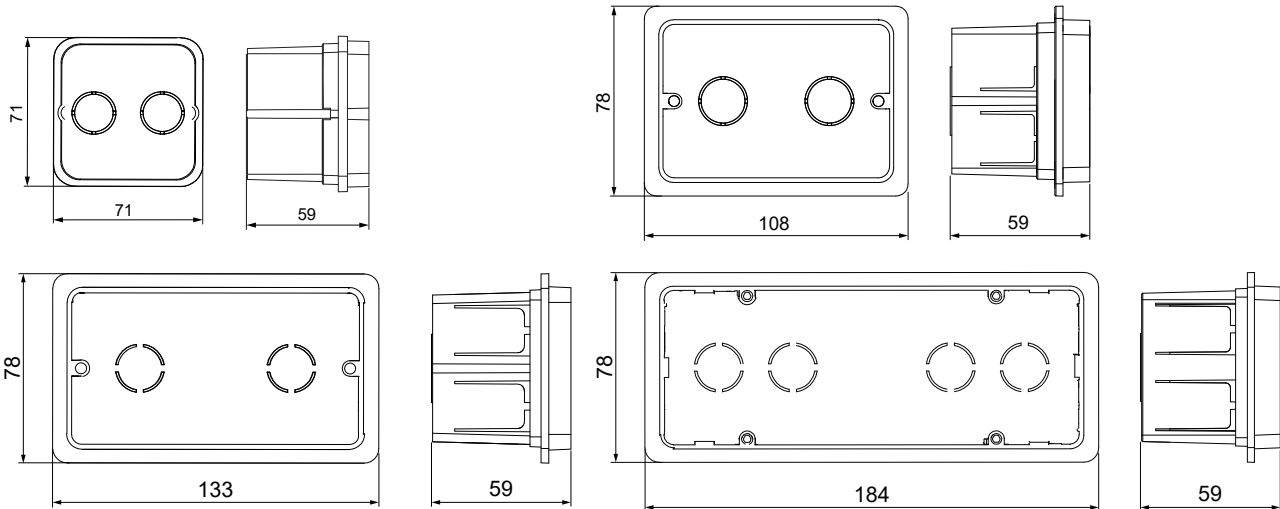

#### Modular installation boxes

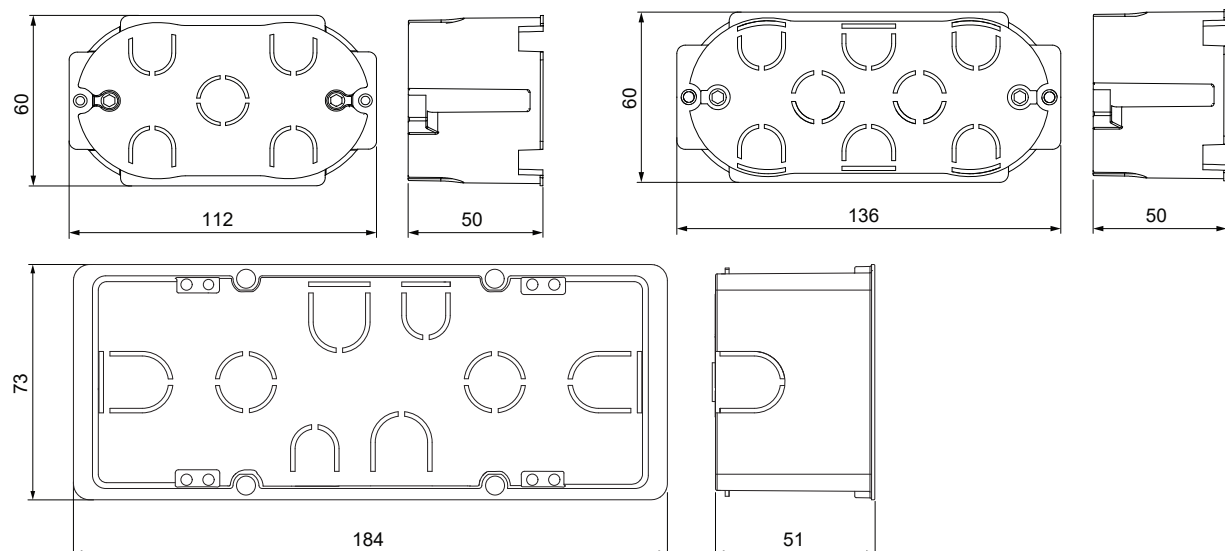

## Reference numbers

## Overview

Ref.	Pages	Ref.	Pages	Ref.	Pages	Ref.	Pages	Ref.	Pages
LMR0100001	19	LMR1422003	19	LMR7253002	27	LMR7722038	28	LMR7964031	28
LMR0100002	19	LMR1422004	19	LMR7253005	27	LMR7723038	28	LMR7964038	28
LMR0100003	19	LMR1432003	20	LMR7253006	27	LMR7724038	28	LMR7967031	28
LMR0100004	19	LMR1432004	20	LMR7254001	27	LMR7727038	28	LMR7967038	28
LMR0104001	19	LMR1490001	20	LMR7257001	27	LMR7732038	28	LMR8162003	31
LMR0104002	19	LMR1501001	19	LMR7262001	27	LMR7733038	28	LMR8163003	31
LMR0104003	19	LMR1501002	19	LMR7262002	27	LMR7734038	28	LMR8164003	31
LMR0104004	19	LMR1501003	19	LMR7262004	27	LMR7737038	28	LMR8167003	31
LMR0120001	20	LMR1501004	19	LMR7262005	27	LMR7762031	28	LMR8263003	31
LMR0120003	20	LMR1901001	19	LMR7262006	27	LMR7762038	28	LMR8263083	29
LMR0120004	20	LMR1901002	19	LMR7262007	27	LMR7763038	28	LMR8263086	29
LMR0124001	19	LMR1901003	19	LMR7263001	27	LMR7822038	29	LMR8263089	29
LMR0124003	19	LMR1901004	19	LMR7263002	27	LMR7822039	29	LMR8264003	31
LMR0124004	19	LMR5210001	23	LMR7263003	27	LMR7823038	29	LMR8267003	31
LMR0130001	20	LMR5210002	23	LMR7263004	27	LMR7823039	29	LMR9331001	21
LMR0130003	20	LMR5210003	23	LMR7263005	27	LMR7824038	29	LMR9331003	21
LMR0130004	20	LMR5210004	23	LMR7263006	27	LMR7824039	29	LMR9341001	21
LMR0140001	20	LMR5310001	23	LMR7263007	27	LMR7827038	29	LMR9341002	21
LMR0140003	20	LMR5310002	23	LMR7263008	27	LMR7827039	29	LMR9341003	21
LMR0140004	20	LMR5310003	23	LMR7263009	27	LMR7832038	29	LMR9341004	21
LMR0200001	19	LMR5310004	23	LMR7264002	27	LMR7832039	29	LMR9810001	25
LMR0200002	19	LMR5410001	23	LMR7264004	27	LMR7833038	29	LMR9810002	25
LMR0200003	19	LMR5510001	23	LMR7264005	27	LMR7833039	29	LMR9810003	25
LMR0200004	19	LMR5510002	23	LMR7264006	27	LMR7834038	29	LMR9810004	25
LMR0220001	20	LMR5510003	23	LMR7264007	27	LMR7834039	29	LMR9910001	23
LMR0220002	20	LMR5510004	23	LMR7267002	27	LMR7837038	29	LMR9910002	23
LMR0220003	20	LMR6020001	31	LMR7267004	27	LMR7837039	29	LMR9910003	23
LMR0220004	20	LMR6020003	31	LMR7267005	27	LMR7842038	29	LMR9910004	23
LMR0230001	20	LMR6128001	25	LMR7267006	27	LMR7842039	29		
LMR0230003	20	LMR6128002	25	LMR7267007	27	LMR7843038	29		
LMR0711001	19	LMR6128003	25	LMR7362002	27	LMR7843039	29		
LMR0711003	19	LMR6128004	25	LMR7362004	27	LMR7844038	29		
LMR0711004	19	LMR6138001	25	LMR7362005	27	LMR7844039	29		
LMR0712001	19	LMR6138003	25	LMR7362006	27	LMR7847038	29		
LMR0712003	19	LMR6231001	25	LMR7362007	27	LMR7847039	29		
LMR0712004	19	LMR6231003	25	LMR7364001	27	LMR7912038	28		
LMR1121001	20	LMR6232001	25	LMR7364002	27	LMR7913038	28		
LMR1140001	20	LMR6232003	25	LMR7364004	27	LMR7914038	28		
LMR1220003	20	LMR6233001	25	LMR7364005	27	LMR7917038	28		
LMR1220004	20	LMR6233003	25	LMR7364006	27	LMR7922038	28		
LMR1401001	19	LMR6234001	25	LMR7364007	27	LMR7923038	28		
LMR1401002	19	LMR6234003	25	LMR7367001	27	LMR7924038	28		
LMR1401003	19	LMR6234004	25	LMR7367002	27	LMR7927038	28		
LMR1401004	19	LMR6341001	25	LMR7367004	27	LMR7932038	28		
LMR1402001	20	LMR6341003	25	LMR7367005	27	LMR7933038	28		
LMR1403001	20	LMR6342001	25	LMR7367006	27	LMR7934038	28		
LMR1404001	19	LMR6342003	25	LMR7367007	27	LMR7937038	28		
LMR1404003	19	LMR7062003	31	LMR7663033	28	LMR7962031	28		
LMR1404004	19	LMR7063003	31	LMR7663035	28	LMR7962038	28		
LMR1412001	19	LMR7064003	31	LMR7663037	28	LMR7963031	28		
LMR1412002	19	LMR7067003	31	LMR7664031	28	LMR7963033	28		
LMR1412003	19	LMR7162003	31	LMR7664038	28	LMR7963034	28		
LMR1412004	19	LMR7252001	27	LMR7667031	28	LMR7963038	28		
LMR1422001	19	LMR7253001	27	LMR7667038	28	LMR7963039	28		







Life Is On | **Schneider**  
Electric

Schneider Electric Industries SAS

35, rue Joseph Monier  
CS 30323  
92506 Rueil Malmaison Cedex  
France

RCS Nanterre 954 503 439  
Capital social 928 298 512 €  
[www.se.com](http://www.se.com)

10-2021

© 2021 - Schneider Electric. All Rights Reserved.  
All trademarks are owned by Schneider Electric Industries SAS or its affiliated companies.  
Document reference: ISC02298EN

This document has been  
printed on recycled paper

