



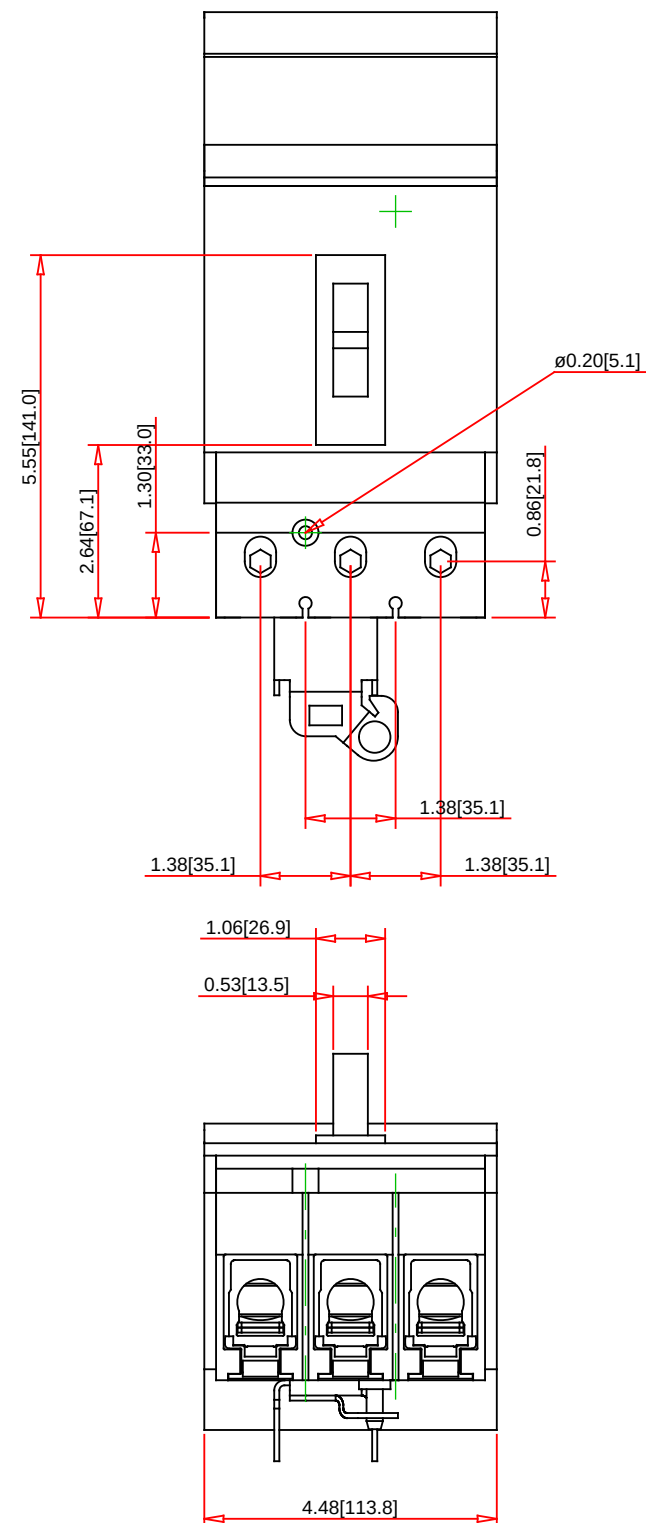

Note:
- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

JGA36200

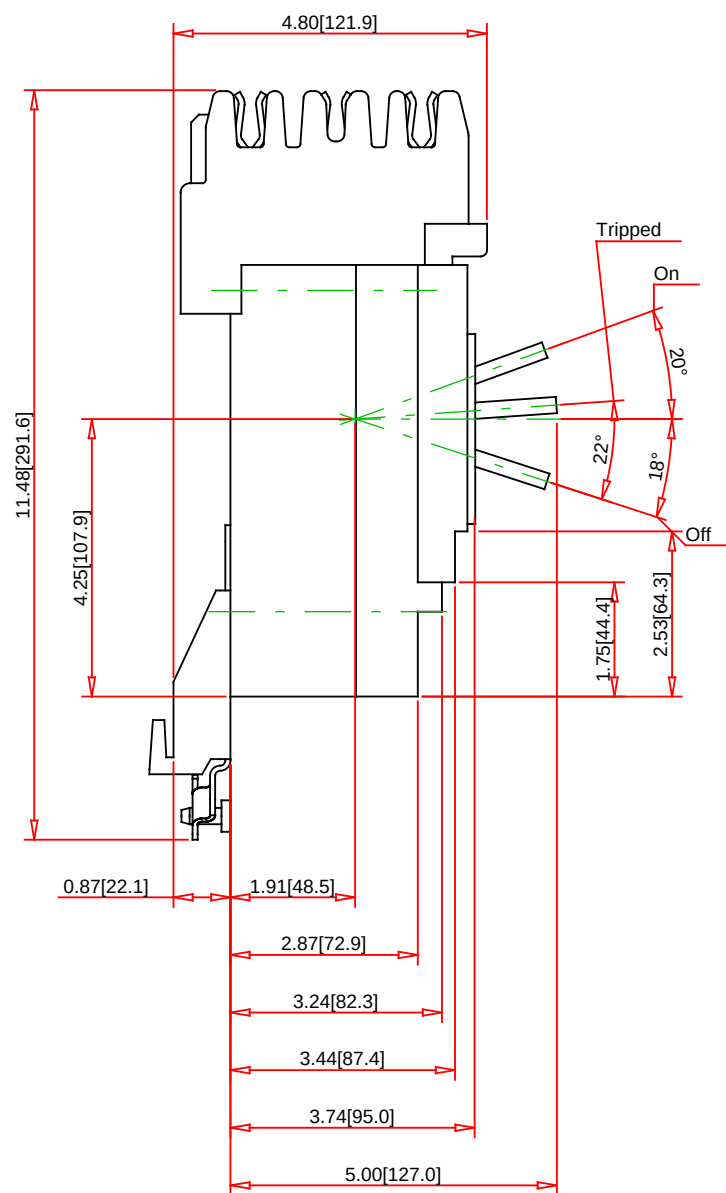

Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 8773425173
Email: CCC@us.schneider-electric.com

Technical Information:

General Application: Provides overload and short circuit protection
For Use With: I-line Panelboards and Switchboards
Approvals: UL Listed - CSA Certified - IEC Rated
Mounting Type: I-Line Plug-On
Terminal Type: I-Line Connection (ON end) - Lugs (OFF end)
Wire Size: #3/0-350 AWG/kcmil(Al/Cu)
Weight: 5 Pounds
Mounting Height: 4.5 Inches

Description: PowerPact J-frame Thermal Magnetic Circuit Breaker
Number of Poles: 3-Pole
Ampere Rating: 200A
Voltage Rating: 600VAC
Interrupting Rating: 65kA at 240VAC - 35kA at 480VAC - 18kA at 600VAC
Fixed AC Magnetic Trip: Low: 1000A - High: 2000A
Phase Connection: ABC

Specification: