


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

LA1KN04

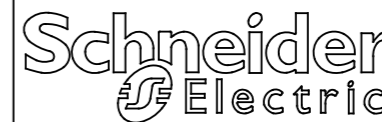

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Contact Rating: A600, Q600 10A
 UL File/CCN: E164353 / NKCR
 CSA File: LR43364 3211 03
 Meets Standard: IEC 60647-1-1
 Weight: 0.10 lb (0.04 kg)
 Termination Method: Screw Clamp
 Control Wire Size: #12 - #18 AWG
 Control Terminal Torque: 7 lb-in (0.8 Nm)
 Mounting Hardware: TeSys K IEC AC or DC Contactor or Control Relay

Description:
 Type:

TeSys K IEC Auxiliary Contact Block Accessory
 TeSys K IEC Contact Block - Front Mount - 0NO, 4NC

Specification: