


Note:  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**LA1KN40**

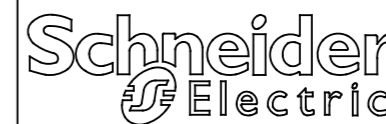

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

Technical Information:

Contact Rating: A600, Q600 10A  
 UL File/CCN: E164353 / NKCR  
 CSA File: LR43364 3211 03  
 Meets Standard: IEC 60647-1-1  
 Weight: 0.10 lb (0.04 kg)  
 Termination Method: Screw Clamp  
 Control Wire Size: #12 - #18 AWG  
 Control Terminal Torque: 7 lb-in (0.8 Nm)  
 Mounting Hardware: TeSys K IEC AC or DC Contactor or Control Relay

Description:  
 Type:

TeSys K IEC Auxiliary Contact Block Accessory  
 TeSys K IEC Contact Block - Front Mount - 4NO, 0NC

Specification: