


Note:  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**LADR2**

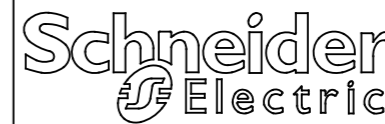

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

Technical Information:

Contact Rating:	A600, Q600 10A
UL File/CCN:	E164862 / NKCR
CSA File:	LR43364 3211 04
Meets Standard:	IEC 60947-5-1
Weight:	0.17 lb (0.08 kg)
Termination Method:	Screw Terminal
Control Wire Size:	#10 - #18 AWG
Control Terminal Torque:	15 lb-in (1.7 Nm)
Mounting Hardware:	TeSys D IEC AC or DC Contactor or Control Relay

Description:  
 Type:

TeSys D IEC Off-Delay Timer - Front Mount - 0.1 to 30 Sec  
 TeSys D IEC Contactor and Control Relay Accessory

Specification: