
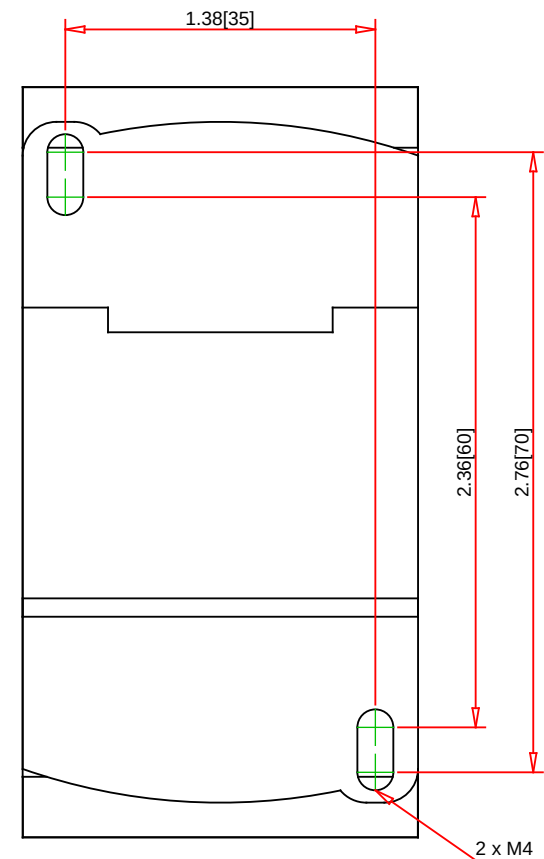
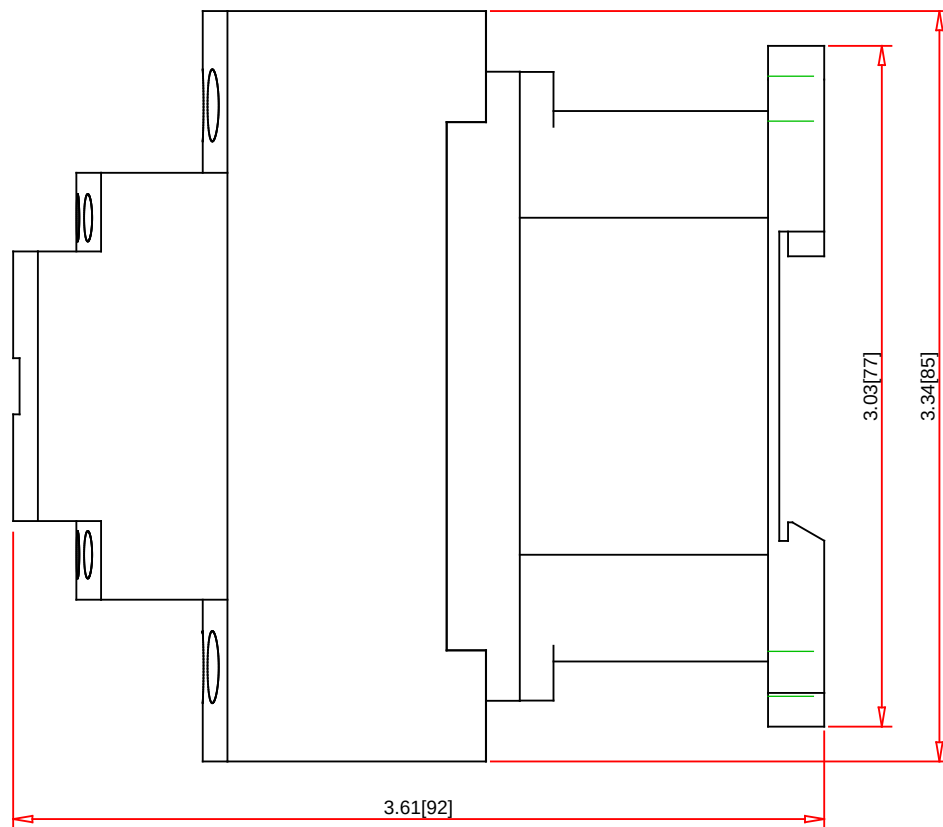


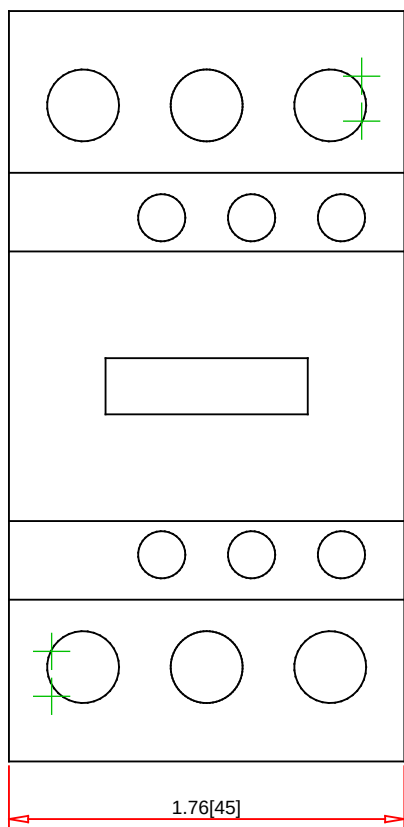

Note:
- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:
LC1D25D7

Schneider Electric
Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 8773425173
Email: CCC@us.schneider-electric.com

Rating: 600V / 25A
UL File/CCN: E164862 / NLDX
CSA File: LR43364 3211 04
Meets Standards: IEC 60647-4
Weight: 0.82 lb (0.37 kg)
Termination Method: Screw Clamp
Wire Size: Power: #6 - #14 AWG
Control: #10 - #18 AWG
Terminal torque: Power: 20 lb-in (2.5 Nm)
Control: 15 lb-in (1.7 Nm)
Mounting Hwd.: 35mm DIN Rail, #8 screw

Technical Information:

Specification:
Description: TeSys D IEC Contactor - 25A - Vac Coil
Type: TeSys D IEC Contactor - 25A - 42Vac Coil
Voltages Code: D7 at 42Vac 50/60 Hz
Coil Consumption: Inrush 70 VA
Sealed 7.5 VA

Single Phase			Three Phase		
115V	230V	200V	230V	460V	575V
2 HP	3 HP	7.5 HP	7.5 HP	15 HP	20 HP