



**Mureva Styl,**  
simply brilliant



[se.com](http://se.com)

Life Is On

**Schneider**  
Electric

Life Is On

# Contents

4	Presentation
13	Inserts For surface mounting and flush mounting
14	Accessories For surface mounting and flush mounting
15	Boxes and frames For surface mounting and flush mounting
16	Complete products Surface mounting Flush mounting
19	Technical information
23	Reference number overview



Fittings available in Polar White and Anthracite Grey



## Mureva Styl, a range of IP55 equipment

At Schneider Electric, we strive towards **technological innovation** on a daily basis. Strict market regulations means developing ever more advanced innovation, to deliver efficiency, **convenience and safety** for you and for your customers.

The heart of this innovation is based on ergonomics - **enabling easy installation** for you and easy operation for occupants.

Mureva Styl is the end result of our research. Mureva Styl reinvents “ease of installation” of your equipment, and innovates - with a design that is **robust yet trendy and unique**.

Simplify your life by opting for **the comfort** that Mureva Styl brings.

More business for you, more satisfaction for your customers.




### The latest innovations

- Smart LED technology for easy location in the dark
- A transparent cover to easily identify between switch and socket

# Mureva Styl, a tough and robust design

The new robust design of Mureva Styl means you can now work with full confidence.

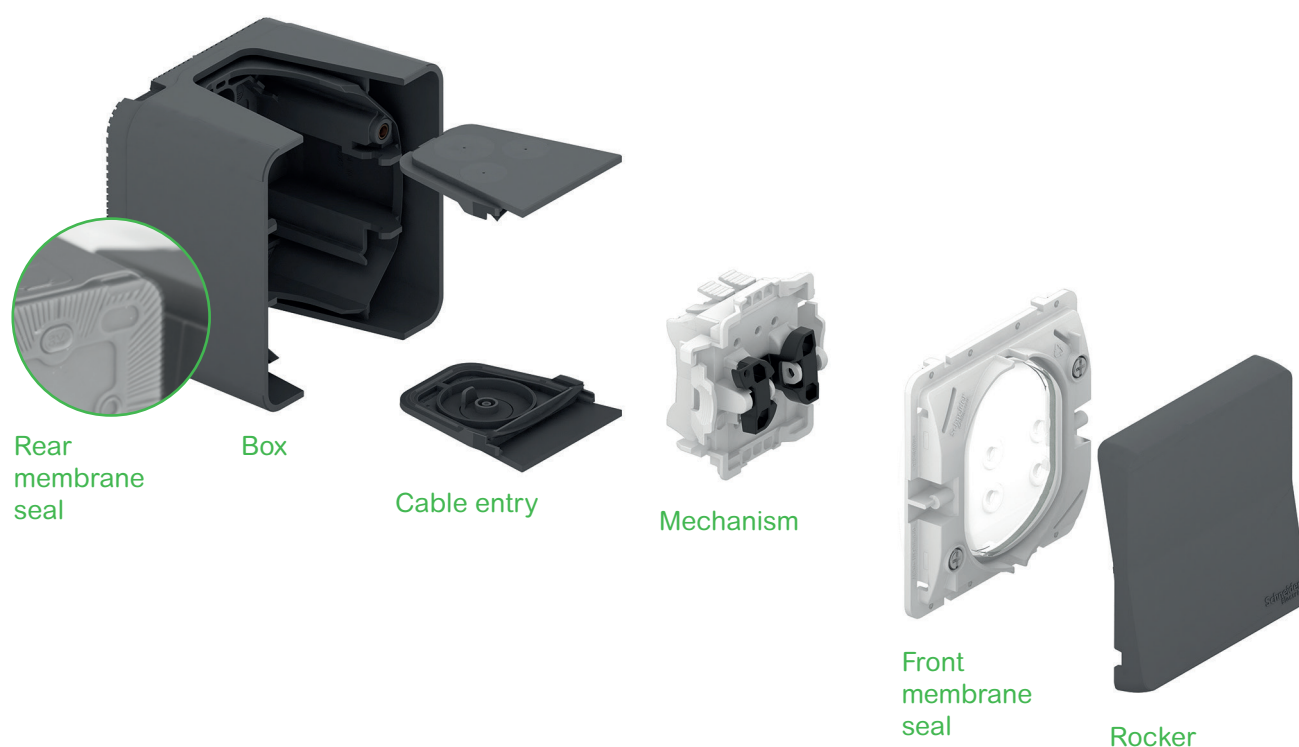

**1** Components are reinforced with strong mechanism fittings, rigid enclosure boxes and frames as well as its waterproof rear membrane seal.

**2** Because all its components are IP55 rated, Mureva Styl withstands the harshest of environment conditions:

- Waterproof, whether open or fitted,
- IK 08 classified for protection from knocks, UV resistant according to ISO4892-2 indoor and outdoor,
- Dirt and dust resistant, as well as resistant to solvent.

# Mureva Styl, an ergonomic design

The biggest advance is in its new ergonomic design which makes for a straightforward installation.



The Mureva Styl range is designed to be installed effortlessly, thanks to its intuitive and intelligent fitting design that is based on advanced ergonomics.

**1** Now it's easy to connect your devices thanks to a insert that gives you plenty of wiring space...

**2** ... Wiring is so simple. It clips and unclips easily.

**3** Socket-outlets, switches and Push buttons can be easily illuminated with plug-and-play LED accessories or hardwired.

**4** A standard switch can be easily be transformed into a Push button thanks to a simple spring mechanism and positioning aid.

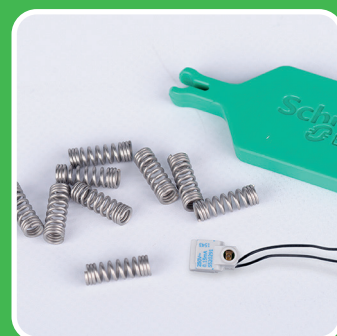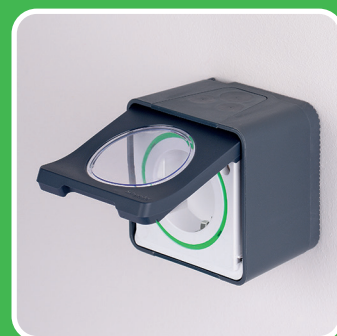

## Mureva Styl, a trendy design

The Mureva Styl range is not just easy to install and able to withstand all conditions, it has also been ingeniously designed with usability in mind.

Its curved profile goes perfectly with all ranges, and visually is a harmonious match with Schneider Electric ranges.

**1** The two smart LEDs built into the sockets which is a Schneider Electric innovation make it easy to check when power is on. An innovative feature that also makes it easy to locate in the dark.

**2** A transparent window cover replaces the opaque cover, meaning no more mistaking a switch with a socket.



### Polar White or Anthracite Grey?

In line with current color trends for the residential and small-commercial markets, Mureva Styl is available in two colors: Polar White and Anthracite Grey. Polar White is discreet and suited to a variety of environments (hospitals, laboratories, warehouses for example...). Whereas, Anthracite Grey is stylish and perfectly suited to offices, garages, lofts and gardens. The plastic fittings are specially treated so that both models resist the build up of dust and dirt.



# The Mureva Styl range, less inventory, more functionality

Reducing its number of components from 272 to just 90, the Mureva Styl range compromises none of its qualities at the expense of functionality.

A range that has been refined to deliver greater efficiency.

	Full product	Product components
<p>Mureva Styl New generation range</p> <p>  Anthracite Grey   Polar White         </p> <p>  </p> <p>90 part numbers</p>		 <p><b>IP 55</b> for surface mounting &amp; for flush mounting</p> <p>Only 2 part numbers to cost out and install and only one product to assemble : simple to cost out with an inventory that is optimized</p>

## Brand features

The Mureva Styl range now brings you a number of new functions : emergency stop button, blind control, key-operated switch



Emergency stop button



Blind control



Key-operated switch

# The Mureva range, a complete waterproof system

And to make installation even easier, Mureva Styl comprises a comprehensive waterproof range.

## Surface-mounted

### Mureva Box

A large selection of boxes wherever security and tightness are required



### Mureva Tube

Designed to be bent without breaking, to ensure a perfectly aligned channel



### Mureva Fix

Designed to ensure a time-proof quality and security in the fixation



## Flush-mounted


### Mureva Styl and Multifix Air flush-mounted box

Deeper for an optimal comfort of installation, they are strong and universal.





# Environmental Data Program

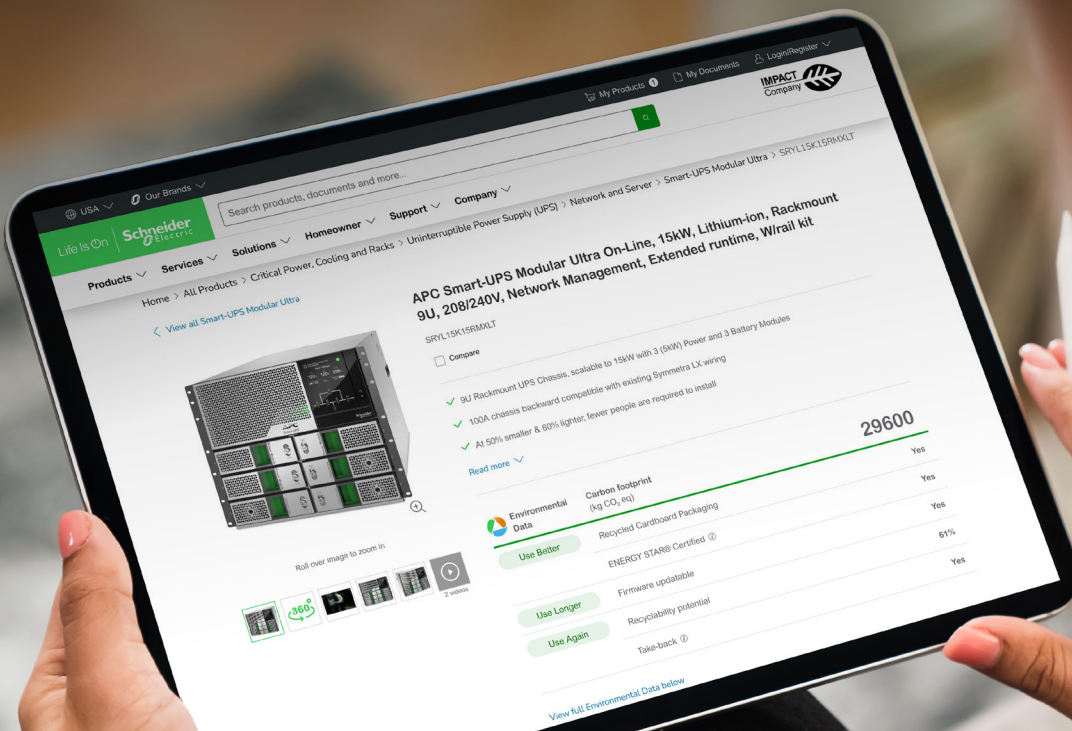


## Next-level transparency for better-informed product choices

The Environmental Data Program is a framework for how we measure, categorize, and compare the environmental attributes and footprint of our products.

Using a rigorous, fact-based methodology, the program provides environmental data from across the product lifecycle.

### Five data categories across the product lifecycle

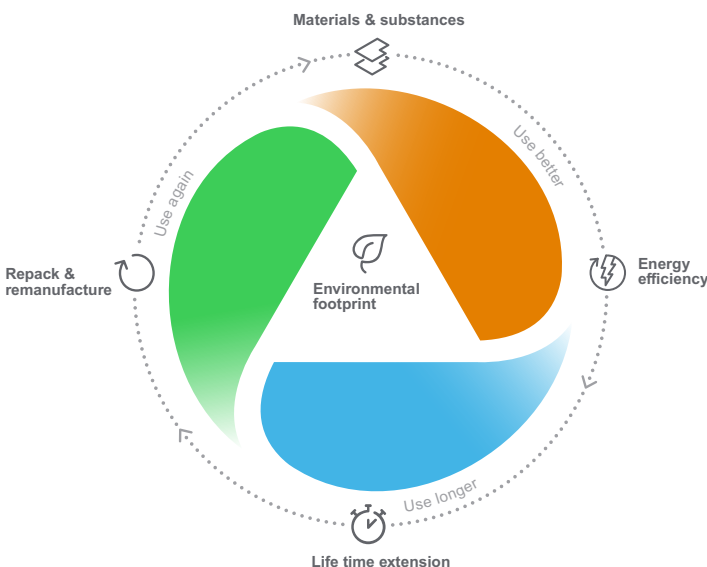

**Use Better:** How sustainable a product is, including environmental footprint, materials and substances, packaging, and energy efficiency.

**Use Longer:** How a product's life time can be effectively extended in terms of reparability and updatability.

**Use Again:** How a product can be reused, from dismantling and remanufacturing to recyclability and manufacturer take back.

With this transparent, verified data, customers and partners are empowered to make conscious environmental choices and accurately evaluate and report on sustainability performance.

All our hardware offers have an associated environmental data available on se.com product pages.



Learn more about the **Environmental Data Program**

# Mureva Styl

## Inserts

For surface mounting and flush mounting

Controls						CE	NF	ERAC
	Single					Double		
	<b>Two-way switch</b>	<b>Intermediate switch</b>	<b>2 pole switch</b>	<b>Push button</b>	<b>Push button with label holder</b>	<b>Double two-way switch</b>	<b>Double Push button</b>	
White	<b>MUR39723</b>	<b>MUR39023</b>	<b>MUR39033</b>	<b>MUR39027</b>	<b>MUR39129</b>	<b>MUR39022</b>		
Anthracite	<b>MUR37021</b>	<b>MUR35020</b>	<b>MUR35034</b>	<b>MUR35027</b>	<b>MUR34029</b>	<b>MUR35019</b>	<b>MUR35326</b>	
Characteristics	10 AX	10 AX	16 AX	10 A	10 A	10 AX	10 A	
	250 V AC screwless IP55 <sup>(1)</sup> - IK08					250 V AC screwless IP55 <sup>(1)</sup> - IK08		

	With lamp		
	<b>Two-way switch</b>	<b>Push button</b>	<b>Double Push button</b>
White	<b>MUR39024</b>	<b>MUR39127</b>	<b>MUR35228</b>
Anthracite	<b>MUR35025</b>	<b>MUR35127</b>	
Characteristics	10 AX	10 A	10 A
	250 V AC screwless blue LED, 0.15 mA - 250 V locator or indicator (not wired)		
		locator	locator (not wired)
	IP55 <sup>(1)</sup> - IK08		

WiFi Repeater	
White	<b>MUR39070</b>
Anthracite	<b>MUR35070</b>
Characteristics	IP55 - IK07

Specialized controls					CE	ERAC	CE	NF	ERAC	
	<b>Key switch</b>		<b>Emergency switch</b>		<b>Roller blind</b>					
	<b>with 2 positions</b>	<b>with 3 positions</b>	<b>Key to release</b>	<b>Turn to release</b>	<b>Push button</b>					
Anthracite	<b>MUR35062</b>	<b>MUR35061</b>	<b>MUR35052</b>	<b>MUR35053</b>	<b>MUR35042</b>					
Characteristics	screw terminals		screw terminals		screwless					
	key switches and emergency switches are with 3 A switches					10 A - 250 V AC				
	IP55 <sup>(1)</sup> - IK08					IP55 <sup>(1)</sup> - IK08				

Signalling device		CE	ERAC
	<b>with red lens for E14 incandescent or LED lamp</b>		
Anthracite	<b>MUR34526</b>		
Characteristics	delivered without lamp see "Lamp for light signal" page 14 screw terminals 5 W maximum IP55 <sup>(1)</sup> - IK08		

Socket-outlets				NF	ERAC
	<b>French</b>		<b>German</b>		
	<b>16 A 2P+E, shuttered pin-earth</b>	<b>16 A 2P+E, shuttered pin-earth</b>	<b>16 A 2P+E, shuttered side-earth</b>	<b>16 A 2P+E, shuttered side-earth</b>	
White	<b>MUR39133</b>		<b>MUR39134</b>	<b>MUR39135</b>	
Anthracite	<b>MUR36133</b>	<b>MUR38030</b>	<b>MUR36134</b>	<b>MUR36135</b>	
Characteristics	screwless		screw terminals		screwless
	250 V AC - 50 Hz		250 V AC - 50 Hz		250 V AC - 50 Hz
	IP55 <sup>(1)</sup> - IK08		IP55 <sup>(1)</sup> - IK08		IP55 <sup>(1)</sup> - IK08

<sup>(1)</sup> when installed in a box or frame

**Surface mounting**



Complete with a box  
▶ page 15




**Flush mounting**






Complete with a frame  
▶ page 15


 
# Accessories


For surface mounting and flush mounting


Rockers			
			
	with bell symbol	with light symbol	for illumination, label holder
White	<b>MUR39201</b>	<b>MUR39202</b>	<b>MUR39203</b>
Anthracite	<b>MUR34201</b>	<b>MUR34202</b>	<b>MUR34203</b>
Characteristics	IP55 - IK08	IP55 - IK08	including label sheet with (blank+bell+light+key marking)



Rockers with lens		
		
	single	double
White	<b>MUR39204</b>	<b>MUR39205</b>
Anthracite	<b>MUR34204</b>	<b>MUR34205</b>
Characteristics	IP55 - IK08	IP55 - IK08




Cable outlet	
	
	for one cable
White	<b>MUR37933</b>
Anthracite	<b>MUR37931</b>
Characteristics	IP55 - IK08 for one cable 3 x 2.5 mm <sup>2</sup>


Set of 10 cable entries		
		
	for 3 cables	for 1 tube
White	<b>MUR39007</b>	<b>MUR39008</b>
Anthracite	<b>MUR35007</b>	<b>MUR35008</b>
Characteristics	IP55 - IK08	ø tube: 6 mm min., 20 mm max.


10 sets of 2 covers for surface-box wall mounting screw head	
	
Anthracite	<b>MUR34206</b>

Set of 10 labelling sheet	
	
	<b>MUR34004</b> with blank + bell + light + key marking

Lamps for light signal		
		
	incandescent	LED
	<b>MUR34555</b>	<b>MUR34556</b>
Characteristics	for MUR34526 signalling device, see page 13	

LED lamps			
			
	Blue LED, 0.15 mA 250 V, wire	Blue LED, 0.15 mA 250 V, plug & play	Blue LED, 5 mA 12-48 V,dc plug & play
	<b>S520291</b>	<b>S520292</b>	<b>S520293</b>
Characteristics	for switches and socket-outlets for RL and special loads	for switches only	for switches only

Spring to transform a switch to Push button	
	
	Spring
	<b>S520299</b>
Characteristics	10 units, delivered in a plastic bag with a positioning aid tool note: Push-button switches are suitable for 10 A loading only (not 10 AX)

Box cover with lid <sup>(1)</sup>	
	
	for New Unica range products
White	<b>MUR39110</b>
Anthracite	<b>MUR35110</b>
Characteristics	IP55 <sup>(2)</sup> - IK06

<sup>(1)</sup> see page 20 and 21 of chapter "Technical informations", the table of Unica and New Unica range products compatible with these box covers with lid.  
<sup>(2)</sup> when installed in a box or frame.






**Surface mounting**  
 Complete with a box  
▶ page 15

**Flush mounting**  
 Complete with a frame  
▶ page 15

# Boxes and frames

For surface mounting and flush mounting








 
 
 
 
 
 
 
Boxes for surface mounting				
				
	<b>1 gang</b>	<b>2 gangs, horizontal</b>	<b>2 gangs, vertical</b>	<b>3 gangs, horizontal</b>
White	<b>MUR39911</b>	<b>MUR39914</b>	<b>MUR39912</b>	<b>MUR39913</b>
Anthracite	<b>MUR37911</b>	<b>MUR37914</b>	<b>MUR37912</b>	<b>MUR37713</b>
Characteristics	IP55 <sup>(1)</sup> - IK08			

Frames for flush mounting					
					
	<b>1 gang</b>	<b>1 gang, with claws</b>	<b>2 gangs, horizontal</b>	<b>2 gangs, vertical</b>	<b>3 gangs, horizontal</b>
White	<b>MUR39107</b>	<b>MUR39108</b>	<b>MUR39101</b>	<b>MUR39151</b>	<b>MUR39109</b>
Anthracite	<b>MUR34107</b>	<b>MUR34108</b>	<b>MUR34101</b>	<b>MUR34151</b>	<b>MUR34109</b>
Characteristics	IP55 <sup>(1)</sup> (on flat/smooth walls only).				


<sup>(1)</sup> when completed with covers



# Complete products

## Surface mounting





Controls								CE	NF	EN	ERC
	Single				Double	With lamp					
											
	Two-way	Intermediate	2 pole	Push button	Double two-way	Two-way	Push button				
											
White	MUR39021 MUR40015 <sup>(D)</sup> MUR89021 <sup>(D)</sup>		MUR40007 <sup>(D)</sup>	MUR39026 MUR40009 <sup>(D)</sup> MUR89026 <sup>(D)</sup>	MUR40016	MUR40018 <sup>(D)</sup>					MUR40010 <sup>(D)</sup>
Anthracite	MUR35021 MUR55021 <sup>(D)</sup> MUR40013 <sup>(D)</sup>	MUR35023	MUR35033 MUR55033 <sup>(D)</sup>	MUR35026 MUR40019 <sup>(D)</sup> MUR85026 <sup>(D)</sup>	MUR35022 MUR55022 <sup>(D)</sup> MUR40014 <sup>(D)</sup>	MUR35024 MUR55024 <sup>(D)</sup>					MUR35028
Characteristics	10 AX 250 V AC screwless	10 AX	16 AX	10 A	10 AX 250 V AC screwless	10 AX 250 V AC screwless blue LED, 0.15 mA 250 V locator or indicator (not wired)	10 A				locator
	IP55 - IK08				IP55 - IK08		IP55 - IK08				

<sup>(D)</sup> Available in DIY Packaging

Mechanical time delay switches		CE	ERC
			
White	MUR39067		
Anthracite	MUR35067		
Characteristics	250 V AC up to 14 min. - adjustable steps: 2 min. screw terminals switching capacity: 10 A IP55 - IK08		

Socket-outlets + two-way switches				CE	NF	EN	ERC
	French		German				
							
	10 AX 2P+E, shuttered + two-way, pin-earth		10 AX 2P+E, shuttered + two-way, side-earth				
Anthracite	MUR36025		MUR36024 MUR56024 <sup>(D)</sup>				
Characteristics	screwless switch: 10 AX-250 V AC IP55 - IK08		screwless switch: 10 AX-250 V AC IP55 - IK08				





<sup>(D)</sup> Available in DIY Packaging

French socket-outlets					NF
	Single		Double	Triple	
					
	16 A 2P+E, shuttered, pin-earth	16 A 2P+E, shuttered, pin-earth	16 A 2P+E, shuttered, horizontal, pin-earth	16 A 2P+E, shuttered, horizontal, pin-earth	
White	MUR39030		MUR36027 <sup>(D)</sup>	MUR36039 <sup>(D)</sup>	
Anthracite	MUR35031	MUR36030	MUR36028	MUR36037 MUR86037 <sup>(D)</sup>	
Characteristics	IP55 - IK08 16 A 250 V AC screwless	16 A 250 V AC screw terminals	prewired IP55 - IK08 16 A 250 V AC screwless	prewired IP55 - IK08 16 A 250 V AC screwless	



<sup>(D)</sup> Available in DIY Packaging

# Complete products

## Surface mounting


 
German socket-outlets				EAC
	Single		Double	Triple
				
	16 A 2P+E, shuttered, screwless	16 A 2P+E, shuttered, screw terminals	16 A 2P+E, shuttered, screwless	16 A 2P+E, shuttered, screw terminals
White	MUR39034	MUR39206 MUR40011 <sup>(D)</sup> MUR89206 <sup>(D)</sup>	MUR39035 MUR40005 <sup>(D)</sup> MUR80005 <sup>(D)</sup> MUR89035 <sup>(D)</sup>	
Anthracite	MUR36034	MUR36731 MUR40012 <sup>(D)</sup> MUR86731 <sup>(D)</sup> MUR56034 <sup>(D)</sup>	MUR36029 MUR40006 <sup>(D)</sup> MUR56029 <sup>(D)</sup> MUR56129 <sup>(D)</sup> MUR80006 <sup>(D)</sup>	MUR36038 MUR86038 <sup>(D)</sup>
Characteristics	IP55 - IK08		prewired IP55 - IK08	prewired IP55 - IK08

<sup>(D)</sup> Available in DIY Packaging


EV Socket-outlets		
	French	German
		
	16 A 2P+E, shuttered, pin-earth	16 A 2P+E, shuttered, side-earth
White	MUR39010	MUR39012
Anthracite	MUR36010	MUR36012
Characteristics	16 A 250 V AC IP55 - IK08	16 A 250 V AC IP55 - IK08

# Complete products



## Flush mounting

Controls		CE	NF	NEC	EAC
	<b>Single</b>				
	<b>Two-way with fixing claws</b>				
White	<b>MUR39721</b> <b>MUR89721<sup>(D)</sup></b>				
Characteristics	10 AX 250 V AC screwless IP55 (on flat/smooth walls only).				


 
<sup>(D)</sup> Available in DIY Packaging

German Socket-outlets		NEC	EAC
		<b>16 A 2P+E, shuttered, side-earth</b>	
White	<b>MUR39132</b> <b>MUR40003<sup>(D)</sup></b> <b>MUR89132<sup>(D)</sup></b>		
Anthracite	<b>MUR36132</b> <b>MUR86132<sup>(D)</sup></b>		
Characteristics	16 A 250 V AC screwless IP55 - IK08		






 
 
 
 
 
<sup>(D)</sup> Available in DIY Packaging

EV Socket-outlets	
<b>French</b>	<b>German</b>
	
<b>16 A 2P+E, shuttered, pin-earth</b>	<b>16 A 2P+E, shuttered, side-earth</b>
White <b>MUR39011<sup>(D)</sup></b>	White <b>MUR39013<sup>(D)</sup></b>
Anthracite <b>MUR36011<sup>(D)</sup></b>	Anthracite <b>MUR36013<sup>(D)</sup></b>
Characteristics	Characteristics
16 A 250 V AC IP55 - IK08	16 A 250 V AC IP55 - IK08

<sup>(D)</sup> Available in DIY Packaging

French Socket-outlets		CE	NF	NEC	EAC
		<b>Two-way</b>			
					
White	<b>MUR39036<sup>(D)</sup></b>				
Anthracite	<b>MUR35036<sup>(D)</sup></b>				
Characteristics	10 A 250 V AC screwless IP55 - IK08				

<sup>(D)</sup> Available in DIY Packaging

Controls		CE	NF	NEC	EAC
	<b>Single</b>	<b>Double</b>	<b>With lamp</b>	<b>With lamp</b>	<b>With lamp and frame</b>
					
	<b>Two-way</b>	<b>Double two-way</b>	<b>Two-way</b>	<b>Push button</b>	<b>Push button</b>
					
White	<b>MUR40000<sup>(D)</sup></b> <b>MUR80000<sup>(D)</sup></b>	<b>MUR40001<sup>(D)</sup></b>	<b>MUR40017<sup>(D)</sup></b>	<b>MUR40021<sup>(D)</sup></b>	
Anthracite					<b>MUR86628<sup>(D)</sup></b>
Characteristics	10 AX 250 V AC IP55 - IK08				


<sup>(D)</sup> Available in DIY Packaging

# Technical information

## Connection examples

### Controls


#### Two-way switches

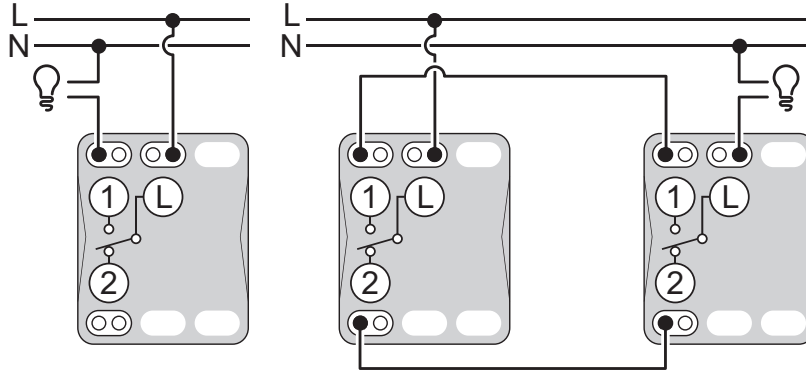

ON/OFF circuit

Two-way circuit

#### Two-way switches with LED

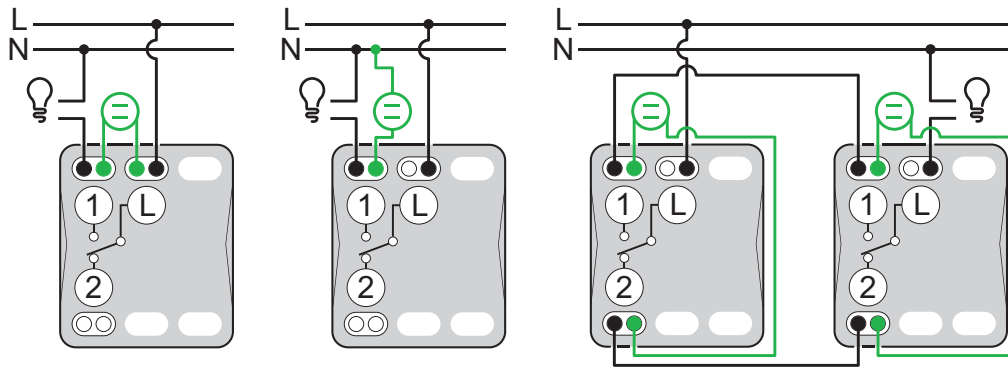


ON/OFF circuit with locator lamp

ON/OFF circuit with indicator lamp

Two-way circuit with locator lamp

#### Double two-way switches

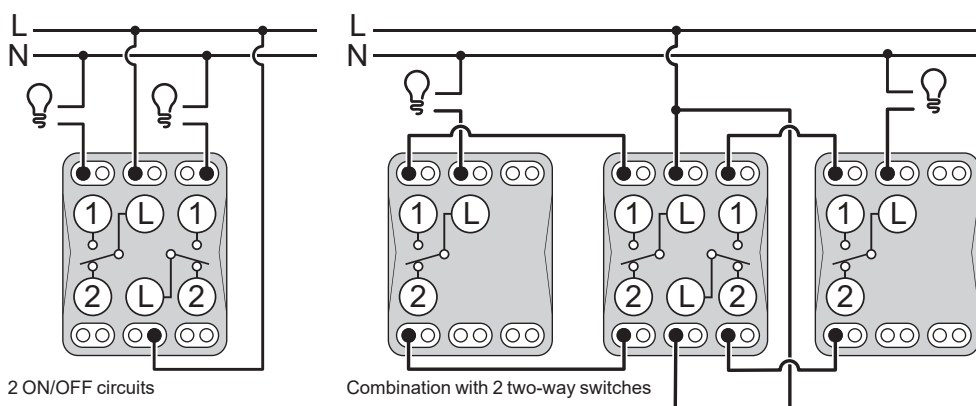


2 ON/OFF circuits

Combination with 2 two-way switches

# Technical information

## Connection examples


### Push button

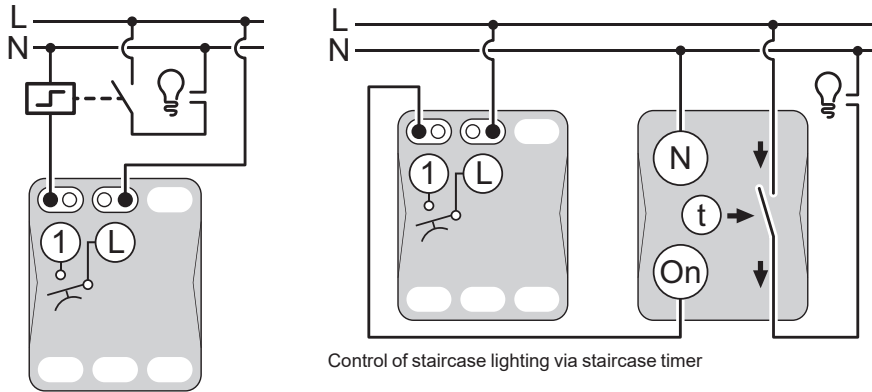

Control of light via impulse relay

Control of staircase lighting via staircase timer

### Push button with LED

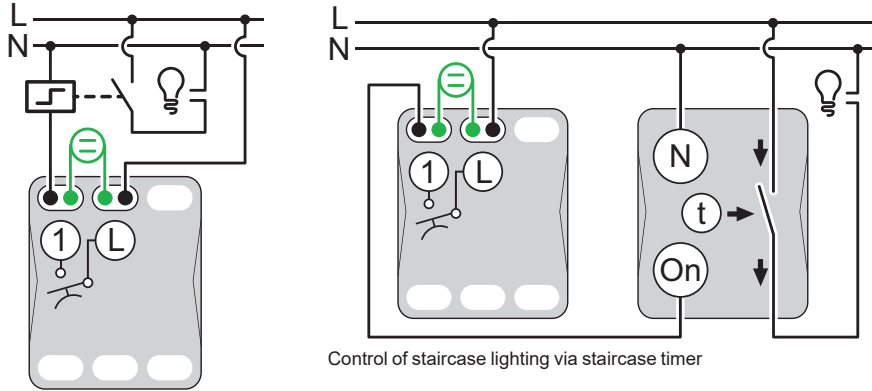


Control of light via impulse relay

Control of staircase lighting via staircase timer

## Specialized controls

### Roller blind push button

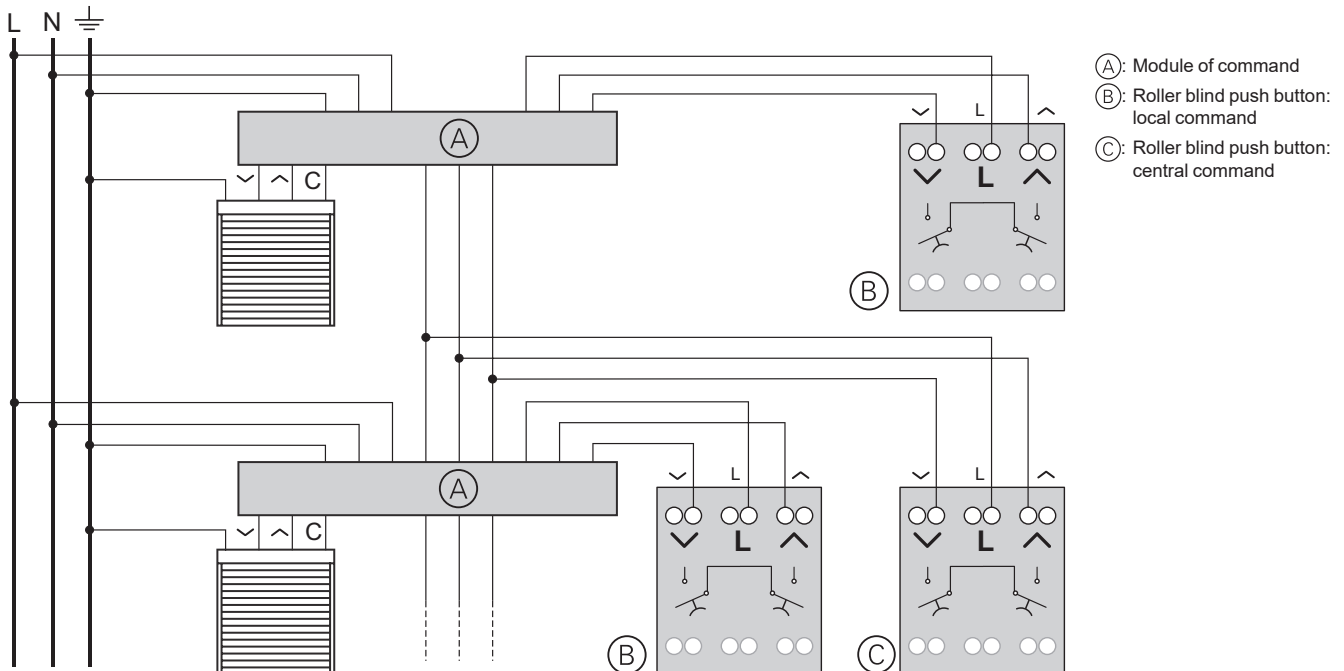

- (A): Module of command
- (B): Roller blind push button: local command
- (C): Roller blind push button: central command


# Technical information

## Lighting circuit equipment dimensioning and selection guide

- For english version; you can use the "[http://download.schneider-electric.com/files?p\\_Doc\\_Ref=A9GT15E](http://download.schneider-electric.com/files?p_Doc_Ref=A9GT15E)" link to download the "Lighting technical guide: How to control and protect lighting circuits?"
- For french version; you can use the "[http://download.schneider-electric.com/files?p\\_Doc\\_Ref=A9GT15F](http://download.schneider-electric.com/files?p_Doc_Ref=A9GT15F)" link to download the "Lighting technical guide: How to control and protect lighting circuits?"

# Technical information

## Dimensions

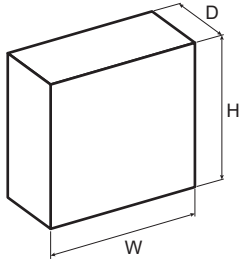

Ref.	Width (W)	Height (H)	Depth (D)
MUR34029	71	71	40
MUR34101	155	84	23
MUR34107	84	84	28
MUR34108	84	84	44
MUR34109	226	84	23
MUR34151	84	155	23
MUR34201	71	70	14
MUR34202	71	70	14
MUR34203	71	70	14
MUR34204	71	70	14
MUR34205	71	70	14
MUR35007	49	42	8
MUR35008	49	42	13
MUR35019	71	71	40
MUR35020	71	71	40
MUR35021	76	76	64
MUR35022	76	76	64
MUR35023	76	76	64
MUR35024	76	76	64
MUR35025	71	71	40
MUR35026	76	76	64
MUR35027	71	71	40
MUR35028	76	76	64
MUR35031	76	76	64
MUR35033	76	76	64
MUR35034	71	71	40
MUR35036	83	83	46
MUR35042	71	71	40
MUR35052	71	71	80
MUR35053	71	71	80
MUR35061	71	71	72
MUR35062	71	71	72
MUR35067	76	76	80
MUR35110	71	71	29
MUR35127	71	71	40
MUR35228	71	71	40
MUR35326	71	71	40
MUR36010	76	76	64
MUR36011	76	76	64
MUR36012	76	76	64
MUR36013	71	71	50
MUR36024	76	147	64
MUR36025	76	147	64
MUR36027	147	76	64
MUR36028	147	76	64
MUR36029	147	76	64
MUR36030	76	76	64
MUR36034	76	76	64
MUR36037	218	76	64
MUR36038	218	76	64
MUR36039	218	76	64
MUR36132	84	84	56
MUR36133	71	71	47
MUR36134	71	71	50
MUR36135	71	71	43
MUR36731	76	76	64
MUR37021	71	71	40
MUR37713	218	76	54
MUR37911	76	76	54
MUR37912	76	147	54
MUR37914	147	76	54
MUR37931	71	71	45
MUR37933	71	71	45
MUR38030	71	71	47
MUR39007	49	42	8
MUR39008	49	42	13
MUR39010	76	76	54
MUR39011	76	76	64
MUR39012	76	76	64
MUR39013	71	71	50
MUR39021	76	76	64
MUR39022	71	71	40
MUR39023	71	71	40
MUR39024	71	71	40

Ref.	Width (W)	Height (H)	Depth (D)
MUR39026	76	76	64
MUR39027	71	71	40
MUR39030	76	76	64
MUR39033	71	71	40
MUR39034	76	76	64
MUR39035	147	76	64
MUR39036	83	83	46
MUR39067	76	76	80
MUR39101	155	84	23
MUR39107	84	84	28
MUR39108	84	84	44
MUR39109	226	84	23
MUR39110	71	71	29
MUR39127	71	71	40
MUR39129	71	71	40
MUR39132	84	84	50
MUR39133	71	71	47
MUR39134	71	71	50
MUR39135	71	71	50
MUR39151	84	155	23
MUR39201	71	71	14
MUR39202	71	70	40
MUR39203	71	70	14
MUR39204	71	70	14
MUR39205	71	70	14
MUR39206	76	76	64
MUR39721	84	84	56
MUR39723	71	71	40
MUR39911	76	76	54
MUR39912	76	147	54
MUR39913	218	76	54
MUR39914	147	76	54
MUR40000	84	84	40
MUR40001	84	84	40
MUR40003	84	84	50
MUR40005	147	76	64
MUR40006	147	76	64
MUR40007	76	76	64
MUR40009	76	76	64
MUR40010	76	76	64
MUR40011	76	76	64
MUR40012	76	76	64
MUR40013	84	84	50
MUR40014	84	84	40
MUR40015	76	76	64
MUR40016	76	76	64
MUR40017	84	84	40
MUR40018	76	76	64
MUR40019	76	76	64
MUR40021	84	84	40
MUR55021	76	76	64
MUR55022	76	76	64
MUR55024	76	76	64
MUR55033	76	76	64
MUR56024	76	147	64
MUR56029	147	76	64
MUR56034	76	76	64
MUR56129	147	76	64
MUR80000	84	84	50
MUR80005	147	76	64
MUR80006	147	76	64
MUR85026	76	76	64
MUR86037	218	76	64
MUR86038	218	76	64
MUR86132	84	84	56
MUR86628	84	84	40
MUR86731	76	76	64
MUR89021	76	76	64
MUR89026	76	76	64
MUR89035	147	76	64
MUR89132	84	84	50
MUR89206	76	76	64
MUR89721	84	84	56

# Reference number overview

Ref.	Page	Ref.	Page	Ref.	Page	Ref.	Page
MUR34004	14	MUR36028	16	MUR39151	15	MUR89035	17
MUR34029	13	MUR36029	17	MUR39201	14	MUR89132	18
MUR34101	15	MUR36030	16	MUR39202	14	MUR89206	17
MUR34107	15	MUR36034	17	MUR39203	14	MUR89721	18
MUR34108	15	MUR36037	16	MUR39204	14	S520291	14
MUR34109	15	MUR36038	17	MUR39205	14	S520292	14
MUR34151	15	MUR36039	16	MUR39206	17	S520293	14
MUR34201	14	MUR36132	18	MUR39721	18	S520299	14
MUR34202	14	MUR36133	13	MUR39723	13		
MUR34203	14	MUR36134	13	MUR39911	15		
MUR34204	14	MUR36135	13	MUR39912	15		
MUR34205	14	MUR36731	17	MUR39913	15		
MUR34206	14	MUR37021	13	MUR39914	15		
MUR34526	13	MUR37713	15	MUR40000	18		
MUR34555	14	MUR37911	15	MUR40001	18		
MUR34556	14	MUR37912	15	MUR40003	18		
MUR35007	14	MUR37914	15	MUR40005	17		
MUR35008	14	MUR37931	14	MUR40006	17		
MUR35019	13	MUR37933	14	MUR40007	16		
MUR35020	13	MUR38030	13	MUR40009	16		
MUR35021	16	MUR39007	14	MUR40010	16		
MUR35022	16	MUR39008	14	MUR40011	17		
MUR35023	16	MUR39010	17	MUR40012	17		
MUR35024	16	MUR39011	18	MUR40013	16		
MUR35025	13	MUR39012	17	MUR40014	16		
MUR35026	16	MUR39013	18	MUR40015	16		
MUR35027	13	MUR39021	16	MUR40016	16		
MUR35028	16	MUR39022	13	MUR40017	18		
MUR35031	16	MUR39023	13	MUR40018	16		
MUR35033	16	MUR39024	13	MUR40019	16		
MUR35034	13	MUR39026	16	MUR40021	18		
MUR35036	18	MUR39027	13	MUR55021	16		
MUR35042	13	MUR39030	16	MUR55022	16		
MUR35052	13	MUR39033	13	MUR55024	16		
MUR35053	13	MUR39034	17	MUR55033	16		
MUR35061	13	MUR39035	17	MUR56024	16		
MUR35062	13	MUR39036	18	MUR56029	17		
MUR35067	16	MUR39067	16	MUR56034	17		
MUR35070	13	MUR39070	13	MUR56129	17		
MUR35110	14	MUR39101	15	MUR80000	18		
MUR35127	13	MUR39107	15	MUR80005	17		
MUR35228	13	MUR39108	15	MUR80006	17		
MUR35326	13	MUR39109	15	MUR85026	16		
MUR36010	17	MUR39110	14	MUR86037	16		
MUR36011	18	MUR39127	13	MUR86038	17		
MUR36012	17	MUR39129	13	MUR86132	18		
MUR36013	18	MUR39132	18	MUR86628	18		
MUR36024	16	MUR39133	13	MUR86731	17		
MUR36025	16	MUR39134	13	MUR89021	16		
MUR36027	16	MUR39135	13	MUR89026	16		

Life Is On



**Schneider Electric Industries SAS**

35, rue Joseph Monier  
CS 30323  
92506 Rueil Malmaison Cedex  
France

RCS Nanterre 954 503 439  
Capital social 896 313 776 €  
[www.schneider-electric.com](http://www.schneider-electric.com)

08 2025  
Mureva Styl catalogue

© 2025 - Schneider Electric. All Rights Reserved.  
All trademarks are owned by Schneider Electric Industries SAS or its affiliated companies.  
LSB03520EN

This document has been  
printed on recycled paper

