

Area of application

- **Unica Basic** to be installed in the universal box. It is supplied with cover frames with 1 to 4 gang, for mounting in horizontal or vertical position (for vertical mounting, the embellishment supplied with the cover frame must be rotated by 90 °). It is available in 4 colors
- **Unica Colors** to be installed in the universal box. It is supplied with cover frames with 1 to 4 gang, for mounting in horizontal or vertical position.
 - range of embellishments with 18 possible finishes.
 - 2 mounting directions according to whether the cover frame is installed in horizontal or vertical position. The touch sensitive protrusions must be placed on the bottom part.
- **Unica Quadro** to be installed in the universal box. It is supplied with cover frames with 1 to 4 gang, for mounting in horizontal or vertical position (for vertical mounting, the embellishment supplied with the cover frame must be rotated by 90 °). It is available in 14 colors.
- **Unica Allegro** to be installed in the rectangular box. It is supplied with cover frames with 1, 2, 3, 4 or 6 modules.
- **Unica Top** and **Unica Plus** to be installed in the universal box with 1 to 4 gang in horizontal position and 1 to 3 gang in vertical position.
- The **Unica Top** and **Unica Basic** ranges can be mounted, with narrow cover and fixing frames for thin panel.
- The **Unica Top**, **Unica Plus**, **Unica Colors** and **Unica Basic** ranges can be mounted with supplementary frames to cover the irregularities on the wall, for the versions with 1, 2 and 3 gang.

Technical data


- All **Unica** finishes are resistant to cleaning products and UV radiation.
- Recyclable thermoplastic materials.
- Self-extinguishing thermoplastic materials with excellent impact strength.
- The **Unica Top** range incorporates Zamak cover frames with electroplating and finishes made of natural wood, not deformable, having undergone an anti-fungal treatment.
- Cover frames are mounted by means of rack type guides eliminating wall irregularities in vertical position:
 - when the box remains sunk in to up to 2.5 mm on the wall.
 - when the box projects by 0.75 mm from the wall.

Standards

In accordance with EN 60669-1.

Dimensions (mm)

Unica Basic, Unica Colors and Unica Quadro

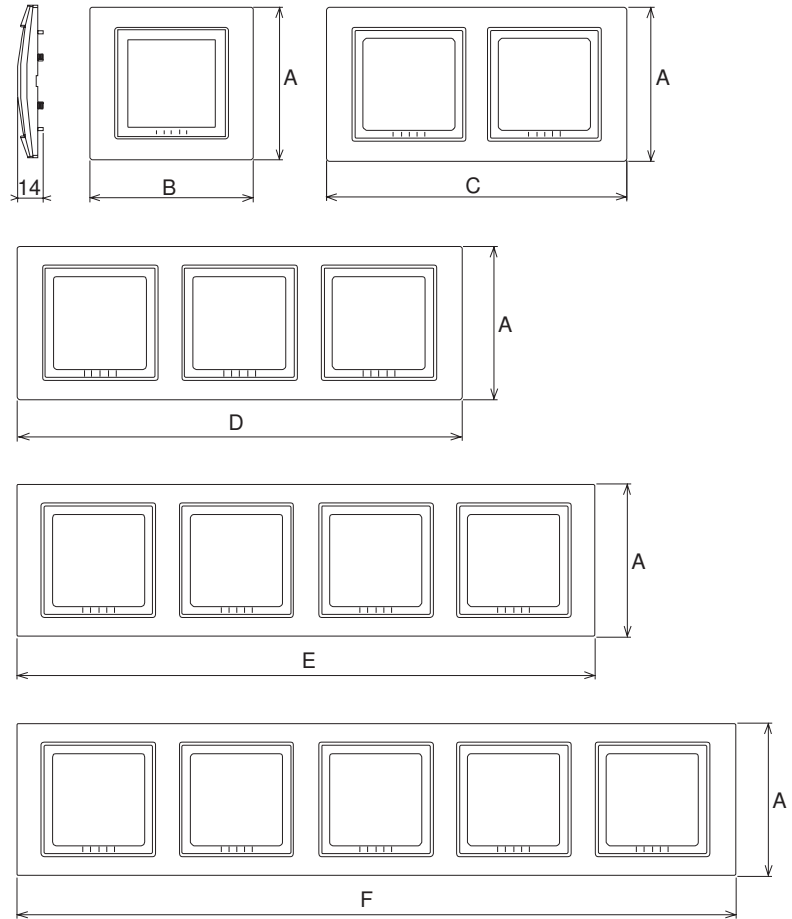

	1 gang	1 gang	2 gang	3 gang	4 gang	5 gang
	A (mm)	B (mm)	C (mm)	D (mm)	E (mm)	F (mm)
Unica Basic	80	85	156	227	298	373
Unica Colors						
Unica Quadro	87	87	158	229	300	

Unica Basic and Unica Colors, Supplementary frames

