



NHA1112806


Output Sinus Filters

VW3A5401 ... 07


Metal kit IP21

VW3A53901 ... 904


VW3A5401
VW3A5402
VW3A5403
VW3A5404
VW3A5405

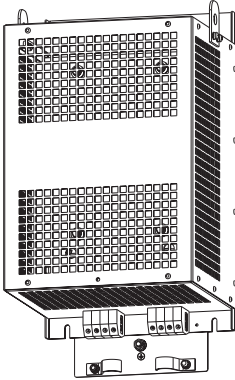

VW3A53901
VW3A53902
VW3A53903
VW3A53904

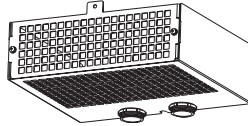

VW3A5406
VW3A5407

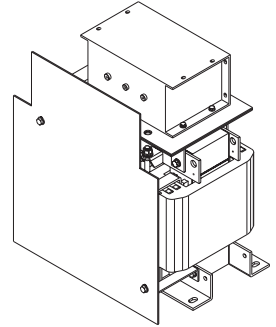

⚠ ⚠ DANGER

HAZARD OF ELECTRIC SHOCK, EXPLOSION, OR ARC FLASH

- Only appropriately trained persons who are familiar with and fully understand the contents of the present manual and all other pertinent product documentation and who have received all necessary training to recognize and avoid hazards involved are authorized to work on and with this equipment.
- Installation, adjustment, repair, and maintenance must be performed by qualified personnel.
- Verify compliance with all local and national electrical code requirements as well as all other applicable regulations with respect to grounding of all equipment.
- Before performing work and/or applying voltage on the equipment, follow the instructions given in the appropriate installation manual.

Failure to follow these instructions will result in death or serious injury.

⚠ CAUTION



SHARP EDGES

Use all necessary personal protective equipment (PPE) such as gloves when performing any type of work whatsoever on or with this product.

Failure to follow these instructions can result in injury or equipment damage.




Schneider Electric Limited
Stafford Park 5
Telford, TF3 3BL, UK

Electrical equipment should be installed, operated, serviced, and maintained only by qualified personnel. No responsibility is assumed by Schneider Electric for any consequences arising out of the use of this product.





© 2023 Schneider Electric. All Rights Reserved.

OUTPUT SINUS FILTERS		METAL KIT IP21
VW3A5401	6A	VW3A53901
VW3A5402	15A	VW3A53901
VW3A5403	25A	VW3A53902
VW3A5404	50A	VW3A53903
VW3A5405	95A	VW3A53904
VW3A5406	180A	-
VW3A5407	305A	-

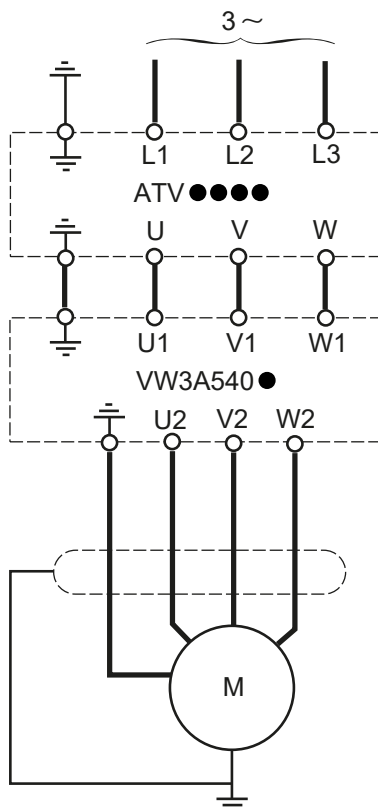


VW3A5401
 VW3A5402
 VW3A5403
 VW3A5404
 VW3A5405


VW3A5401 + VW3A53901
 VW3A5402 + VW3A53901
 VW3A5403 + VW3A53902
 VW3A5404 + VW3A53903
 VW3A5405 + VW3A53904

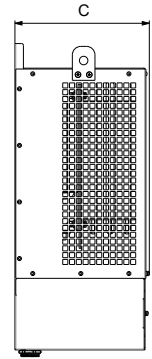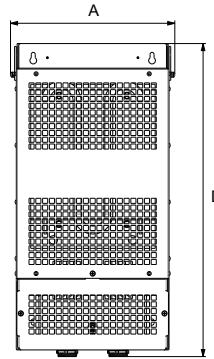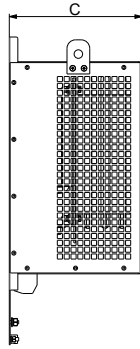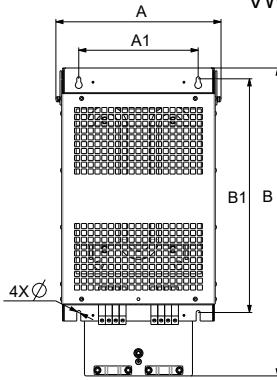

OUTPUT SINUS FILTERS	A		B		C		D		A1		B1		Ø	
	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in
VW3A5401 + VW3A53901	220	8.7	445	17.5	210	8.3	455	17.9	160	6.3	351	13.8	7	0.28
VW3A5402 + VW3A53901	220	8.7	445	17.5	210	8.3	455	17.9	160	6.3	351	13.8	7	0.28
VW3A5403 + VW3A53902	295	11.6	520	20.5	215	8.5	530	20.9	210	8.3	411	16.2	7	0.28
VW3A5404 + VW3A53903	300	11.8	545	21.5	245	9.6	560	22.0	210	8.3	411	16.2	7	0.28
VW3A5405 + VW3A53904	380	15.0	740	29.1	285	11.2	760	29.9	290	11.4	565	22.2	10	0.39



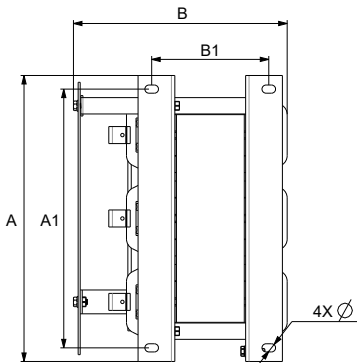


VW3A5406
 VW3A5407


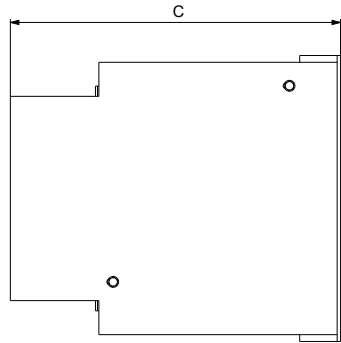


OUTPUT SINUS FILTERS	A		B		C		A1		B1		Ø	
	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in
VW3A5406	430	16.9	350	13.8	495	19.5	380	15.0	172	6.8	12	0.47
VW3A5407	460	18.1	370	14.6	565	22.2	410	16.1	204	8.0	15	0.59

 
VW3A5401, VW3A5402,
 VW3A5403, VW3A5404,
 VW3A5405

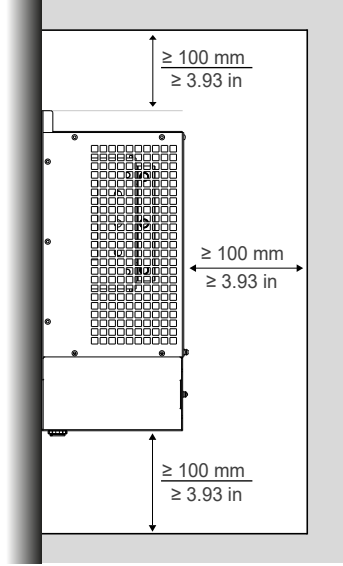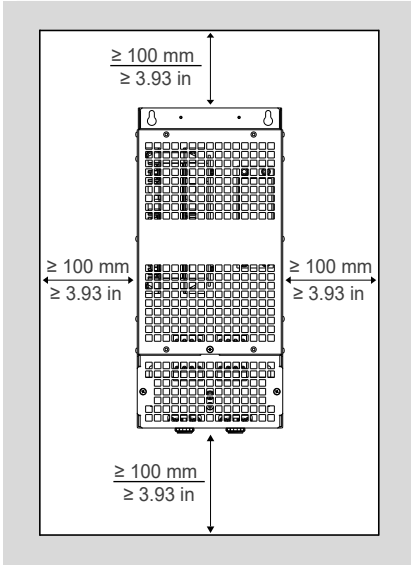


VW3A5406, VW3A5407

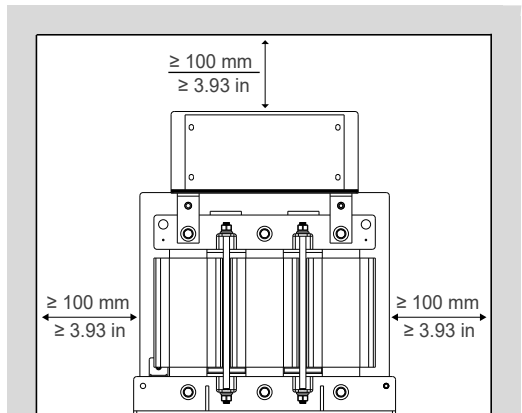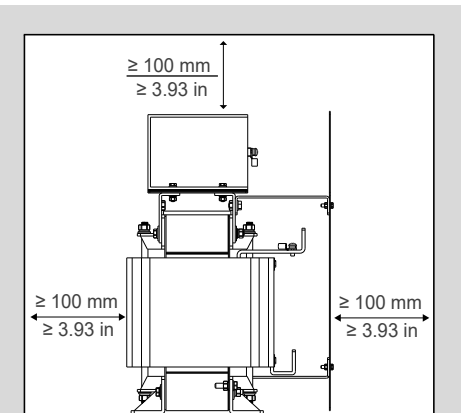


1

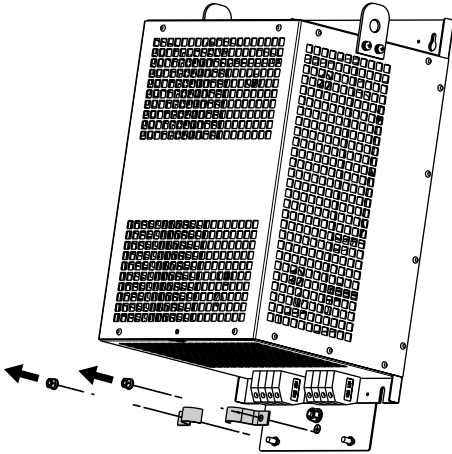


2

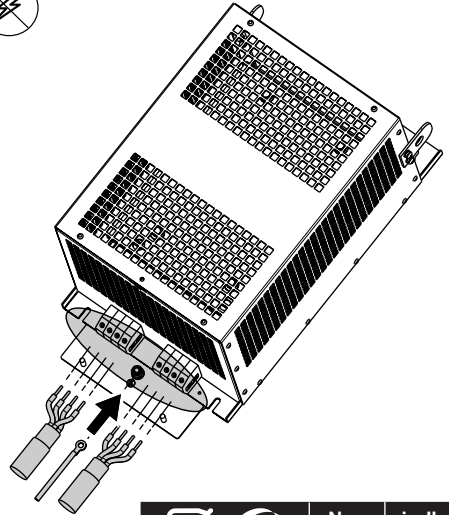


	N.m	in-lb
VW3A5401 ... 03	1.45	13
VW3A5404	2.82	25
VW3A5405	4.52	40




3

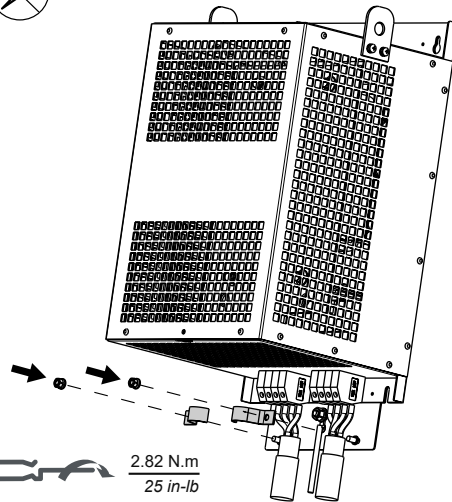


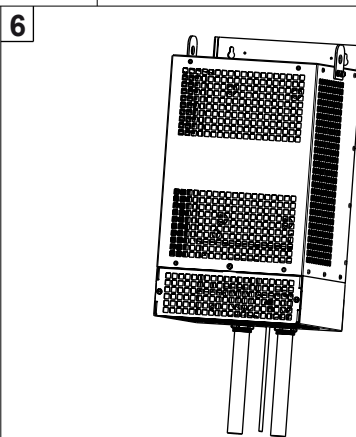
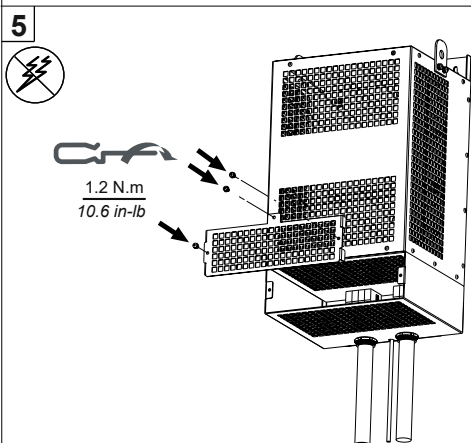
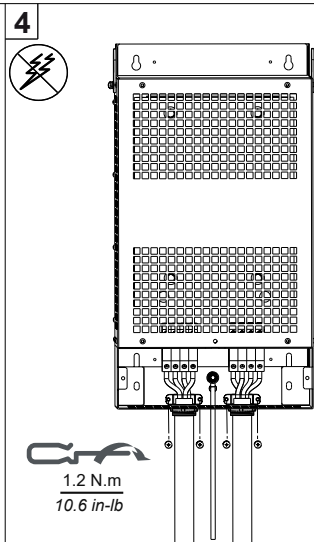
4

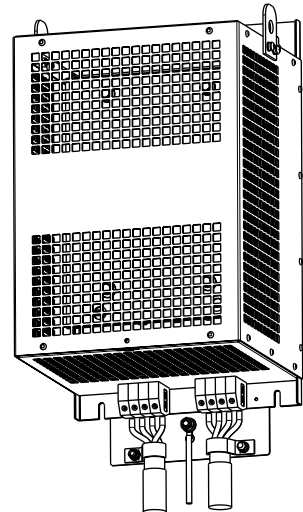


2.82 N.m
25 in-lb

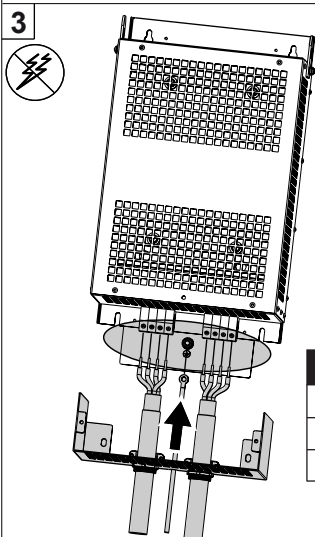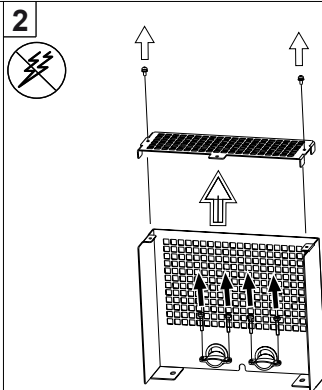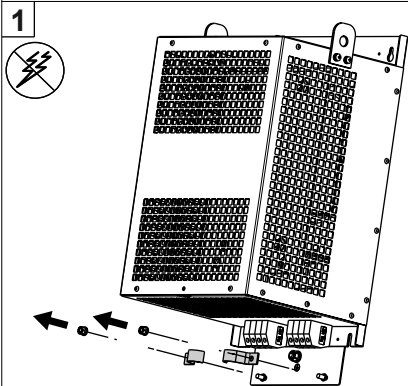


	N.m	in-lb
VW3A5401 ... 03	1.45	13
VW3A5404	2.82	25
VW3A5405	4.52	40




1

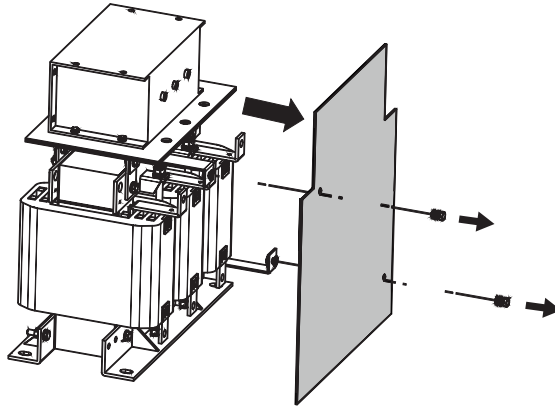

2

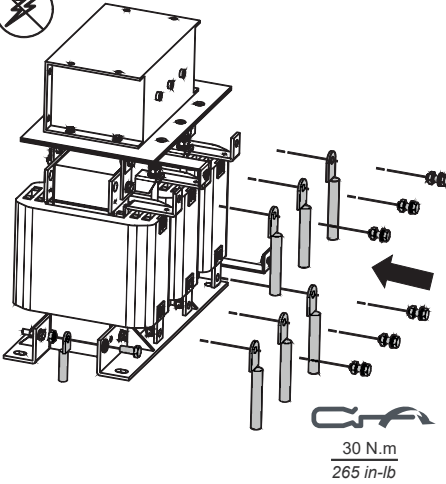

3

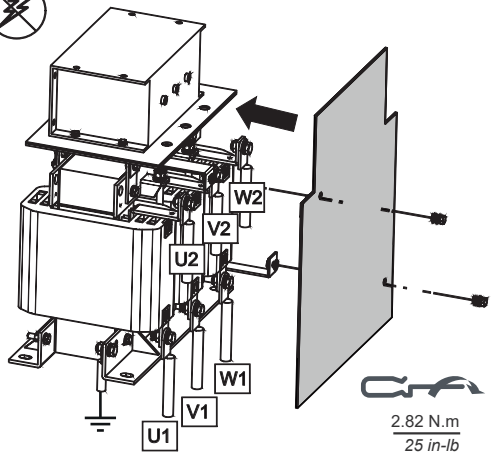

4

