

Thank you for choosing Schneider Electric AvatarOn series products. To ensure proper application of our product, please read through the following information before installation and use.

This application guide applies to the following products.

(Notes:suffix_WE/WG/GH/LW/WD/ST_C5/G2 etc. mean the colors and sales areas)

Cat. No.	Description
E8315USB	13 A 250 V SW Skt w 2.1 A USB Charger

SPECIFICATIONS

 
USB Input Voltage:	220–250 V~
USB Input Frequency:	50/60 Hz
USB Input Current:	0.45 A
USB Output Voltage:	5 V DC
USB Output Current:	2.1 A max
USB Protection:	Over heat, over current, over voltage
13 A Socket Voltage:	250 V~
13 A Socket Current:	13 A
Mounting Centre:	60.3 mm
Operating Temperature:	-5 °C to +40 °C

QGH80093339 V02

IMPORTANT NOTE


1. The products must be installed by qualified electricians.
2. Check your local wiring regulations before installation.
3. It is recommended to install the product with a 47 mm wallbox.
4. Suitable for mounting on concrete or other non-combustible surface only.
5. Protect the surround to prevent damage during product installation.
6. Turn off the power supply when you clean the product. Use a piece of soft, slightly-moistened cloth or tissue paper to wipe off the dust and dirt on the surface. Avoid using corrosive chemicals.
7. This product is permanently connected and does not contain a power isolation device or switch. If power isolation to the product is required, obtain a suitable external isolation device or switch and install in an accessible location.
8. Ensure your device's Battery Charging Specification is suitable for this USB Charger before charging.
9. Do not insert metal objects into USB Charger.
10. User will feel some heat at the product surface when charging is in progress.
11. Indoor use only.

WIRING DIAGRAMS



MOUNTING INSTRUCTION

1. Connect the wires to the terminals (it is recommended to leave 10–12 mm bare metal wire) and tighten the terminal screws.
2. Screw the grid plate onto the wall box.
3. Snap on the product cover.

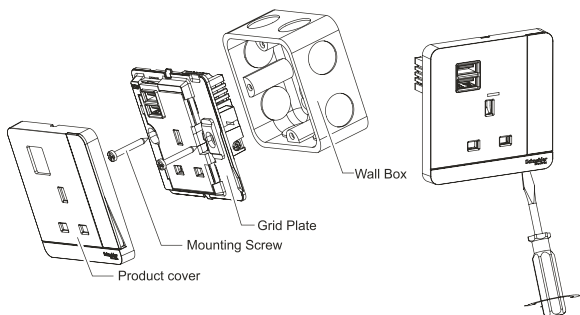

Insert a screwdriver into the clip lock, and twist the screwdriver to remove the product cover.

شكراً لاختياركم سلسلة منتجات شneider إلكتروك أفاتار أون. لغرض الاستخدام الملائم لمنتجاتنا، يُرجى قراءة المعلومات التالية قبل التركيب والاستخدام.

يطبق دليل الاستخدام هذا على المنتجات التالية:

(ملاحظة: المقاطع التالية تشير إلى الألوان ومناطق البيع: ST_C5 / G2 / WD / LW / GH / WG / WE، إلخ.)

رقم الصنف الوصف

E8315USB مقبس 13 أمبير، 250 فولت، أبيض، بشاحن USB 2,1 أمبير


المواصفات

مدخل USB، جهد:	250 – 220 فولت تقريباً
مدخل USB، تردد:	60/50 هرتز
مدخل USB، تيار:	0,45 أمبير
مخرج USB، جهد:	5 فولت تيار مباشر
مخرج USB، تيار:	2,1 أمبير، كحد أقصى
حماية USB:	الحرارة الزائدة، التيار الزائد، الجهد الزائد
مقبس 13 أمبير، جهد:	250 فولت تقريباً
مقبس 13 أمبير، تيار:	13 أمبير
مركز التركيب:	60,3 مم
درجة حرارة التشغيل:	5- درجة مئوية إلى 40 درجة مئوية تقريباً

ملاحظة مهمة


- يجب تركيب المنتجات بمعرفة فني كهرباء مؤهل.
- يُرجى مراجعة لوائح التمديدات الكهربائية المحلية قبل عملية التركيب.
- يُفترض تركيب المنتج على عمق 47 مم للصندوق الجداري.
- يتلاءم للتركيب على الخرسانات المسلحة أو الأسطح غير القابلة للاشتعال فقط.
- يُرجى مراعاة الأشياء المحيطة لتجنب أي ضرر أثناء عملية تركيب المنتج.
- قم بفصل مصدر التغذية بالطاقة عند تنظيف المنتج؛ واستخدم قطعة من القماش الناعم والمندى على نحو لطيف، أو استخدم منديل ورقي لإزالة الأتربة والقاذورات؛ كذلك قم بالتنظيف باستخدام منظف مخفف إذا لزم الأمر، ولكن تجنب استخدام أية مواد كيميائية آكلة.
- هذا المنتج متصل بشكل دائم ولا يحتوي على جهاز أو مفتاح عزل الطاقة. إذا كانت هناك حاجة لعزل الطاقة للمنتج، يجب الحصول على جهاز عزل خارجي مناسب أو التبدل وتثبيته في مكان يسهل الوصول إليه.
- يُرجى التأكد من تلاؤم مواصفة شحن بطارية الجهاز الخاص بك مع شاحن USB قبل عملية الشحن.
- لا تُدخل أية أشياء معدنية في شاحن USB.
- يشعر المستخدم بوجود بعض الحرارة بسطح المنتج أثناء عملية الشحن.
- للاستخدام داخل المباني فقط.

 مخطط التمديدات الكهربائية



إرشادات التركيب

- قم بتوصيل الأسلاك إلى الأطراف (يُنصح بترك مسافة 10-12 مم من السلك المعدني العارٍ)، ثم قم بإحكام المسامير اللولبية للأطراف.
- ثبت اللوحة الشبكية على الصندوق الجداري بواسطة المسامير اللولبية.
- انزع غطاء المنتج.

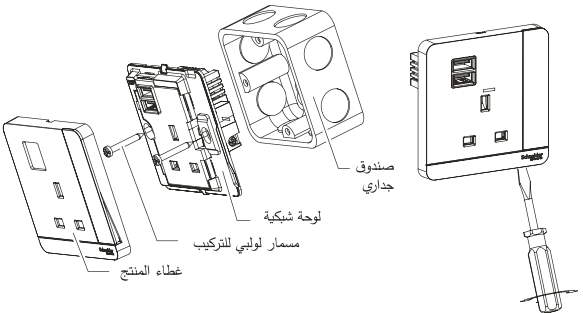

أدخل المفك في قفل المشبك، ثم أدر المفك لإزالة الغطاء.