


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**SSLZRA1**

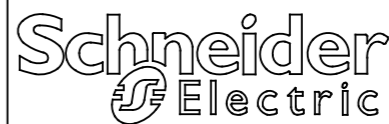

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Approvals: UL, CSA, CE, RoHS  
 Dielectric Strength: 2500 V  
 Operating Temperature [°C]: -40 to +70  
 Storage Temperature [°C]: -40 to +85  
 Weight [g/lb]: 28.5 / 0.063

Description:  
 Current Rating (AMPS): 6  
 Control (Input) Voltage: 5 - 24 VDC  
 Switching Voltage : 1-48 VDC / 24-280 VAC  
 Mounting Style : Panel  
 Compatibility:

**Specification:**

Screw Terminal Socket, 5-24VDC Input  
 6  
 5 - 24 VDC  
 1-48 VDC / 24-280 VAC  
 Panel  
 SSL1\*\*\*\*JD, SSL1\*\*\*\*JDR, SSL1\*\*\*\*BD, SSL1\*\*\*\*BDR