





# Altivar


## VW3 A5 201 ... 211

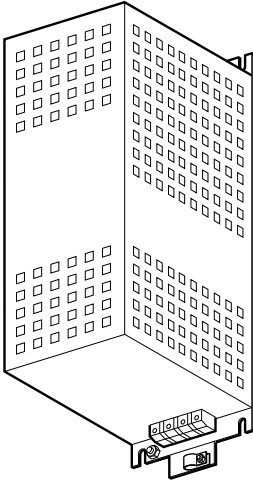


VW3 A5 201	11 A	50 W
VW3 A5 202	16 A	70 W
VW3 A5 203	33 A	120 W
VW3 A5 204	66 A	180 W
VW3 A5 205	95 A	250 W
VW3 A5 206	180 A	400 W

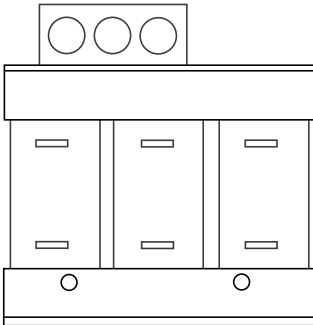


VW3 A5 207	200 A	945 W
VW3 A5 208	300 A	1360 W
VW3 A5 209	400 A	1900 W
VW3 A5 210	600 A	2370 W
VW3 A5 211	1200 A	5150 W

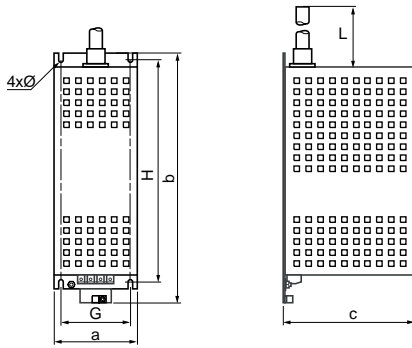


	a		b		c		G		H		Ø		L	
	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.
VW3 A5 201	120	4.72	335	13.19	160	6.30	100	3.94	280	11.02	6,6	0.26	700	27.6
VW3 A5 202	120	4.72	405	15.95	190	7.48	100	3.94	350	13.78	6,6	0.26	900	35.4
VW3 A5 203	150	5.91	470	18.50	240	9.45	120	4.72	380	14.96	6,6	0.26	900	35.4
VW3 A5 204	210	8.27	650	25.59	280	11.02	160	6.30	530	20.87	8,6	0.34	1500	59
VW3 A5 205	250	9.84	780	30.71	360	14.17	200	7.87	650	25.59	11	0.43	1600	63
VW3 A5 206	310	12.20	1060	41.73	375	14.76	220	8.66	880	34.65	11	0.43	2700	106

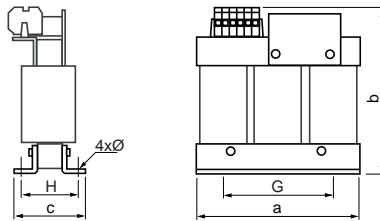


	a		b		c		G		H		Ø	
	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.
VW3 A5 207	420	16.54	500	19.69	290	11.42	370	14.57	194	7.64	11 x 15	0.43 x 0.59

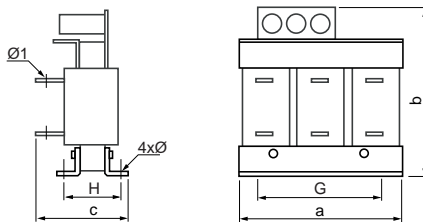

	a		b		c		G		H		Ø		Ø1	
	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.	mm	in.
VW3 A5 208	420	16.54	500	19.69	345	13.58	370	14.57	231	9.09	11 x 15	0.43 x 0.59	11	0.43
VW3 A5 209	480	18.90	600	23.62	340	13.39	430	16.93	238	9.37	13 x 18	0.51 x 0.71	11	0.43
VW3 A5 210	480	18.90	710	27.95	370	14.57	430	16.93	258	10.16	13 x 18	0.51 x 0.71	14	0.55
VW3 A5 211	620	24.41	930	36.61	500	19.69	525	20.67	352	13.86	13 x 22	0.51 x 0.87	4 x 11	4 x 0.43

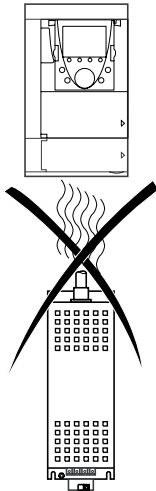

VW3 A5 201 ... 206

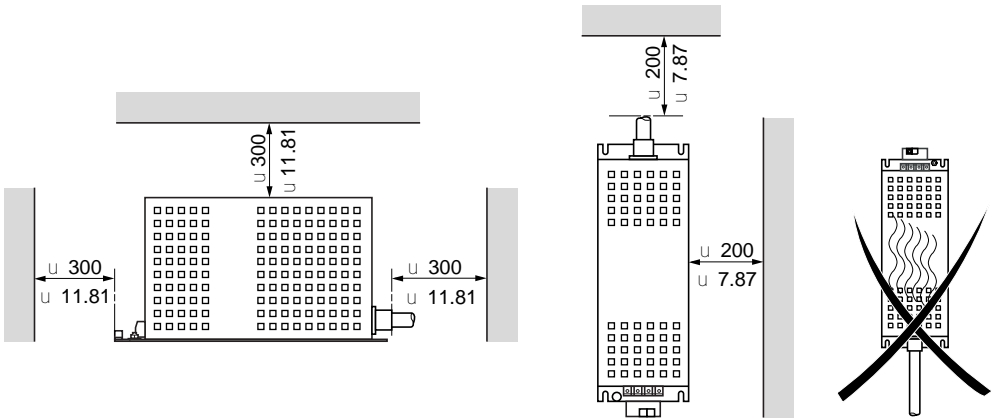

VW3 A5 207 ... 211

