


# Product data sheet

Specifications

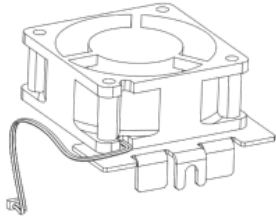

Wear part, fan for variable speed drive, Altivar Process 600 900, IP55, up to 22kW, from 380 to 480V

VX5VP50A001

## Main

Range compatibility	Altivar Process 600/900
Accessory / separate part type	Internal fan
Accessory / separate part category	Cooling accessory
Product or component type	Fan

## Complementary

Kit composition	Fan Mounting bracket Instruction sheet
-----------------	--

Product compatibility	Variable speed drive ATV650 wall mount 0.75 kW 380...480 V Variable speed drive ATV650 wall mount 1.5 kW 380...480 V Variable speed drive ATV650 wall mount 2.2 kW 380...480 V Variable speed drive ATV650 wall mount 3 kW 380...480 V Variable speed drive ATV650 wall mount 4 kW 380...480 V Variable speed drive ATV650 wall mount 5.5 kW 380...480 V Variable speed drive ATV650 wall mount 7.5 kW 380...480 V Variable speed drive ATV650 wall mount 11 kW 380...480 V Variable speed drive ATV650 wall mount 15 kW 380...480 V Variable speed drive ATV650 wall mount 18.5 kW 380...480 V Variable speed drive ATV650 wall mount 22 kW 380...480 V Variable speed drive ATV950 wall mount 0.75 kW 380...480 V Variable speed drive ATV950 wall mount 1.5 kW 380...480 V Variable speed drive ATV950 wall mount 2.2 kW 380...480 V Variable speed drive ATV950 wall mount 3 kW 380...480 V Variable speed drive ATV950 wall mount 4 kW 380...480 V Variable speed drive ATV950 wall mount 5.5 kW 380...480 V Variable speed drive ATV950 wall mount 7.5 kW 380...480 V Variable speed drive ATV950 wall mount 11 kW 380...480 V Variable speed drive ATV950 wall mount 15 kW 380...480 V Variable speed drive ATV950 wall mount 18.5 kW 380...480 V Variable speed drive ATV950 wall mount 22 kW 380...480 V
-----------------------	--

## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.1 cm
Package 1 Width	17.2 cm
Package 1 Length	23.6 cm
Package 1 Weight	265 g
Unit Type of Package 2	S03
Number of Units in Package 2	8

Package 2 Height	30 cm
Package 2 Width	30 cm
Package 2 Length	40 cm
Package 2 Weight	2.326 kg

## Offer Sustainability

REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
China RoHS Regulation	<a href="#">China RoHS declaration</a>
RoHS exemption information	Yes
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>

## Contractual warranty

Warranty	18 months
----------	-----------

## Recommended replacement(s)